



Trac-Lites™ 10W LED R600L Series

Innovative LED lighting in an economical design



The Juno® Trac-Lites R600L Series features stylish – yet economical – LED track fixtures, with simple and timeless aesthetics. Their high performance LED arrays provide outstanding reliability, performance and color quality/consistency. Approximating the light output and distribution of 50W MR16 halogen lamps, they utilize about 20% of the energy with a rated life of 50,000 hours. R600L Series fixtures are compatible with Juno Trac-Lites and Trac-Master™ Trac and system components.

Features:

- 2700K, 3000K, 3500K or 4000K white phosphor high performance LEDs
- 80 CRI minimum standard, optional high CRI versions offer 90 or 97 CRI minimum
- Integral driver to minimize overall fixture footprint
- Proprietary, interchangeable thermoplastic lenses and TIR optics available in factory-configured spot, narrow flood or flood beam spreads
- 350° horizontal coverage, 90° vertical aiming capability
- Designed for greater than 50,000 hour operating life
- Dimmable - see specification sheet for compatible dimmers
- White, black, bronze or silver finishes
- ENERGY STAR® Certified, DesignLights Consortium® Qualified and versions certified as CEC Title 24 compliant
- 5-year warranty from the date of purchase Consortium® Qualified

juno®

Juno® Trac-Lites™ 10W LED R600L Series

Ordering Information

Examples: R600L 27K 80CRI PDIM FL BZ, R600L G2 27K 97CRI PDIM NFL BL

Series	Generation	Color Temperature	Color Rendering Index	Dimming	Beam Spread	Finish
R600L 10W LED	Blank Gen 1 (80 or 90 CRI only) G2 (97 CRI only)	27K 2700K 30K 3000K 35K 3500K 40K 4000K	80CRI 80 CRI Minimum 90CRI* 90 CRI Minimum 97CRI* 97 CRI Minimum (Available in 27K, 30K and 40K only)	PDIM Phase Dimmable	SP Spot NFL Narrow Flood FL Flood UNF Universal Beam (Includes narrow flood and flood lenses)	BL Black BZ Bronze SL Silver WH White

* Certified as CEC Title 24 compliant


Accessories

Cat. No.	Description
TLENS4 NFLD	Lens - Narrow Flood
TLENS4 FLD	Lens - Flood
TIR4 SPT BLCK	TIR Optic - Spot, Black
TIR4 SPT WHT	TIR Optic - Spot, White

Finishes



Dimensions

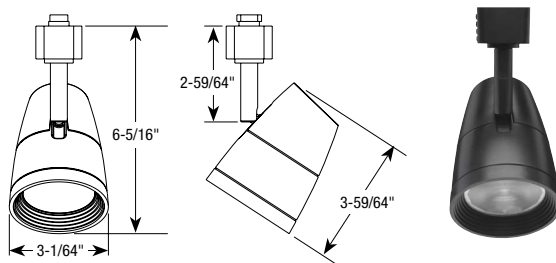

Juno Trac-Lites R600L LED Track Kits

These all-inclusive track kits are the perfect solution for small installations that need just a few track fixtures and a small section of track, or for installations that have many short track sections, each with just a few fixtures. Each kit includes three universal beam R600L LED track fixtures, one 4' Trac-Lites track section, one floating electrical feed and mounting hardware. Kits are available in all R600L CCTs, CRIs and finishes to suit any retail, commercial or residential application.



Ordering Information

Example: R4K3600L 27K 90CRI PDIM UNF BZ

Series	Color Temperature	Color Rendering Index	Dimming	Beam Spread	Finish
R4K3600L R600L Trac Kit (3) 10W LED Heads and (1) 4' Track	27K 2700K 30K 3000K 35K 3500K 40K 4000K	80CRI 80 CRI Minimum 90CRI* 90 CRI Minimum 97CRI* 97 CRI Minimum (Available in 27K, 30K and 40K only)	PDIM Phase Dimmable	UNF Universal Beam (includes narrow flood & flood lenses)	BL Black BZ Bronze SL Silver WH White

* Certified as CEC Title 24 compliant



©2017 Acuity Brands Lighting, Inc. The marks appearing in this catalog are trademarks of Acuity Brands Lighting, Inc. Products shown in this brochure may be covered by U.S. and international patents and patents pending. Specifications subject to change without notice. Printed in the U.S.A.