 
 



General Construction Finishes

		CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302	STAIN- LESS TYPE 430	BROWN WRINKLE	IVORY WRINKLE
	9 Blanks (Box Mntg. 3.281") (9B)	83159	86159	93159	97159	98159	99159
	10 Blanks (Box Mntg. 3.281") (10B)	83160	86160	93160	97160	98160	99160
	Block Duplex/GFI Recept. (SRM)	83401	86401	93401	97401	98401	99401
	2 Block Duplex/GFI Recepts. (2SRM)	83402	86402	93402	97402	98402	99402
	3 Block Duplex/GFI Recepts. (3SRM)	83403	86403	93403	97403	98403	99403
	4 Block Duplex/GFI Recepts. (4SRM)	83404	86404	93404	97404	98404	99404
	5 Block Duplex/GFI Recepts. (5SRM)	83405	86405	93405	97405	98405	99405
	6 Block Duplex/GFI Recepts. (6SRM)	83406	86406	93406	97406	98406	99406
	7 Block Duplex/GFI Recepts. (7SRM)	83407	86407	93407	97407	98407	99407
	8 Block Duplex/GFI Recepts. (8SRM)	83408	86408	93408	97408	98408	99408
	9 Block Duplex/GFI Recepts. (9SRM)	83409	86409	93409	97409	98409	99409
	10 Block Duplex/GFI Recepts. (10SRM)	83410	86410	93410	97410	98410	99410
	One 5/8" ID Phone (Box Mntg. 3.281") (01)*	83201	86201	93201	97201	98201	99201
	Two 5/8" ID Phones (Box Mntg. 3.281") (02)*	83202	86202	93202	97202	98202	99202
	One 5/8" ID Phone with Metal Bushing (Box Mntg. 3.281") (61)*	83591	86591	93591	97591	98591	99591
	One Phone .5" with .375 ID Grommet and Mounting Strap (Device Mntg. 2.375")*	83181	86181	93181	97181	98181	99181
	One Phone 1.405" with 1" ID Plastic Bushing (Box Mntg. 3.281") (71)*	83581	86581	93581	97581	98581	99581

Material Specifications

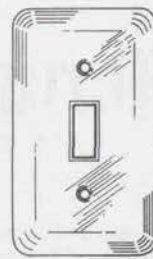

S = Standard Shape

P = Princess Shape



Listed 883C unless marked with asterisk(*).
Meets Federal Specification WP455A. All
plates supplied with matching screws.

Steel


(Preplated to Underwriters
Laboratories, Inc. specifications)

	Finish	Shape	Thickness	U.S. Bureau Standards Symbols	Finish Designator	Cat. Page #
Almond (ALM)	Smooth, Semi-Gloss	S	.030	—	44000	A14-20
Aluminum Paint (CDA)	Semi-Gloss	S	.030	—	88000	A21-27
Black Paint (BL)	Matte	S	.030	—	87000	A21-27
Brass Paint (BA)	Matte	S	.030	—	81000	A14-20
Brass Paint (BA-PRL)	Matte	P	.030	—	71000	A48-53
Brown Paint (BK)	Smooth, Semi-Gloss	S	.030	—	82000	A14-20
Brown Paint (DB)	Hard Baked, Wrinkle	S	.030	—	98000	A7-13
Brown Paint (DB-PRL)	Hard Baked, Wrinkle	P	.030	—	78000	A48-53
Chrome Plate (CA)	Mirror Polish	S	.030	—	83000	A7-13
Chrome Plate (CA-PRL)	Mirror Polish	P	.030	—	73000	A48-53
Gray	Smooth, Semi-Gloss	S	.030	—	58000	A21-27
Ivory (IA)	Smooth, Semi-Gloss	S	.030	—	84000	A14-20
Ivory (IA-PRL)	Smooth, Semi-Gloss	P	.030	—	74000	A48-53
Ivory (DI)	Hard Baked, Wrinkle	S	.030	—	99000	A7-13
Ivory (DI-PRL)	Hard Baked, Wrinkle	P	.030	—	79000	A48-53
Red (RA)	Smooth, Semi-Gloss	S	.030	—	51000	A21-27
White (WA)	Smooth, Semi-Gloss	S	.030	—	86000	A7-13
White (WA-PRL)	Smooth, Semi-Gloss	P	.030	—	76000	A48-53
White (DW)	Hard Baked, Wrinkle	S	.030	—	85000	A14-20
White (DW-PRL)	Hard Baked, Wrinkle	P	.030	—	75000	A48-53
Zinc Coat (AUNF)	Smooth, Dull	S	.030	—	89000	A21-27
Zinc Coat (AUNF-PRL)	Smooth, Dull	P	.030	—	80000	A42-47


General Construction Finishes

For color photos of finishes see
inside front cover.

STANDARD SHAPE

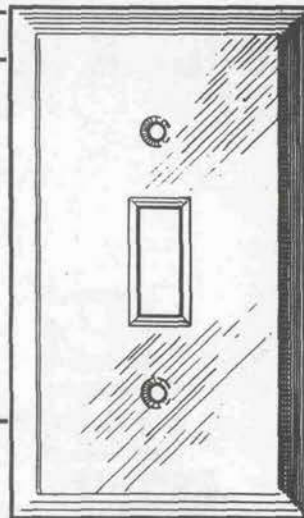


 See page A84 for ordering
Custom Plates not found in
this listing.


	CHROME PLATED	WHITE SEMI- GLOSS	STAIN- LESS TYPE 302 (.035") Spec. Grade Satin Finish (302SS)	STAIN- LESS TYPE 430 (.030") Satin Finish (SS)	BROWN WRINKLE	IVORY WRINKLE
 1 Toggle Switch (1T)	Polished Steel (CA) 83071	Painted Steel (WA) 86071	83071	86071	93071	97071
 2 Toggle Switches (2T)	83072	86072	93072	97072	98072	99072
 3 Toggle Switches (3T)	83073	86073	93073	97073	98073	99073
 4 Toggle Switches (4T)	83074	86074	93074	97074	98074	99074
 5 Toggle Switches (5T)	83075	86075	93075	97075	98075	99075
 6 Toggle Switches (6T)	83076	86076	93076	97076	98076	99076
 7 Toggle Switches (7T)	83077	86077	93077	97077	98077	99077
 8 Toggle Switches (8T)	83078	86078	93078	97078	98078	99078
 9 Toggle Switches (9T)	83079	86079	93079	97079	98079	99079
 10 Toggle Switches (10T)	83080	86080	93080	97080	98080	99080
 1 Duplex Receptacle (10DR)	83101	86101	93101	97101	98101	99101
 2 Duplex Receptacles (20DR)	83102	86102	93102	97102	98102	99102

WALL PLATE COLOR GUIDE

STANDARD SHAPE

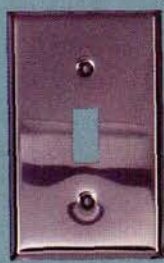


A

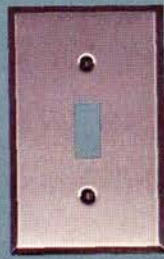

B



C

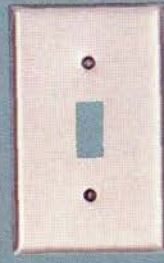

D



E




F




G




H

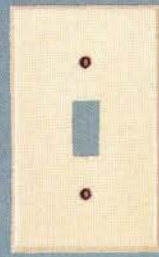

I

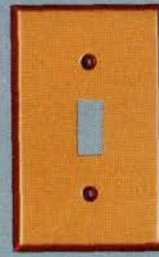


J

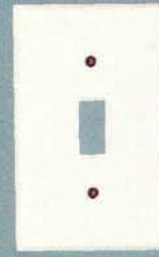

K




L

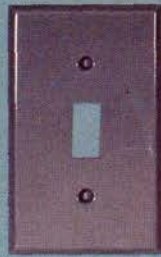

M



N

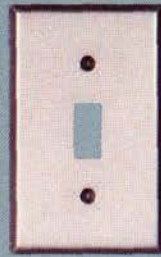

O



P



Q



R



S



T



U

A. Polished Chrome (83000)
B. Stainless Steel (97000,
93000, 70000)
C. Polished Stainless
(68000)
D. Clear Anodized Aluminum
(95000)
E. Satin Aluminum (62000)
F. Ivory Wrinkle (99000)

G. Brown Wrinkle (98000)
H. White Wrinkle (85000)
I. Ivory Semi-Gloss (84000)
J. Sprayed Brass Matte
(81000)
K. White Semi-Gloss (86000)
L. Brown Semi-Gloss
(82000)
M. Gray Semi-Gloss (58000)

N. Red Semi-Gloss (51000)
O. Aluminum Painted
Steel/Cadilite (88000)
P. Black Matte (87000)
Q. Satin Brass (94000,
96000)
R. Bank Bronze (65000)
S. Satin Bronze (66000)
T. Statuary Bronze (69000)
U. Polished Brass (64000)