

LED TASK STAR PRO

COLOR CHANGEABLE


LTSPRO is constructed with aluminum housing and a matte white polycarbonate diffuser. It has a hi-low rocker switch and a slide selector switch for changing Kelvin color temperature. This sleek fixture features edge lit technology which means no hot spots on the polished marble or granite counter top. The 1 inch low profile design means the fixture remains hidden.

The quality of light is the best in the industry with a 90 color rendering index (CRI) and up to 60 lumens per watt. Rated to 50,000 hours and dimmable with most ELV dimmers, LTSPRO is the most versatile task light on the market today. Ships complete with captive mounting screws, cord and plug, end to end connector and romex connector for hardwire.

Features

- ✓ Adjustable to 3 color temperatures: 2700K, 3300K and 4000K (warm white to cool white)
- ✓ Dimmable with most ELV dimmers
- ✓ Comes with High / Low Switch
- ✓ Low power consumption
- ✓ Edge Lit technology eliminates hot spots – smooth luminance
- ✓ Fast and easy installation – quick connects, captive mounting screws
- ✓ Comes with cord and plug as well as knockouts for hardwire
- ✓ 3/8" connector provided
- ✓ Shallow profile conceals fixture
- ✓ Linkable up to 400 watts
- ✓ 90 CRI – the best in the business!
- ✓ Available in 6 sizes – 9", 12", 18", 24", 32" and 40"
- ✓ 3 year limited warranty
- ✓ cETLus and Energy Star listed

NSL
NATIONAL SPECIALTY LIGHTING
www.nslusa.com

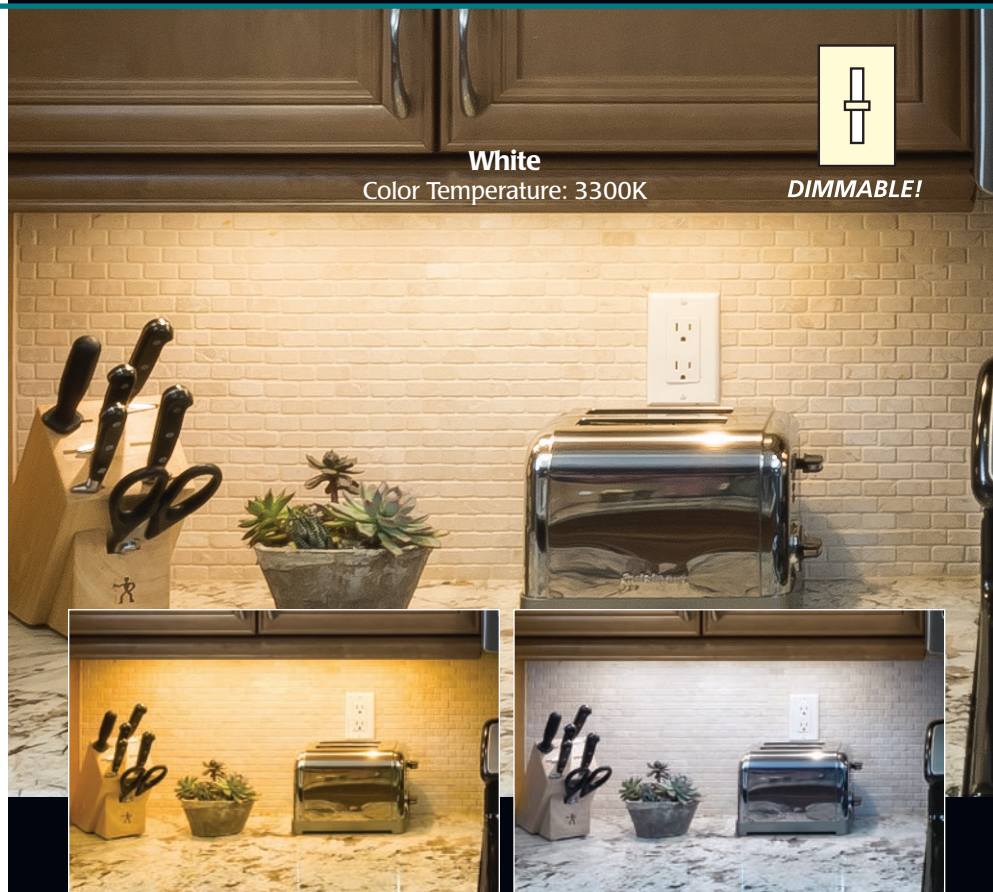

Warm White
Color Temperature: 2700K

Cool White
Color Temperature: 4000K



Applications

- ✓ Under cabinet task light
- ✓ Over cabinet accent light
- ✓ Display cases and exhibits
- ✓ Merchandising
- ✓ Indirect accent light
- ✓ Wall units and bars
- ✓ Office work stations



Uniform lighting with Edge Lit technology



DIMMABLE!

Construction

Housing is made from extruded aluminum. End caps are molded from high impact PC plastic.

Finish

White, Black, Bronze, and Satin Nickel finish.

Diffuser

Matte white polycarbonate diffuser.

Electrical

This unit is wired for 120V operation. High/low switch included.

Lamping


LED's are 2700K, 3300K, 4000K non-replaceable. Rated for 50,000 hrs. 90+ CRI.

Certification

Fixtures are cETLus listed for dry locations.

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 3 years from date of purchase.

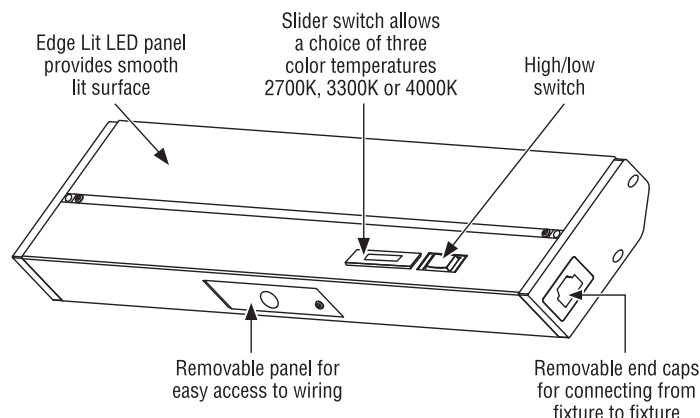

Includes

- | | |
|------------------------------------|---------------------|
| (1) Under cabinet lighting fixture | (1) Romex connector |
| (1) 6' cord and plug | (2) Wood screws |
| (1) End-to-end connector | (1) 8" jumper cable |

Specifications

	LTSPRO-9-YY*	LTSPRO-12-YY*	LTSPRO-18-YY*	LTSPRO-24-YY*	LTSPRO-32-YY*	LTSPRO-40-YY*
Input Power	120V					
Power Factor	0.95					
LEDs	Epistar					
LED Life	50,000 hours					
Color Temperature CCT	2700K – 4000K					
Lumens	150–200	250–300	380–450	650–700	850–900	950–1000
Color Rendering Index	90+					
Dimmable	Yes					
Construction	Extruded aluminum housing / High impact PC plastic end caps / Matte white polycarbonate diffuser					
Appearance Size (L x W x H)	9" x 3.5" x 1" 22.9 x 8.9 x 2.5cm	12" x 3.5" x 1" 30.5 x 8.9 x 2.5cm	18" x 3.5" x 1" 45.7 x 8.9 x 2.5cm	24" x 3.5" x 1" 61.0 x 8.9 x 2.5cm	32" x 3.5" x 1" 81.3 x 8.9 x 2.5cm	40" x 3.5" x 1" 101.6 x 8.9 x 2.5cm

* Trim Finish: BK = Black, BZ = Bronze, SN = Satin Nickel, WH = White

4 Finishes available

LED Task Star Pro comes in four colors: Black, Bronze, Satin Nickel & White



LTSPRO-JB

Hardwire junction box for LTSPRO fixtures - allows for direct wiring installation, eliminating the visible household wire.



Accessories (Ordered Separately)

LTSPRO-J-12*	12" jumper cable
LTSPRO-J-18*	18" jumper cable
LTSPRO-J-24*	24" jumper cable
LTSPRO-J-32*	32" jumper cable
LTSPRO-PC-72*	72" replacement power cord and plug
RC-01	3/8" Romex connector

* NOTE: add (-BK) at the end of part number for black cable.



Specifications and dimensions subject to change without notice.

www.nslusa.com

NSL LIGHTING
NATIONAL SPECIALTY LIGHTING