



GE's LED fixture portfolio that ships in 2 or 5 days



QUICKSHIP Portfolio

Indoor


LTL Series

2x2, 2x4



BT/BR/BV/ET Series

2x2, 2x4, and EMBB
Surface mount kits (BT, BR, BV,
AB, AC, AD)

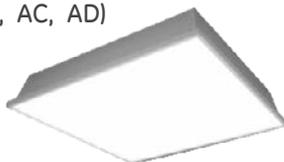

LVT Series

2x2, 2x4



Refit Door Kit

2x2, 2x4



RX Series

6" & 8" - 1000, 1500, 2000 lm



DI Series

4" and 6" Round Housing
Infusion™ Light Modules
Reflectors



WS Series

4' Wrap Fixture
Narrow and Wide Body



FM Series

Flush Mount Fixture



RFR/SFF Series

Surface Mount Downlight



LTC Series

600 Lumen Track Light



QUICKSHIP Portfolio

Architectural

LLW Series
Wall Washer



Outdoor

Evolve™ LED – E2SA
Security Light



Evolve™ LED – EANA
Area Site Light



Evolve™ LED – EFNA
Flood Light



Evolve™ LED – EG2R
Garage Light



Evolve™ LED – EWS2
Area Light
Scalable Wall pack



QUICKSHIP Portfolio

Industrial

Albeo™ LED – ABR1

High Bay Luminaire



Albeo™ LED – ABV2

High Bay Luminaire



Albeo™ LED – ALR1

4' and 8' Linear Fixture



Albeo™ LED – ALV1

4' and 8' Linear Fixture



Indoor Fixtures

Lumination™ LTL Series LED Luminaires



- Ideal for general indoor lighting in office, commercial, retail and education applications
- Fits perfectly into T-grid drop ceilings for easy high-tech retrofits
- Provides high uniformity across the lens
- Available in 2x2 and 2x4 models
- CCT: 3500K, 4000K, 5000K
- Typical CRI of 83+
- 2x2: 30-38W at 3300-4000 lumens
- 2x4: 36-47W at 4000-4800 lumens
- L70 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Lumination™ LTL Series LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|-----------------------|--|----------|------------|----------|------------|
| 93038953 | LTL22A020MM835VQLTWHT | 2X2, 120-277V, 2000 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93038954 | LTL22A020MM840VQLTWHT | 2X2, 120-277V, 2000 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93038955 | LTL24A030MM835VQLTWHT | 2X2, 120-277V, 3000 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93038956 | LTL24A030MM840VQLTWHT | 2X2, 120-277V, 3000 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93038732 | LTL22A033MM835VQLTWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 2 days | 81-200 | 2 weeks |
| 93037164 | LTL22A033MM840VQLTWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 2 days | 41-200 | 2 weeks |
| 93039408 | LTL22A033MM835VQLTWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-20 | 2 days | 21-80 | 2 weeks |
| 93039409 | LTL22A033MM840VQLTWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-20 | 2 days | 21-80 | 2 weeks |
| 93039410 | LTL24A048MM835VQLTWHT | 2X4, 120-277V, 4800 lumen, 80 CRI, 3500K, 0-10V | 1-80 | 2 days | 81-200 | 2 weeks |
| 93035531 | LTL24A048MM840VQLTWHT | 2X4, 120-277V, 4800 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 2 days | 41-200 | 2 weeks |
| 93039411 | LTL24A048MM835VQLTWHT | 2X4, 120-277V, 4800 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-20 | 2 days | 21-80 | 2 weeks |
| 93039348 | LTL24A048MM840VQLTWHT | 2X4, 120-277V, 4800 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-20 | 2 days | 21-80 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ BT Series LED Luminaires



- Ideal for general indoor lighting in office, commercial, retail and education applications
- Fits perfectly into T-grid drop ceilings for easy high-tech retrofits
- Provides high uniformity across the lens
- Converts to surface mount with surface mount kit
- Available in 1x4, 2x2, and 2x4 models
- CCT: 3500K, 4000K
- Typical CRI of 80+
- 1x4: 42W at 4000-4200 lumens
- 2x2: 34W at 3300-3500 lumens
- 2x4: 43W at 4500-4700 lumens
- L70 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Lumination™ BT Series LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|--|----------|------------|----------|------------|
| 26822 | BT220D2AVWHT | 2X2, 120-277V, 2000 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 26821 | BT220D3AVWHT | 2X2, 120-277V, 2000 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 26798 | BT220A2AVWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 2 days | 41-200 | 2 weeks |
| 26842 | BT220A2AVWHT | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-10 | 2 days | 11-50 | 2 weeks |
| 26790 | BT220A3AVWHT | 2X2, 120-277V, 3500 lumen, 80 CRI, 4000K, 0-10V | 1-80 | 2 days | 81-200 | 2 weeks |
| 26835 | BT220A3AVWHT | 2X2, 120-277V, 3500 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-10 | 2 days | 11-50 | 2 weeks |
| 26973 | BT240D2AVWHT | 2X4, 120-277V, 3000 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 26941 | BT240D3AVWHT | 2X4, 120-277V, 3000 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 26844 | BT240A2AVWHT | 2X4, 120-277V, 4500 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 2 days | 41-200 | 2 weeks |
| 26870 | BT240A2AVWHT | 2X4, 120-277V, 4500 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-10 | 2 days | 11-50 | 2 weeks |
| 26843 | BT240A3AVWHT | 2X4, 120-277V, 4700 lumen, 80 CRI, 4000K, 0-10V | 1-80 | 2 days | 81-200 | 2 weeks |
| 26845 | BT240A3AVWHT | 2X4, 120-277V, 4700 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-10 | 2 days | 11-50 | 2 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ BR Series LED Luminaires



- Ideal for general indoor lighting in office, commercial, retail and education applications
- Easy and quick install into T-bar ceiling grids
- Perfect for new construction, remodel or retrofit projects
- Drop down door with accessible components
- Converts to surface mount with surface mount kit
- Available in 1x4, 2x2 or 2x4 models
- CCT: 3500K, 4000K
- Typical CRI of 80+
- 1x4: 42W at 3800-4000 lumens
- 2x2: 37W at 3325-3500 lumens
- 2x4: 49W at 4750-5000 lumens
- L70 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Lumination™ BR Series LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|---|----------|------------|----------|------------|
| 94993 | BR220A3AVWHT | 2X2, 120-277V, 3500 lumen, 80 CRI, 4000K, 0-10V | 1-80 | 1 week | 81-200 | 2 weeks |
| 94994 | BR220A2AVWHT | 2X2, 120-277V, 3325 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 95051 | BR240A3AVWHT | 2X4, 120-277V, 5000 lumen, 80 CRI, 4000K, 0-10V | 1-80 | 1 week | 81-200 | 2 weeks |
| 95053 | BR240A2AVWHT | 2X4, 120-277V, 4750 lumen, 80 CRI, 3500K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ BV Architectural Series LED Luminaires



- Provides visual appeal ideal for office, retail, or any space that requires a three dimensional look
- Curving and delineated details add creative appeal
- High uniformity across the lens
- Converts to surface mount with surface mount kit
- Access to components from beneath the ceiling
- Available in 2x2 and 2x4 models
- CCT: 3500K, 4000K
- Typical CRI of 80+
- 2x2: 33W at 3200-3250 lumens
- 2x4: 48W at 5100-5200 lumens
- L85 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Lumination™ BV Architectural Series LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|---|----------|------------|----------|------------|
| 27075 | BV220A3AVWHT | 2X2, 120-277V, 3250 lumen, 80 CRI, 4000K, 0-10V | 1-20 | 1 week | 21-80 | 2 weeks |
| 27084 | BV220A2AVWHT | 2X2, 120-277V, 3200 lumen, 80 CRI, 3500K, 0-10V | 1-20 | 1 week | 21-80 | 2 weeks |
| 27482 | BV240A3AVWHT | 2X4, 120-277V, 5200 lumen, 80 CRI, 4000K, 0-10V | 1-20 | 1 week | 21-80 | 2 weeks |
| 64096 | BV240A2AVWHT | 2X4, 120-277V, 5100 lumen, 80 CRI, 3500K, 0-10V | 1-20 | 1 week | 21-80 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ ET Series LED Luminaires



- Advanced edge lit LED optical system provides high uniformity, excellent efficiency, improved spacing criteria, and reduced glare
- Easily installs in the most commonly used T-bar ceiling grids
- Diffused lens gives an evenly illuminated appearance
- May come equipped with Intrinsic™ technology which provides uniform light distribution
- Available in 1x4, 2x2, and 2x4 models
- CCT: 3000K, 3500K, 4000K
- Typical CRI of 80+
- 1x4: 38W at 3800-4000 lumens
- 2x2: 42W at 3500-3900 lumens
- 2x4: 47-54W at 3800-4500 lumens
- L85 @ 50,000 hours
- 0-10V dimming, DALI

The descriptions above represent the entire portfolio of Lumination™ ET Series LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|---|----------|------------|----------|------------|
| 69278 | ET220A3AVWHT | 2X2, 120-277V, 3900 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 69277 | ET220A2AVWHT | 2X2, 120-277V, 3700 lumen, 80 CRI, 3500K, 0-10V | 1-20 | 1 week | 21-200 | 2 weeks |
| 67603 | ET240A3AVWHT | 2X4, 120-277V, 4000 lumen, 80 CRI, 4000K, 0-10V | 1-20 | 2 weeks | 21-80 | 4 weeks |
| 67602 | ET240A2AVWHT | 2X4, 120-277V, 3800 lumen, 80 CRI, 3500K, 0-10V | 1-20 | 2 weeks | 21-80 | 4 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ LVT Series LED Luminaires



- Ideal for general indoor lighting in office, commercial, retail and education applications
- Fits perfectly into T-grid drop ceilings for easy high-tech retrofits
- Provides high uniformity across the lens
- Available in 1x4, 2x2, and 2x4 models
- CCT: 3500K, 4000K, 5000K
- Typical CRI of 80+
- 2x2: 19-47.5W at 2000-5000 lumens
- 2x4: 28-69.5W at 3000-7200 lumens
- L70 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Lumination™ LVT Series LED Luminaires. For more in-depth information, please visit gelighting.com.




Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|---------------------------|--|----------|------------|----------|------------|
| 93041491 | LVT22A033MM835VQLTWHTTE | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V | 1-80 | 1 week | 81-200 | 2 weeks |
| 93041945 | LVT22A033MM840VQLTWHTTE | 2X2, 120-277V, 3300 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93043419 | LVT22A033MM835VQLTWHTTEEL | 2X2, 120-277V, 3300 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-20 | 1 week | 21-80 | 2 weeks |
| 93049018 | LVT22A033MM840VQLTWHTTEEL | 2X2, 120-277V, 3300 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-20 | 1 week | 21-80 | 2 weeks |
| 93046039 | LVT24A048MM835VQLTWHTTE | 2X4, 120-277V, 4800 lumen, 80 CRI, 3500K, 0-10V | 1-80 | 1 week | 81-200 | 2 weeks |
| 93044222 | LVT24A048MM840VQLTWHTTE | 2X4, 120-277V, 4800 lumen, 80 CRI, 4000K, 0-10V | 1-40 | 1 week | 41-200 | 2 weeks |
| 93050625 | LVT24A048MM835VQLTWHTTEEL | 2X4, 120-277V, 4800 lumen, 80 CRI, 3500K, 0-10V, Emergency Light | 1-20 | 1 week | 21-80 | 2 weeks |
| 93050746 | LVT24A048MM840VQLTWHTTEEL | 2X4, 120-277V, 4800 lumen, 80 CRI, 4000K, 0-10V, Emergency Light | 1-20 | 1 week | 21-80 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ LED Surface Mount Kit

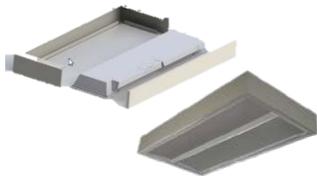

- Converts recessed fixture to surface mount
- Universal installation for any of the recessed series that offers simple installation without ordering different luminaires
- Provides high uniformity across the lens
- Includes capability for fixture with emergency battery
- White finish
- Available in 1x4, 2x2, and 2x4 models
- 1x4: BT or BR, BV, AB, AC kits
- 2x2: BT or BR, BV, AB, AC kits
- 2x4: BT or BR, BV, AB, AC kits

The descriptions above represent the entire portfolio of Lumination™ LED Surface Mount Kits. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|--------|-----------|--|----------|------------|----------|------------|
| 212462 | B22 SMK | 2X2 Surface Mount Kit for BT, LTL, LVT | 1-20 | 2 days | 21-80 | 2 weeks |
| 212463 | B24 SMK | 2X4 Surface Mount Kit for BT, LTL, LVT | 1-20 | 2 days | 21-80 | 2 weeks |
| 212459 | A22 SMK | 2X2 Surface Mount Kit for BR, BV, LBV, AC, LAC, AD, LAD, AB, LAB | 1-20 | 2 days | 21-80 | 2 weeks |
| 212460 | A24 SMK | 2X4 Surface Mount Kit for BR, BV, LBV, AC, LAC, AD, LAD, AB, LAB | 1-20 | 2 days | 21-80 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ LED Refit Door Kit



- LED upgrade for Linear Fluorescent Fixtures
- Simple and fast installation
- Reduced glare
- Provides high uniformity, great efficiency and reduced glare
- Available in 2x2 and 2x4 models (1x4 custom)
- CCT: 3500K, 4000K
- Typical CRI of 80+
- 2x2: 21W at 1950-2000 lumens
- 2x4: 36W at 3900-4100 lumens
- L70 @ 50,000 hours
- 0-10V Dimming

The descriptions above represent the entire portfolio of Lumination™ LED Refit Door Kits. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|--------|----------------------|---|----------|------------|----------|------------|
| 208160 | LED20/DK22/835/10/SO | 2X2, 120-277V, 1950 lumen, 83 CRI, 3500K, 0-10V | 1-20 | 2 days | 21-80 | 2 weeks |
| 208161 | LED20/DK22/840/10/SO | 2X2, 120-277V, 2000 lumen, 82 CRI, 4000K, 0-10V | 1-40 | 2 days | 41-80 | 2 weeks |
| 208162 | LED35/DK24/835/10/SO | 2x4, 120-277V, 3900 lumen, 83 CRI, 3500K, 0-10V | 1-20 | 2 days | 21-80 | 2 weeks |
| 208163 | LED35/DK24/840/10/SO | 2x4, 120-277V, 4100 lumen, 82 CRI, 4000K, 0-10V | 1-80 | 2 days | 81-200 | 2 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ RX Series LED Downlights



- Ideal for office, retail, hospitals, schools, airports, government facilities and shopping malls
- Visually pleasing and energy efficient
- Great solution to replace 1 or 2-lamp CFL downlights
- Extremely quick and easy installation into most 6-inch and 8-inch CFL rough-in frames
- CCT: 3000K, 3500K, 4000K
- Typical CRI of 82
- 6 inch: 14W at 1000 lumens
- 8 inch: 14W at 1000 lumens; 19.5W at 1500 lumens; 25W at 2000 lumens
- L70 @ 50,000 hours
- Non-dimming

The descriptions above represent the entire portfolio of Lumination™ RX Series LED Downlights. For more in-depth information, please visit gelighting.com.



Small Lot


| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|--------------|--|----------|------------|----------|------------|
| 93034746 | LRXR610840MD | 6" Round, 120-277V, 1000 lumen, 82 CRI, 4000K, 0-10V | 1-160 | 1 week | 161-320 | 2 weeks |
| 93034752 | LRXR810840MD | 8" Round, 120-277V, 1000 lumen, 82 CRI, 4000K, 0-10V | 1-160 | 1 week | 161-320 | 2 weeks |
| 93034755 | LRXR818840MD | 8" Round, 120-277V, 1800 lumen, 82 CRI, 4000K, 0-10V | 1-160 | 1 week | 161-320 | 2 weeks |
| 93034758 | LRXR830840MD | 8" Round, 120-277V, 3000 lumen, 82 CRI, 4000K, 0-10V | 1-160 | 1 week | 161-320 | 2 weeks |
| 212702 | RX610830MV | 6" Round, 120-277V, 1000 lumen, 82 CRI, 3000K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212703 | RX610835MV | 6" Round, 120-277V, 1000 lumen, 82 CRI, 3500K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212705 | RX810830MV | 8" Round, 120-277V, 1000 lumen, 82 CRI, 3000K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212706 | RX810835MV | 8" Round, 120-277V, 1000 lumen, 82 CRI, 3500K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212707 | RX810840MV | 8" Round, 120-277V, 1000 lumen, 82 CRI, 4000K | 1-160 | 2 days | 161-320 | 2 weeks |
| 212708 | RX815830MV | 8" Round, 120-277V, 1500 lumen, 82 CRI, 3000K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212709 | RX815835MV | 8" Round, 120-277V, 1500 lumen, 82 CRI, 3500K | 1-160 | 1 week | 161-320 | 2 weeks |
| 212710 | RX815840MV | 8" Round, 120-277V, 1500 lumen, 82 CRI, 4000K | 1-160 | 2 days | 161-320 | 2 weeks |
| 212711 | RX820830MV | 8" Round, 120-277V, 2000 lumen, 82 CRI, 3000K | 1-160 | 1 week | 161-320 | 2 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ DI Series LED Downlights

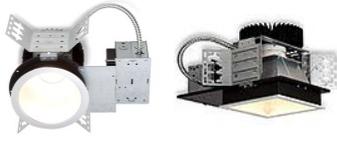

- Ideal for retail, office and hospitality applications
- Changeable lighting module that can be scaled for any environment
- Available in four color temperatures and five lumen packages, all with 90+ CRI
- Reflector is available in narrow, medium and wide light distribution patterns
- Available in 4" and 6" round or square luminaires, wall washing is an option
- CCT: 2700K, 3000K, 3500K, 4000K
- Typical CRI of 90
- 4": 14W at 1000 lumens; 51W at 4000 lumens
- 6": 14W at 1000 lumens; 51W at 4000 lumens
- L85 @ 50,000 hours
- 0-10V dimming, Phase dimming to 10%

The descriptions above represent the entire portfolio of Lumination™ DI Series LED Downlights. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|----------------|---|----------|------------|----------|------------|
| 83628 | DI4SLL1V10HO | 4" Square Housing-Only, Low-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 93020883 | DI4SLL2V10HO | 4" Square Housing-Only, Low-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83624 | DI4RLL1V10HO | 4" Round Housing-Only, Low-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83625 | DI4RLL2V10HO | 4" Round Housing-Only, Low-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 93020884 | DI6SLL1V10HO | 6" Square Housing-Only, Low-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 93019376 | DI6SLL2V10HO | 6" Square Housing-Only, Low-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 93020885 | DI6SHL1V10HO | 6" Square Housing-Only, High-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 93020886 | DI6SHL2V10HO | 6" Square Housing-Only, High-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83630 | DI6RLL1V10HO | 6" Round Housing-Only, Low-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83632 | DI6RLL2V10HO | 6" Round Housing-Only, Low-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83633 | DI6RHL1V10HO | 6" Round Housing-Only, High-Lumen Platform, 120V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 83638 | DI6RHL2V10HO | 6" Round Housing-Only, High-Lumen Platform, 277V, 0-10V | 1-40 | 1 week | 41-80 | 2 weeks |
| 19394 | DLM1000/935 | 1000 lumen, 90 CRI, 3500K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19395 | DLM1000/940/G2 | 1000 lumen, 90 CRI, 4000K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19485 | DLM1500/935 | 1500 lumen, 90 CRI, 3500K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19492 | DLM1500/940/G2 | 1500 lumen, 90 CRI, 4000K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19525 | DLM2000/935 | 2000 lumen, 90 CRI, 3500K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19526 | DLM2000/940/G2 | 2000 lumen, 90 CRI, 4000K | 1-40 | 1 week | 41-80 | 2 weeks |
| 19595 | DLM3000/935 | 3000 lumen, 90 CRI, 3500K | 1-40 | 1 week | 41-80 | 2 weeks |
| 34178 | DLM3000/940/G2 | 3000 lumen, 90 CRI, 4000K | 1-40 | 1 week | 41-80 | 2 weeks |
| 34185 | DLM4000/935 | 4000 lumen, 90 CRI, 3500K | 1-40 | 1 week | 41-80 | 2 weeks |
| 34186 | DLM4000/940/G2 | 4000 lumen, 90 CRI, 4000K | 1-40 | 1 week | 41-80 | 2 weeks |
| 93984 | RDI4RWSDMR | 4" Round Reflector, Wide Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93985 | RDI4RWSDWT | 4" Round Reflector, Wide Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93986 | RDI4SWSDMR | 4" Square Reflector, Wide Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93987 | RDI4SWSDWT | 4" Square Reflector, Wide Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93988 | RDI6RNSDMR | 6" Round Reflector, Narrow Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93989 | RDI6RNSDWT | 6" Round Reflector, Narrow Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93990 | RDI6RWSDMR | 6" Round Reflector, Wide Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93991 | RDI6RWSDWT | 6" Round Reflector, Wide Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93992 | RDI6MSDMR | 6" Square Reflector, Medium Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93993 | RDI6MSDWT | 6" Square Reflector, Medium Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93994 | RDI6SWSDMR | 6" Square Reflector, Wide Distribution, Semi-Diffuse, Polished Flange | 1-80 | 1 week | 81-200 | 2 weeks |
| 93995 | RDI6SWSDWT | 6" Square Reflector, Wide Distribution, Semi-Diffuse, White Flange | 1-80 | 1 week | 81-200 | 2 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ WS Series Surface Mount LED Luminaires



- Commercial ceiling fixture that provides high quality, excellent efficiency and reduced glare in cooler and wash down applications
- Upgrade to the Linear Fluorescent Fixture
- High uniformity
- Available in 2x2 and 2x4 models (1x4 custom)
- CCT:4000K
- Typical CRI of 80+
- L70 @ 50,000 hours
- Typical efficiency: 103-113 LPW

The descriptions above represent the entire portfolio of Lumination™ WS Series Surface Mount LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|--|----------|------------|----------|------------|
| 26722 | WS4N0A3SVWHT | Wrap 4'x7" (Narrow Body), 5600 lumen, 4000K, 0-10V | 1-40 | 2 days | 41-80 | 2 weeks |
| 26787 | WS4W0A3SVWHT | Wrap 4'x14" (Wide Body), 8000 lumen, 4000K, 0-10V | 1-40 | 2 days | 41-80 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ FM Series Surface Mount LED Luminaires



- Ideal for hospitality, office, and residential applications in retrofit and new construction
- Quick installation with included mounting brackets and hardware
- Light is distributed evenly without pixilation resulting in a soft glow around the fixture
- ENERGY STAR® certified
- CCT: 2700K
- Typical CRI of 80
- L70 @ 25,000 hours
- Typical efficiency: 65 LPW
- Non-dimming

The descriptions above represent the entire portfolio of Lumination™ FM Series Surface Mount LED Luminaires. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|--------------|-------------------------------------|----------|------------|----------|------------|
| 33741 | LED15FMM9-W | 9" Surface Light, 1000 lumen, 2700K | 1-80 | 1 week | 81-200 | 2 weeks |
| 20433 | LED15FMM12-W | 12" Surface Light, 975 lumen, 2700K | 1-80 | 1 week | 81-200 | 2 weeks |

* Shipment time subject to inventory availability

Lumination™ RFR/SFR Series Surface Mount LED Luminaires



- Easily installs into a junction box or downlight can
- Features a slim, modern design
- Provides uniform lit appearance
- Available in 4" round and 6" square
- CCT: 3000K, 3500K
- Typical CRI of 80+
- L70 @ 30,000 hours
- Typical efficiency: 65 LPW
- Dimming: 10-100 Triac (Phase) dimming

The descriptions above represent the entire portfolio of Lumination™ RFR/SFR Series Surface Mount LED Luminaires.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|---------------------|-----------------------------------|----------|------------|----------|------------|
| 93029327 | SFR6-15-108351VPHWT | 6" Square Surface Mount Downlight | 1-160 | 1 week | 161-320 | 2 weeks |
| 93029291 | RFR5-11-078301VPHWT | 4" Round Surface Mount Downlight | 1-160 | 1 week | 161-320 | 2 weeks |
| 93034173 | #6MTL | 6" Surface Mount Kit | 1-160 | 1 week | 161-320 | 2 weeks |
| 93034174 | #4MTL | 4" Surface Mount Kit | 1-160 | 1 week | 161-320 | 2 weeks |

* Shipment time subject to inventory availability



Indoor Fixtures

Lumination™ LTC Series LED Track Light



- Stylish alternative to PAR lamp holder
- Affordable solution to bring a sleek, clean look to your space
- Flexibility to customize for your space with accessories, beam angles and colors

- CCT: 2700K, 3000K, 4000K
- Typical CRI of 90
- 9.2W at 600 lumens
- L70 @ 50,000 hours
- Dimming: Triac & ELV (Forward & Reverse Phase) dimming standard, down to 10%

The descriptions above represent the entire portfolio of Lumination™ RX Series LED Downlights. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|------------------------|--|----------|------------|----------|------------|
| 93042342 | LTCIDA106SP930PQJ1WHTE | LTC, 120V, 600 lumen, 90 CRI, 3000K, Spot, Juno adapter, White | 1-40 | 1 week | 41-100 | 6 weeks |
| 93042343 | LTCIDA106SP930PQJ1BLCK | LTC, 120V, 600 lumen, 90 CRI, 3000K, Spot, Juno adapter, Black | 1-40 | 1 week | 41-100 | 6 weeks |
| 93042345 | LTCIDA106SP930PQG1WHTE | LTC, 120V, 600 lumen, 90 CRI, 3000K, Spot, Global adapter, White | 1-40 | 1 week | 41-100 | 6 weeks |
| 93042346 | LTCIDA106SP930PQG1BLCK | LTC, 120V, 600 lumen, 90 CRI, 3000K, Spot, Global adapter, Black | 1-40 | 1 week | 41-100 | 6 weeks |

* Shipment time subject to inventory availability



Architectural Fixtures

Lumination™ Architectural LLW Series LED Wall Washers



- Precise use of light output / eliminates socket shadows that are common when using fluorescent fixtures
- Consistent color with 3-step MacAdam ellipse color binning
- Available in a variety of optics to architectural designs
- Field-adjustable mounting for precise fixture angle
- Connect up to 300 fixtures in series
- Easy Installation
- Universal 120-277 input
- L85 at 50,000 hours
- 0-10V dimmable (as low as 3%)
- IP51, dry or damp location rated
- 5 year limited warranty
- No UV emissions

The descriptions above represent the entire portfolio of Lumination™ Architectural LLW Series LED Wall Washers. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|-------|-----------------------|---|----------|------------|----------|------------|
| 10739 | LLWSOB004CV827VQTMWHT | Standard Output Cove, 120-277V, 400 lumen, 80 CRI, 2700K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10740 | LLWSOB004CV830VQTMWHT | Standard Output Cove, 120-277V, 400 lumen, 80 CRI, 3000K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10741 | LLWSOB004CV835VQTMWHT | Standard Output Cove, 120-277V, 400 lumen, 80 CRI, 3500K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10747 | LLWSOB004CV840VQTMWHT | Standard Output Cove, 120-277V, 400 lumen, 80 CRI, 4000K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10750 | LLWHOB007CV827VQTMWHT | High Output Cove, 120-277V, 700 lumen, 80 CRI, 2700K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10758 | LLWHOB007CV835VQTMWHT | High Output Cove, 120-277V, 700 lumen, 80 CRI, 3500K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10763 | LLWHOB007CV840VQTMWHT | High Output Cove, 120-277V, 700 lumen, 80 CRI, 4000K, 0-10V | 1-200 | 1 week | 201-500 | 2 weeks |
| 10892 | LLWHOB007GZ827VQTMWHT | High Output Grazer, 120-277V, 700 lumen, 80 CRI, 2700K, 0-10V | 1-100 | 1 week | 101-300 | 2 weeks |
| 10895 | LLWHOB007GZ830VQTMWHT | High Output Grazer, 120-277V, 700 lumen, 80 CRI, 3000K, 0-10V | 1-100 | 1 week | 101-300 | 2 weeks |
| 10899 | LLWHOB007GZ835VQTMWHT | High Output Grazer, 120-277V, 700 lumen, 80 CRI, 3500K, 0-10V | 1-100 | 1 week | 101-300 | 2 weeks |
| 65467 | LWW1-MT48/0 | Mounting Track 48" (10) | 1-300 | 1 week | 301-600 | 2 weeks |

* Shipment time subject to inventory availability



Outdoor Fixtures

Evolve™ LED Security Light – E2SA



- Ideal for outdoor work yards, roadside commercial establishments, suburban developments and rural areas
- Built to withstand harsh elements
- Die-cast aluminum housing
- Structured LED arrays for optimized type 3 and type 5 square distributions
- CCT: 4000K
- Typical CRI of 80
- L70 @ 100,000 hours
- 0-10V Dimming

The descriptions above represent the entire portfolio of Evolve™ LED Security Light – E2SA. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|-----------------|---|----------|------------|----------|------------|
| 93023249 | E2SA0A1B31402NN | Security, 120V-277V, 3,600 lumen, 4000K | 1-10 | 1 week | 11-99 | 2 weeks |
| 215014 | E2SA0B1B31402NN | Security, 120V-277V, 5,200 lumen, 4000K | 1-10 | 1 week | 11-99 | 2 weeks |

* Shipment time subject to inventory availability

Evolve™ LED Area Light – EANA



- Ideal for site, area, and general lighting applications
- Provides uniformity, vertical light distribution, reduced on-site glare and effective security light levels
- Obtain efficient parking space with dimming and occupancy sensing features
- Multiple mounting options
- CCT: 4000K, 5000K
- Typical CRI of 70
- L85 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Evolve™ LED Area Light – EANA. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|------------------------|---|----------|------------|----------|------------|
| 93026611 | EANA0D35401CDKBZ | Area, 120V-277V, Asymmetric Wide, 9,600 lumen, 4000K, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93026613 | EANA0F35401CDKBZ | Area, 120V-277V, Asymmetric Wide, 13,400 lumen, 4000K, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93032612 | EALS010H4AF740NDD1DKBZ | Area, 120V-277V, Type IV, 20,000 lumen, 198W, 4000K, Universal Mounting Arm, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93032945 | EALS010K4AF740NDD1DKBZ | Area, 120V-277V, Type IV, 27,900 lumen, 322W, 4000K, Universal Mounting Arm, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |

* Shipment time subject to inventory availability

Evolve™ LED Flood Light – EFNA



- Ideal for flood lighting applications including: Billboard/bulletin, spot and flag poles, building façade' and general parking
- Die-cast aluminum housing incorporating heat sink
- Reflective technology to optimize efficiency and minimize glare
- Multiple mounting options
- CTT: 4000K, 5000K
- Typical CRI of 70
- L85 @ 50,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Evolve™ LED Flood Light – EFNA. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|------------------------|---|----------|------------|----------|------------|
| 209106 | EFNA0F35401KDKBZ | Flood, 120V-277V, Asymmetric Wide, 13,400 lumen, 4000K Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93037878 | EFH1010AA66750ADT1DKBZ | Flood, 120V-277V, NEMA 6x6, 18,800 lumen, 150W, 5000K, Trunnion Mount, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93040050 | EFH1010EE76750ADT1DKBZ | Flood, 120V-277V, NEMA 7x6, 18,800 lumen, 150W, 5000K, Trunnion Mount, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 93035238 | EFH1010EE66750ADT1DKBZ | Flood, 120V-277V, NEMA 6x6, 18,800 lumen, 150W, 5000K, Trunnion Mount, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |

* Shipment time subject to inventory availability



Outdoor Fixtures

Evolve™ LED Garage Light – EG2R



- Ideal for garage, warehouse, walkway and stairway lighting
- Die-cast aluminum housing incorporating heat sink
- Provides high uniformity and vertical light distribution
- Features programmable motion sensing, step dimming and daylight harvesting
- Standard color: White
- Available with seven different mounting options
- CCT: 4000K, 5000K
- Typical CRI of 70
- L70 @ 100,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Evolve™ LED Garage Light – EG2R. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|--------|--------------------|--|----------|------------|----------|------------|
| 210737 | EG2R0A5PS5011WHITE | Garage, 120V-277V, 5,000 lumen, 5000K, White | 1-10 | 1 week | 11-99 | 2 weeks |

* Shipment time subject to inventory availability

Evolve™ LED Area Light Scalable Wall Pack – EWS2



- Ideal for wall mounted, site, area, and general lighting applications
- Provides uniformity, vertical light distribution, reduced offsite visibility/on-site glare and effective security light levels
- Die-cast aluminum housing
- Operates well in cold temperatures
- CCT: 4000K, 5000K
- Typical CRI of 70
- L85 @ 50,000 hours

The descriptions above represent the entire portfolio of Evolve™ LED Area Light Scalable Wall Pack – EWS2. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|--------|------------------|--|----------|------------|----------|------------|
| 215362 | EWS20A7D1401DKBZ | Wall Pack, 120V-277V, Asymmetric Forward, 3,100 lumen, 4000K, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |
| 216115 | EWS20C7D1501DKBZ | Wall Pack, 120V-277V, Asymmetric Forward, 4,800 lumen, 5000K, Bronze | 1-10 | 1 week | 11-99 | 2 weeks |

* Shipment time subject to inventory availability



Industrial Fixtures

Albeo™ LED Luminaire – ABR1



- IP66 rated fixture for industrial environments with high ambient temperatures and wet applications
- Modular design: single and double fixture options
- Cable/chain, rod or pendant mount
- Daylight and motion controls

- CCT: 4000K, 5000K
- Typical CRI of 70
- Lumen output: 9,000-46,000 lm
- L70 @ 100,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Albeo™ LED Luminaire – ABR1. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|-------------------|---|----------|------------|----------|------------|
| 93014044 | ABR101H571NNSTANW | Highbay, 120-277V, 11,800 lumen, 5000K, 120°, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2 weeks |
| 93014051 | ABR101T571NNSTANW | Highbay, 120-277V, 8,800 lumen, 5000K, 120°, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2 weeks |
| 213915 | ABR102H571NNSTANW | Highbay, 120-277V, 23,000 lumen, 5000K, 120°, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2 weeks |

* Shipment time subject to inventory availability

Albeo™ LED Luminaire – ABV2



- Ideal for warehouse, cold storage, industrial, gymnasium, sports arena, retail, and high-ceiling applications
- Modular design: 1 and 2 modules
- Combination of steel and aluminum housing
- Daylight and motion controls

- CCT: 4000K, 5000K
- Typical CRI of 70
- Lumen output: 9,000-24,000 lm
- L70 @ 100,000 hours
- 0-10V dimming

The descriptions above represent the entire portfolio of Albeo™ LED Luminaire – ABV1. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time* | Lot Size | Lead Time* |
|----------|----------------------|---|----------|------------|----------|------------|
| 93053082 | ABV201T471NVSTKNW1PK | Highbay, 120-277V, 9,000 lumen, 4000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053084 | ABV201T571NVSTKNW1PK | Highbay, 120-277V, 9,100 lumen, 5000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053097 | ABV201V471NVSTKNW1PK | Highbay, 120-277V, 12,000 lumen, 4000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053098 | ABV201V571NVSTKNW1PK | Highbay, 120-277V, 12,300 lumen, 5000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053100 | ABV202T471NVSTKNW1PK | Highbay, 120-277V, 24,100 lumen, 4000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053102 | ABV202T571NVSTKNW1PK | Highbay, 120-277V, 18,300 lumen, 5000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053103 | ABV202V471NVSTKNW1PK | Highbay, 120-277V, 24,600 lumen, 4000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053104 | ABV202V571NVSTKNW1PK | Highbay, 120-277V, 18,300 lumen, 5000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053082 | ABV201T471NVSTKNW1PK | Highbay, 120-277V, 9,000 lumen, 4000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |
| 93053084 | ABV201T571NVSTKNW1PK | Highbay, 120-277V, 9,100 lumen, 5000K, 120°, 70 CRI, White | 1-10 | 1 week | 11 - 800 | 2 weeks |

* Shipment time subject to inventory availability



Industrial Fixtures

Albeo™ LED Luminaire – ALR1



- Ideal for low bay and task level applications in commercial, industrial, warehouse, office and education settings
 - IP65 rated
 - IP66 rated motion sensors
 - Fiberglass housing with diffuser
 - Chain or surface mount
 - Available in 4' and 8' models
- CCT: 4000K, 5000K
 - Typical CRI of 70
 - Lumen output: 3,300-14,800 lm
 - L70 @ 100,000 hours
 - 0-10V dimming

The descriptions above represent the entire portfolio of Albeo™ LED Luminaire – ALR1. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time | Lot Size* | Lead Time* |
|--------|------------------------|---|----------|-----------|-----------|------------|
| 216582 | ALR101H4714SNNSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216579 | ALR101H5714SNNSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216581 | ALR101T4714SNNSTKNW1PK | Linear, 120V - 277V, 4' Length, 3,300 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216578 | ALR101T5714SNNSTKNW1PK | Linear, 120V-277V, 4' Length, 3,300 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216583 | ALR101V4714SNNSTKNW1PK | Linear, 120V-277V, 8' Length, 14,800 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216580 | ALR101V5714SNNSTKNW1PK | Linear, 120V-277V, 8' Length, 14,800 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |

* Shipment time subject to inventory availability

Albeo™ LED Luminaire – ALV1



- Ideal for low bay and task level applications in commercial, industrial, warehouse, office and education settings
 - Recommended for low bay lighting at 20 ft. or lower
 - Stamped metal housing
 - Chain/cable or surface mount
 - Available in 4' and 8' models
- CCT: 4000K, 5000K
 - Typical CRI of 70
 - Lumen output: 3,350-14,800
 - L70 @ 100,000 hours

The descriptions above represent the entire portfolio of Albeo™ LED Luminaire – ALV1. For more in-depth information, please visit gelighting.com.



Small Lot

| SKU # | Cat Logic | Description | Lot Size | Lead Time | Lot Size* | Lead Time* |
|----------|------------------------|--|----------|-----------|-----------|------------|
| 216576 | ALV101H4714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216573 | ALV101H5714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216575 | ALV101T4714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 3,300 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216572 | ALV101T5714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 3,300 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216577 | ALV101V4714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 7,300 lumen, 4000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 216574 | ALV101V5714SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 7,300 lumen, 5000K, 70 CRI, White | 1-5 | 1 week | 6 - 200 | 2-3 weeks |
| 93044117 | ALV10H47D4SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 4000K, 70 CRI, White, Diffused lens | 1-10 | 1 week | 6 - 200 | 2-3 weeks |
| 93044116 | ALV10H57D4SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 5,300 lumen, 5000K, 70 CRI, White, Diffused lens | 1-10 | 1 week | 6 - 200 | 2-3 weeks |
| 93044115 | ALV10T47D4SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 3,300 lumen, 4000K, 70 CRI, White, Diffused lens | 1-10 | 1 week | 6 - 200 | 2-3 weeks |
| 93044114 | ALV10T57D4SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 3,300 lumen, 5000K, 70 CRI, White, Diffused lens | 1-10 | 1 week | 6 - 200 | 2-3 weeks |
| 93044113 | ALV10V47D4SNVSTKNW1PK | Linear, 120V-277V, 4' Length, 7,300 lumen, 4000K, 70 CRI, White, Diffused lens | 1-10 | 1 week | 6 - 200 | 2-3 weeks |

* Shipment time subject to inventory availability





www.gelighting.com

GE and the GE Monogram are trademarks of the General Electric Company. All other trademarks are the property of their respective owners. Information provided is subject to change without notice. All values are design or typical values when measured under laboratory conditions. GE Lighting and GE Lighting Solutions, LLC are businesses of the General Electric Company.
© 2016 GE.

16-0225 (Rev. 9/1/2016)