



Non-Conductive Fiberglass Rodders



Rod Or Fish Conduit 2-4" In Diameter

Based on the overwhelming success of our original Good Buddy® and customer suggestions, Jameson offers a comprehensive Good Buddy® family to meet various applications for 3/8" rod:

Manhole-to-riser, riser-to-riser, cable vaults and large conduit runs.

- 7" Bending Radius
- 1,000-lb Tensile/Pull Strength
- Accessory Kit, End Ferrule and Pulling Eye Included

3/8"
OD ROD
.250" Core

Part Number	Good Buddy® Rodders	Weight
9-25-300M	300' X 3/8" Good Buddy	52 Lbs.
9-25-400M	400' X 3/8" Good Buddy	59 Lbs.
11A-25-400M	400' X 3/8" Good Buddy II	73 Lbs.
11A-25-500M	500' X 3/8" Good Buddy II	80 Lbs.
11A-25-600M	600' X 3/8" Good Buddy II	87 Lbs.
9A-25-300M	300' X 3/8" Good Buddy III	53 Lbs.
9A-25-400M	400' X 3/8" Good Buddy III	60 Lbs.

All Good Buddy® conduit rodder models come standard with rod marked in 5' increments. Add 'MM' to part number for metric measure (1m increments).

Good Buddy®

The original Good Buddy® operates horizontally or vertically and has a folding frame for easier handling and transport. Available only from Jameson, the frame detaches from the reel to allow for increased functionality in confined spaces.


Good Buddy® II

Developed for longer runs. Available in lengths up to 600', the non-folding frame operates vertically or horizontally. To ease transport of the increased rod weight, the frame features heavy duty wheels.

Good Buddy® III

Features a slimmer frame, handle and wheels. Designed for maximum portability, the Good Buddy® III operates horizontally or vertically.

Part Number	Accessories	
9-25-AK	Accessory Kit	End Ferrule, Splice Ferrule, Adhesive, Emery Cloth, Canvas Pouch
9-139	Swivel Eye	Attach pull line or grip to freely rotating eye
9-141	Roller Guide	Guides rod through bends, sweeps, misalignments, wires
11-142	Shackle Fitting	Use with Swivel Eye for larger pulling loop to attach Pulling Eye. Must use 11-139 Swivel Eye.
9-143	Swivel Coupling	Connect two rods when single length is not long enough; provides rotation when pulling line, wire or rope.
9-148	Rod Grapples	Connects two rodders from opposite directions
9-25-12ST	12" Stinger	Stinger Tip guides rod through bends, sweeps, misalignments
9-25-24ST	24" Stinger	
9-140	Splice Repair Kit	Splice Ferrule, Adhesive, Emery Cloth, Instructions
9-146	End Ferrule Repair	End Ferrule, Adhesive, Emery Cloth, Instructions
11A-AWK	AT Wheel Kit	Replacement All-Terrain Wheel Kit (2 wheels/ axle) for Good Buddy II only

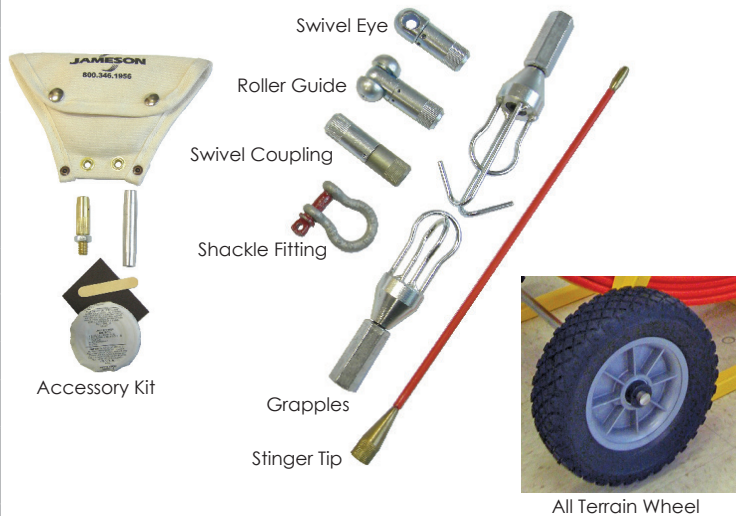



29"



Detach or Fold Frame For Transport Into Confined Areas

Good Buddy®

- 300' and 400' lengths
- Unit folds to 10" width for carrying into manholes or reel can be detached from frame
- New frame handle for ease of transport and handling
- Friction brake and safety roller feed
- Operates vertically or horizontally
- Accessory Kit Included

29"H x 29"L x 27"W (Folds to 10" Width)

39"



Increased Rod Length For Longer Runs

Good Buddy® II

- 400', 500' and 600' lengths
- Oversized wheels to support weight of longer rod
- Frame handle and wheels for transport
- Friction brake and safety roller feed
- Operates vertically or horizontally
- Accessory Kit Included

39"H x 32"L x 18"W

32"



Smaller Frame For Maximum Portability

Good Buddy® III

- 300' and 400' lengths
- Wheels and frame handle for transport
- Smaller frame size than GB or GB II
- Friction brake and safety roller feed
- Operates vertically or horizontally
- Accessory Kit Included

32"H x 28"L x 13"W