

Section F: Exit Signs and Emergency Lights





Emergency Lights

EMERGENCY LIGHT



EL2N

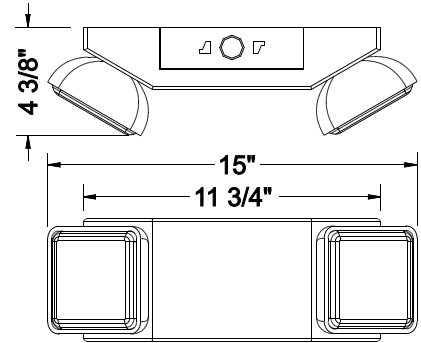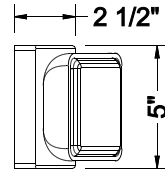

- Listed for Damp Location
- 120/277 VAC with Universal Transformer
- Two 5.4W Wedge base Lamps
- 90 minutes Emergency Operation
- 6V, 4.5Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light

- Completely Self-Contained
- Fully Automatic Operation
- Universal Mounting Plate
- Quick-Wire
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Wall or Ceiling Mount



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Cat. No.	Housing Color	Self-Diagnostic Test
EL2N	W (White) B (Black)	SDT

Quick-Ship Model


EL2N



MR16 EMERGENCY LIGHT



EL2H

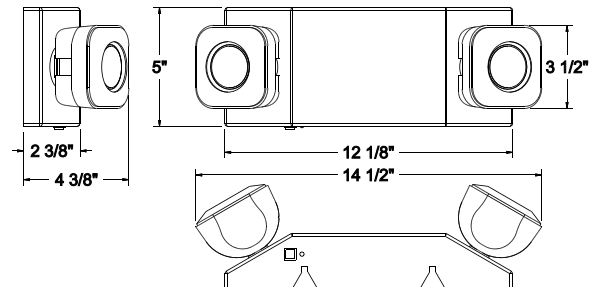

- 120/277 VAC with Universal Transformer
- Two 6V MR16 5W Halogen Lamps
- 90 minutes Emergency Operation
- 6V, 4.5Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light

- Completely Self-Contained
- Fully Automatic Operation
- Compact Low Profile Design
- Adjustable Heads
- Universal Mounting Plate
- Quick-Wire
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Wall or Ceiling Mount



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Cat. No.	Housing Color	Self-Diagnostic Test
EL2H	W (White) B (Black)	SDT

Quick-Ship Model

EL2H




HIGH OUTPUT EMERGENCY LIGHT WITH REMOTE CAPACITY

Remote-Capable for up to 2 Additional Heads



EL2N-HO

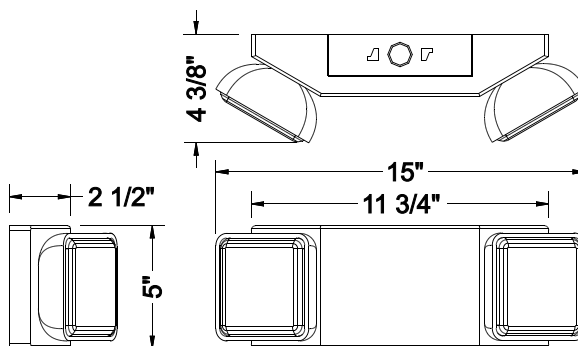

- Listed for Damp Location
- 120/277 VAC with Universal Transformer
- Two 5.4W Wedge Base Lamps Std. (Optional 9W)
- 90 minutes Emergency Operation w/ 4 5.4W. Heads
- 6V, 7Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)

- Charge Rate/Power on LED Indicator
- Completely Self-Contained
- Fully Automatic Operation
- Universal Mounting Plate
- Quick-Wire
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Wall or Ceiling Mount



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Output / Number of Heads

Cat. No.	Self-Diagnostic Test
EL2N-HO	SDT


Watts for	Battery	Lamp	Total No. of Connected 5.4W Heads		
90 Min.	Voltage	Wattage	3 Hrs	2 Hrs	1-1/2 Hrs
22	6V	5.4W	2	3	4



HIGH OUTPUT MR16 EMERGENCY LIGHT WITH REMOTE CAPACITY



EL2H-HO

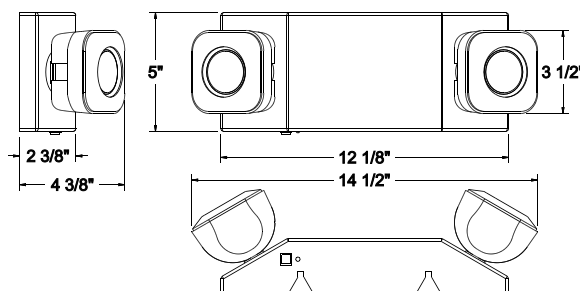

- 120/277 VAC with Universal Transformer
- Two 6V 5W MR16 Halogen Lamps
- 90 minutes Emergency Operation w/ up to 4 Heads
- 6V, 7Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light

- Completely Self-Contained
- Fully Automatic Operation
- Compact Low Profile Design
- Adjustable Heads
- Universal Mounting Plate
- Quick-Wire
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Wall or Ceiling Mount



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Output / Number of Heads

Cat. No.	Self-Diagnostic Test
EL2H-HO	SDT

Watts for	Battery	Lamp	Total No. of Connected 5W Heads		
90 Min.	Voltage	Wattage	3.3 Hrs	2.2 Hrs	1-1/2 Hrs
22	6V	5W	2	3	4




Emergency Lights

EMERGENCY LIGHT



EL2F

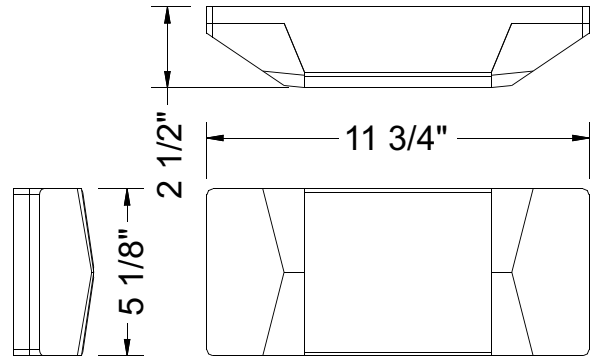

- 120/277 VAC with Universal Transformer
- Two T5 5W Wedge base Lamps
- 90 minutes Emergency Operation
- 6V, 4.5Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Charge Rate/Power on LED Indicator Light

- Completely Self-Contained
- Fully Automatic Operation
- Stylish Flushed Heads
- Injection-Molded, V-O Flame retardant, thermoplastic casing

Cat. No.	Housing Color
EL2F	W (White) B (Black)

Quick Ship Item


EL2F



REMOTE-CAPABLE RECESSED EMERGENCY LIGHT



EL2R

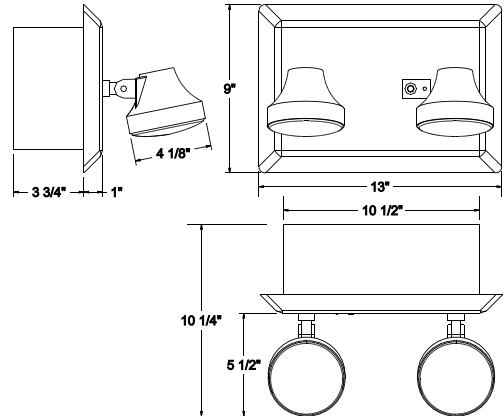

- Listed for Damp Location
- 120/277 VAC with Universal Transformer
- Two 7.2W Wedge Base Lamps Std. (Optional 9W)
- 90 minutes Emergency Operation w/ 4 5.4W Heads
- 6V, 10Ah Lead-Acid, Maintenance-Free Battery
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)

- Charge Rate/Power on LED Indicator
- Completely Self-Contained
- Fully Automatic Operation
- Universal Mounting Plate
- Quick-Wire
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Recessed Mount



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Output / Number of Heads

Cat. No.	Optional Two 9W Heads Provides 90 min.	Self-Diagnostic Test
EL2R	9W	SDT

Watts for	Battery	Lamp	Total No. of Connected 5.4W Heads		
90 Min.	Voltage	Wattage	3 Hrs	2 Hrs	1-1/2 Hrs
22	6V	5.4W	2	3	4




Emergency Lights

HIGH OUTPUT REMOTE-CAPABLE
EMERGENCY LIGHTS

EL2T6

EL2T12

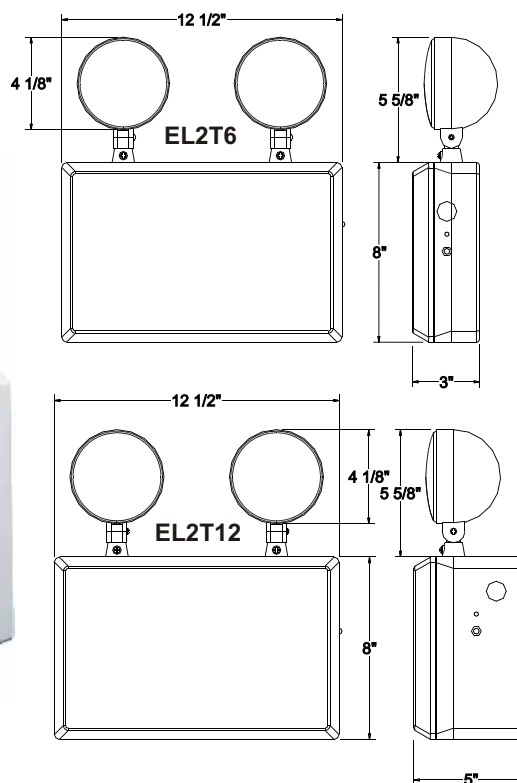

Cat. No.	Watts for 90 Min.	Battery Voltage	Lamp Wattage	Total No. of Connected Heads		
				4 Hrs	2 Hrs	1-1/2 Hrs
EL2T628	28	6V	7.2W	-	2	3
EL2T636	36	6V	7.2W	-	3	4
EL2T650	50	6V	7.2W	2	4	6
EL2T672	72	6V	7.2W	3	7	9
EL2T6100	100	6V	7.2W	4	9	12
EL2T1228	28	12V	9W	-	2	3
EL2T1236	36	12V	9W	-	3	4
EL2T1250	50	12V	9W	2	3	5
EL2T1272	72	12V	9W	3	5	7
EL2T12100	100	12V	9W	4	7	10

- 120/277 VAC with Universal Transformer
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- Pure Lead, Maintenance-Free Battery



Exit Signs



LED EXIT SIGN WITH BATTERY BACK-UP



ESBL

- Listed for Damp Location
- Single/Double Face
- 120/277 VAC
- 25 years LED Lamp Life
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- Ni-Cad Back-up Battery

- 3.2W Total (Red) / 3.8W Total (Green)
- Completely Self-Contained
- Fully Automatic Operation
- Injection-Molded thermoplastic casing
- 6" Tall Letters
- Universal K.O. Chevrons
- Side, Top, or Back Mount
- Universal Mounting Canopy Included

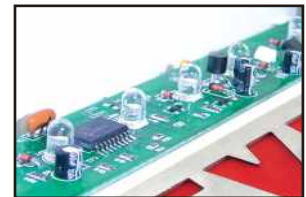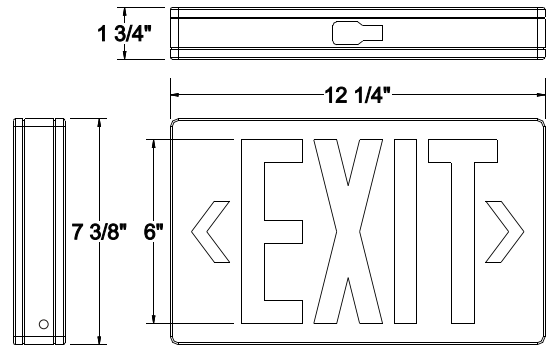

Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Cat. No.	Housing Color	Letter Color	Remote Capacity	Self-Diagnostic Test
ESBL	W (White)	R (Red)	RC	SDT
	B (Black)	G (Green)		

Quick-Ship Models
ESBL-R
ESBL-G




AC ONLY LED EXIT SIGN



ESL

- Single/Double Face
- Listed for Damp Location
- 120/277 VAC
- 25 years LED Lamp Life

- Completely Self-Contained
- Injection-Molded thermoplastic casing
- 6" Tall Letters
- Universal K.O. Chevrons
- Side, Top, or Back Mount
- Universal Mounting Canopy Included

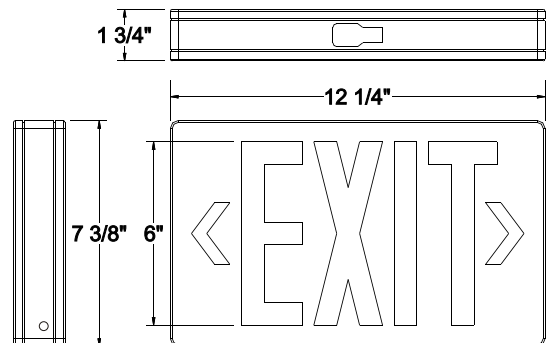

Cat. No.	Housing Color	Letter Color
ESL	W (White)	R (Red)
	B (Black)	G (Green)

Quick-Ship Models
ESL-R
ESL-G




DOUBLE CIRCUIT (AC/GENERATOR) LED EXIT SIGN



ESL2C

- Single/Double Face
- 120/277 VAC Line or Generator
- Six 150mA Red LEDs or Twelve 100mA Green LEDs
- 3.2W on Red LEDs or 3.8W on Green LEDs
- 25 years LED Lamp Life
- Push to Test Switch

Cat. No.	Housing Color	Letter Color
ESL2C	W (White)	R (Red)
	B (Black)	G (Green)

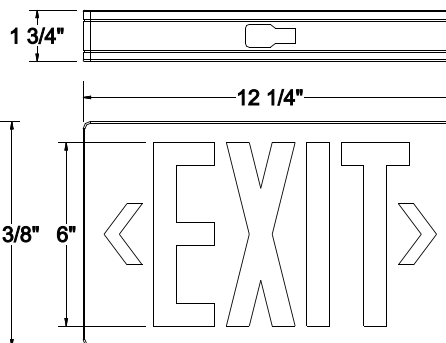

- Completely Self-Contained
- Fully Automatic Operation
- Compact Low Profile Design
- Injection-Molded thermoplastic casing
- 6" Tall Letters
- Universal K.O. Chevrons
- Side, Top, or Back Mount
- Universal Mounting Canopy Included




AC ONLY INCANDESCENT EXIT SIGN



ES

- Single/Double Face
- 120 VAC
- Two 15W T6 Incandescent Lamps

Cat. No.	Housing Color
ES	W (White)

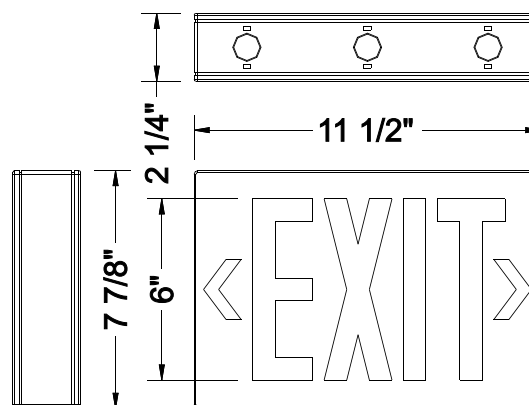



- Red & Green Letter Plates Included
- Injection-Molded thermoplastic casing
- 6" Tall Letters
- Side, Top, or Back Mount
- Universal Mounting Canopy Included



CAST ALUMINUM LED EXIT SIGN



ES LA

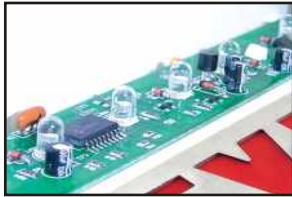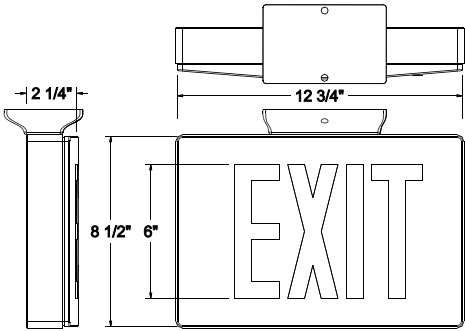

- 120/277 VAC
- 25 years LED Lamp Life
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light (EB units)
- Ni-Cad Back-up Battery (EB units)

- Specification Grade
- Fully Automatic Operation
- Curved Design
- 6" Tall Letters
- Side, Top, or Back Mount
- Universal Mounting Canopy Included

Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Cat. No.	Letter Color	Face Color	No. of Face	Operation	Self-Diagnostic Test
ES LA	R (Red)	A (Brushed Alum.)	1 (Single)	EB (Battery Back-up)	SDT
	G (Green)	W (White)	2 (Double)	AC (AC only)	
		B (Black)			



Exit Signs

SELF-ILLUMINATING
LOW-LEVEL EXIT SIGN

ESI-G

- Non-Electrical, Non-Nuclear
- Non-Radioactive
- 3 to 5 footcandles ambient lighting for 60 to 90 minutes
- Observable from 50 feet
- 10 years operational life
- Aluminum Body
- Photoluminescent Surface




ESI-R

Also Available in RED Letters

- Single Sided with 6" Green EXIT Letters
- **Two Directional Arrow Stickers Included**
- Wall/Surface Mount
- Suitable for Floor-Proximity Mounting
- With Built-in Mounting Bracket


Cat. No.	Letter Color
ESI	G (Green) R (Red)

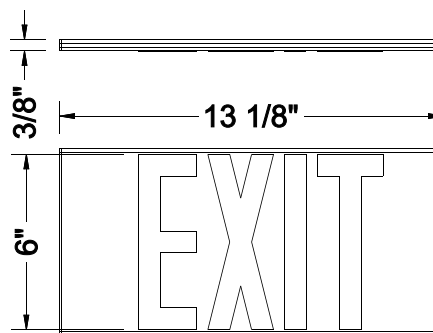SELF-ILLUMINATING
TRITIUM (NUCLEAR) EXIT SIGN

ESN


- Non-Electrical, Nuclear
- 10 footcandles ambient lighting for 60 to 90 minutes
- Observable from 50 feet
- 10 or 20 years operational life
- 7.03Ci for 10-Yr model, 11.47Ci for 20-Yr model

- Tritium-powered, Self-Illuminating
- Weatherproof and Explosion-Proof
- 6" EXIT Letters
- Letter-shaped light tubes for best lighting
- Suitable for Floor-Proximity Mounting
- With Built-in Mounting Bracket

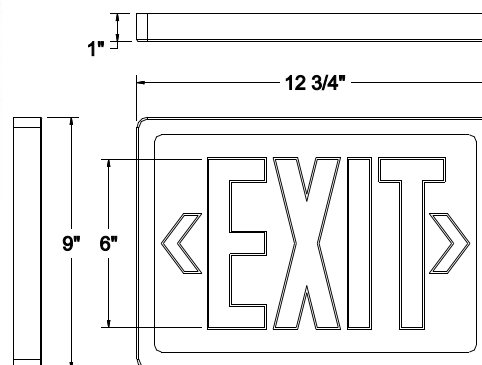

Cat. No.	Frame Color	Face Color	No. of Face	Life in Years
ESN	W (White)	R (Red)	1 (Single)	10 (10 years)
	B (Black)	G (Green)	2 (Double)	20 (20 years)

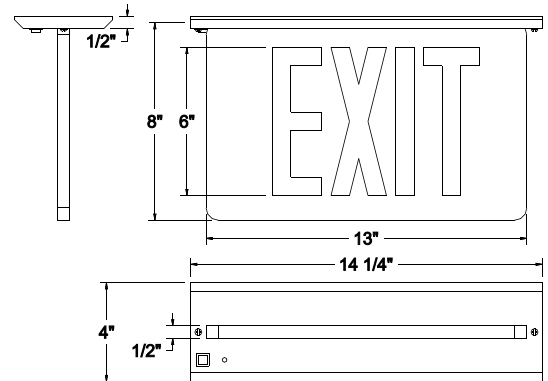


Exit Signs**EDGE-LIT LED EXIT SIGN (RECESSED-MOUNT)****ESRE**

- 120/277 VAC
- 3W for AC Only (AC), 5W for Battery Backup (EB)
- Ultra Bright LEDs
- AC On Indicator Light and Test Switch (EB units)
- Automatic, Low Voltage Disconnect (LVD)
- Sealed Lead Battery (EB units)

- Recessed-Mount
- UV Stabilized Ultra Clear Acrylic Panel
- 6" Tall Letters
- Infield installable directional arrows
- Mylar Insert for Double-Face Unit
- Mounting Bar Hanger Included

Cat. No.	Panel Color	Casing Finish	No. of Face	Operation
ESRE	R (Red on Clear)	A (Anodized Alum.)	1 (Single)	EB (Battery Back-up)
	G (Green on Clear)	W (White)	2 (Double)	AC (AC only)

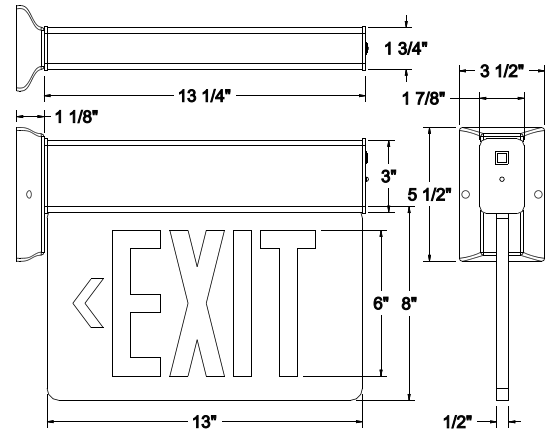**EDGE-LIT LED EXIT SIGN (SURFACE-MOUNT)****ESSE**

- 120/277 VAC
- 3W for AC Only (AC), 5W for Battery Backup (EB)
- Ultra Bright LEDs
- AC On Indicator Light and Test Switch (EB units)
- Automatic, Low Voltage Disconnect (LVD)
- Sealed Lead Battery (EB units)

- Surface Mount (Wall, Ceiling, or Side)
- Premium Grade Extruded Aluminum Housing
- UV Stabilized Ultra Clear Acrylic Panel
- 6" Tall Letters
- Infield installable directional arrows
- Mylar Insert for Double-Face Unit
- Tri-Mount Canopy Included

Cat. No.	Panel Color	Casing Finish	No. of Face	Operation
ESSE	R (Red on Clear)	A (Anodized Alum.)	1 (Single)	EB (Battery Back-up)
	G (Green on Clear)	W (White)	2 (Double)	AC (AC only)





Exit Sign & Emergency Lights Combo

EMERGENCY LIGHT/LED EXIT SIGN COMBINATION UNIT



EECL

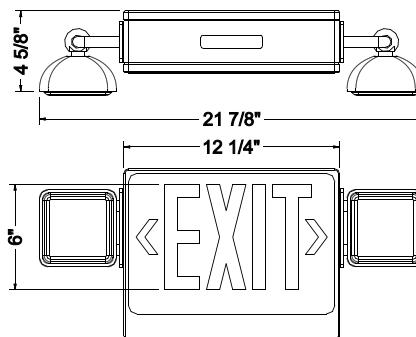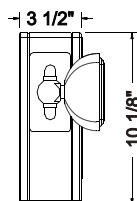

- Listed for Damp Location
- Single/Double Face
- 120/277 VAC with Universal Transformer
- Two 5W T5 Wedge base Emergency Lamps
- 90 minutes Emergency Operation
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- 6V, 4.5Ah Pure Lead, Maintenance-Free Battery

- Completely Self-Contained
- Fully Automatic Operation
- 180° Rotatable Heads
- Injection-Molded thermoplastic casing
- Universal K.O. Chevrons
- Top or Wall Mount
- Universal Mounting Canopy Included



Optional Self Diagnostic/Self Test feature offers the ultimate worry-free maintenance & reliability

Cat. No.	Housing Color	Letter Color	Self-Diagnostic Test	Remote Capacity
EECL	W (White)	R (Red)	SDT	RC
	B (Black)	G (Green)		

Quick-Ship Models


EECL-R
EECL-G



EMERGENCY LIGHT/LED EXIT SIGN COMBINATION UNIT



ESBL2N

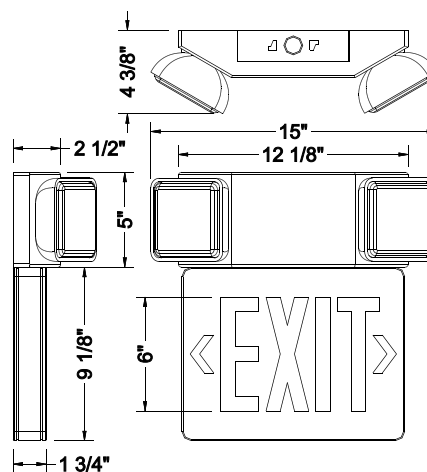

- Single/Double Face
- 120/277 VAC with Universal Transformer
- Two 5W T5 Wedge base Emergency Lamps
- 90 minutes Emergency Operation
- Environmentally-Coated Solid State Charger
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- 6V, 4.5Ah Lead-Calcium, Maintenance-Free Battery

- Completely Self-Contained
- Fully Automatic Operation
- Injection-Molded, V-O Flame retardant, high-impact, thermoplastic casing
- Universal K.O. Chevrons
- Wall or Ceiling Mount
- Universal Mounting Canopy Included

Cat. No.	Housing Color	Letter Color
ESBL2N	W (White)	R (Red)
		G (Green)

Quick-Ship Models

ESBL2N-R
ESBL2N-G



Wet Location Products

REMOTE-CAPABLE WET LOCATION
(NEMA4) EMERGENCY LIGHT



EL2TN4



- NEMA4 Wet Location Listed
- 0°C to 40°C Rated
- With Remote Capability
- 120 or 277 VAC
- Two T5 7.2W Wedge base Lamps
- 90 minutes Emergency Operation
- Short Circuit and Power Loss Protection and Deep Battery Discharge Protection
- Sealed Momentary Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- 6V, 7Ah Pure Lead, Maintenance-Free Battery

Cat. No.


EL2TN4

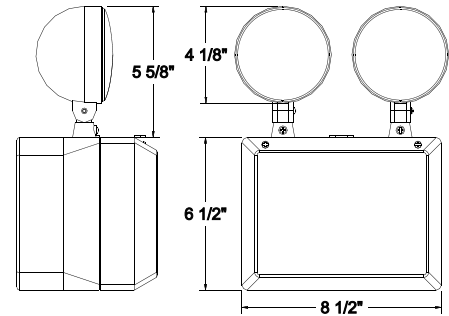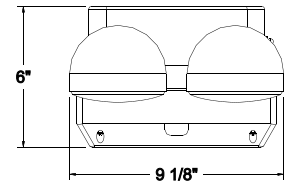

- Resistant to Corrosive Atmospheres, Non-Hazardous Dust, Water Sprays or Splashing Water.
- ABS, Corrosion-proof, UV Stabilized White Casing
- Automatic Brownout Feature
- Completely Self-Contained

REMOTE-CAPABLE WET LOCATION
(NEMA4) EXIT SIGNS

ESLN4

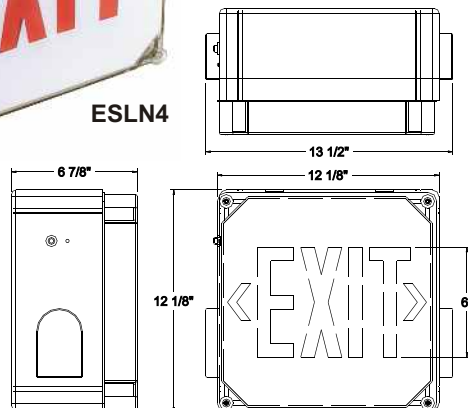

Operation	Cat. No.	Letter Color
AC only	ESLN4-AC	R (Red)
		G (Green)
Battery Back-up	ESLN4-EB	R (Red)
		G (Green)
Double Circuit: AC/Generator	ESLN4-2C	R (Red)
		G (Green)


- NEMA4 Wet Location Listed
- 0°C to 40°C Rated
- 120/277 VAC
- 5.6W LEDs
- AC On Indicator Light and Test Switch
- 90 Minutes Emergency Operation (EB Units)
- Automatic, Low Voltage Disconnect (LVD)
- 25 years LED Life
- Sealed Lead Battery (EB Units)

- Resistant to Corrosive Atmospheres, Non-Hazardous Dust, Water Sprays or Splashing Water.
- ABS, UV Stabilized Enclosure
- Removable Directional Arrows
- 6" Tall Letters
- Extremely Low Operating Costs
- Meets NFPA Life Safety 101, NEC, OSHA and Local and State Codes



WET LOCATION (NEMA 4)
COMBINATION UNIT

ESBL2N4

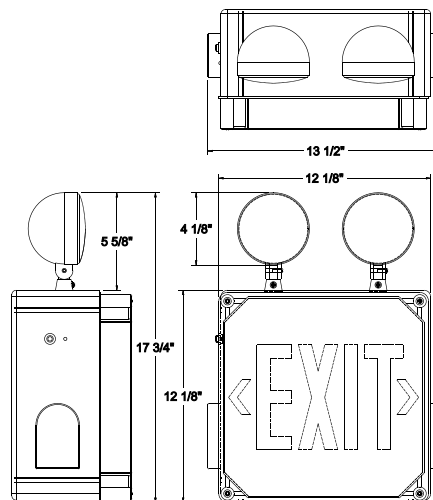

- NEMA4 Wet Location Listed
- 0°C to 40°C Rated
- 120/277 VAC
- Two 5W T5 Wedge base Emergency Lamps
- AC On Indicator Light and Test Switch
- 90 Minutes Emergency Operation
- Automatic, Low Voltage Disconnect (LVD)
- 25 years lamp life
- Sealed Lead Battery

- Resistant to Corrosive Atmospheres, Non-Hazardous Dust, Water Sprays or Splashing Water.
- ABS, UV Stabilized Enclosure
- Removable Directional Arrows
- 6" Tall Letters
- Meets NFPA Life Safety 101, NEC, OSHA and Local and State Codes




Cat. No.	Letter Color
ESBL2N4	R (Red)
	G (Green)

LED SALIDA SIGN WITH BATTERY BACK-UP



SSBL

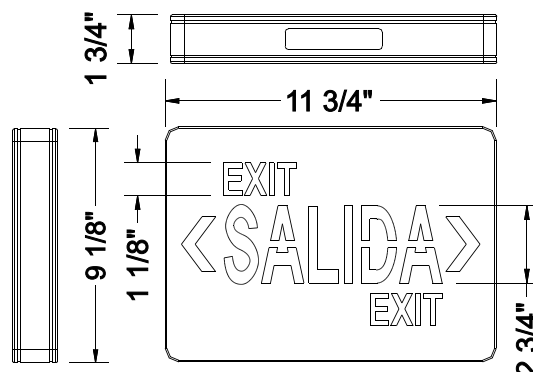

Cat. No.	Letter Color
SSBL	R (Red) G (Green)

- Listed for Damp Location
- Single/Double Face
- 120/277 VAC
- 25 years LED Lamp Life
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- Ni-Cad Back-up Battery


- Completely Self-Contained
- Fully Automatic Operation
- Injection-Molded thermoplastic casing
- SALIDA Letters with EXIT Letters
- Universal K.O. Chevrons
- Side, Top, or Back Mount
- Universal Mounting Canopy Included



EMERGENCY LIGHT/LED SALIDA SIGN COMBINATION UNIT



SECL

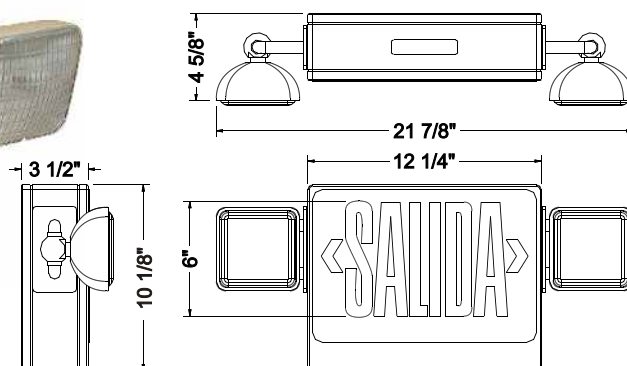

Cat. No.	Letter Color
SECL	R (Red) G (Green)

- Listed for Damp Location
- Single/Double Face
- 120/277 VAC with Universal Transformer
- Two 5W T5 Wedge base Emergency Lamps
- 90 minutes Emergency Operation
- Short Circuit and Power Loss Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- 6V, 4.5Ah Pure Lead, Maintenance-Free Battery

- Completely Self-Contained
- Fully Automatic Operation
- Injection-Molded thermoplastic casing
- Universal K.O. Chevrons
- Top or Wall Mount
- Universal Mounting Canopy Included







City of New York Approved Products



CITY OF NEW YORK APPROVED EMERGENCY LIGHTS



NYELX-2

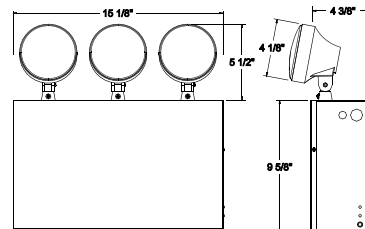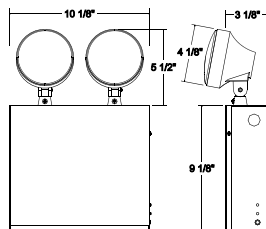NYELX-3
NYELX-4

- Heavy Duty 20GA Steel Construction
- 120/277 VAC with Universal Transformer
- PAR36 Lamps
- Short Circuit and Power Loss Protection
- Brownout Protection
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- Pure Lead, Maintenance-Free Battery



- Powder-Coated for extra durability
- Completely Self-Contained
- Fully Automatic Operation
- Glare-Free, Adjustable Round Heads
- Ceiling or Wall Mount
- Mounting Hardware Included

City of New York Unit - For Standard Units, See Page F4

Cat. No.	Battery Voltage	No. of Heads	Total Capacity	Lamp Wattage Per Head
NYELX-2	6V	2	18W	9W
NYELX-3	12V	3	27W	9W
NYELX-4	12V	3 (Capable of 4th Head)	50W	12W



 CITY OF NEW YORK APPROVED STEEL LED EXIT SIGN 8" LETTERS

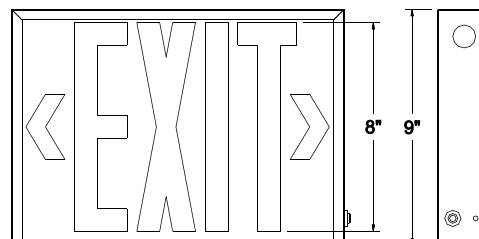NYESL
NYESBL

- Rugged 20GA Steel Construction
- 120/277 VAC
- 25 years LED Lamp Life
- Single/Double Face
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light

- Fully Automatic Operation
- LED Energy Saving Technology
- Red 8" Tall Letters
- Universal K.O. Chevrons
- Side, Top, or Back Mount
- Mounting Hardware Included

City of New York Unit - For Standard Steel Exit Sign, See Page F5

Cat. No.	Description
NYESL	AC Only
NYESBL	NAC/DC with Battery Back-Up




City of New York Approved Products

CITY OF NEW YORK APPROVED EDGE-LIT RECESSED LED EXIT SIGN 8" LETTERS



NYESRE

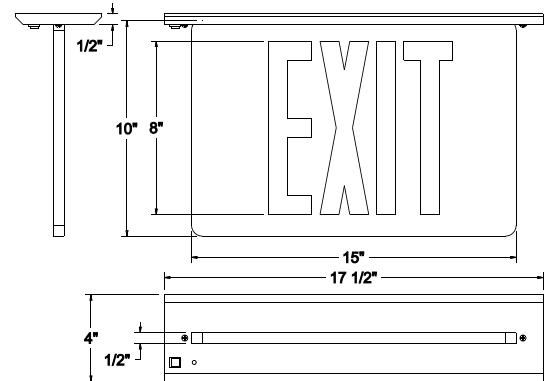

- 120/277 VAC
- 3W for AC Only (AC), 5W for Battery Backup (EB)
- Ultra Bright LEDs
- AC On Indicator Light and Test Switch (EB units)
- Automatic, Low Voltage Disconnect (LVD)
- Sealed Lead Battery (EB units)

- Recessed-Mount
- UV Stabilized Ultra Clear Acrylic Panel
- Red 8" Tall Letters
- Infield installable directional arrows
- Mylar Insert for Double-Face Unit
- Mounting Bar Hanger Included

City of New York Unit - For Standard Model, See Page F9


Cat. No.	Casing Finish	No. of Face	Operation
NYESRE	A (Anodized Alum.)	1 (Single)	EB (Battery Back-up)
	W (White)	2 (Double)	AC (AC only)



CITY OF NEW YORK APPROVED EDGE-LIT SURFACE LED EXIT SIGN 8" LETTERS



NYESSE

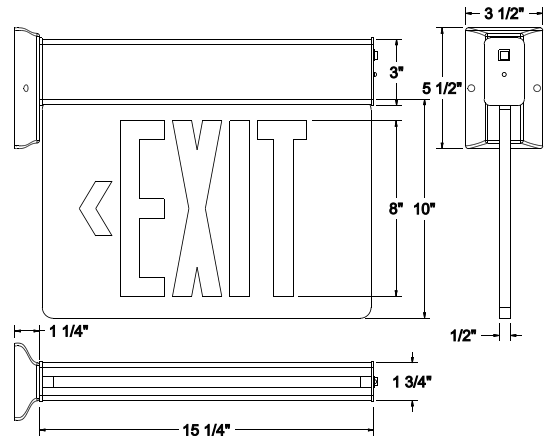

- 120/277 VAC
- 3W for AC Only (AC), 5W for Battery Backup (EB)
- Ultra Bright LEDs
- AC On Indicator Light and Test Switch (EB units)
- Automatic, Low Voltage Disconnect (LVD)
- Sealed Lead Battery (EB units)

- Surface Mount (Wall, Ceiling, or Side)
- Premium Grade Extruded Aluminum Housing
- UV Stabilized Ultra Clear Acrylic Panel
- Red 8" Tall Letters
- Infield installable directional arrows
- Mylar Insert for Double-Face Unit
- Tri-Mount Canopy Included

City of New York Unit - For Standard Model, See Page F9

Cat. No.	Casing Finish	No. of Face	Operation
NYESSE	A (Anodized Alum.)	1 (Single)	EB (Battery Back-up)
	W (White)	2 (Double)	AC (AC only)







**CITY OF NEW YORK APPROVED
CAST ALUMINUM LED EXIT SIGN
8" LETTERS**



NYESLA

- 120/277 VAC
- Built-in Self-Diagnostic Test (SDT)
- 25 years LED Lamp Life
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light (EB units)
- Ni-Cad Back-up Battery (EB units)

- Specification Grade
- Fully Automatic Operation
- Curved Design
- Red 8" Tall Letters
- Side, Top, or Back Mount
- Universal Mounting Canopy Included

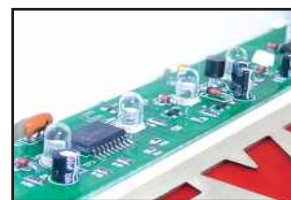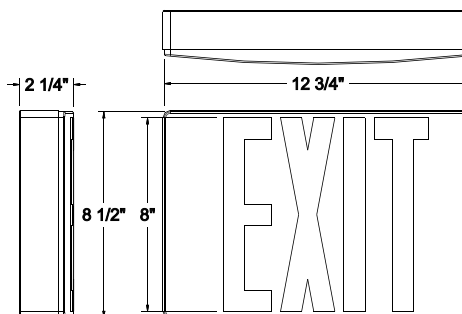

Built-in Self Diagnostic/Self Test
feature offers the ultimate worry-free
maintenance & reliability


City of New York Unit - For Standard Model, See Page F7

Cat. No.	Operation
NYESLA	EB (Battery Back-up) AC (AC only)



**CITY OF NEW YORK APPROVED
STEEL COMBINATION UNIT
8" LETTERS**

NYEECL

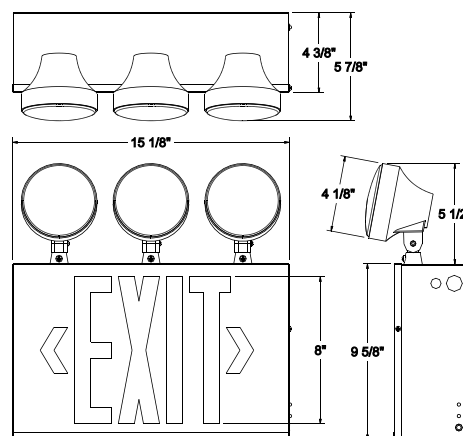

- Rugged 20GA Steel Construction
- 120/277 VAC
- 5W T5 Wedge base Emergency Lamps
- 90 Minutes Emergency Operation
- 25 years LED Lamp Life
- Push to Test Switch
- Automatic, Low Voltage Disconnect (LVD)
- Charge Rate/Power on LED Indicator Light
- Ni-Cad Back-up Battery

- Glare-Free 180° Rotatable Round Heads
- Fully Automatic Operation
- LED Energy Saving Technology
- Red 8" Tall Letters
- 3 Standard Heads - 12W per Head
- Universal K.O. Chevrons
- Top or Back Mount
- Mounting Hardware Included

Cat. No.
NYEECL



Shields and Wire Guards


SHIELDS



PCS-R



PCS-D

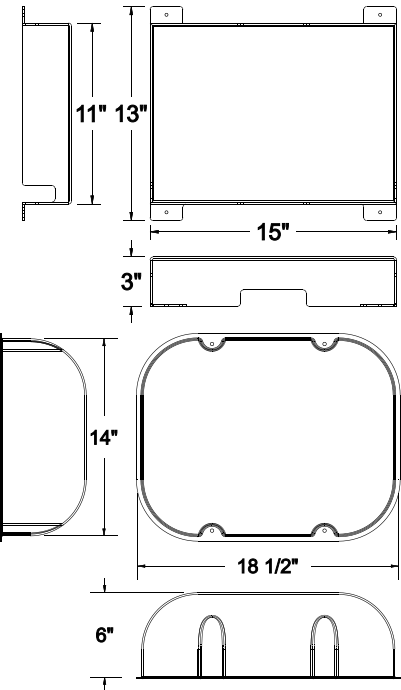

Cat. No.	Description
PCS-R	Polycarbonate Vandal/Environmental Rectangular Shield
PCS-D	Polycarbonate Vandal/Environmental Dome Shield


WIRE GUARDS



WG-15



WG-30

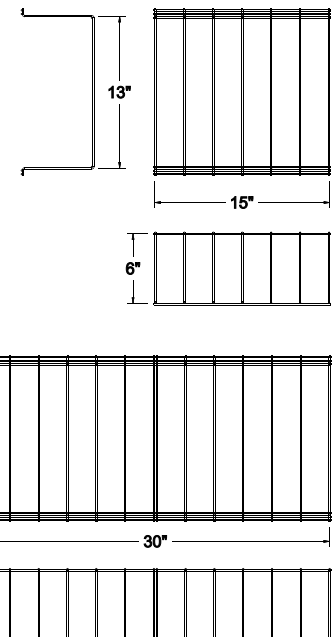


Cat. No.	Description
WG-15	15" Wire Guard
WG-30	30" Wire Guard


FLUORESCENT EMERGENCY LIGHTING BALLASTS




BAL650C

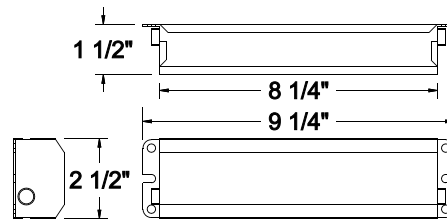


BAL500

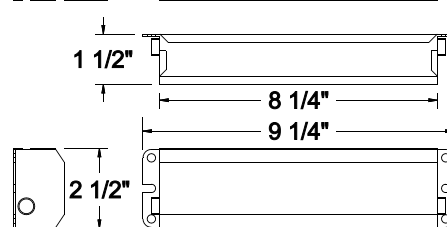


BAL700

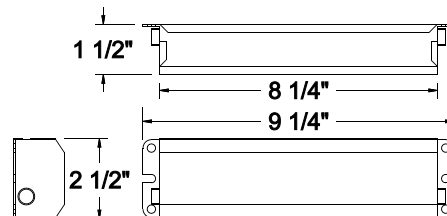

BAL1400

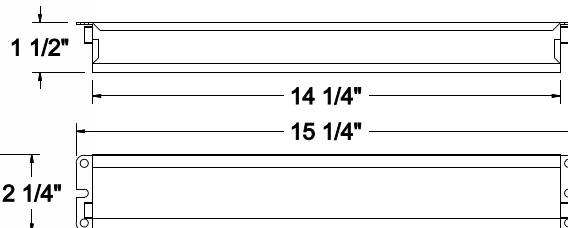

BAL3000

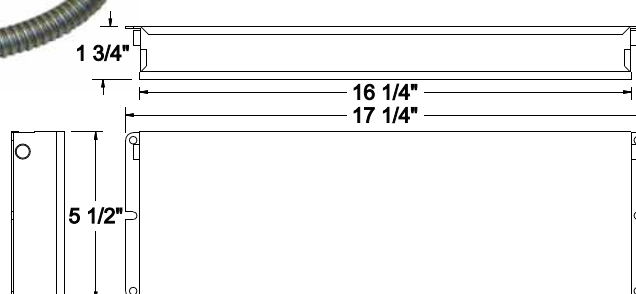
 
 
 
 





 




- 120/277 VAC, Fully Automatic Operation
- 280mA Charging current
- 24Hr Recharging Time
- 90 minutes of emergency operation
- Wireway or Fixture Mount
- Battery, Charger, Invertor Circuit in a Single Package



Emergency Lighting Ballasts

FLUORESCENT EMERGENCY LIGHTING BALLASTS LAMP COMPATIBILITY CHART

Cat. No.	Description	
BAL650C-2PIN	For 2-Pin Compact Fluorescent Lamp Operates One 13W - 42W or Two 13W - 39W Twin, Quad Lamps	 
BAL650C-4PIN	For 4-Pin Compact Fluorescent Lamp Operates One 13W - 42W or Two 13W - 39W Twin, Quad, Triple-Twin, Long Compact or 2D Lamps	 
BAL500	Operates One 17W - 40W (2' - 4') T8, T10, or T12 Lamp	 
BAL700	Operates One 17W - 215W (2' - 8'), or Two 17W - 40W (2' - 4') T8, T9, T10, or T12 Lamps	 
BAL1400	Operates One 17W - 215W (2' - 8'), or Two 17W - 40W (2' - 4') T8, T9, T10, or T12 Lamps	 
BAL3000	Operates One of: F025, FB024 T8, F032, FB031 T8, F096 T8, F017, FB016, F40T12, F40/U, F48T12/HO, F96T12, HO, VHO Or Two of: F025, FB024 T8, F032, FB031 T8, F017, FB016, F40T12, F40/U	  

Cat. No.	Lumens	Battery	Power
BAL650C	300 ~ 750	3.6V	14.4 Wh
BAL500	350 ~ 450	2.4V	9.6 Wh
BAL700	600 ~ 700	3.6V	14.4 Wh
BAL1400	1100 ~ 1400	6.0V	24.4 Wh
BAL3000	1450 ~ 3500	14.4V	40.0 Wh




Under Cabinet Lights


UNDER CABINET LIGHTS




UCL-12

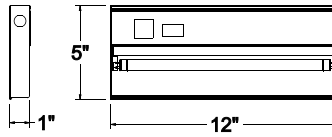


UCL-21

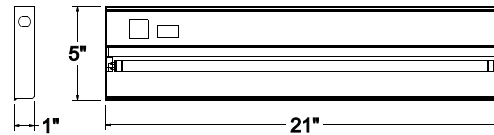


UCL-24

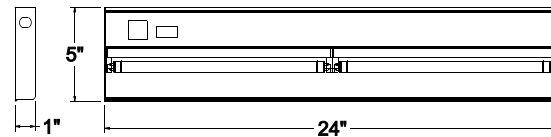

UCL-33

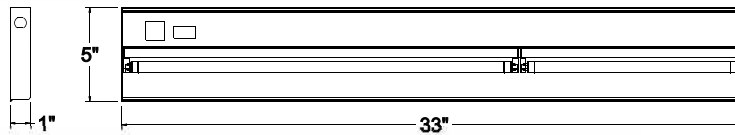

UCL-42

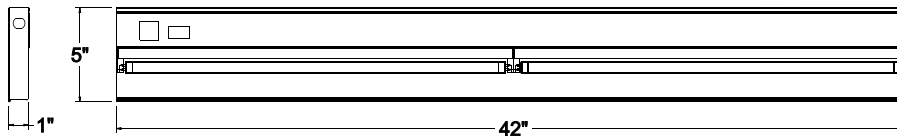

- 120~125 VAC
- T5 Fluorescent Lamp
- Electronic Class P Ballast
- Turn Switch Included
- Heavy Gage Steel with Flush Ends
- K.O.s on Top, Sides, and Back
- Baked white enamel
- With Rust Inhibiting Phosphate Coat

Cat. No.	Description	Lamps (Included)
UCL-12	12" Under Cabinet Electronic Ballast	One 8W T5
UCL-21	21" Under Cabinet Electronic Ballast	One 13W T5
UCL-24	24" Under Cabinet Electronic Ballast	Two 8W T5
UCL-33	33" Under Cabinet Electronic Ballast	One 8W T5 & One 12W T5
UCL-42	42" Under Cabinet Electronic Ballast	Two 13W T5



Replacements Batteries and Lamps

F21

REPLACEMENT BATTERIES & LAMPS



EB-6



EB-48



EIB-5



EHB-5

Cat. No.	Description	For Use With
EB-6	6V, 4.5Ah Lead Calcium Replacement Battery	All Orbit Emergency Lights & Combination Units
EB-48	4.8V, 650mAh Ni-Cad Replacement Battery	All Orbit Exit Signs Excluding Combination Units

Cat. No.	Description	For Use With
EIB-5	6V, 5W Wedge-Base Incandescent Lamp	All Orbit Wedge-Based Incandescent Units
EHB-5	6V, 5W MR16 Halogen Lamp	EL2H, ESBL2H

LED RETROFIT KITS



LRK-HW



LRK-SI

- 120 VAC
- 2.8W per Kit (Set of Two LED Base)
- Mounting Bracket and Double-Sided Tape included (LRK-HW)
- Socket Adapters (Bayonet, Intermediate or Candelabra) Included (LRK-SI)

Cat. No.	Description
LRK-HW-R	Hard-Wire Red LED Retrofit Kit
LRK-HW-G	Hard-Wire Green LED Retrofit Kit
LRK-SI-R	Screw-In Red LED Retrofit Kit
LRK-SI-G	Screw-In Green LED Retrofit Kit



REMOTE HEAD LAMPS



RH16-1





RH16-2

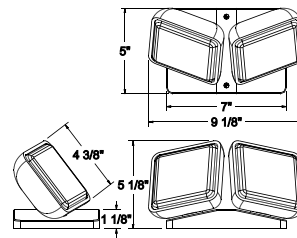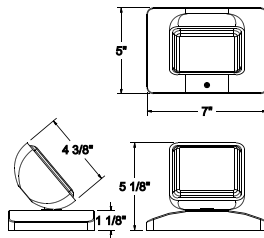

RHT5-1





RHT5-2

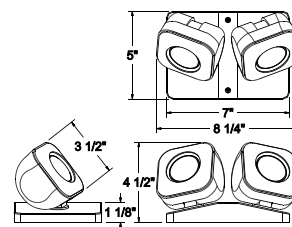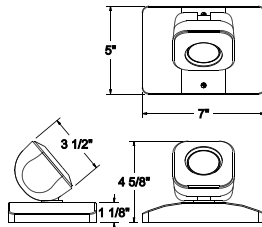

RH36-1





RH36-2

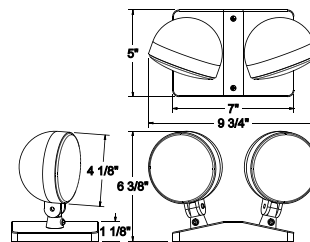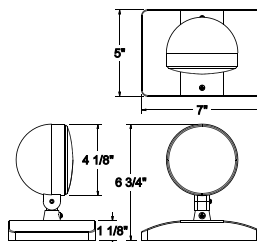

RH36WP-1



RH36WP-2

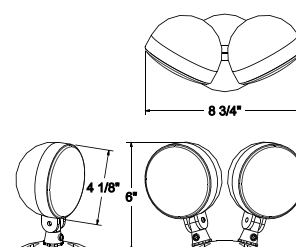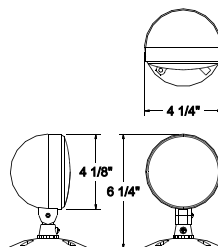

Cat. No.	No. of Heads	Voltage	Wattage
RH16 (MR16 Remote Head)	1 (One)	6 (6V)	5 (5W)
	2 (Two)		
RHT5 (T5 Wedge Lamp Remote Head)	1 (One)	6 (6V)	5 (5W)
	2 (Two)		9 (9W)
	1 (One)	12 (12V)	7.2 (7.2W)
	2 (Two)		12 (12W)
RH36 (PAR36 Remote Head)	1 (One)	6 (6V)	5 (5W)
	2 (Two)		9 (9W)
	1 (One)	12 (12V)	7.2 (7.2W)
	2 (Two)		12 (12W)
RH36WP (PAR36 Weatherproof Remote Head)	1 (One)	6 (6V)	7.2 (7.2W)
	2 (Two)		

