

Structural/Beam

HAMMER-ON BEAM FLANGE CLIP

- Zinc-plated spring steel
- Std. Pkg: 50



ITEM	FLANGE	LOAD (LBS)	PRICE EACH
BCX	3/32" - 9/64"	160	\$0.55
BCX18	1/8" - 1/4"	200	\$0.57
BCX516	5/16" - 1/2"		\$0.58
BCX916	9/16" - 3/4"		\$0.59

HAMMER-ON BEAM FLANGE CLAMP

- Black spring steel
- Std. Pkg: 100



ITEM	FLANGE	HOLE THREAD	PRICE EACH
BC18	1/8" to 1/4"	1/4-20	\$0.69
BC516	5/16" to 1/2"		\$0.79
BC916	9/16" to 3/4"		\$1.09



HAMMER-ON BEAM FLANGE CLAMP WITH 1/4-20 STUD

- Galvanized steel
- Std. Pkg: 100



ITEM	FLANGE	HOLE THREAD	PRICE EACH
BC18ST	1/8" to 1/4"	1/4-20	\$0.79
BC516ST	5/16" to 1/2"		\$0.99
BC916ST	9/16" to 3/4"		\$1.29



IRON BEAM CLAMPS

- Zinc-plated iron
- Back & bottom threaded holes



ITEM	JAW OPENING	HOLE THREAD	LOAD (LBS)	STD. PKG.	PRICE EACH
MBC-1024	7/8"	10-24	375	100	\$1.49
MBC-1420	7/8"	1/4-20	450	50	\$0.74
MBC-3816	1-1/8"	3/8-16	1300	25	\$2.69
MBC-1213	1-3/8"	1/2-13	1700	10	\$4.99



Structural/Beam

WIDE-MOUTH IRON BEAM CLAMPS

- Zinc-plated iron
- Back/bottom threaded holes



ITEM	HOLE	LOAD (LBS)	STD. PKG.	PRICE EACH
MBC-1420WM	1/4-20	450	50	\$7.99
MBC-3816WM	3/8-16	1300	25	\$9.99
MBC-1213WM	1/2-13	1700	10	\$12.99



**HUGE
3-1/8" JAW
OPENING!**

SLIM-BODY IRON BEAM CLAMP

- Zinc-plated iron
- Back/bottom threaded holes
- Std. Pkg: 50



ITEM	JAW OPENING	HOLE	LOAD (LBS)	PRICE EACH
MBC-3816EV	13/16"	3/8-16	900	\$2.69



HEAVY-DUTY IRON BEAM CLAMP

- Zinc-plated iron
- Back/bottom threaded holes
- Std. Pkg: 10




ITEM	JAW OPENING	HOLE	LOAD (LBS)	PRICE EACH
MBC-1213XL	31/32"	1/2-13	1700	\$7.99



**HEAVY-DUTY
BODY!**

STAINLESS STEEL STAMPED BEAM CLAMPS

- Back/bottom threaded holes
- 316 Stainless steel

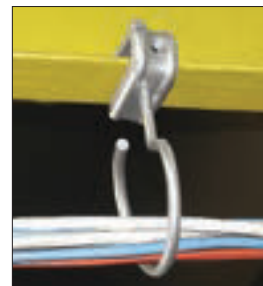


ITEM	JAW SIZE	HOLES BACK & BOTTOM	LOAD (LBS)	STD. PKG.	PRICE EACH
BC-1420-SS	0.59"	1/4-20	150	100	\$5.99
BC-3816-SS	15/16"	3/8-16	200	25	\$9.99



Structural/Beam

STEEL BEAM CLAMPS

- Back/bottom threaded holes
- Zinc-plated steel

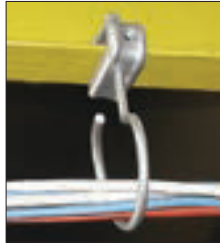

ITEM	JAW SIZE	HOLES BACK & BOTTOM	LOAD (LBS)	STD. PKG.	PRICE EACH
BC-1024	0.59"	10-24	100	100	\$1.19
BC-1420	0.59"	1/4-20	100	100	\$0.79
BC-3816	15/16"	3/8-16	200	25	\$2.49



SPRING-STEEL BEAM CLAMP - LIGHT DUTY

- Back/bottom threaded holes
- Black-oxide steel
- Std. Pkg: 100



ITEM	JAW SIZE	HOLES BACK & BOTTOM	PRICE EACH
BC1	3/4"	10-24 & 1/4-20 plus 3/8" hole	\$0.89



STAINLESS STEEL REVERSIBLE BEAM CLAMP

- Jam nut prevents vibratory loosening
- 304 Stainless steel
- Std. Pkg: 25



ITEM	JAW OPENING	HOLE THREAD	PRICE EACH
JFCS-3816SS	3/4"	3/8-16	\$10.99

STEEL REVERSIBLE BEAM CLAMP

- Jam nut prevents vibratory loosening
- Zinc-plated steel
- Std. Pkg: 25



ITEM	JAW OPENING	HOLE THREAD	PRICE EACH
JFCS-3816	3/4"	3/8-16	\$1.09



Structural/Beam

JUNIOR REVERSIBLE IRON BEAM CLAMPS

- Jam nut prevents vibratory loosening
- Zinc-plated



ITEM	HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
JFC-1420	1/4-20	3/4"	50	\$1.29
JFC-3816	3/8-16	3/4"	25	\$0.99
JFC-1213	1/2-13	3/4"	25	\$1.69
JFC-5811	5/8-11	7/8"	25	\$2.99



REVERSIBLE BLACK IRON BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
MFC-3816	3/8-16	1-1/4"	25	\$1.69
MFC-1213	1/2-13	1-1/4"	25	\$2.29
MFC-5811	5/8-11	1-3/8"	25	\$4.39
MFC-3410	3/4-10	1-3/8"	25	\$4.39



STAINLESS STEEL ROD-HANGER BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	BOTTOM HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
SCC-3816SS	3/8-16	3/4"	25	\$6.99
SCC-1213SS	1/2-13	3/4"	25	\$8.99
SCC-5811SS	5/8-11	3/4"	25	\$16.99
SCC-3410SS	3/4-10	3/4"	25	\$21.99

GALVANIZED STEEL ROD-HANGER BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	BOTTOM HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
SCC-3816	3/8-16	3/4"	25	\$2.39
SCC-1213	1/2-13	3/4"	25	\$2.79
SCC-5811	5/8-11	3/4"	25	\$5.49
SCC-3410	3/4-10	3/4"	25	\$5.99

Structural/Beam

BLACK STEEL ROD-HANGER BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	BOTTOM HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
SCC-3816BK	3/8-16	3/4"	25	\$2.19
SCC-1213BK	1/2-13	3/4"	25	\$1.49
SCC-5811BK	5/8-11	3/4"	25	\$3.99
SCC-3410BK	3/4-10	3/4"	25	\$5.69

GALVANIZED IRON ROD- HANGER BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	BOTTOM HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
MCC-3816	3/8-16	3/4"	25	\$2.09
MCC-1213	1/2-13	3/4"	25	\$2.39
MCC-5811	5/8-11	3/4"	25	\$5.69
MCC-3410	3/4-10	3/4"	25	\$4.79

BLACK IRON ROD-HANGER BEAM CLAMPS

- Jam nut prevents vibratory loosening



ITEM	BOTTOM HOLE THREAD	JAW OPENING	STD. PKG.	PRICE EACH
MCC-3816BK	3/8-16	3/4"	25	\$1.99
MCC-1213BK	1/2-13	3/4"	25	\$2.29
MCC-5811BK	5/8-11	3/4"	25	\$4.79
MCC-3410BK	3/4-10	3/4"	25	\$4.69

**NEED A SPECIAL PART?
CALL TODAY!**

Structural/Beam

"QUICK SHOT" ROD HANGERS

• Std. Pkg: 50



Full
Thread
Rod

Slick
Rod



Shoot into metal,
concrete and other
building materials.

THREADED ROD

ITEM	DROP ROD	OVERALL LENGTH	PRICE EACH
STF1424	1/4"-20	24"	\$2.89
STF1430	1/4"-20	30"	\$3.09
STF1436	1/4"-20	36"	\$3.39
STF1448	1/4"-20	48"	\$4.99

SLICK ROD

ITEM	THREAD SIZE	OVERALL LENGTH	PRICE EACH
STF0024	No thread, smooth rod 1/4" Dia.	24"	\$2.89
STF0030	No thread, smooth rod 1/4" Dia.	30"	\$2.99
STF0036	No thread, smooth rod 1/4" Dia.	36"	\$3.39

Call for Custom Lengths

"QUICK SHOT" THREADED-ROD COUPLER

• Std. Pkg: 50



ITEM	ROD COUPLER	OVERALL LENGTH	PRICE EACH
STF14	1/4"-20	6"	\$1.09

Structural/Beam

"QUICK-SCREW" THREADED-ROD COUPLER

- Coupler thread: 1/4"-20
- Overall length: 6"
- Std. Pkg: 50



Item: STF14NP

\$1.09 Each

BAR-JOIST WASHERS


- Std. Pkg: 50



ITEM	BOLT SIZE	PRICE EACH
23WBJ	1/4"	\$0.20
24WBJ	3/8"	\$0.20

"QUICK SHOT" THREADED HANGER CLIPS

- Std. Pkg: 100

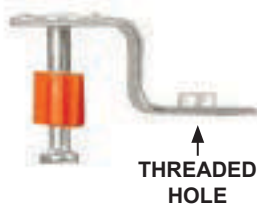

ITEM	THREADED HOLE	PRICE EACH
TRH-1420	1/4-20	\$0.65
TRH-3816	3/8-16	\$0.69

THREADED HANGER FOR WOOD

- Std. Pkg: 100



ITEM	HOLE THREAD	OVERALL LENGTH	PRICE EACH
SMY142W	1/4-20	2"	\$1.39
SMY382W	3/8-16	2-1/2"	\$1.39

THREADED HANGER FOR SHEET METAL

- Std. Pkg: 100



ITEM	HOLE THREAD	OVERALL LENGTH	PRICE EACH
SMY141S	1/4-20	1"	\$1.49
SMY381S	3/8-16	1"	\$1.49

Structural/Beam

THREADED ROD HANGERS FOR MASONRY/BRICK


- Zinc-plated steel
- Std. Pkg: 100



ITEM	HOLE THREAD	PRICE EACH
SMY141C	1/4-20	\$
SMY381C	3/8-16	\$

ROD ANGLE BRACKETS

- Zinc-plated steel

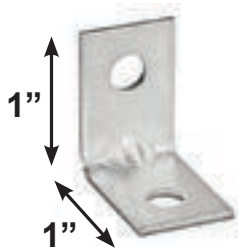

ITEM	FOR ROD SIZE	THRU HOLE SIZE		STD. PKG.	PRICE EACH
		Small	Large		
BA-1/4	1/4"	.250	.250	100	\$0.35
BAT-3/8	3/8"	.280"	.385"	100	\$0.39

Corner reinforcing rib prevents bending!

THREADED ROD HANGER/HAMMER-ON BEAM CLAMP ASSEMBLY

- Black-oxide steel



ITEM	FITS BEAM THICKNESS	ROD SIZE	STD. PKG.	PRICE EACH
R1814T	1/8" to 1/4"	1/4-20	100	\$1.09
R51614T	5/16" to 1/2"	1/4-20	100	\$1.09
R91614T	9/16" to 3/4"	1/4-20	100	\$1.29

WALL-MOUNT THREADED ROD HANGERS

- Black-oxide & zinc-plated steel



ITEM	THREADED HOLE	STD. PKG.	PRICE EACH
R014T	1/4-20	100	\$0.89
R038T	3/8-16	100	\$0.89

Structural/Beam

MULTI-FUNCTION CLIP FOR PLAIN OR THREADED ROD

- Black-oxide spring steel
- Std. Pkg: 50




ITEM	CONDUIT SIZE	PRICE EACH
APS	Attaches to #12 wire to 3/8" rod. Provides #10-24 & 1/4"-20 mounting holes.	\$0.39



Need It Guaranteed For Life?

WE'VE GOT STAINLESS

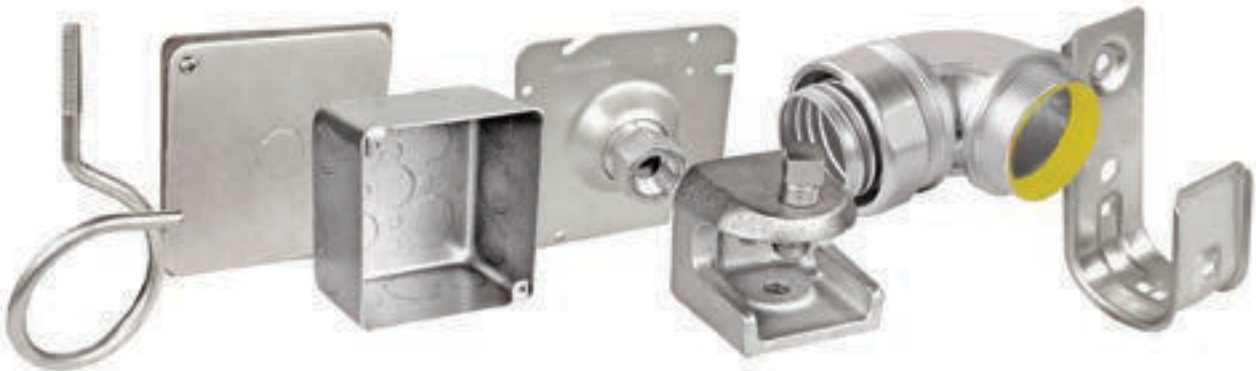

In Stock...Same Day Shipping!