



CAT6 PATCH CABLE

UNSHIELDED (BARE COPPER)

SKU: 094-SERIES

Conductor

Size	24AWG Stranded
Material	Bare Copper

Jacket

Material	Flame Retardant PVC
Diameter	5.8±0.2mm

Connectors


RJ45	8P/8C Gold Plated 50U"
------	------------------------

RoHS Compliant	Yes
Insulation Resistance	Min. 5000 MΩ Km
Conductor Resistance	Max. 9.38 Ω/100m

Approvals

UL cUL Listed, ETL / 3P Certified ANSI/TIA-568-C.2 Category 5e standards.

Available in many colors.

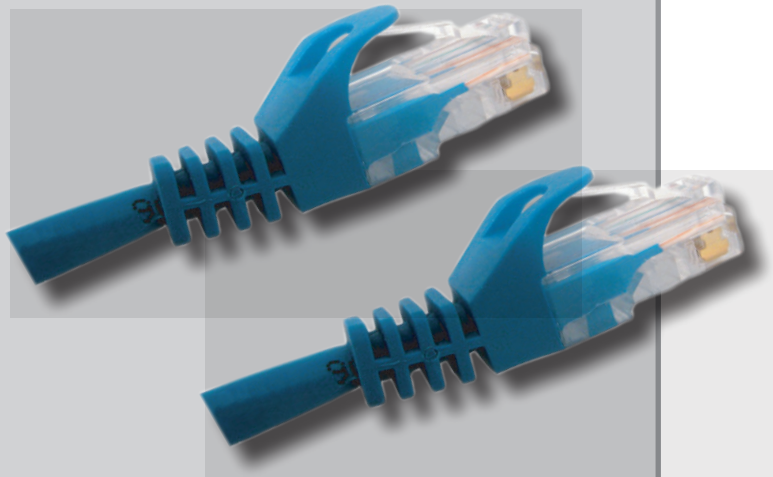

VERTICAL CABLE

951.696.7772 California

800.749.2447 Florida

845.391.8318 New York



www.verticalcable.com

Rev. 02/2014

Subject to change without notice.