



Turning Light into Savings ▶▶▶



SCM Slim Canopy DLC V4.0 Premium

28W, 42W, 45W, 59W, 70W

Our Slim canopy is DLC V4.0 listed and UL listed for wet locations with a rating of IP65.

Aesthetically pleasing construction, low-profile design with die-cast aluminum housing, shatter-resistant polycarbonate prismatic lens. Dustproof, sealed structure, multiple 1/2" conduit entrances on side. The Canopy supports pendant mounting and direct surface ceiling mounting.

Ideal applications for parking garage, walkway and entrance lighting etc.

Key Features & Benefits

- ▶ DesignLights Consortium Qualify V4.0 Premium
- ▶ Optional Microwave Motion Sensor
- ▶ Parking Garage Certified
- ▶ 0-10V dimmable with motion sensor option
- ▶ Default : Light dims to 30% when no motion is detected with motion sensor option
- ▶ Long Life LED chips
- ▶ Uniform and consistent color
- ▶ Excellent thermal design
- ▶ Aluminum & shatter-resistant polycarbonate lens
- ▶ Universal voltage 100-277V
- ▶ Working temperature : -4°F ~122°F
- ▶ 50,000 hrs rated average life

Applications

- ▶ Security Lighting
- ▶ Pathway Lighting
- ▶ Ceiling Lighting
- ▶ Parking Lighting

Color Choices



White



Black

Qualifications




Item Code	Description	Color Temp	Wattage	Lumen Output	Equivalent Wattage	Voltage (V)	Dimming	Beam Angle	Color	Sensor			
7468	LED-FXSCM28/40K/BK	4000K	28	3,236	150W	120-277	0-10V	160°	Black		●	●	●
7469	LED-FXSCM28/50K/BK	5000K	28	3,375	150W	120-277	0-10V	160°	Black		●	●	●
7470	LED-FXSCM42/40K/BK	4000K	42	4,871	175W	120-277	0-10V	160°	Black		●	●	●
7471	LED-FXSCM42/50K/BK	5000K	42	5,003	175W	120-277	0-10V	160°	Black		●	●	●
7472	LED-FXSCM59/40K/BK	4000K	59	6,800	250W	120-277	0-10V	160°	Black		●	●	●
7473	LED-FXSCM59/50K/BK	5000K	59	6,985	250W	120-277	0-10V	160°	Black		●	●	●
7495	LED-FXSCM28/40K/WH	4000K	28	3,236	150W	120-277	0-10V	160°	White		●	●	●
7496	LED-FXSCM28/50K/WH	5000K	28	3,375	150W	120-277	0-10V	160°	White		●	●	●
7497	LED-FXSCM42/40K/WH	4000K	42	4,871	175W	120-277	0-10V	160°	White		●	●	●
7498	LED-FXSCM42/50K/WH	5000K	42	5,003	175W	120-277	0-10V	160°	White		●	●	●
7499	LED-FXSCM59/40K/WH	4000K	59	6,800	250W	120-277	0-10V	160°	White		●	●	●
7500	LED-FXSCM59/50K/WH	5000K	59	6,985	250W	120-277	0-10V	160°	White		●	●	●


Microwave Motion Sensor Included

Item Code	Description	Color Temp	Wattage	Lumen Output	Equivalent Wattage	Voltage (V)	Dimming	Beam Angle	Beam Angle	Sensor			
7560	LED-FXSCM45/50K/BK-SEN	5000K	45	4,000	175W	120-277	--	140°	Black	●	●	●	●
7561	LED-FXSCM45/50K/WH-SEN	5000K	45	4,000	175W	120-277	--	140°	White	●	●	●	●
7489	LED-FXSCM28/40K/BK-SEN	4000K	28	3,236	150W	120-277	0-10V	160°	Black	●	●	●	●
7490	LED-FXSCM28/50K/BK-SEN	5000K	28	3,375	150W	120-277	0-10V	160°	Black	●	●	●	●
7491	LED-FXSCM42/40K/BK-SEN	4000K	42	4,871	175W	120-277	0-10V	160°	Black	●	●	●	●
7492	LED-FXSCM42/50K/BK-SEN	5000K	42	5,003	175W	120-277	0-10V	160°	Black	●	●	●	●
7493	LED-FXSCM59/40K/BK-SEN	4000K	59	6,800	250W	120-277	0-10V	160°	Black	●	●	●	●
7494	LED-FXSCM59/50K/BK-SEN	5000K	59	6,985	250W	120-277	0-10V	160°	Black	●	●	●	●
7564	LED-FXSCM70/50K/BK-SEN	5000K	70	5,900	250W	120-277	--	140°	Black	●	●	●	●
7565	LED-FXSCM70/50K/WH-SEN	5000K	70	5,900	250W	120-277	--	140°	White	●	●	●	●

► Dimensions

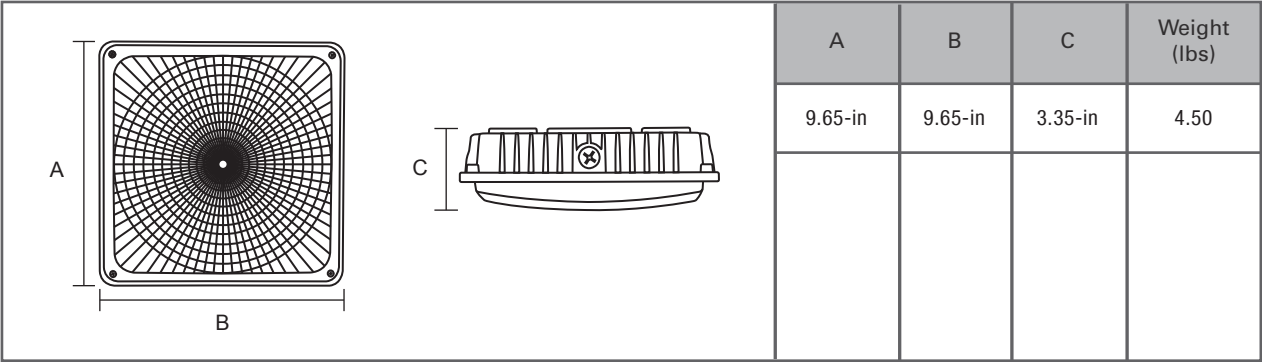

► Illuminance Distribution

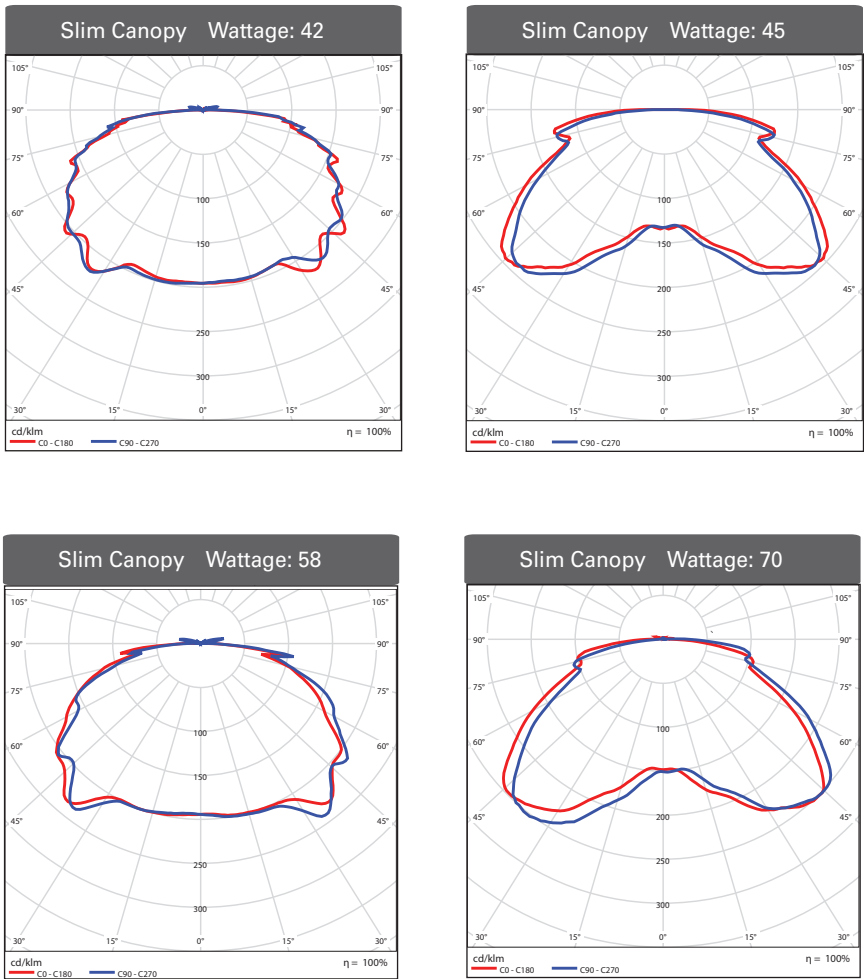

► Master Carton Package

