

Ram and Hand Pump Hydraulic Driver Kits

SLUG-BUSTER®



7646

- Fast, easy and simple to operate.
- Compact design for field use on construction sites and maintenance jobs.
- Punches 10 times faster than wrench method.
- Will also drive 751 Cable Cutter head.
- Can be used with all standard round, Slug-Buster® and Slug-Splitter® punch sizes.
- Can be used with non-round punches (adapter may be required).
- 3-foot hose.
- Powerful 11-ton hydraulic ram.


Cat. No.	UPC No.	Description	Weight	
			lbs.	kg.
7646	15906	Driver, hand pump, draw studs, adapter, spacers, Kwik Stepper® Step Bit and plastic case	20	9.1
7306SB	34360	Driver, hand pump, Slug-Buster® punches, dies and draw studs for 1/2" through 2" conduit, adapter, spacers, Kwik Stepper® Step Bit and plastic case	24	10.9
7310SB	34361	Driver, hand pump, Slug-Buster® punches, dies and draw studs for 1/2" through 2" and 2-1/2" through 4" standard conduit size punches, dies and draw studs, adapter, spacers, Kwik Stepper® Step Bit and steel case	54	24.5
7646PgSB	32799	Metric - Driver, Slug-Buster® Pg punches, dies and draw studs for 15.2 mm through 60.0 mm, adapter, spacers, Kwik Stepper® Step Bit and plastic case	24	10.9
38520	38520	Driver, hand pump, Slug-Buster® punches and draw studs for 1/2" through 3" and 4" conduit, adapter, spacers, Kwik Stepper® Step Bit and steel case	48	21.8

STEEL CAPACITIES FOR CONDUIT SIZES

Required Draw Stud and Accessories	Standard & Slug-Buster® Punches						Standard				Slug-Splitters®					
	1/2"	3/4"	1"	1-1/4"	1-1/2"	2"	2-1/2"	3"	3-1/2"	4"	1/2"	3/4"	1"	1-1/4"	1-1/2"	2"
3/4" Stud (03294), 3/8" Stud (30043) & Spacers																
3/4" Stud (03294), Long Spacer																
3/4" Stud (03294), Short Spacer																
3/4" Stud (03294)																
3/4" Stud (03294), & Sleeve (03170)																
7/16" Stud (29451)																
3/4" Stud (29452) & Spacer																

 10 GA. MILD STEEL

 10 GA. STAINLESS STEEL

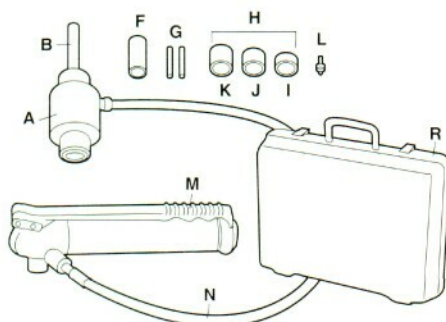

RAM AND HAND PUMP HYDRAULIC DRIVER PARTS IDENTIFICATION

Key	Cat./UPC No.	Description
A	746 / 17091	Ram (includes Item B)
B	2113AA / 03294	Draw Stud-3/4" x 5-3/8"
F	1557AA / 03170	Punch Sleeve
G	1614SS / 30043	Draw Stud-3/8" x 2-13/16"
H	15908	Spacer Group (includes Items I, J and K)
I	1924AA / 03248	Spacer-Short
J	1925AA / 03249	Spacer-Medium
K	1926AA / 06904	Spacer-Long
L	34410	Kwik Stepper® Step Bit 1/2"
M	767 / 13284	Hydraulic Hand Pump
N	06302 / 06302	High Pressure Hose-1/4" x 3'
R	30206	Plastic Case

Ram and Hand Pump Kits Parts List

	Cat. No.	UPC No.	Description	Hole Size						Kit Cat./UPC No.				
				Conduit & Pipe Size	Actual		Pg	ISO	7646/ 15906	7306SB/ 34360	7310SB/ 34361	7646PgSB/ 32799	38520	
					ø inch	ø mm								
Punches and Dies	721-1/2	31756	1/2" Conduit Size Slug-Buster® Punch	1/2"	7/8	0.885	22.5	16	-		1	1	1	1
	14722	14722	1/2" Conduit Size Die	1/2"	7/8	0.885	22.5	16	-		1	1	1	1
	721-3/4	31757	3/4" Conduit Size Slug-Buster® Punch	3/4"	-	1.115	28.3	21	-		1	1		1
	124AV	06972	3/4" Conduit Size Die	3/4"	-	1.115	28.3	21	-		1	1		1
	721-1	31758	1" Conduit Size Slug-Buster® Punch	1"	-	1.362	34.6	-	-		1	1		1
	126AV	04011	1" Conduit Size Die	1"	-	1.362	34.6	-	-		1	1		1
	721-1-1/4	31759	1-1/4" Conduit Size Slug-Buster® Punch	1-1/4"	1-11/16	1.701	43.2	-	-		1	1		1
	128AV	04013	1-1/4" Conduit Size Die	1-1/4"	1-11/16	1.701	43.2	-	-		1	1		1
	721-1-1/2	31760	1-1/2" Conduit Size Slug-Buster® Punch	1-1/2"	1-15/16	1.951	49.6	-	-		1	1		1
	440AV	04061	1-1/2" Conduit Size Die	1-1/2"	1-15/16	1.951	49.6	-	-		1	1		1
	721-2	31761	2" Conduit Size Slug-Buster® Punch	2"	2-3/8	2.416	61.5	-	-		1	1		1
	442AV	04063	2" Conduit Size Die	2"	2-3/8	2.416	61.5	-	-		1	1		1
	1429AV	04175	2-1/2" Conduit Size Punch	2-1/2"	2-7/8	2.914	74.0	-	-			1		1
	1430AV	04177	2-1/2" Conduit Size Die	2-1/2"	2-7/8	2.914	74.0	-	-			1		1
	1431AV	04180	3" Conduit Size Punch	3"	3-1/2	3.539	89.9	-	-			1		1
	1432AV	04183	3" Conduit Size Die	3"	3-1/2	3.539	89.9	-	-			1		1
	2982AV	04653	3-1/2" Conduit Size Punch	3-1/2"	4	4.044	102.7	-	-			1		
	2981AV	04652	3-1/2" Conduit Size Die	3-1/2"	4	4.044	102.7	-	-			1		
	2984AV	04655	4" Conduit Size Punch	4"	4-1/2	4.544	115.4	-	-			1		1
	2983AV	04654	4" Conduit Size Die	4"	4-1/2	4.544	115.4	-	-			1		1
	31969	31969	Slug-Buster® Punch	-	-	0.598	15.2	9	-				1	
	32002	32002	Die	-	-	0.598	15.2	9	-				1	
	31970	31970	Slug-Buster® Punch	-	-	0.732	18.6	11	-				1	
	32003	32003	Die	-	-	0.732	18.6	11	-				1	
	31971	31971	Slug-Buster® Punch	-	-	0.803	20.4	13	20				1	
	32004	32004	Die	-	-	0.803	20.4	13	20				1	
	31973	31973	Slug-Buster® Punch	3/4"	-	1.115	28.3	21	-				1	
	32006	32006	Die	3/4"	-	1.115	28.3	21	-				1	
	36284	36284	30.5 mm Slug-Buster® Punch	-	1-7/32	1.210	30.5	-	-				1	
	36279	36279	30.5 mm Die	-	1-7/32	1.210	30.5	-	-				1	
	31975	31975	Slug-Buster® Punch	-	-	1.457	37.0	29	-				1	
	32008	32008	Die	-	-	1.457	37.0	29	-				1	
	31976	31976	Slug-Buster® Punch	-	-	1.850	47.0	36	-				1	
	32009	32009	Die	-	-	1.850	47.0	36	-				1	
	31978	31978	Slug-Buster® Punch	-	-	2.362	60.0	48	-				1	
	32011	32011	Die	-	-	2.362	60.0	48	-				1	
Draw Studs and Misc.	746	17091	Ram (includes following item)							1	1	1	1	1
	2113AA	03294	- Draw Stud-3/4" x 5-3/8"							1	1	1	1	1
	1557AA	03170	Punch Sleeve							1	1	1	1	1
	1614SS	30043	Draw Stud-3/8" x 2-13/16"							2	2	2	2	2
	15908	15908	Spacer Group (includes 1 ea. of the following 3 items)											
	1924AA	03248	- Spacer-Short							1	1	1	1	1
	1925AA	03249	- Spacer-Medium							1	1	1	1	1
	1926AA	06904	- Spacer-Long							1	1	1	1	1
	34410	34410	Kwik Stepper® Step Bit 1/2"							1	1	1	1	1
	767	13284	Hydraulic Hand Pump							1	1	1	1	1
	06302	06302	High Pressure Hose-1/4" x 3'							1	1	1	1	
	30206	30206	Plastic Case							1	1		1	
	18402	18402	Steel Case									1		1
	25094	25094	Punch Tray									1		