


CADDY®

Fixings, Fasteners and Supports

Featured Products

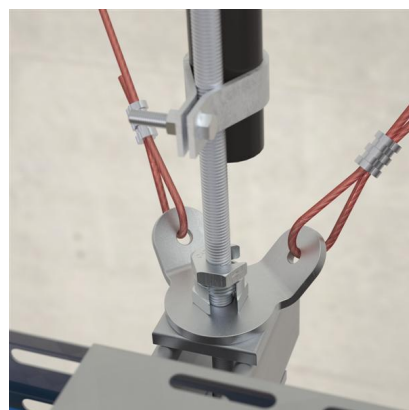

ERICO®

Cable Spool



- Cut to length as needed
- Pre-stretched restraint cable

Material: Steel

Finish: Pre-galvanized, Painted



Part Number	Article Number	Brace Size	Diameter	Cable Length	UL Listed Load	Color
CSB12CBL	402190	#12	2,4 mm	76,2 m	2.668 N	Red
CSB18CBL	402191	#18	3,2 mm	76,2 m	4.893 N	White
CSB36CBL	402192	#36	4,8 mm	76,2 m	12.455 N	Blue
CSB48CBL	402193	#48	6 mm	76,2 m	20.461 N	Yellow

Cable is powder coated.

Crimping Sleeve



- Creates secure loop ends
- Crimp with swaging tools

Material: Copper

Finish: Electro-galvanized



Part Number	Article Number	Brace Size
CSB12SLVB	402194	#12
CSB18SLVB	402195	#18
CSB36SLVB	402196	#36
CSB48SLVB	402197	#48

Two side-by-side crimps required on #12 and #18 cable. Three side-by-side crimps required on #36 and #48 cable.
Check crimp with gauge (not included).



Loop Attachment Kit



- Two-way bracing kit with crimp sleeves
- Wraps around structural steel members

Material: Steel



Part Number	Article Number	Brace Size	Brace Length	Cable Length	UL Listed Load	Color
CSB12B00L7	402230	#12	2,1 m	3,3 m	2.668 N	Red
CSB12B00L10	402232	#12	3,0 m	4,2 m	2.668 N	Red
CSB18B00L7	402231	#18	2,1 m	3,3 m	4.893 N	White
CSB18B00L10	402233	#18	3,0 m	4,2 m	4.893 N	White

Stake eyes not included.

No Pry Clip



- Eliminates prying effect on fasteners and anchors

Material: Steel

Finish: Electro-galvanized



Part Number	Article Number	Brace Size	Hole Size	UL Listed Load
CSBNPC12	402208	#12, #18, #36	14 mm	12.460 N

Stake Eye Kit



- Attaches to steel, wood or concrete structures
- Two-way bracing kit with crimp sleeves and stake eyes
- Swaged-on stake eye, pre-bent to 45 degrees

Material: Steel



Part Number	Article Number	Brace Size	Hole Size	Brace Length	Cable Length	UL Listed Load	Color
CSB12BD38L7	402218	#12	11 mm	2,1 m	3,3 m	2.668 N	Red
CSB12BD38L10	402221	#12	11 mm	3,0 m	4,2 m	2.668 N	Red
CSB12BD50L7	402224	#12	14 mm	2,1 m	3,3 m	2.668 N	Red
CSB12BD50L10	402227	#12	14 mm	3,0 m	4,2 m	2.668 N	Red
CSB18BD38L7	402219	#18	11 mm	2,1 m	3,3 m	4.893 N	White
CSB18BD38L10	402222	#18	11 mm	3,0 m	4,2 m	4.893 N	White
CSB18BD50L7	402225	#18	14 mm	2,1 m	3,3 m	4.893 N	White
CSB18BD50L10	402228	#18	14 mm	3,0 m	4,2 m	4.893 N	White
CSB36BD38L7	402220	#36	11 mm	2,1 m	3,3 m	12.455 N	Blue
CSB36BD38L10	402223	#36	11 mm	3,0 m	4,2 m	12.455 N	Blue
CSB36BD50L7	402226	#36	14 mm	2,1 m	3,3 m	12.455 N	Blue
CSB36BD50L10	402229	#36	14 mm	3,0 m	4,2 m	12.455 N	Blue

Kits contain copper sleeves.

Cable Cutter




- Designed to reduce cable fraying

Material: Steel

Part Number	Article Number	Brace Size
CSBC9	402211	#12, #18, #36, #48



Manual Swaging Tool

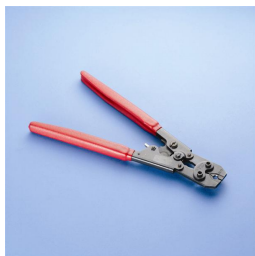

Material: Steel



Part Number	Article Number	Brace Size	Listings
CSB12SBHS	404461	#12	-
CSB48	402212	#48	UL




Multi-Size Manual Swaging Tool




Material: Steel

Part Number	Article Number	Brace Size
CSB3346SB	402209	#12, #18, #36

Universal Restraint Clip

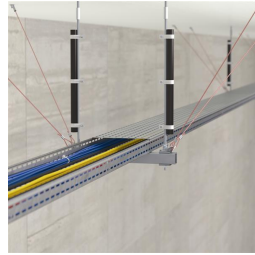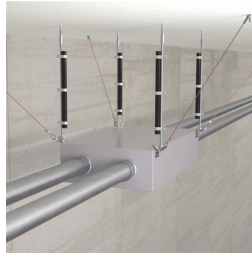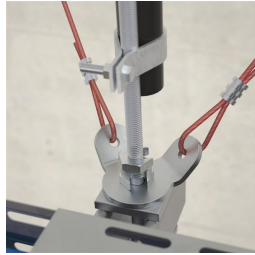

- Attaches cable brace to structure

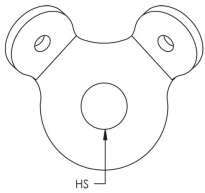

Material: Steel

Finish: Electro-galvanized




Part Number	Article Number	Brace Size	Hole Size HS	UL Listed Load
CSBURC38	402198	#12, #18, #36	11 mm	7.117 N
CSBURC12	402199	#12, #18, #36	14 mm	7.117 N
CSBURC58	402200	#12, #18, #36	17 mm	7.117 N
CSBURC4812	402204	#48	14 mm	20.460 N
CSBURC4858	402205	#48	17 mm	20.460 N
CSBURC4834	402206	#48	21 mm	20.460 N

Mount to the structure using the center hole. Loop cable through the holes in the bent tabs and crimp in place.
For #48 cable, use two clips stacked together.



Universal Restraint Clip, Retrofit

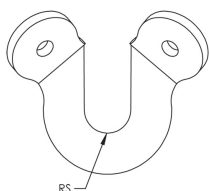

- Slotted design ideal for attaching to existing threaded rod on trapezes

Material: Steel

Finish: Electro-galvanized

Part Number	Article Number	Brace Size	Rod Size RS
CSBURCR38	402201	#12, #18	M10
CSBURCR12	402202	#12, #18	M12
CSBURCR58	402203	#12, #18	M16

One fastener required for #12 cable. Two stacked fasteners required for #18 cable.

UL is a registered certification mark of UL LLC.

WARNING

ERICO products shall be installed and used only as indicated in ERICO's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your ERICO customer service representative. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.

WARRANTY

ERICO products are warranted to be free from defects in material and workmanship at the time of shipment. NO OTHER WARRANTY, WHETHER EXPRESS OR IMPLIED (INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE), SHALL EXIST IN CONNECTION WITH THE SALE OR USE OF ANY ERICO PRODUCTS. Claims for errors, shortages, defects or nonconformities ascertainable upon inspection must be made in writing within 5 days after Buyer's receipt of products. All other claims must be made in writing to ERICO within 6 months from the date of shipment or transport. Products claimed to be nonconforming or defective must, upon ERICO's prior written approval in accordance with its standard terms and procedures governing returns, promptly be returned to ERICO for inspection. Claims not made as provided above and within the applicable time period will be barred. ERICO shall in no event be responsible if the products have not been stored or used in accordance with its specifications and recommended procedures. ERICO will, at its option, either repair or replace nonconforming or defective products for which it is responsible or return the purchase price to the Buyer. THE FOREGOING STATES BUYER'S EXCLUSIVE REMEDY FOR ANY BREACH OF ERICO WARRANTY AND FOR ANY CLAIM, WHETHER SOUNDING IN CONTRACT, TORT OR NEGLIGENCE, FOR LOSS OR INJURY CAUSED BY THE SALE OR USE OF ANY PRODUCT.

LIMITATION OF LIABILITY

ERICO excludes all liability except such liability that is directly attributable to the willful or gross negligence of ERICO's employees. Should ERICO be held liable its liability shall in no event exceed the total purchase price under the contract. ERICO SHALL IN NO EVENT BE RESPONSIBLE FOR ANY LOSS OF BUSINESS OR PROFITS, DOWNTIME OR DELAY, LABOR, REPAIR OR MATERIAL COSTS OR ANY SIMILAR OR DISSIMILAR CONSEQUENTIAL LOSS OR DAMAGE INCURRED BY BUYER.

Copyright © 2013 ERICO International Corporation. All rights reserved.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH, and LENTON are registered trademarks of ERICO International Corporation.