

Job Name/Title: _____ Catalog Number _____

Contractor: _____ Notes: _____

Rigid Conduit Bodies with Cover and Gasket

Threaded LB Type

Features

- Threaded LB type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

Applications

- Provides access to conductors for pulling, splicing and maintenance

Standard Material


- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

Standard Finish

- Powder coat



UL Standard: 514A
Fed. Spec. W-C-586D
NEMA FB 1

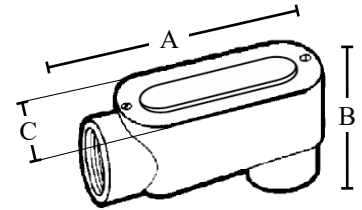

Catalog Number	UPC	Size	Wire Size		Unit Carton	Ship Case	Weight/Case	Inches		
			Max. Number	Max. Size				A	B	C
LB1CG	20841	1/2"	1	6 AWG	10	100	34	4.295	2.15	1.33
LB2CG	20851	3/4"	2	6 AWG	10	50	23	5.09	2.43	1.54
LB3CG	20861	1"	3	6 AWG	5	25	19	5.915	2.765	1.74
LB4CG	20871	1-1/4"	3	2 AWG	2	10	14	7.894	3.665	2.49
LB5CG	20881	1-1/2"	3	2 AWG	2	10	15	7.894	3.665	2.49
LB6CG	20891	2"	3	2/O AWG	1	5	14	10.134	4.275	3.10
LB7CG	20901	2-1/2"	3	2/O AWG	---	1	7	12.50	5.437	4.45
LB8CG	20911	3"	3	4/O AWG	---	1	7	12.50	5.675	4.45
LB9CG	20921	3-1/2"	3	500 MCM	---	1	10	15.50	6.922	5.50
LB10CG	20931	4"	3	500 MCM	---	1	10	15.50	6.922	5.50