



Enhancing
the Lighting
Experience

LED Color Preference Fixtures!

2017/2018
CATALOG

COMMERCIAL
INDUSTRIAL
RESIDENTIAL



Represented by
Phoenix Sales & Marketing, Inc.
www.myphoenixsales.com

Flushmounts



These luminaires can replace most fixture types in residential and commercial retail spaces and are ideal for hallways, corridors, utility spaces and work areas. Available in round or square in a variety of color temperatures, these fixtures are designed for most applications.

The addition of Color Preference™ technology to some items allows the installer to select the color temperature through a switch on the unit.

- Easy installation
- ENERGY STAR® 2.0 certified
- Rated life: 50,000 hours
- 5 year limited warranty
- ADA compliant
- Color Preference™ technology featured on select items
- Multi-volt, dimming, and step dimming motion sensor options available



12in. & 16in. Low Profile



I-Series Brushed Nickel



7in. Low Profile



Reva Stepped Lens

ETi LED Flushmounts

Model #	Part #	Description	Wattage	Lumens	CCT	Input Voltage	Case Pack
54436201	FM-12-14-827-MV-N-B	12" Round Low Profile - Non-Dimmable	14	980	2700	120-277	6
54436241	FM-12-14-840-MV-N-B	12" Round Low Profile - Non-Dimmable	14	1000	4000	120-277	6
54437201	FM-16-22-827-MV-N-B	16" Round Low Profile - Non-Dimmable	22	1500	2700	120-277	4
54437241	FM-16-22-840-MV-N-B	16" Round Low Profile - Non-Dimmable	22	1600	4000	120-277	4
54437261	FM-16-22-850-MV-N-B	16" Round Low Profile - Non-Dimmable	22	1600	5000	120-277	4
54663142	FM-7-11-840-SV-N-O	7" Round Low Profile - Non-Dimmable	11.5	810	4000	120	6
54663142	FM-11-14-840-SV-D-C	11" Round I-Series Brushed Nickel Trim - Dimmable	14	980	4000	120	4
54620142	FM-15-22-840-SV-D-C	15" Round I-Series Brushed Nickel Trim - Dimmable	22	1550	4000	120	3
54074343	FM-12-14-840-SV-D-E	12" Round Reva Stepped Lens - Dimmable	14	1000	4000	120	4
54075343	FM-16-22-840-SV-D-E	16" Round Reva Stepped Lens - Dimmable	22	1640	4000	120	3
54618244	FM-20-30-840-SV-D-E	20" Round Reva Stepped Lens - Dimmable	30	2200	4000	120	2
54614142	FM-24-40-840-SV-D-E	24" Round Reva Stepped Lens - Dimmable	40	2900	4000	120	2
54436511*	FM-12-16-902-MV-D-B	12" Round Color Preference™ Low Profile - 0-10V Dimmable (T24) Compatible with Step Dimming Motion Sensor accessory	16	1000	3000/4000/5000	120-277	6
54437511*	FM-16-24-902-MV-D-B	16" Round Color Preference™ Low Profile - 0-10V Dimmable (T24) Compatible with Step Dimming Motion Sensor accessory	24	1600	3000/4000/5000	120-277	4

* Available in Q4 2017



Recessed Downlights



Our offering of recessed downlight retrofits provides high quality replacements for traditional incandescent and halogen downlights reducing both energy consumption and maintenance. These products are great in both residential and commercial applications.

The addition of Color Preference™ technology to some items allows the installer to select the color temperature through a switch on the unit.

- 5 year limited warranty
- Rated life: 50,000 hours
- ENERGY STAR 2.0 certified
- IC Rated for direct contact with insulation
- ASTM Certified Airtight product available
- Color Preference™ technology featured on select items
- All 4" and 5"/6" are wet location rated for showers and exterior use
- Dimmable
- T24 qualified product available
- 80 and 90 CRI available



Color Preference™
Recessed Retrofit Downlight Kit



Recessed Retrofit
Downlight Kit



AC Power Recessed
Retrofit Downlight Kit



8in. High Output Downlight

ETi LED Recessed Downlights

Model #	Part #	Description	Wattage	Lumens	CCT	Input Voltage	Case Pack
53081141	DL-8-26-840-MV-D	8" High Output Downlight - 0-10V Dimmable	26	2025	4000	120-277	12
53185143	DL-4-10-902-SV-D	4" Color Preference™ Downlight - Dimmable (T24)	10	625	3000/4000/5000	120	4
53186143	DL-6-11-902-SV-D	5"/6" Color Preference™ Downlight - Dimmable (T24)	11	670	3000/4000/5000	120	4
53185142	DL-4-10-901-SV-D	4" Color Preference™ Downlight - Dimmable (T24)	10	625	2700/3000/4000	120	4
53186142	DL-6-11-901-SV-D	5"/6" Color Preference™ Downlight - Dimmable (T24)	11	670	2700/3000/4000	120	4
53186401*	DL-6-11-901-SV-D	5"/6" Color Preference™ Downlight - Dimmable (T24)	11	800	2700/3000/4000	120	4
53186311*	DL-6-11-902-SV-D	5"/6" Color Preference™ Downlight Kit - Dimmable (T24)	11	800	3000/4000/5000	120	4
53192211*	DL-6-14-902-MV-D	5"/6" Color Preference™ Downlight, 0-10V Dimmable (T24)	14	800	3000/4000/5000	120-277	4
53189111*	DL-8-40-902-MV-D	8"/10" Color Preference™ Downlight, 0-10V Dimmable (T24)	40	3000	3000/4000/5000	120-277	4
90600193*	DL-10TR	10" Downlight Trim	—	—	—	—	—
53181101	DL-4-10-927-SV-D	4" Recessed Retrofit Downlight Kit - Dimmable (T24)	10	625	2700	120	4
53167103	DL-6-10-927-SV-D	5"/6" Recessed Retrofit Downlight Kit - Dimmable (T24)	10.5	670	2700	120	4
53167141	DL-6-10-940-SV-D	5"/6" Recessed Retrofit Downlight Kit - Dimmable (T24)	10.5	670	4000	120	4
53179111	DL-6-18-930-SV-D	5"/6" Recessed Retrofit Downlight Kit - Dimmable (T24)	18	1300	3000	120	4
53182201*	DL-4-10-827-SV-D	4" AC Power Recessed Retrofit Downlight Kit - Dimmable	10.5	625	2700	120	4
53193101*	DL-6-11-827-SV-D	5"/6" AC Power Recessed Retrofit Downlight Kit - Dimmable	11	670	2700	120	4
53193141*	DL-6-11-840-SV-D	5"/6" AC Power Recessed Retrofit Downlight Kit - Dimmable	11	670	4000	120	4

* Available in Q4 2017



Spin Lights™



Our patented Spin Light™ is the easiest way to convert a plain lampholder into an attractive, energy efficient LED flushmount fixture. Installation is literally as easy as screwing in a light bulb. Without doing any wiring, you can replace exposed sockets and bare bulbs in basements, garages, closets and other areas with high quality LED lighting. This versatile product can also be used in new work applications with the provided hardware and adapter.

The addition of Color Preference™ technology to some items allows the installer to select the color temperature through a switch on the unit.

- Rated life: 50,000 hours
- ENERGY STAR 2.0 certified
- Passive infrared motion sensor (PIR) option available
- Damp location rated
- 5 year limited warranty
- Available in keyless or pull chain models
- Color Preference™ technology featured on select items

Patented Spin Lights™ install in seconds!



7in. Spin Light



7in. Spin Light with pull chain



11in. Spin Light

ETi LED Spin Lights™

Model #	Part #	Description	Wattage	Lumens	CCT	Input Voltage	Case Pack
54606211	SL-7-11-830-SV-N	7" Spin Light	11.5	810	3000	120	5
54606242	SL-7-11-840-SV-N	7" Spin Light	11.5	830	4000	120	5
54617141	SLP-7-11-840-SV-N	7" Spin Light - Pull Chain	11.5	830	4000	120	5
54652141	SL-11-22-840-SV-N	11" Spin Light	22	1600	4000	120	4
54690112	SL-7-11-802-SV-N	7" Color Preference™ Spin Light	11.5	810	3000/4000/5000	120	5
54606342*	SL-7-11-840-SV-N-OS	7" Spin Light with PIR Motion Sensor	11.5	830	4000	120	5
54652144**	SL-11-22-840-SV-N-BN	11" Spin Light Brushed Nickel	22	1600	4000	120	4



* Available in Q4 2017 ** Available in Q1 2018

A UNIQUE APPROACH. EXTRAORDINARY RESULTS.



ETi Solid State Lighting, Inc. provides the latest in LED lighting technology for today's extremely competitive and fast-paced marketplace.

Our North American headquarters in Vernon Hills, IL, represents a formidable global organization. ETi Solid State

Lighting, Inc., a wholly owned subsidiary of Elec-Tech Solid State Lighting (HK) Ltd., offers a growing line of products that includes LED tubes, a broad range of LED fixtures, LED downlights, and portable LED lights. With Jadestone managed funds holding 100% interest in Elec-Tech Solid State Lighting (HK) Ltd., the company is well-positioned for future growth, building on its established manufacturing capabilities, end-user driven product innovation, global management team, and robust customer base.



CONTACT US

1.855.384.7754

ETiSSL.com

ETi Solid State Lighting, Inc.
720 Corporate Woods Parkway
Vernon Hills, IL 60061
Fax: 847.383.6256

ETi Solid State Lighting, Inc. is a wholly owned subsidiary of Elec-Tech Solid State Lighting (HK) Ltd.




**SOLID STATE
LIGHTING INC.**

FOR MORE INFORMATION,
VISIT ETiSSL.com

TO ORDER:

www.ETiSSL.com/contact-us/

Call: 1.855.ETi.SSLI (1.855.384.7754)

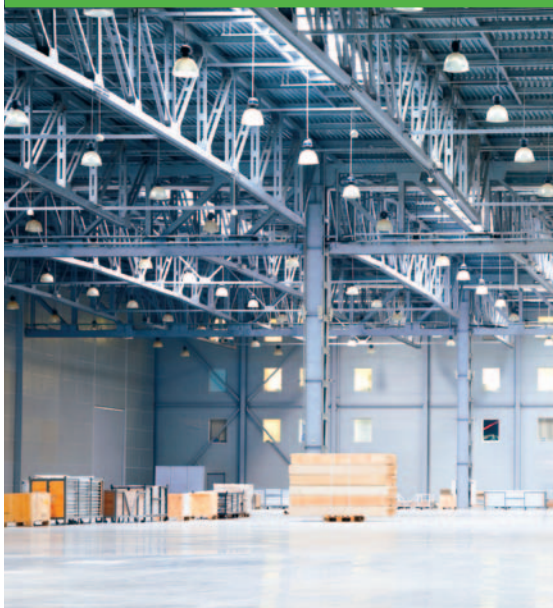

Standard shipping turnaround time is 24 to 48 hours

Midwest and West coast shipping locations

Customer Service Hours: 8:00AM – 5:00PM CST

(1.855.384.7754) 855.ETi.SSLI

Fax: 847.383.6256