



Turning Light into Savings ▶▶▶



Emergency
Battery Back Up
Available



TF

2'x2' / 2'x4' Troffer

20W, 30W, 38W, 49W, 50W

Our naturaLED Troffer is the perfect solution for your interior lighting needs. The troffers come in 2x2 and 2x4 for TBar/Grid ceilings and are designed for easy installation and maximum energy savings. The Mounting can fit for both 1" and 9/16" T-bar grids.

All troffers are available in DLC 4.0 Premium and up to 6900 lumens with excellent consistent color.

Key Features & Benefits

- ▶ DLC 4.0 Premium
- ▶ Lightweight for easy installation
- ▶ Available in 2'x2' and 2'x4' configurations
- ▶ Uniform and consistent color
- ▶ Excellent thermal design
- ▶ Long life LED chips
- ▶ Cold-Rolled Steel
- ▶ 0-10V dimming
- ▶ Powerfactor >0.9
- ▶ CRI: 80
- ▶ 120-277V
- ▶ Operating Temperature: (-4°F ~104°F)
- ▶ 50,000 hrs rated average life

Applications

- ▶ Conference/ Meeting Rooms
- ▶ Factories/ Offices
- ▶ Schools/ Universities
- ▶ Hospitals
- ▶ Hotels

Color Choices



White

Qualifications



Item Code	Description	Color Temp	Wattage	Lumen Output	Equivalent Wattage	Voltage (V)	Dimming	Rated Hours	Size		
2'x2' Fixture											
7034	LED-FXTF20/2x2/835	3500K	19.5	2,600	60-70	120-277	0-10V	50,000	2'x2'		
7035	LED-FXTF20/2x2/840	4000K	19.5	2,600	60-70	120-277	0-10V	50,000	2'x2'		
7036	LED-FXTF20/2x2/850	5000K	19.5	2,600	60-70	120-277	0-10V	50,000	2'x2'		

2'x4' Fixture


7037	LED-FXTF30/2x4/835	3500K	30	3,900	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7038	LED-FXTF30/2x4/840	4000K	30	3,900	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7039	LED-FXTF30/2x4/850	5000K	30	3,900	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7040	LED-FXTF49/2x4/835	3500K	49.5	6,760	120-130 (4 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7041	LED-FXTF49/2x4/840	4000K	49.5	6,760	120-130 (4 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7042	LED-FXTF49/2x4/850	5000K	49.5	6,760	120-130 (4 lamp fixture)	120-277	0-10V	50,000	2'x4'		

Item Code	Description	Color Temp	Wattage	Lumen Output	Equivalent Wattage	Voltage (V)	Dimming	Rated Hours	Size		
2'x2' Fixture											
7150	LED-FXTF38/2X2/835	3500K	38	3,545	60-70	120-277	0-10V	50,000	2'x2'		
7151	LED-FXTF38/2X2/840	4000K	38	3,545	60-70	120-277	0-10V	50,000	2'x2'		
7152	LED-FXTF38/2X2/850	5000K	38	3,545	60-70	120-277	0-10V	50,000	2'x2'		




2'x4' Fixture

7183	LED-FXTF50/2X4/835	3500K	50	4,953	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7184	LED-FXTF50/2X4/840	4000K	50	4,953	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		
7185	LED-FXTF50/2X4/850	5000K	50	4,953	90-100 (3 lamp fixture)	120-277	0-10V	50,000	2'x4'		

► Dimensions

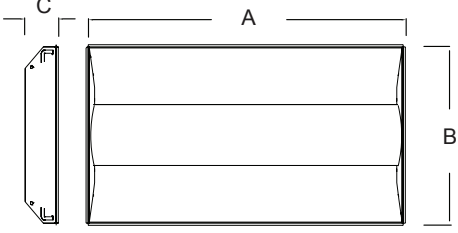	Wattage	A	B	C	Weight (lbs)
	2'x2'	23.75-in	23.75-in	4.50-in	7.95
	2'x4'	48.00-in	23.75-in	4.50-in	9.95

► Illuminance Distribution

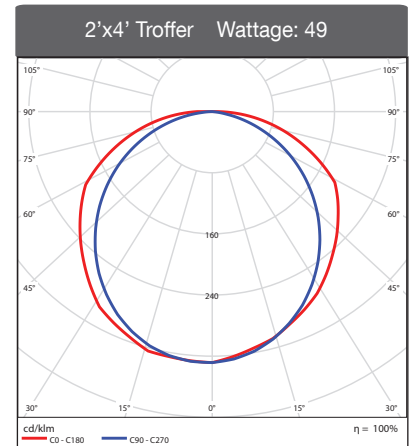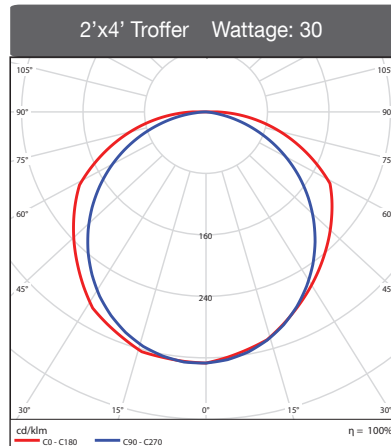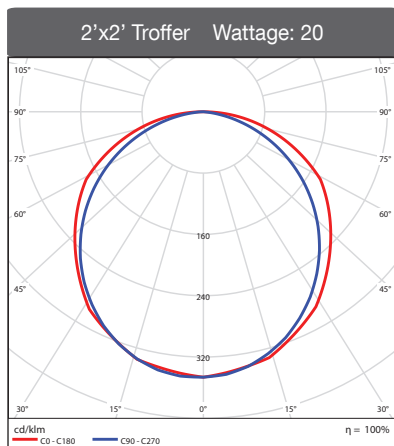

► Master Carton Package

