





TRULUX™ Single Color Tape Light


Trulux offers four different grades of light output and multiple color temperatures so you can pick the best combination for your project/installation. Light output ranges from 100Lm – 570Lm per foot and color temperatures include 2400K, 2700K, 3000K, and 4000K, all with 94+ CRI, optimal for creating inviting spaces.

Standard Grade [pg. 14-15](#)

High Output [pg. 16-17](#)

High Output Max [pg. 18-19](#)

Spec Grade [pg. 20-21](#)

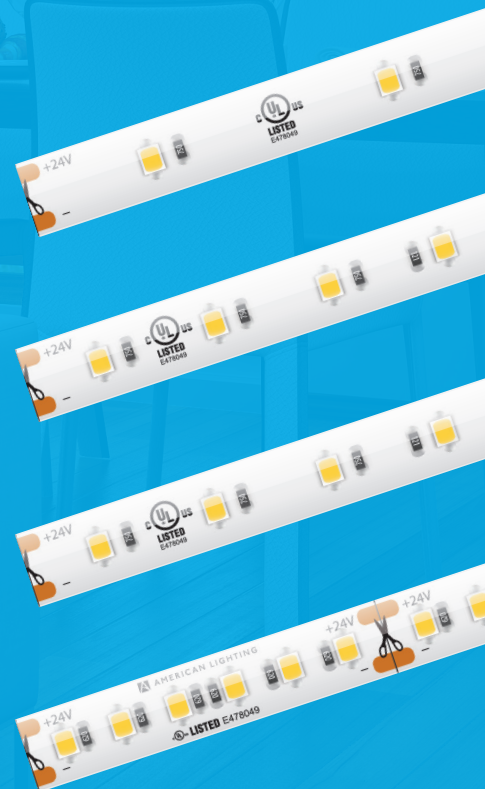




Features

- Excellent color rendering (96+ CRI)
- Color temperatures from 2400K to 4000K
- 100-155 lumens per foot performance
- Consumes only 2.7 watts per foot
- Dimmable with ELV dimmers
- Cuttable every 6.56" (24V) and 3.94" (12V)
- 32.8 ft (24V) / 27 ft (12V) max run
- (IP54) unjacketed or (IP65) jacketed versions
- 50,000 hours rated life

 Available CCT



Control Options

- Trulux Single Color Controls
 - Requires LED-DR Driver + Trulux Receiver
- Primary Side Dimming
 - Requires Standard Dimmer + ELV Driver or LP-DR Driver

Listing / Ratings




TRULUX™ Standard Grade - 24V / 12V

Build an economical and versatile layered lighting system with Standard Trulux Tape Light with light output ranging from 140-155 lumens per foot and easy to work with run lengths up to 32.8 feet. Single color Trulux controller + receiver combo include wall controls in touch or dial versions; also pair with the Trulux App for even greater control freedom.

Technical Information

Series	STL
Input Voltage	24V / 12V (STL-WW-100-12V only)
CCT	2400K / 2700K / 3000K / 4000K
CRI	96+
Wattage	2.7W per ft
Lumens	Up to 155Lm per ft
Max Run	32.8 feet (24V) / 27 feet (12V)
Cuttable	Every 6.56" (24V) / 3.94" (12V)
IP Rating	IP54 (unjacketed) / IP65 (jacketed)
Dimmable	5-100%
Rating	cULus Listed
Rated Life	50,000 hrs

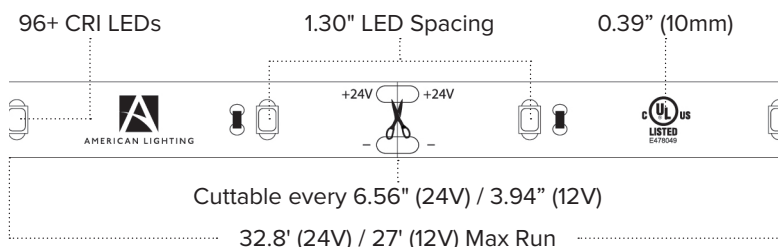



2400K Deluxe Warm White	2700K Ultra Warm White	3000K Warm White	4000K White
2.7W per ft / up to 140Lm per ft	2.7W per ft / up to 146Lm per ft	2.7W per ft / up to 150Lm per ft	2.7W per ft / up to 155Lm per ft
16.4ft & 32.8ft Reels			

	STL-UWX (16.4' / 140Lm/ft) STL-UWX-33 (32.8' / 140Lm/ft)	STL-UWW (16.4' / 146Lm/ft) STL-UWW-33 (32.8' / 146Lm/ft)	STL-WW (16.4' / 150Lm/ft) STL-WW-33 (32.8' / 150Lm/ft)	STL-WH (16.4' / 155Lm/ft) STL-WH-33 (32.8' / 155Lm/ft)
--	---	---	---	---

	STL65-UWX (16.4' / 100Lm/ft)	STL65-UWW (16.4' / 105Lm/ft)	STL65-WW (16.4' / 115Lm/ft)	STL65-WH (16.4' / 125Lm/ft)
--	-------------------------------------	-------------------------------------	------------------------------------	------------------------------------

100ft Reels

	Unavailable	STL-UWW-100 (100' / 146Lm/ft)	STL-WW-100 (100' / 150Lm/ft)	Unavailable
--	-------------	--------------------------------------	-------------------------------------	-------------

	Unavailable	Unavailable	STL-WW-100-12V (100' / 150Lm/ft)	Unavailable
--	-------------	-------------	---	-------------

Custom Cut

	STL-UWX-CC (140Lm/ft)	STL-UWW-CC (146Lm/ft)	STL-WW-CC (150Lm/ft)	STL-WH-CC (155Lm/ft)
--	------------------------------	------------------------------	-----------------------------	-----------------------------

STL (IP54) 16.4ft Reels include: Attached 3ft lead wires / (3) TL-CONKIT / (3) Connector Blocks
 STL65 (IP65) 16.4ft Reels include: (1) Male (1) Female connector / (3) TL-CONKIT
 STL (IP54) 100ft Reels include: Attached 3ft lead wires / (5) TL-CONKIT / (5) Connector Blocks
 Custom Cut: Please allow up to 2-4 weeks for custom cut order processing and delivery


Building a Single Color Trulux System?

See pages (22-23) for compatible single color Trulux controllers


Trulux Single Color Accessories


Trulink 4-in-1 Connector Kit TL-CONKIT	Trulink 4-in-1 Connector Block TL-BLKS (Qty 10)	TL-2SPL Splice Connector TL-2L (L) Snap connector TL-2T (T) Snap connector TL-2X (X) Snap connector	Linking Cables (IP54) TL-2JUMP-5 (6") TL-2JUMP-1 (12") TL-2JUMP-2 (24")	DC Connector Snap to DC Jack TL-2DC	Linking Cables (IP65) TL-2JUMP65-5 (6") TL-2JUMP65-1 (12") TL-2JUMP65-2 (24")

Trulux Controller Set-up

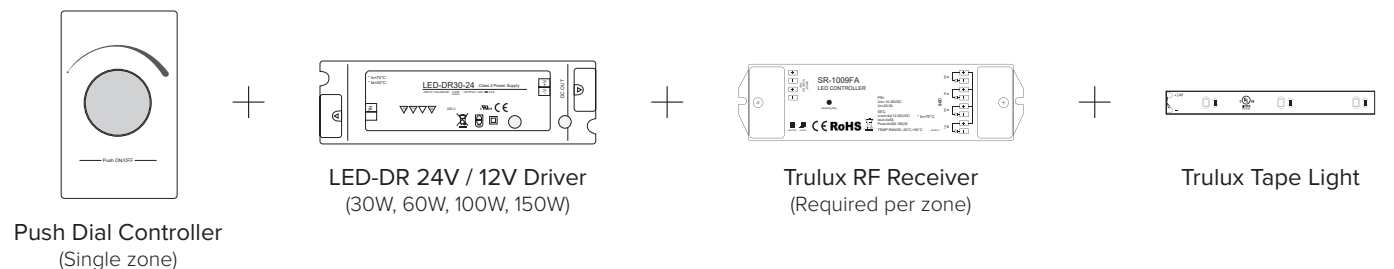

Primary Side Dimming Set-up

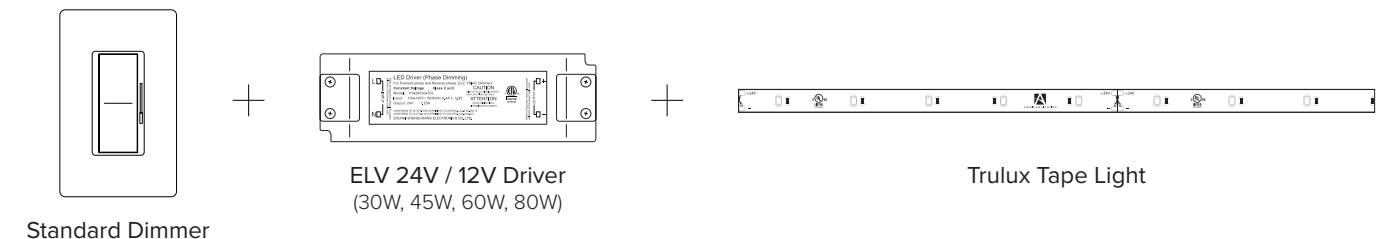


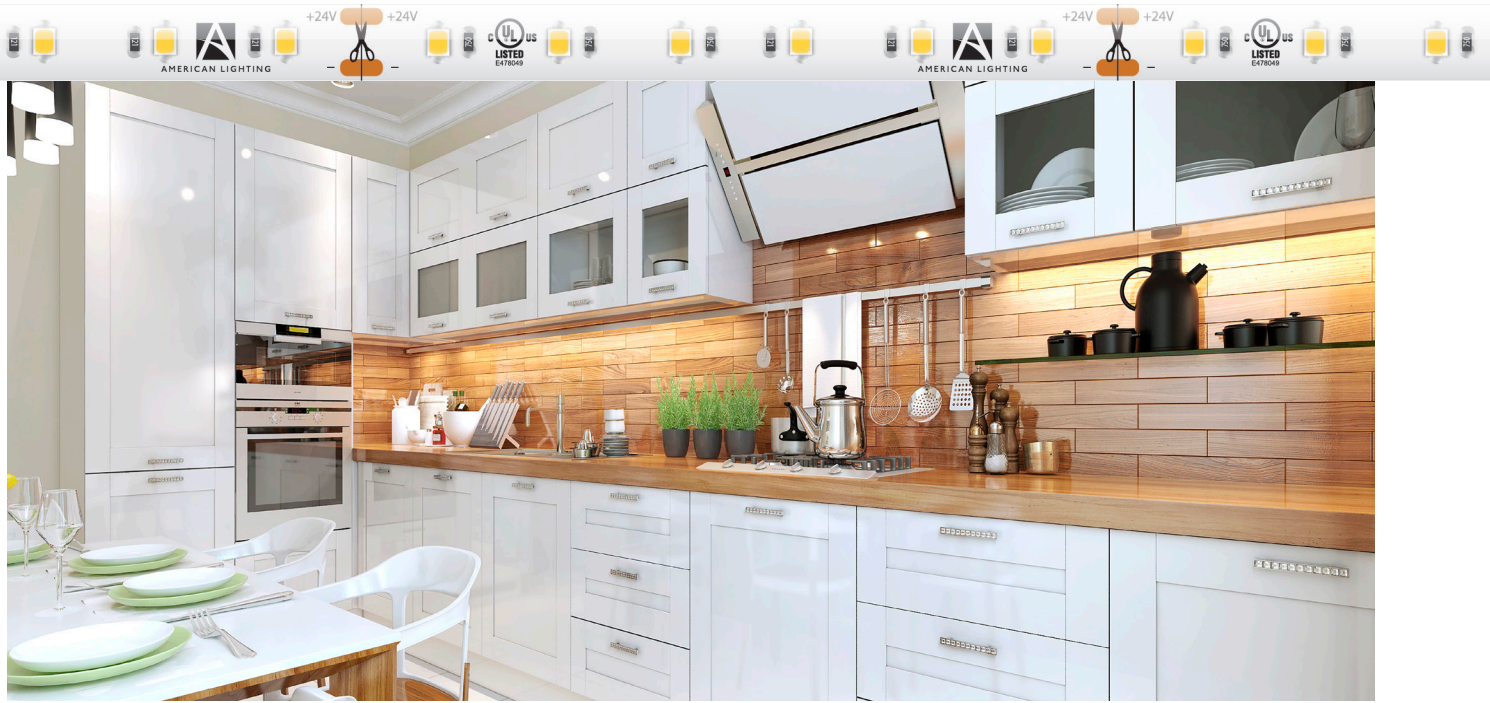

Features

- Excellent color rendering (96+ CRI)
- Color temperatures from 2400K to 4000K
- 200-310 lumens per foot performance
- Consumes only 4.6 watts per foot
- Dimmable with ELV dimmers
- Cuttable every 3.94"
- 22 foot max run
- (IP54) unjacketed or (IP65) jacketed versions
- 50,000 hours rated life

 Available CCT



Control Options

- Trulux Single Color Controls
 - Requires LED-DR Driver + Trulux Receiver
- Primary Side Dimming
 - Requires Standard Dimmer + ELV Driver or LP-DR Driver

Listing / Ratings




TRULUX™ High Output - 24V

Use High Output Trulux Tape Light and extrusions to build your own task lighting systems or custom linear lighting fixtures. Light output ranges from 200-310 lumens per foot in easy to work with run lengths up to 22 feet.

Technical Information

Series	HTL
Input Voltage	24V
CCT	2400K / 2700K / 3000K / 4000K
CRI	96+
Wattage	4.6W per ft
Lumens	Up to 310Lm per ft
Max Run	22 feet
Cuttable	Every 3.94"
IP Rating	IP54 (unjacketed) / IP65 (jacketed)
Dimmable	5-100%
Rating	cULus Listed
Rated Life	50,000 hrs

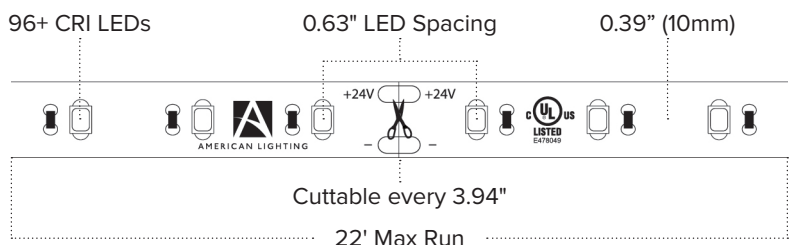



2400K Deluxe Warm White	2700K Ultra Warm White	3000K Warm White	4000K White
4.6W per ft / up to 285Lm per ft	4.6W per ft / up to 285Lm per ft	4.6W per ft / up to 300Lm per ft	4.6W per ft / up to 310Lm per ft

16.4ft Reels

	HTL-UWX (16.4' / 285Lm/ft)	HTL-UWW (16.4' / 285Lm/ft)	HTL-WW (16.4' / 300Lm/ft)	HTL-WH (16.4' / 310Lm/ft)
	Unavailable	HTL65-UWW (16.4' / 200Lm/ft)	HTL65-WW (16.4' / 220Lm/ft)	Unavailable

100ft Reels

	Unavailable	HTL-UWW-100 (100' / 285Lm/ft)	HTL-WW-100 (100' / 300Lm/ft)	Unavailable
--	-------------	--------------------------------------	-------------------------------------	-------------

Custom Cut

	HTL-UWX-CC (285Lm/ft)	HTL-UWW-CC (285Lm/ft)	HTL-WW-CC (300Lm/ft)	HTL-WH-CC (310Lm/ft)
--	------------------------------	------------------------------	-----------------------------	-----------------------------

HTL (IP54) 16.4ft Reels include: Attached 3ft lead wires / (3) TL-CONKIT / (3) Connector Blocks

HTL65 (IP65) 16.4ft Reels include: (1) Male + (1) Female connector / (3) TL-CONKIT

HTL (IP54) 100ft Reels include: Attached 3ft lead wires / (5) TL-CONKIT / (5) Connector Blocks

Custom Cut: Please allow up to 2-4 weeks for custom cut order processing and delivery

Building a Single Color Trulux System?

See pages (22-23) for compatible single color Trulux controllers

Trulux Single Color Accessories



Trulink 4-in-1
Connector Kit
TL-CONKIT



Trulink 4-in-1
Connector Block
TL-BLKS (Qty 10)



TL-2SPL Splice Connector
TL-2L (L) Snap connector
TL-2T (T) Snap connector
TL-2X (X) Snap connector



Linking Cables (IP54)
TL-2JUMP-5 (6")
TL-2JUMP-1 (12")
TL-2JUMP-2 (24")




DC Connector
Snap to DC Jack
TL-2DC




Linking Cables (IP65)
TL-2JUMP65-5 (6")
TL-2JUMP65-1 (12")
TL-2JUMP65-2 (24")

Trulux Controller Set-up

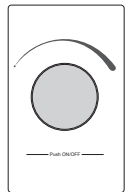

Push Dial Controller
(Single zone)

 +



LED-DR 24V Driver
(30W, 60W, 100W, 150W)

+




Trulux RF Receiver
(Required per zone)

+



Trulux Tape Light

Primary Side Dimming Set-up

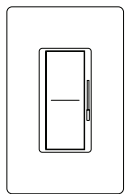

Standard Dimmer

+



ELV 24V Driver
(30W, 45W, 60W, 80W)

+



 
Trulux Tape Light



Features

- Excellent color rendering (90+ CRI)
- Color temperatures from 2700K to 4000K
- Up to 121 lumens per foot performance
- Consumes up to 1.46 watts per foot
- Dimmable with ELV dimmers
- Cuttable every 1.97"
- 65.6 foot max run
- (IP54) unjacketed
- 50,000 hours rated life

Available CCT



Control Options

- Trulux Single Color Controls
 - Requires LED-DR Driver + Trulux Receiver
- Primary Side Dimming
 - Requires Standard Dimmer + ELV Driver

Listing / Ratings




TRULUX™ High Output Max - 24V

For large scale projects, High Output Max (run) Tape provides a more convenient installation by minimizing drivers and connections. HTMR is a great tool for lighting coves, corridors, lobbies, and retail spaces with your choice of 2700K, 3000K, or 4000K white light.

Technical Information

Series	HTMR
Input Voltage	24V
CCT	2700K / 3000K / 4000K
CRI	90+
Wattage	Up to 1.46W per ft
Lumens	Up to 121Lm per ft
Max Run	65.6 feet
Cuttable	Every 1.97"
IP Rating	IP54 (unjacketed)
Dimmable	5-100%
Rating	cULus Listed
Rated Life	50,000 hrs

HTMR Series Tape Light is not compatible with LP-DR series drivers. Recommended use is with LED-DR series or ELV series drivers only.

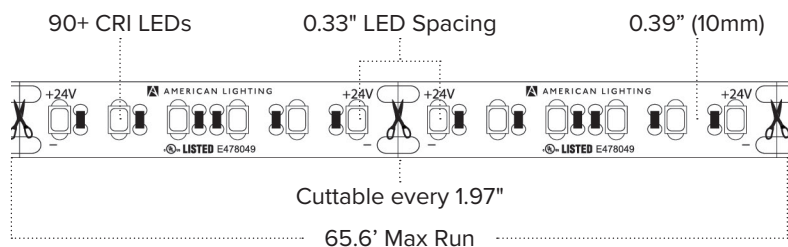



2700K
Ultra Warm White
1.46W per ft / 118Lm per ft

3000K
Warm White
1.46W per ft / 120Lm per ft

4000K
White
1.46W per ft / 121Lm per ft

65.6ft Reels



HTMR-UWW (65.6ft)

HTMR-WW (65.6ft)

HTMR-WH (65.6ft)

HTMR (IP54) 65.6ft Reels include: Attached 3ft lead wires / (3) TL-CONKIT, and (3) connector blocks

Building a Single Color Trulux System?

See pages (22-23) for compatible single color Trulux controllers

Trulux Single Color Accessories



Trulink 4-in-1
Connector Kit
TL-CONKIT



Trulink 4-in-1
Connector Block
TL-BLKS (Qty 10)



TL-2SPL Splice Connector
TL-2L (L) Snap connector
TL-2T (T) Snap connector
TL-2X (X) Snap connector



Linking Cables (IP54)
TL-2JUMP-.5 (6")
TL-2JUMP-1 (12")
TL-2JUMP-2 (24")




DC Connector
Snap to DC Jack
TL-2DC




Linking Cables (IP65)
TL-2JUMP65-.5 (6")
TL-2JUMP65-1 (12")
TL-2JUMP65-2 (24")

Trulux Controller Set-up

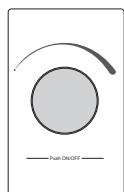

Push Dial Controller
(Single zone)

 

LED-DR 24V Driver
(30W, 60W, 100W, 150W)




Trulux RF Receiver
(Required per zone)




Trulux Tape Light

Trulux 4 Zone Controller Set-up

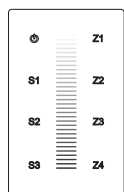


Touch Slide Controller
(4 zone)

 

LED-DR 24V Driver
(30W, 60W, 100W, 150W)




Trulux RF Receiver
(Required per zone)

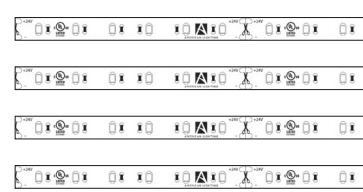

Trulux Tape Light

Primary Side Dimming Set-up

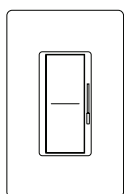

Standard Dimmer



ELV 24V Driver
(30W, 45W, 60W, 80W)



 
Trulux Tape Light



Features

- Excellent color rendering (96+ CRI)
- Color temperatures from 2400K to 4000K
- 280-570 lumens per foot performance
- Consumes only 7.8 watts per foot
- Dimmable with ELV dimmers
- Cuttable every 1.97"
- 13.1 foot max run
- (IP54) unjacketed or (IP65) jacketed versions
- 50,000 hours rated life

Available CCT



Control Options

- Trulux Single Color Controls
- Requires LED-DR Driver + Trulux Receiver
- Primary Side Dimming
- Requires Standard Dimmer + ELV Driver or LP-DR Driver

Listing / Ratings




TRULUX™ Spec Grade - 24V

At full brightness our Spec Grade Trulux Tape Light offers up to 570 lumens per foot and perfect for both task and ambient lighting when dimmed with our Trulux controls. The superior light output is best used in large open spaces in both residential and commercial applications.

Technical Information

Series	SPTL
Input Voltage	24V
CCT	2400K / 2700K / 3000K / 4000K
CRI	96+
Wattage	7.8W per ft
Lumens	Up to 570Lm per ft
Max Run	13.1 feet
Cuttable	Every 1.97"
IP Rating	IP54 (unjacketed) / IP65 (jacketed)
Dimmable	5-100%
Rating	cULus Listed
Rated Life	50,000 hrs

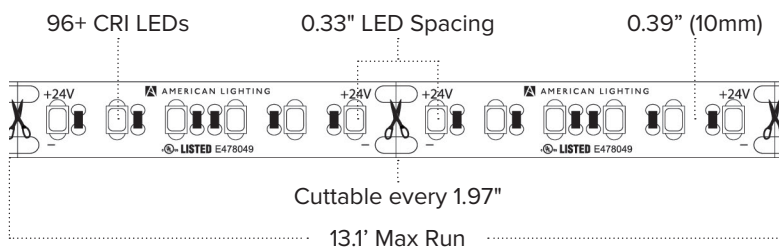

**2400K****Deluxe Warm White**

7.8W per ft / up to 480Lm per ft

2700K**Ultra Warm White**

7.8W per ft / up to 485Lm per ft

3000K**Warm White**

7.8W per ft / up to 525Lm per ft

4000K**White**

7.8W per ft / up to 570Lm per ft

13.1ft Reels

**SPTL-UWX-13** (13.1' / 480Lm/ft)**SPTL-UWW-13** (13.1' / 485Lm/ft)**SPTL-WW-13** (13.1' / 525Lm/ft)**SPTL-WH-13** (13.1' / 570Lm/ft)**SPTL65-UWX-13** (13.1' / 280Lm/ft)**SPTL65-UWW-13** (13.1' / 290Lm/ft)**SPTL65-WW-13** (13.1' / 310Lm/ft)**SPTL65-WH-13** (13.1' / 320Lm/ft)

Custom Cut

**SPTL-UWX-CC** (480Lm/ft)**SPTL-UWW-CC** (485Lm/ft)**SPTL-WW-CC** (525Lm/ft)**SPTL-WH-CC** (570Lm/ft)

SPTL (IP54) 13.1ft Reels include: Attached 3ft lead wires / (3) TL-CONKIT / (3) Connector Blocks

SPTL65 (IP65) 13.1ft Reels include: (1) Male + (1) Female connectors / (3) TL-CONKIT

SPTL (IP54) 100ft Reels include: Attached 3ft lead wires / (5) TL-CONKIT / (5) Connector Blocks

Custom Cut: Please allow up to 2-4 weeks for custom cut order processing and delivery


Building a Single Color Trulux System?

See pages (22-23) for compatible single color Trulux controllers


Trulux Single Color Accessories

**Trulink 4-in-1
Connector Kit
TL-CONKIT****Trulink 4-in-1
Connector Block
TL-BLKS** (Qty 10)**TL-2SPL** Splice Connector
TL-2L (L) Snap connector
TL-2T (T) Snap connector
TL-2X (X) Snap connector**Linking Cables (IP54)**
TL-2JUMP-5 (6")
TL-2JUMP-1 (12")
TL-2JUMP-2 (24")**DC Connector
Snap to DC Jack
TL-2DC****Linking Cables (IP65)**
TL-2JUMP65-5 (6")
TL-2JUMP65-1 (12")
TL-2JUMP65-2 (24")

Trulux Controller Set-up

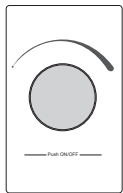**Push Dial Controller**
(Single zone)**LED-DR 24V Driver**
(30W, 60W, 100W, 150W)**Trulux RF Receiver**
(Required per zone)**Trulux Tape Light**

Primary Side Dimming Set-up

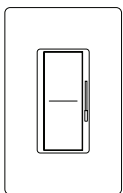**Standard Dimmer****ELV 24V Driver**
(30W, 45W, 60W, 80W)**Trulux Tape Light**

TRULUX™ Single Color Controllers


1-100% full range dimming via dial or touch slide wall controls let you have full control over your Trulux system. Featuring ultra responsive touch controls and quality construction that will stand the test of time. No flickering, no signal wiring, and no input wiring; Simply mount to the wall and sync with Trulux receivers.



SRF-BATT

Trulux Push Dial Wall Control
(Single Color / Single Zone)


- Push dial On/Off control dimmer
- Full range dimming (1-100%)
- Glass faceplate with satin nickel dial
- Wireless installation - No power wire
- Pair multiple receivers to a single control
- RF signal (up to 65 feet)
- Battery powered (CR2032)
- Requires Trulux receiver for install

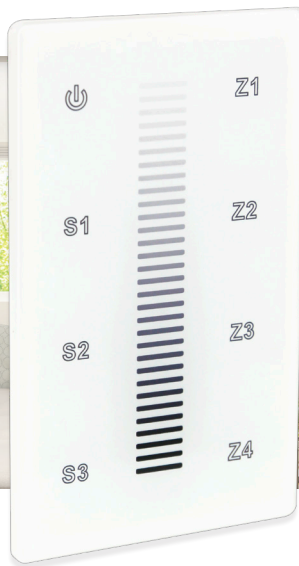

SRF-4Z-3P

Trulux Touch Slide Wall Control
(Single Color / 4 Zones / 3 Scenes)

- Touch On/Off control
- Touch slide control provides full range dimming (1-100%)
- Glass faceplate with back-lit buttons
- 3 programmable scenes
- 4 dedicated zone selection
- Pair multiple receivers to a single control
- RF signal (up to 65 feet)
- Requires 12V-24V DC input power wire and Trulux receiver for install

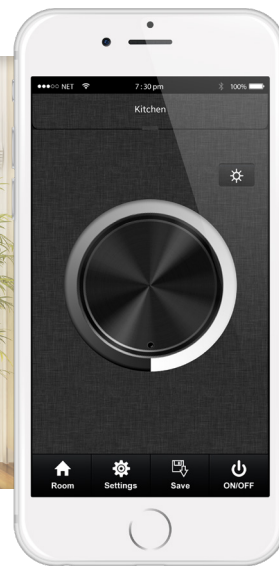

TRULUX MOBILE APP


Multi Zone Trulux Controller
(Multi Color / Multi Room or Zones)

- Mobile Phone or Tablet App ready
- Interactive dial controls
- Set up to 8 dedicated rooms or zones
- Create and save custom settings
- Control Single Color, Tunable CCT, and RGB/RGB+WW installations
- Use in addition to any Trulux controllers or as a standalone system
- Requires TruHub (RF-WIFI-8) router and receivers for 2 to 8 zone installations; or the RF to Wifi receiver (REC-5A-4Z-WIFI) for single zone applications


Available on Google Play & App Store:



Trulux Controller Set-up

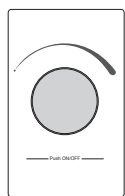

Push Dial Controller
(Single zone)

 

LED-DR 24V / 12V Driver
(30W, 60W, 100W, 150W)



Trulux RF Receiver
(Required per zone)



Trulux Tape Light

TRULUX™ Single Color Accessories

Building a Trulux system is easy! Our Trulux controllers utilize wireless technology to make installation a breeze. All that's required is a 120V power source to a 12V/24V driver which is then fed to a Trulux receiver. Wire your tape to the receiver, sync the receiver to the controller, and you're all set.

TRULUX SINGLE ZONE



Single Zone Push Dial
Wireless RF Wall Controller

SRF-BATT



LED-DR 24V Drivers

LED-DR30-24 (30W)
LED-DR60-24 (60W)
LED-DR100-24 (100W)
LED-DR150-24 (150W)

LED-DR 12V Drivers

LED-DR30-12 (30W)
LED-DR60-12 (60W)
LED-DR100-12 (100W)
LED-DR150-12 (150W)



Trulux RF Receiver
(Required per zone)

REC-5A-4Z

TRULUX 4 ZONE



4 Zone Touch Slide
RF Wall Controller

SRF-4Z-3P



LED-DR 24V Drivers

LED-DR30-24 (30W)
LED-DR60-24 (60W)
LED-DR100-24 (100W)
LED-DR150-24 (150W)

LED-DR 12V Drivers

LED-DR30-12 (30W)
LED-DR60-12 (60W)
LED-DR100-12 (100W)
LED-DR150-12 (150W)



Trulux RF Receiver
(Required per zone)

REC-5A-4Z

TRULUX APP MULTI ZONE



Trulux Mobile App
Mobile Phone / Tablet
(Control up to 8 rooms/zones)



LED-DR 24V Drivers

LED-DR30-24 (30W)
LED-DR60-24 (60W)
LED-DR100-24 (100W)
LED-DR150-24 (150W)

LED-DR 12V Drivers

LED-DR30-12 (30W)
LED-DR60-12 (60W)
LED-DR100-12 (100W)
LED-DR150-12 (150W)



Trulux TruHub
Wifi to RF Wireless Router
(Required for 2 - 8 zone installations)

WIFI-RF-8



Trulux RF Receiver
(Required per zone)

REC-5A-4Z

ALTERNATE DIMMING



Primary Side Dimming
Standard Dimmer



ELV 24V Drivers

ELV-30-24 (30W)
ELV-45-24 (45W)
ELV-60J-24 (60W)
ELV-80J-24 (80W)

ELV 12V Drivers

ELV-30-12 (30W)
ELV-45-12 (45W)
ELV-60J-12 (60W)
ELV-80J-12 (80W)

For more on Single Color Trulux controllers and receivers, see pages (58-59) for additional information

Trulux Single Color Accessories



Trulink 4-in-1
Connector Kit
TL-CONKIT



Trulink 4-in-1
Connector Block
TL-BLKS (Qty 10)



TL-2SPL Splice Connector
TL-2L (L) Snap connector
TL-2T (T) Snap connector
TL-2X (X) Snap connector



Linking Cables (IP54)
TL-2JUMP-.5 (6")
TL-2JUMP-1 (12")
TL-2JUMP-2 (24")



DC Connector
Snap to DC Jack
TL-2DC



Linking Cables (IP65)
TL-2JUMP65-.5 (6")
TL-2JUMP65-1 (12")
TL-2JUMP65-2 (24")