


MOUNTS TO STANDARD 2-GANG PLASTIC OR METAL BOX

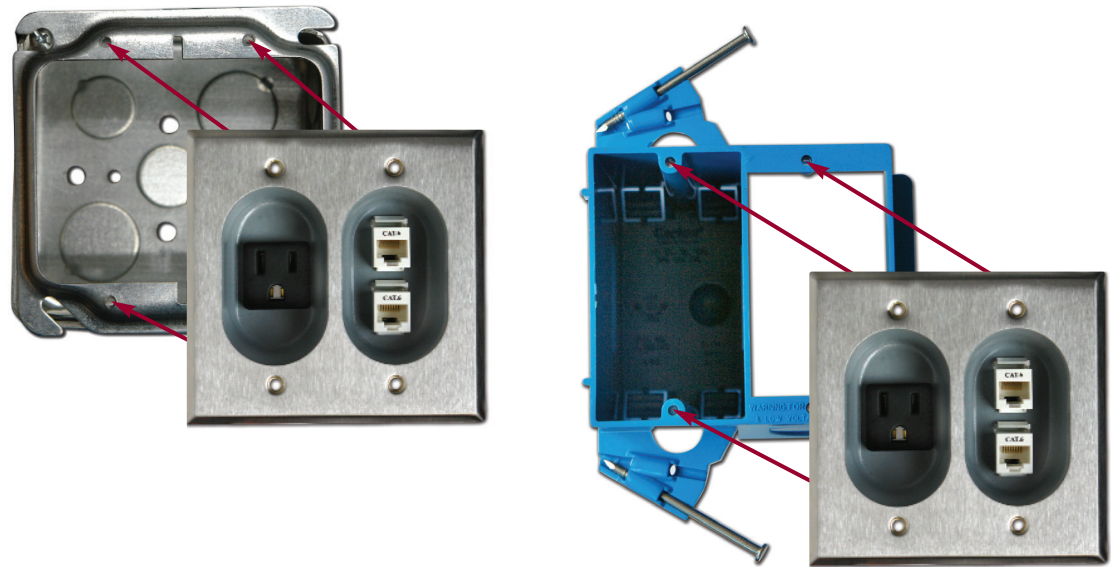

Other products from Mulberry



METAL WALLPLATES



**UNBREAKABLE
THERMOPLASTIC
WALLPLATES**




WEATHERPROOF



**BOX COVERS AND
CONDUIT BODIES**



**Home Entertainment
Covers**

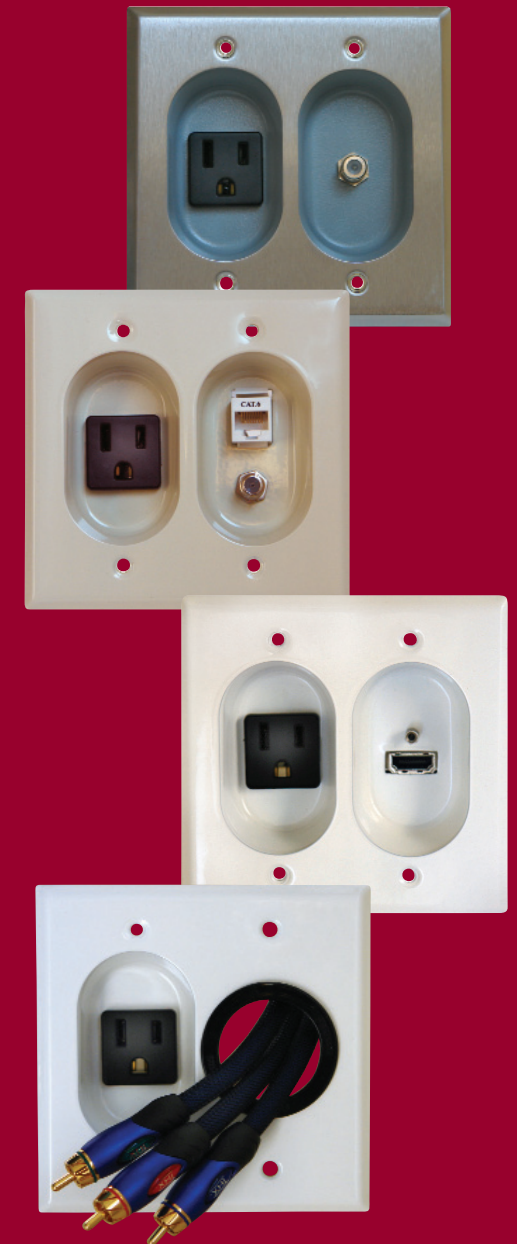

**NOW MOUNT
FLAT PANEL
TELEVISIONS
AND OTHER
AUDIO/VIDEO/DATA
CONNECTIONS
TIGHT TO
THE WALL**



Mulberry Metal Products, Inc., Union, NJ

tel: 908-688-8850 fax: 908-688-7294
e-mail: sales@mulberrymetal.com www.mulberrymetal.com

Your Complete Wallplate Source!



HOME ENTERTAINMENT COVERS

Including Recessed Wallplates

- Centralized AC power, audio, video and/or data connections from one location
- Ideal for wall mounted flat panel televisions
- Easily mounts to any standard 1- or 2- gang plastic or metal outlet box
- Perfect for new and retrofit applications
- Receptacles and connectors included
- Plates are made of stainless steel or metal with a powder coat finish
- Custom openings, combinations, and colors available
- Engraving and silkscreening available
- Made in USA
- In stock and ready for immediate delivery



Plug-In Receptacle

Size	1-gang
Components	15 amp plug-in receptacle
Smooth White	40550
Smooth Ivory	40555
Stainless Steel	40560



F-Connector*

Size	2-gang
Components	15 amp plug-in receptacle F-type connector
Smooth White	40551
Smooth Ivory	40556
Stainless Steel	40561



HDMI

Size	1-gang
Components	HDMI, female/female
Smooth White	40565
Smooth Ivory	40568
Stainless Steel	40571



HDMI*

Size	2-gang
Components	15 amp plug-in receptacle HDMI, female/female
Smooth White	40566
Smooth Ivory	40569
Stainless Steel	40572



Cat 6 and F-Connector*

Size	2-gang
Components	15 amp plug-in receptacle Cat 6 and F-type connector
Smooth White	40552
Smooth Ivory	40557
Stainless Steel	40562



HDMI (not recessed)

Size	1-gang
Components	HDMI, female/female
Smooth White	86458
Smooth Ivory	84458
Stainless Steel	97458



Cat 6 Connectors*

Size	2-gang
Components	15 amp plug-in receptacle two (2) Cat 6 connectors
Smooth White	40553
Smooth Ivory	40558
Stainless Steel	40563



1" Opening (not recessed)

Size	2-gang
Components	1.0" feed-thru opening with rubber grommet
Smooth White	86706
Smooth Ivory	84706
Stainless Steel	97706



1.625" Opening (not recessed)

Size	2-gang
Components	1.625" feed-thru opening
Smooth White	86708
Smooth Ivory	84708
Stainless Steel	97708



Plug-In Receptacles*

Size	1-gang
Components	(2) amp plug-in receptacles
Smooth White	40574
Smooth Ivory	40576
Stainless Steel	40578



1.375" Opening*

Size	2-gang
Components	15 amp plug-in receptacle 1.375" feed-thru opening
Smooth White	40567
Smooth Ivory	40570
Stainless Steel	40573



1" Opening Split Plate (not recessed)


Size	1-gang
Components	1.0" feed-thru opening with rubber grommet box mounting
Smooth White	86625
Smooth Ivory	84625
Stainless Steel	97625



1" Opening Split Plate (not recessed)

Size	2-gang
Components	1.0" feed-thru opening with rubber grommet and mounting straps device mounting
Smooth White	86626
Smooth Ivory	84626
Stainless Steel	97626

DIMENSIONS

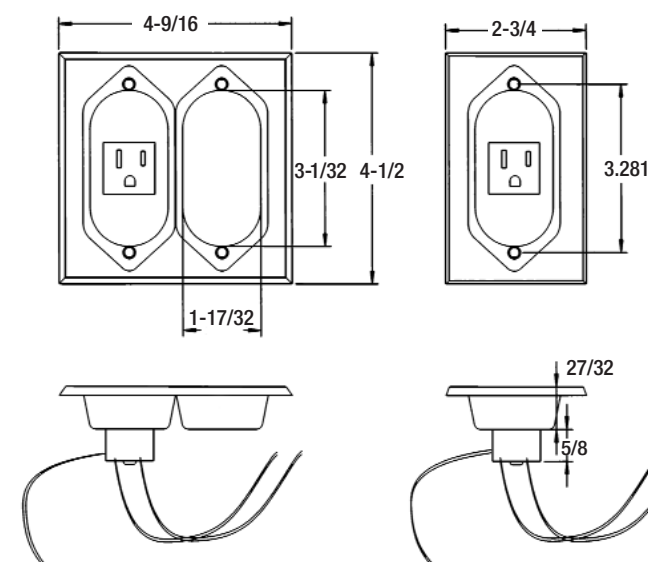

* EYE CATCHING POP PACKAGING

