



#### Features

- Advanced dimming with Pro-DIM technology: 0-10V and/or AB dimming
- No Polarity: lamp ends can be reversed
- Same wiring as fluorescent lamp/ballast system
- UL 1598C for safety
- Full glass as fluorescent T5
- No Mercury, No UV
- Suitable for Dry and Damp Locations
- Low Temperature Operation
- Instant On
- 50,000 hours with no limitation on On/Off Cycles
- 5-year Warranty
- Evaluated for use in totally enclosed, recessed luminaires, surface mount wall and ceiling luminaires, outdoor luminaires (open surface mount luminaires with compartment protection from weather)
- For use with Class 2 driver only


## CoreTech LED Series


### PRODUCT SPECIFICATIONS



Model	Mode	System Wattage	Lamp Wattage	Length	CRI	Initial Lumens	System Efficacy (lm/W)	Beam Angle	CCT	DLC
L48T5/835/24G-XT	T5HE	18	15	46"	82	2200	122	240°	3500K	Yes
L48T5/840/24G-XT	T5HE	18	15	46"	82	2200	122	240°	4000K	Yes
L48T5/850/24G-XT	T5HE	18	15	46"	82	2200	122	240°	5000K	Yes
L48T5/835/24G-XT	T5HO	27	24	46"	82	3300	122	240°	3500K	Yes
L48T5/840/24G-XT	T5HO	27	24	46"	82	3300	122	240°	4000K	Yes
L48T5/850/24G-XT	T5HO	27	24	46"	82	3300	122	240°	5000K	Yes
L48T5/830/24G-XT	T5HE	18	15	46"	82	2200	122	240	3000K	Yes
L48T5/830/24G-XT	T5HO	27	24	46"	82	3300	122	240	3000K	Yes

## Wiring diagram

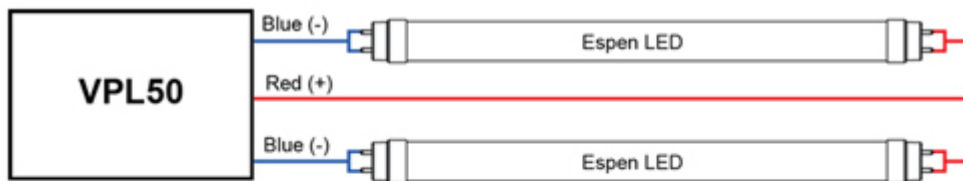

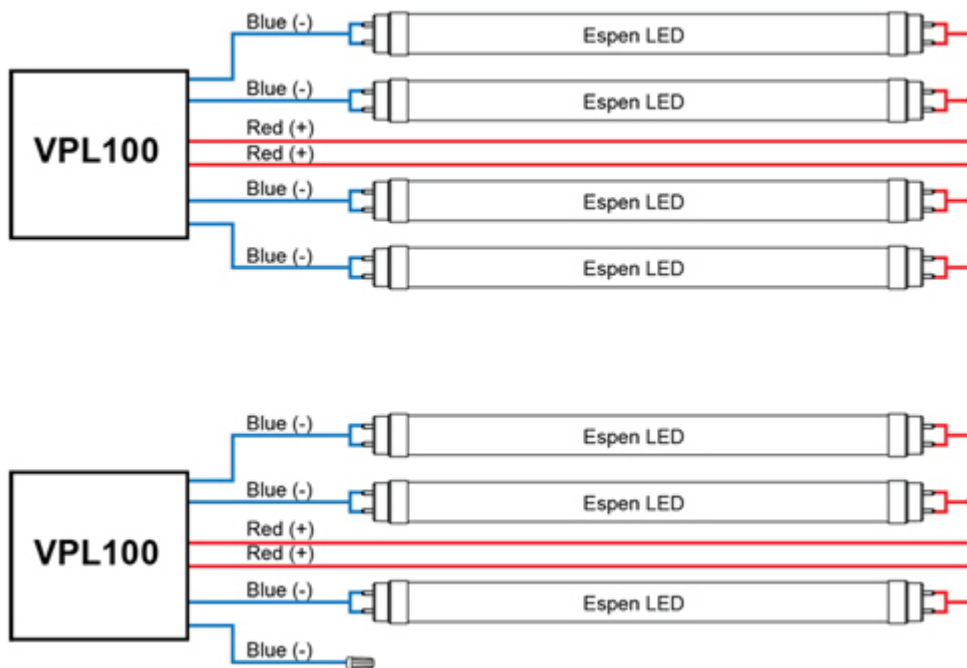

Specification data is based on tests performed in a controlled environment and represents relative performance. Actual performance can vary depending on operating conditions. Application and performance data subject to change without notice. All specifications are nominal unless noted otherwise.

Espen Technology, Inc. | 12257 Florence Avenue | Santa Fe Springs, CA 90670 | Phone: (562) 529-2938 | Fax: (562) 529-2978  
Toll Free: (866) 933-7736 | Email: [info@espentech.com](mailto:info@espentech.com) | [www.espentech.com](http://www.espentech.com)