


# Temp Lights / Contractor Series

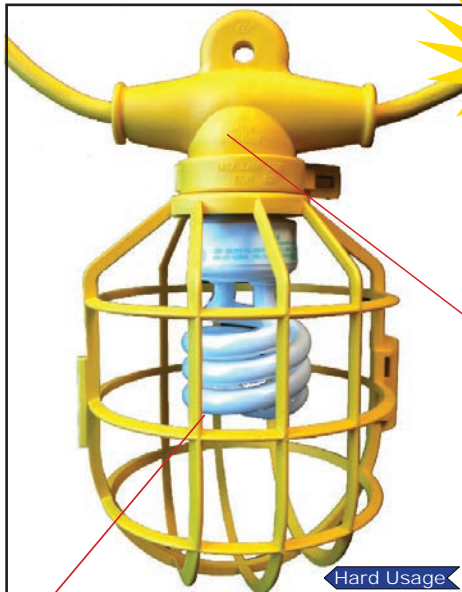

ALL  
YELLOW  
UNIT

## Contractor Grade Temporary Light Stringer

**GL-100MPC** is constructed of SJTW cord available in 14/2 & 12/3 construction in lengths of 50ft -100ft. Listed for hard usage / outdoor usage. 100ft standard includes cages & molded 15A straight blade plug. Compact design packaging for less warehouse space & easy job site clean up.

All Yellow "High Visable" Unit




Bergen's unique "snap lock" cage design eliminates those annoying screws & saves time, money & hassle during installation. Bergen's Contractor Grade Series was truly made with the Contractor in mind!

Snap Lock Cage



GREEN FRIENDLY

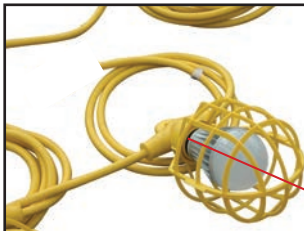


Low Profile Molding Design

Unlike competitors, Bergen's mold design allows all units to be compatible with CFL or LED medium base lamps.

15A Male Plug



Full Color Packaging

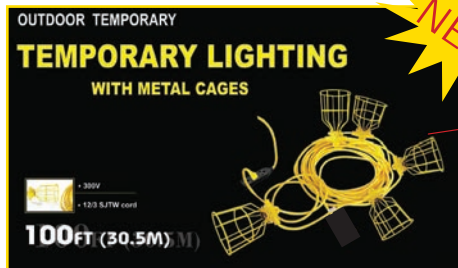

**GL100MC-123MPC**

Bergen's new Heavy Duty 12awg 3wire temporary light stringer is factory packaged with 10 Yellow Metal Lamp Guards (MC-200Y). Full Color packaging for display! Also available in 50ft (GL50MC-123MPC).



### ORDERING INFORMATION

Cat #	Description	Lamp Style	Case/Wt
GL100-142MPC	14/2 SJTW, 100' w/15A male plug	150w max Type "A"	13
GL50-142MPC	14/2 SJTW, 50' w/15A male plug	150w max Type "A"	6
GL100-123MPC	12/3 SJTW, 100' w/15A male & female	150w max Type "A"	18
GL50-123MPC	12/3 SJTW, 50' w/15A male & female	150w max Type "A"	9



Bergen Industries, Inc. | P. 800.875.1846 | F. 800.875.9419 | [www.bergeninc.com](http://www.bergeninc.com)