

# TDD2 LED

LED Area Light

## Value and Versatility Defined

Replace your 175W mercury vapor “barn light” with the powerful TDD2 LED luminaire that produces 4,700 lumens yet consumes only 41W for energy savings up to 80%.

### Key Features:

- Impact resistant polycarbonate lens provides a traditional appearance while the secondary lens provides a weatherproof seal
- LED lumen maintenance of L87/100,000 hours
- Includes twist-lock photocell for dusk to dawn operation
- Easily mounts directly to a wall, post or existing 1-5/8” mounting arm



Learn more about the TDD2 LED at [www.lithonia.com](http://www.lithonia.com)

# TDD2 LED Area Light


Ordering Information

EXAMPLE: TDD2 LED P1 50K 120 PER DNA

TDD2 LED											
Series		Light Engine		Color temperature		Voltage		Control Options		Finish	
TDD2 LED	LED Area Light	P1	4700 lumens	50K	5000K	120	120V	PER	Twist-lock Photocell	DNA	Gray



## Product Dimensions

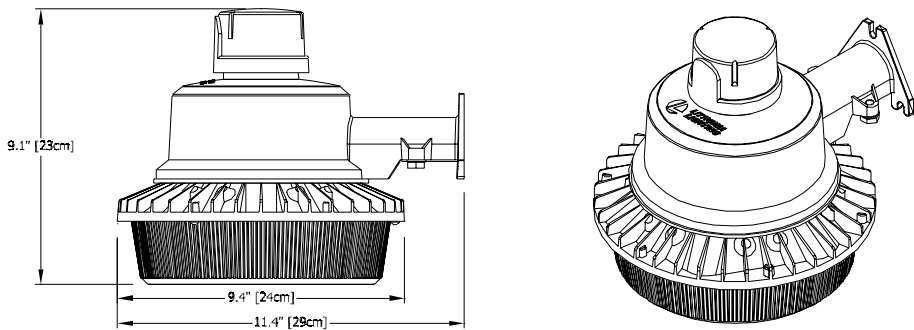

## Need more out of your LED luminaires?

You choose

TDD2 LED

You replace

100W MH  
175W MH

You save

\$31.72  
\$67.85

You win

Save up to 80%  
in Energy Costs

<sup>1</sup> Based on 10 hours operation per day and energy costs of \$.11 per kWh

