

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Vornado Chandelier 3000K

Model & Size	Color Temp	Finish	Watt	LED Lumens	Delivered Lumens
PD-87720 20"	3000K	CH Chrome	30.5W	2825	2075
	3000K	WT White	30.5W	2825	2075

Example: **PD-87720-CH**

DESCRIPTION

Harmony out of chaos, Vornado is a free flowing mobius strip of high-powered LED illumination. A simple, yet dynamic piece, Vornado is hand crafted to perfection. The flexible" composite diffuser maximizes brightness and eliminates LED hot spot. Vornado is suspended on four thin low profile cables without the need for an additional power cord, lending to a " simple and minimalistic design. Adjustable to different lengths through a push-pin locking mechanism at the canopy.

FEATURES

 
- Free flowing mobius strip of light
- Simple yet dynamic statement piece
- Each piece is hand crafted. Expect slight variations.
- Frosted extruded diffuser creates even illumination
- Assembled with a frosted joint clip, with optional chrome clip included
- Cable suspension carrying low voltage may be field shortened
- Driver concealed within the canopy
- 5 year warranty

SPECIFICATIONS


Color Temp:	3000K
Input:	120-277 VAC, 50/60Hz
CRI:	90, 80
Dimming:	ELV: 100 - 5%, 0-10V: 100 - 5%, ELV: 100 - 10%
Rated Life:	60000 Hours
Mounting:	Heavy gauge retention clips support trim firmly. Safety cabling standard.
Standards:	ETL, cETL, Title 24 JA8-2016 Compliant Damp Location Listed
Construction:	Aluminum body with flexible composite diffuser



FINISHES



LINE DRAWING

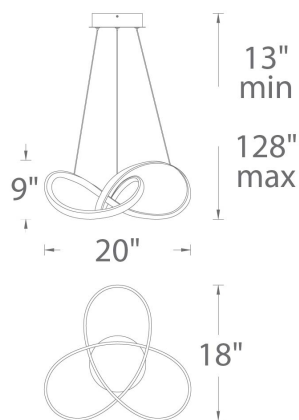

PD-87720

