

ET599DBZ; ET599DB ET599DN; ET599DW

LED Cylinder Track Fixture Dimmable




PROJECT INFORMATION:

Project Name: _____

Fixture Type: _____

Date: _____

DIMENSIONS

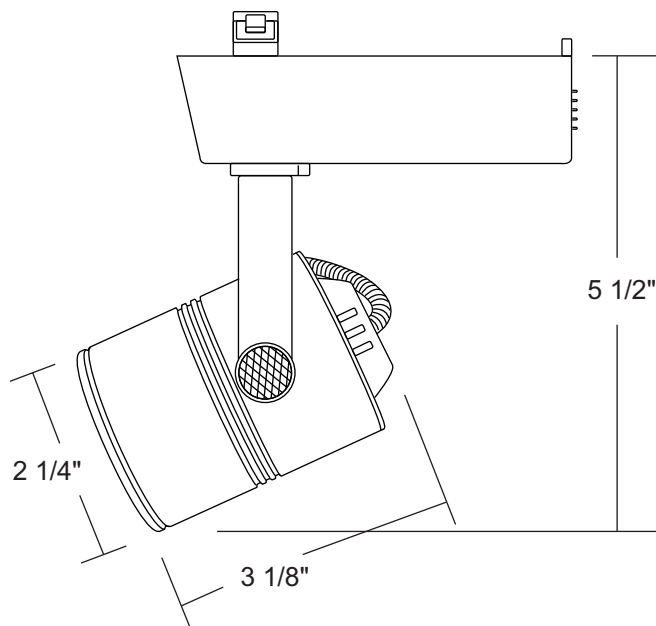

PRODUCT SPECIFICATIONS

All track heads except HID have adjustable track adapter to allow for use with single circuit and double circuit tracks

- Cylinder
- Die-cast Aluminum Housing
- 90° vertical adjustment
358° rotation
- Includes driver
- Use with ELCO 120V Single or Double Circuit Track or 120V Monopoints

Lamp: CREE LED chip, CRI 80

ET599: (1) 10W, 3000°K, 700 lm, 40° beam angle

Lamp Driver: 120V AC, dimmable

Dimensions: Length: 3 1/8"
Diameter: 2 1/4"
Max. Extension: 5 1/2"

Finish: (B) Black, (N) Brushed Nickel, (W) White,
(BZ) Bronze

Labels: U.L. listed

CATALOG NUMBER

Example: ET599DB (Black)
ET599DN (Brushed Nickel)
ET599DW (White)
ET599DBZ (Bronze)