



Lights the way to safety

# Commercial Lighting Sales

---

6797 Dorsey Road, Suite 3  
Elkridge, MD 21078

Baltimore Phone: 410-796-1033

Fax: 410-796-7660

DC Area: 301-621-1650

Please send quote requests to  
[quotes@commercial-ltg.com](mailto:quotes@commercial-ltg.com)

For Orders: [orders@commercial-ltg.com](mailto:orders@commercial-ltg.com)

**Lightalarms® Emergency Lighting  
Unit & Exits ready to be delivered  
when you need them**

Consignment warehouse locations throughout the  
United States

To view our full-line Catalog, visit our website:

**[www.lightalarms.com](http://www.lightalarms.com)**



## GRANDE™ EXIT SERIES



- Thermoplastic Housing
- Universal wall, end or ceiling mount
- Nickel-Cadmium Battery
- Red Long-Life LED Illumination
- Model available with Self-Diagnostics

MODEL #	DESCRIPTION
GRANNRW	Red Legend, Self-Powered
GRANNDRW	Red Legend, Self-Powered with Diagnostic

## QUICK™ QLX & QLXN SERIES



- Thermoplastic Housing
- Universal wall, end or ceiling mount
- QLXN exits offer Nickel-Cadmium battery
- Choice of Model in Red or Green Long-Life LED Illumination

MODEL #	DESCRIPTION
QLX500RN	Red Legend, AC-Only
QLXN500RN	Red Legend, Self-Powered
QLXN500GN	Green Legend, Self-Powered

## QUICK™ UQLXN-2MR COMBINATION SERIES



- Thermoplastic Housing
- Universal wall, end or ceiling mount
- 6V Lead-Calcium Battery
- Red Long-Life LED Illumination
- Fully adjustable MR16 lamp heads

MODEL #	DESCRIPTION
UQLXN500R-2MRSN	Red Legend, (2) full adjustable 6V-5W MR16 Halogen Lamp heads

## QUICK™ UQLXN2-SQ & UQLXN-OR-ID COMBINATION & REMOTE CAPACITY SERIES



- Thermoplastic housing
- Wall or ceiling mount
- 6V Lead-Calcium Battery
- Choice of Model in Red or Green Long-Life LED Illumination
- Self-Diagnostic and remote capacity models available

MODEL #	DESCRIPTION
UQLXN500R-2SQ	Red Legend, adjustable top or side 6V-5.4W wedge based lamp heads, no remote capacity
UQLXN500R-2SQR	Red Legend, adjustable top or side 6V-5.4W wedge based lamp heads, 12W remote capacity
UQLXN500G-2SQ	Green Legend, adjustable top or side 6V-5.4W wedge based lamp heads, no remote capacity
UQLXN500R-OR-ID	Red Legend, no heads, 24W remote capacity, self-diagnostics


## SIMPLICITY™ UNIVERSAL EDGE-LIT SERIES



- Extruded Aluminum housing
- Universal surface or recessed wall, end or ceiling mount
- Universal Single and Double face Panel
- 6UEN exits offer Nickel-Cadmium battery
- Choice of Model in Red or Green Long-Life LED Illumination

MODEL #	DESCRIPTION
6UEARM	Red Legend, AC-Only, brushed aluminum finish
6UEAGM	Green Legend, AC-Only, brushed aluminum finish
6UENRM	Red Legend, Self-powered, brushed aluminum finish
6UENGM	Green Legend, Self-Powered, brushed aluminum finish

## GALAXY™ SLIM TX & TXE SERIES

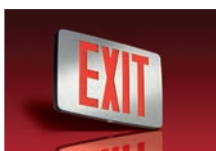

- Die-Cast Aluminum Slim housing
- Wall, end or ceiling mount
- Choice of housing colors
- TXE Models offer Nickel-Cadmium battery
- Choice of Model in Red or Green Long-Life LED Illumination

MODEL #	DESCRIPTION
<b>AC-only</b> TXBGA TXBRA TXWRW 2TXBRA	Single face, Green Legend, black frame with brushed aluminum faceplate Single face, Red Legend, black frame with brushed aluminum faceplate Single face, Red Legend, white frame and faceplate Double face, Red Legend, black frame with brushed aluminum face
<b>Self-Powered</b> TXEBGA TXEBRA TXEWRW TXEWGW 2TXEBGA 2TXEBRA 2TXEWRW	Single face, Green Legend, black frame with brushed aluminum face Single face, Red Legend, black frame with aluminum face Single face, Red Legend, white frame and face Single Face, Green Legend, white frame and face Double face, green Legend, black frame with aluminum face Double face, red Legend, black frame with aluminum face Double face, red Legend, white frame and face

## REPLACEMENT BATTERIES



- Sealed Maintenance-Free Lead-Calcium

MODEL #	DESCRIPTION
860.0004-L	6V-4.5AH Sealed Lead-Calcium
860.0010-L	6V-12.0AH Sealed Lead-Calcium

# EMERGENCY BATTERY UNITS & REMOTE HEADS



## 605 SERIES



- 6 Volt
- Thermoplastic Housing
- Fully adjustable lighting head
- Recessed Ceiling Mount
- 6V-8W Bi-Pin Halogen Lamp
- Lead Calcium Battery

MODEL #	DESCRIPTION
LS605P1	6V-10W with no remote capacity

## IC-2 SERIES



- 6 Volt
- Thermoplastic Housing
- Ceiling or Wall Mount
- 6V-5.4W Wedge Based Lamps
- Lead Calcium Battery

MODEL #	DESCRIPTION
IC-2	6V-12W with no remote capacity

## LCA-2SQ SERIES



- 6 Volt
- Thermoplastic Housing
- (2) Fully adjustable lighting heads
- Ceiling or Wall Mount
- 6V-5.4W Wedge Based Lamps
- Lead Calcium Battery

MODEL #	DESCRIPTION
LCA-2SQ	6V-12W with no remote capacity
LCA-2SQR	6V-23W with 11W remote capacity <sup>1</sup>
	<sup>1</sup> Remote Capacity based on 90 minutes

## LCA-2 & LCA1250 SERIES



- Choice of 6V or 12V Models
- Thermoplastic Housing
- (2) Fully adjustable lighting heads
- 6V unit ceiling or wall, 12V unit wall mount
- 6V-6W or 12V-12W MR16 Halogen Lamps
- Lead Calcium Battery

MODEL #	DESCRIPTION
LCA-2MRS	6V-12W with no remote capacity
LCA1250-2M12	12V-50W with 26W remote capacity <sup>1</sup>
	<sup>1</sup> Remote Capacity based on 90 minutes

## PG & P12G SERIES



- Choice of 6V or 12V Models
- Steel Housing
- (2) Fully adjustable lighting heads
- Wall mount
- 9W wedge based lamps
- Lead Calcium Battery

MODEL #	DESCRIPTION
2PG1/L9-M	6V-18W, two heads with no remote capacity <sup>1</sup>
2PG1/L9-PA-M	6V-27W two heads with 9W remote capacity <sup>1</sup>
2PG2/L9-M	6V-54W, two heads with 36W remote capacity <sup>1</sup>
2P12G1/L8-M	12V-54W, two heads with 38W remote capacity <sup>1</sup>
	<sup>1</sup> Remote Capacity based on 90 minutes

## PQ & P12Q SERIES



- Choice of 6V or 12V Models
- Steel Housing
- (2) Fully adjustable lighting heads
- Wall mount
- 9W wedge based lamps
- Lead Calcium Battery

MODEL #	DESCRIPTION
2PQ2/L9-M	6V-100W, two heads with 82W remote capacity <sup>1</sup>
2P12Q1/L8-M	12V-100W, two heads, with 84W remote capacity <sup>1</sup>
2P12Q2/L8-M	12V-200W, two heads, with 184W remote capacity <sup>1</sup>
	<sup>1</sup> Remote Capacity based on 90 minutes

## ELF645 SERIES



- Indoor Par 36 Remote head
- Choice of 6V or 12V operation
- Choice of Single or Double head models
- Thermoplastic Housing
- Fully adjustable lighting heads
- Wall mount
- 9W Incandescent wedge based lamps

MODEL #	DESCRIPTION
ELF645/L9-M6	Single Head, 6V-9W Incandescent lamp, Mist white housing color
ELF645/L8-M12	Single Head, 12V-9W Incandescent lamp, Mist white housing color
ELF645D/L9-M6	Double Head, (2) 6V-9W Incandescent lamps, Mist white housing color
ELF645D/L8-M12	Double Head, (2) 12V-9W Incandescent lamps, Mist white housing color

## ELF647 SERIES



- Outdoor Par 36 Remote head
- Choice of 6V or 12V operation
- Choice of Single or Double head models
- Thermoplastic Housing
- Fully adjustable lighting heads
- Wall mount
- Bi-Pin Halogen lamp

MODEL #	DESCRIPTION
ELF647/LH4-M6	Single Head, 6V-6W Bi-Pin Halogen lamp, Mist white housing color
ELF647D/LH4-M6	Double Head, (2) 6V-6W Bi-Pin Halogen lamp, Mist white housing color
ELF647/LH8-M12	Single Head, 12V-8W Bi-Pin Halogen lamp, Mist white housing color
ELF647D/LH8-M12	Double Head, (2) 12V-8W Bi-Pin Halogen lamps, Mist white housing color

## UQLXN500-2LED SERIES – CLUSTER™ LED FAMILY



- Thermoplastic housing
- Universal, wall or ceiling mount
- 3.6V Nickel-Metal Hydride Battery
- Red Long-Life LED Illumination
- Fully adjustable 3.6W LED lamp heads

MODEL #	DESCRIPTION
UQLXN500R-2LED	Red Legend with remote capacity <sup>1</sup>
UQLXN500G-2LED	Green Legend with remote capacity <sup>1</sup>
<sup>1</sup> Remote capacity can ONLY be used to power the Cluster™ LED ELF652D/LED remote head or to extend the combo's emergency run time beyond the standard 90 minutes	

## LCA-2LEDR SERIES – CLUSTER™ LED FAMILY



- Thermoplastic Housing
- (2) Fully adjustable 3.6W LED lighting heads
- Ceiling or Wall Mount
- 3.6V Nickel-Metal Hydride Battery

MODEL #	DESCRIPTION
LCA-2LED	Cluster™ LED battery with remote capacity <sup>1</sup>
<sup>1</sup> Remote capacity can ONLY be used to power the Cluster™ LED ELF652D/LED remote head or to extend the combo's emergency run time beyond the standard 90 minutes	

## ELF652D SERIES – CLUSTER™ LED FAMILY



- Choice of Indoor and Outdoor Application
- Double Remote head
- Thermoplastic Housing
- Fully adjustable lighting heads
- Wall mount
- 3.6V 3.6W LED Cluster lamp type

MODEL #	DESCRIPTION
ELF652D/LED	Indoor remote (draw 3.6V-3.6W) <sup>1</sup>
ELF652D/LED-WP	Weather-Proof remote (draw 3.6V-3.8W) <sup>1</sup>
<sup>1</sup> ELF652D Remote heads Can only be powered by the UQLXN500R-2LED, UQLXN500G-2LED or LCA-2LED models	

## LADL SERIES



- Steel housing contains, battery, battery charger, transfer circuit and high frequency inverter
- Operating temperature 68°F to 125°F (0°C to 50°C)
- External mounting to a fluorescent fixture

MODEL #	DESCRIPTION
LADL12	(1) Lamp 1400 Lumens, (2) lamp 700 Lumens
LADL18	(1) Lamp 650 Lumens
LADL20	(1) Lamp 650 Lumens, (2) lamp 325 Lumens
LADL30-N	(1) Lamp 3000 Lumens, (2) lamp 1500 Lumens
LADL32	(1) Lamp 500 Lumens
LADL7	(1) Lamp 700 Lumens, (2) lamp 350 Lumens

## MN125 SERIES



- Interruptible 125W Mini Inverter
- Operates, Incandescent, Fluorescent, and LED lamp types
- 18 Gauge Steel Housing
- Dimensions: 23.15" X 11.71 X 4.5"
- Surface Mount

MODEL #	DESCRIPTION
MN125-SM	125W interruptible modified sine wave output inverter

## MN375 SERIES



- Interruptible 375W Mini Inverter
- Operates, Incandescent, Fluorescent, and LED lamp types
- 18 Gauge Steel Housing
- Dimensions: 23" X 11.83 X 8.2"
- Surface Mount

MODEL #	DESCRIPTION
MN375	375W interruptible pure sine wave output inverter

## MN350 SERIES



- Interruptible 350W Mini Inverter
- Operates, Incandescent, Fluorescent, and LED lamp types
- 16 Gauge Steel Housing
- Dimensions: 23" X 17.83 X 8.2"
- Surface Mount

MODEL #	DESCRIPTION
MN350	350W Uninterruptible double conversion pure sine wave output inverter