

Rod Hanger Beam Clamp Model 200



*for a
better
mousetrap
see page 113*

Features

- Available for threaded rod sizes $\frac{3}{8}$ " to $\frac{1}{2}$ " dia.
- For attachment to beams or angles up to $\frac{3}{4}$ " (20 mm) thick.
- Locknut and hardened cup point setscrew to provide secure grip on tapered sections.
- Stamped steel with electrogalvanized finish for good corrosion protection.
- Available in hot dipped galvanized finish or made from AISI 304 stainless (special order).
- Retaining strap available separately, for more secure attachment for industrial or seismic applications.



Applications

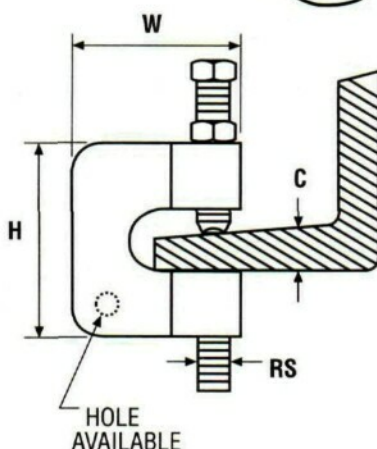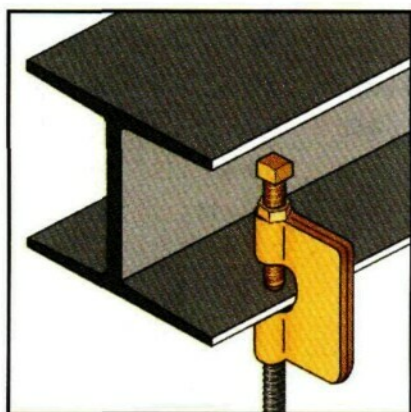

Sizing Chart

Catalog Number	RS	M	C Max IN	H IN	W IN	Coating	Qty. Per Box	l.bs.
2000037EG	$\frac{3}{8}$ " - 16	$\frac{3}{8}$ " - 16	$\frac{3}{4}$ "	$2\frac{3}{8}$ "	$2\frac{1}{4}$ "	EG	100	250
2000050EG	$\frac{1}{2}$ " - 13	$\frac{1}{2}$ " - 13	$\frac{3}{4}$ "	$2\frac{3}{8}$ "	$2\frac{1}{8}$ "	EG	50	760

NOTE: Safety factor of 5.

A = Flange Width C = Flange Size \varnothing = Diameter H = Fastener Height
M = Bolt Size P = Fastener Width PS = Pipe Size Rigid/EMT RS = Rod Size


Industrial

CADDY®

Read safety instructions and instruction sheets contained in packages before using or applying fastener.

CADDY® Fasteners Are UL Listed And ISO 9001 Compliant

With our official registration and full compliance with ISO 9001 and our UL Listing, ERICO® is continually striving to exceed industry standards in every aspect of our business.

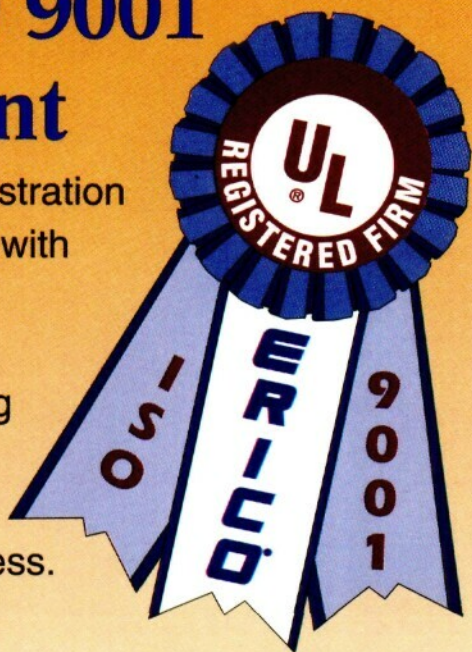

*For a complete list of
UL Listed Fasteners,
contact the factory.*

