



STAPLE GUNS & STAPLES

MT-72



**M721168
M721189**

MT-59



**M591189
M591189BL**

MT-25



**M256, M257,
M259**

MT-72 Staple Gun:

Professional wire & cable staple gun. Shoots large UL listed & C-UL listed insulated staples for non metallic sheathed cable, 12/2, 14/2 and other wire up to 1/2". Wire guide for proper fit. All steel construction and patented jam proof mechanism.

MT-59 Staple Gun:

Wiring Tacker for UL listed & C-UL listed insulated staples. Ideal for installing RG6 and RG6 Quad shield TV/Cable/Computer wire up to 5/16" wide. Steel construction, grooved guide. Patented jam proof mechanism.

MT-25 Staple Gun:

Low voltage wire staple gun. Fits wire up to 1/4". Built in grooved guide to prevent wire damage. All steel construction. Patented jam proof mechanism.

STOCK NO.	UPC NO.	DESCRIPTION	WEIGHT	QTY/. PKG.
MT72	23672	Staple Gun	2.5 lbs	1
M721168	23676	¹³ / ₆₄ " x ³¹ / ₆₄ " Insulated Staple	0.55 lbs	300
M721189	23680	¹¹ / ₃₂ " x ¹⁹ / ₃₂ " Insulated Staple	0.58 lbs	300
MT59	23659	Staple Gun	2.08 lbs	1
M591189	23665	⁵ / ₁₆ " x ⁵ / ₁₆ " Clear Insulated Staple	0.275 lbs	300
M591189BL	23670	⁵ / ₁₆ " x ⁵ / ₁₆ " Black Insulated Staple	0.275 lbs	300
MT25	23625	Staple Gun	2.08 lbs	1
M256	23630	¹ / ₄ " x ³ / ₈ " Non-insulated Staple	0.29 lbs	1,000
M257	23635	¹ / ₄ " x ⁷ / ₁₆ " Non-insulated Staple	0.34 lbs	1,000
M259	23640	¹ / ₄ " x ⁹ / ₁₆ " Non-insulated Staple	0.40 lbs	1,000

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

WIRE TACKERS

ARROW® MODEL T75™ WIRE & CABLE STAPLER
USES T75™ STAPLES (5/8" (16MM) 7/8" (22MM))



- Durable Chrome Finish
- All-Steel Construction
- Cushioned Grip
- Grooved Guide
- Grooved Driving Blade
- Chrome Finish Resists Wear and Tear
- Patented Jam-Proof Mechanism
- Easy Squeeze Double Leverage Operation
- For wires up to 1/2" (12mm)
- NM Sheathed Cable up to #12 3-Wire
- CATV
- Communications
- Alarm Systems
- Electronics

STOCK NO.	UPC NO.	DESCRIPTION	QTY. PER PKG.	SUGGESTED TRADE LIST PRICE PER
MT75	23675	Wire & Cable Staple Gun	1	84.88/ea.
M7510S	23693	5/8 Staple UL Listed	1000	22.10/pkg.
M7510	23590	5/8 Staple Not UL Listed	1000	16.40/pkg.
M7514S	23687	7/8 Staple UL Listed	1000	24.55/pkg.
M7514	23594	7/8 Staple Not UL Listed	1000	18.05/pkg.

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

AMERICA'S SOURCE FOR PREMIER AND INNOVATIVE FASTENERS & ANCHORS

ONLY METALLICS!




A Modern Up to Date
Roll Threading Machine
at our Affiliate, Avanti Screw.




Metallics and Avanti Screw, Inc., prime American manufacturers of fastener products, have always worked to present the latest in fastener technology to our distributors and their contractors/users.

Hex Washer Head fasteners have historically only offered three drives-the hex, phillips and the slot. In 1999, we introduced "The QuaDrive" square, hex, slotted and phillips, in fourteen of the most popular sizes of sheet metal screws.


The QuaDrive


Square Drive


+


Hex


+


Slotted

+



Phillips

=


QuaDrive

**America's Newest Drive - Designed, Developed and
Manufactured by Metallics/Avanti Screw**

These sheet metal screws are being manufactured to fill the need of the growing demand in the North American markets.

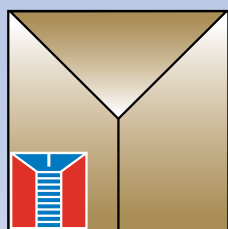

Metallics


Caulking Guns

NEW!
2014-2015

**[CONTRACTOR
APPROVED]**



CG77 Has Ratchet Rod

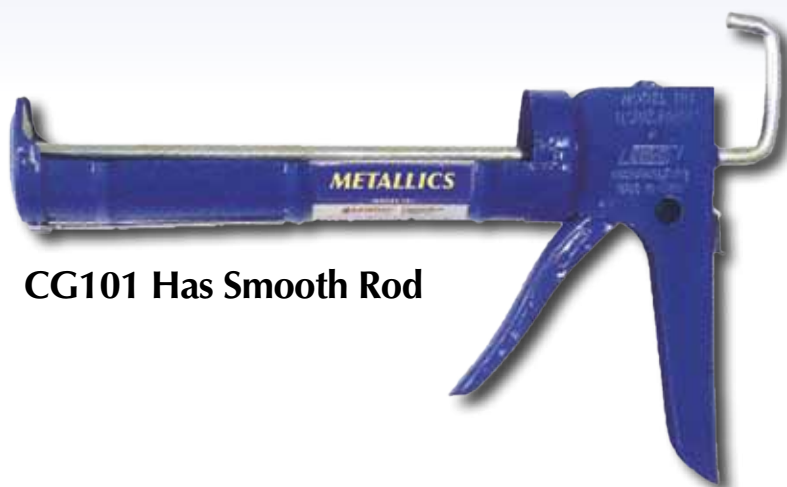

CG101 Has Smooth Rod

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
CG77	35060	Caulking Gun with Ratchet Rod, Cradle Frame 10oz.	1	\$ 12.70
CG101	35065	Caulking Gun with Smooth Rod, Seal Punctuer Tool, Spout Cutter, Ladder Hook 10oz.	1	\$ 14.65

"Growth Through Innovation"


Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

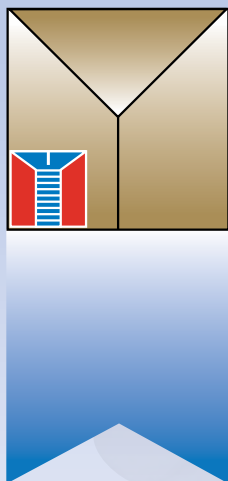

Metallics

Work Gloves

NEW!
2014-2015

**[CONTRACTOR
APPROVED]**



- 100% Cotton Standard Weight
- Brown Jersey Glove
- Knit Wrist
- Sold in dozen pairs per pkg.
- One size fits all

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MBJ1	17665	100% Cotton Standard Weight Brown Jersey Work Glove	12 pair	\$ 24.68

★ ★ ★ ★ ★ *"Growth Through Innovation"* ★ ★ ★ ★ ★

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com



ISOMAX® IMPACT DRIVER KIT

11 PIECE IMPACT DRIVER BIT KIT
PERFECT FOR REMOVING TIGHT OR STUCK SCREWS

- Perfect for Removing Tight, or Stuck Screws!
- Includes Comfortable Impact Absorbing Hand-Grip with Hand Guard
- Comes with Bit Holder, 9 Tips and Sturdy Molded Plastic Storage Case.



Square Drive

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
IBTK11	32771	11 pc. Impact Driver Kit with plastic Handle	2.3 lbs	1	47.20

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



ISOMAX® IMPACT DRIVER BIT KIT

13 PIECE IMPACT DRIVER BIT KIT



Hex



Slotted



Phillips



Square Drive

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
IBTK13	32773	13 pc. Impact Driver Bit Kit	.42 lbs	1	45.17

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

15 IN ONE RACHET SCREWDRIVER

Handle Contains 1 each
of bits listed below



STOCK NO.	UPC NO.	DESCRIPTION	QTY.	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
SD15B	35025	Screwdriver	1	.50	52.23/ea
15-1 REPLACEMENT BITS (PKG. 6 BITS PER PKG.)					
SDR1B	35028	1/8" Slotted x #0 Phillips	6	.50	31.58/ea pkg
SDR2B	35030	1/4" x 3/16" Slotted	6	.50	31.58/ea pkg
SDR3B	35032	1/4" Slotted x #2 Phillips	6	.50	31.58/ea pkg
SDR4B	35034	5/32" Slotted x #3 Phillips	6	.50	31.58/ea pkg
SDR5B	35036	#1 x #2 Phillips	6	.50	31.58/ea pkg
SDR6B	35038	T15 x T20 Torx Compatible	6	.50	38.28/ea pkg
SDR7B	35040	S1 x S2 Square	6	.50	38.28/ea pkg

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



25' PRO TAPE MEASURE

Cushion Grip Provides Non-slip Grip and Helps Protect Tape
Quick release and locking button
Tape 7/8" wide for extra strength

STOCK NO.	UPC NO.	DESCRIPTION	QTY.	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
MPT1	31304	Tape Measure	1	.79	38.50/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

LUTZ® IS A REGISTERED TRADEMARK



UTILITY KNIFE


Heavy Duty • Xtra Blades in handle • Retractable Blade

STOCK NO.	UPC NO.	DESCRIPTION	QTY.	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
MUK1	31308	Utility Knife	1	.60	18.65/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST


FOUR-WAY SCREWDRIVER

 Convenience of 4 Screwdrivers in One!



SD4W1

 Includes:
3/16 & 9/32 Slotted bit
#1 & #2 Phillips bit



SD4W2

Includes:
#1 & #2 Square bit
#1 & #2 Phillips bit

Attractive
counter
display
included
with 12 or
more!


- Reversible Shaft
- Heavy Duty Black Plastic Handle with Gold Imprint

SPECIAL ORDER

PRIVATE LABELING AVAILABLE
with purchases of 72 or more drivers
(Specify handle color: Red, Black, Light Blue, Dark Blue, Yellow, Green)

STOCK NO.	UPC NO.	DESCRIPTION	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD4W1	35001	4-way Phillips and Slotted Points	.32	1	16.30/ea
SD4W2	35002	4-way Phillips and Square Points	.31	1	16.30/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

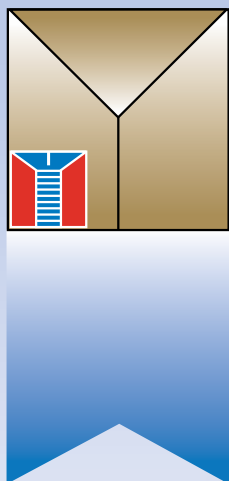

Metallics

Mighty Marker

6 Assorted Colors!

Yellow • Blue • Red • White • Black • Green



**[CONTRACTOR
APPROVED]**



- Permanent, waterproof and quick dry paint
- Indoor and outdoor
- Marks metal and most surfaces
- Medium line
- Aluminum barrel with paint-fed fiber tip
- Oil based opaque fast dry paint
- Fade and abrasion resistant
- Conforms to ASTM 4236

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MM01606	14637	Mighty Marker – 6 pack assorted colors	6	\$ 32.48

★ ★ ★ ★ ★ “Growth Through Innovation” ★ ★ ★ ★ ★

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

 
TOOLS, DRILLS AND ACCESSORIES

SIX-WAY SCREWDRIVER

Same great features as our 4-Way Screwdriver **PLUS** a hardened steel tube for use as a $\frac{1}{4}$ " or $\frac{5}{16}$ " hex nut driver!




$\frac{5}{16}$ " Hex Driver $\frac{1}{4}$ " Hex Driver



SD6W1

 Includes:
3/16 & 9/32 Slotted bit
#1 & #2 Phillips bit



SD6W2

Includes:
#1 & #2 Square bit
#1 & #2 Phillips bit

Attractive counter display included with 12 or more!

- Reversible Steel Shaft with Hex Drivers
- Heavy Duty Black Plastic Handle with Gold Imprint

SPECIAL ORDER

PRIVATE LABELING AVAILABLE

with purchases of 72 or more drivers
(Specify handle color: Red, Black, Light Blue, Dark Blue, Yellow, Green)

STOCK NO.	UPC NO.	DESCRIPTION	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD6W1	35010	6-way Phillips and Slotted Points	.35	1	19.95/ea
SD6W2	35011	6-way Phillips and Square Points	.35	1	19.95/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



THREE-IN-ONE TAP THREAD CLEANING TOOL

STOCK NO.	UPC NO.	DESCRIPTION	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
681032	16345	6-32,8-32,10-32 Thread Cleaning Tool	.34	1	29.00/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST




MAGNETIC BIT AND NUT SETTER KIT

- Three sizes of Nut Setters and one size Bit Holders
- Magnetized for ease of use
- Be professional, be prepared

STOCK NO.	UPC NO.	DESCRIPTION	SIZE	QTY.	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MTKQ	10890	Mag. Hex Bit Holder	1/4 x 2"	2	.8	1	76.30/ea
		Mag Nut Setter	1/4 x 2"	2			
		Mag Nut Setter	5/16 x 2"	2			
		Mag Nut Setter	3/8 x 2"	2			

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

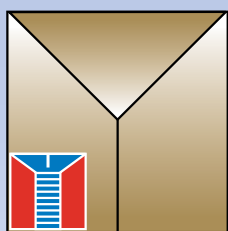


Metallics



Extra Long Power Bits

**[CONTRACTOR
APPROVED]**

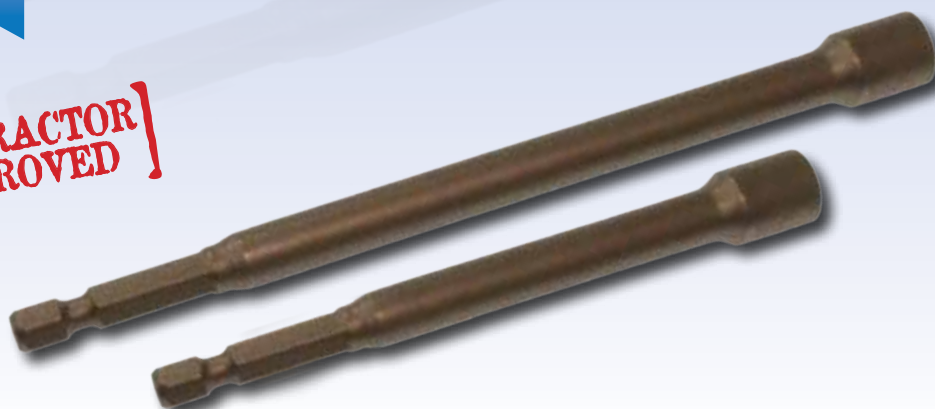

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MT208L4	27150	1/4 x 4 Extra Long Power Bit	2	\$ 19.50
MT208L6	27155	1/4 x 6 Extra Long Power Bit	2	\$ 23.13
MT210L4	10523	5/16 x 4 Extra Long Power Bit	2	\$ 22.23
MT210L6	10526	5/16 x 6 Extra Long Power Bit	2	\$ 34.23
MT212L4	27165	3/8 x 4 Extra Long Power Bit	2	\$ 24.75
MT212L6	27170	3/8 x 6 Extra Long Power Bit	2	\$ 44.25
MT208L4B	27151	1/4 x 4 Extra Long Power Bit (bulk packed)	EACH	\$ 11.25
MT208L6B	27156	1/4 x 6 Extra Long Power Bit (bulk packed)	EACH	\$ 13.75
MT210L4B	10524	5/16 x 4 Extra Long Power Bit (bulk packed)	EACH	\$ 11.11
MT210L6B	10527	5/16 x 6 Extra Long Power Bit (bulk packed)	EACH	\$ 17.11
MT212L4B	27166	3/8 x 4 Extra Long Power Bit (bulk packed)	EACH	\$ 14.75
MT212L6B	27171	3/8 x 6 Extra Long Power Bit (bulk packed)	EACH	\$ 27.75

Other sizes, materials and quantities available by request.

★ ★ ★ ★ ★ "Growth Through Innovation" ★ ★ ★ ★ ★


Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

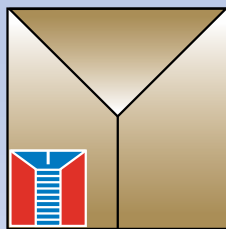

Metallics

**[CONTRACTOR
APPROVED]**

NEW!
2014-2015

High-Speed Twist Drills

Fractional Sizes – Individually Packaged

- Jobber length - 118° Point
- Fractional sizes
- Bright finish
- In single pouch



* 1/4 reduced shank

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
HSD1E	39801	1/16 x 1-7/8" drill	1	\$ 1.75
HSD2E	39802	5/64 x 2" drill	1	\$ 1.75
HSD3E	39803	3/32 x 2-1/4" drill	1	\$ 1.78
HSD4E	39804	7/64 x 2-5/8" drill	1	\$ 1.80
HSD5E	39805	1/8 x 2-3/4" drill	1	\$ 2.03
HSD6E	39806	9/64 x 2-7/8" drill	1	\$ 2.20
HSD7E	39807	5/32 x 3-1/8" drill	1	\$ 2.23
HSD8E	39808	11/32 x 3-1/4" drill	1	\$ 2.50
HSD9E	39809	3/16 x 3-1/2" drill	1	\$ 2.90
HSD29E	39829	13/64 x 3-5/8" drill	1	\$ 3.25
HSD10E	39810	7/32 x 3-3/4" drill	1	\$ 3.43
HSD11E	39811	15/64 x 3-7/8" drill	1	\$ 3.78
HSD12E	39812	1/4 x 4" drill	1	\$ 4.40
HSD13E	39813	17/64 x 4-1/8" drill	1	\$ 5.18
HSD14E	39814	9/32 x 4-1/4" drill	1	\$ 6.08
HSD15E	39815	19/64 x 4-3/8" drill	1	\$ 6.45
HSD16E	39816	5/16 x 4-1/2" drill	1	\$ 6.63
HSD16RE	39916	5/16 x 4" drill	1	\$ 7.33
HSD17E	39817	21/64 x 4-5/8" drill	1	\$ 7.35
HSD18E	39818	11/32 x 4-3/4" drill	1	\$ 8.25
HSD19E	39819	23/64 x 4-7/8" drill	1	\$ 9.35
HSD20E	39820	3/8 x 5" drill	1	\$ 9.63
HSD20RE	39920	3/8 x 4" drill	1	\$ 10.18
HSD21E	39821	25/64 x 5-1/8" drill	1	\$ 10.25
HSD22E	39822	13/32 x 5-1/4" drill	1	\$ 10.98
HSD23E	39823	27/64 x 5-3/8" drill	1	\$ 12.15
HSD24E	39824	7/16 x 5-1/2" drill	1	\$ 12.65
HSD24RE	39924	7/16 x 4" drill	1	\$ 12.98
HSD25E	39825	29/64 5-5/8" drill	1	\$ 15.25
HSD26E	39826	15/32 x 5-3/4" drill	1	\$ 14.70
HSD27E	39827	31/64 x 5-7/8" drill	1	\$ 15.65
HSD28E	39828	1/2 x 6" drill	1	\$ 16.28
HSD28RE	39928	1/2 x 4" drill	1	\$ 16.98

Other sizes, materials and quantities available by request.


"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

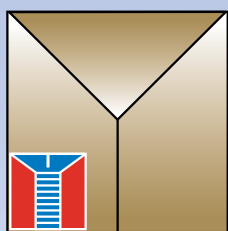

Metallics



High-Speed Twist Drills

Numbered Sizes – Individually Packaged

**[CONTRACTOR
APPROVED]**

- Jobber length - 118° Point
- Numbered sizes
- Black oxide finish
- In single pouch



PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
NHSD6E	39706	#6 x 3-3/4" drill	1	\$ 4.36
NHSD7E	39707	#7 x 3-5/8" drill	1	\$ 4.12
NHSD8E	39708	#8 x 3-5/8" drill	1	\$ 3.68
NHSD9E	39709	#9 x 3-5/8" drill	1	\$ 3.63
NHSD10E	39710	#10 x 3-5/8" drill	1	\$ 3.52
NHSD11E	39711	#11 x 3-1/2" drill	1	\$ 3.52
NHSD20E	39720	#20 x 3-1/4" drill	1	\$ 2.87
NHSD21E	39721	#21 x 3-1/4" drill	1	\$ 2.98
NHSD22E	39722	#22 x 3-1/8" drill	1	\$ 2.62
NHSD25E	39725	#25 x 3" drill	1	\$ 2.59
NHSD26E	39726	#26 x 3" drill	1	\$ 2.59
NHSD28E	39728	#28 x 2-7/8" drill	1	\$ 2.62
NHSD29E	39729	#29 x 2-7/8" drill	1	\$ 2.62
NHSD30E	39730	#30 x 2-3/4" drill	1	\$ 2.62
NHSD31E	39731	#31 x 2-3/4" drill	1	\$ 2.62
NHSD35E	39735	#35 x 2-5/8" drill	1	\$ 2.62
NHSD36E	39736	#36 x 2-1/2" drill	1	\$ 2.62
NHSD37E	39737	#37 x 2-1/2" drill	1	\$ 2.02
NHSD43E	39743	#43 x 2-1/4" drill	1	\$ 2.02

Other sizes, materials and quantities available by request.

Metallics



Bristol, Connecticut
Mancos Valley, Colorado
www.metallicsonline.com

"Growth Through Innovation"


Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • Fax 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • Fax 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

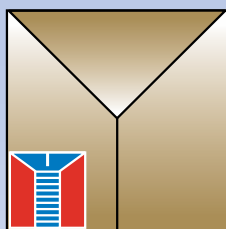

Metallics

NEW!
2014-2015

Heavy Duty Cobalt Steel - 135° Split Point Drills

Fractional Sizes – Individually Packaged

- Cobalt Steel
- Jobber Length - 135° Point
- Fractional Sizes
- Yellow Finish
- In Single Pouch

USES

- Hardened Steel
- Stainless Steel
- High Temp Alloys
- Heat Treated Material
- Abrasive Plastics
- Titanium



**[CONTRACTOR
APPROVED]**

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
HSSC1E	28201	1/16 x 1-7/8" drill	1	\$ 3.15
HSSC2E	28202	5/64 x 2" drill	1	\$ 3.53
HSSC3E	28203	3/32 x 2-1/4" drill	1	\$ 3.85
HSSC4E	28204	7/64 x 2-5/8" drill	1	\$ 4.05
HSSC5E	28205	1/8 x 2-3/4" drill	1	\$ 4.58
HSSC6E	28206	9/64 x 2-7/8" drill	1	\$ 4.95
HSSC7E	28207	5/32 x 3-1/8" drill	1	\$ 5.43
HSSC8E	28208	11/64 x 3-1/4" drill	1	\$ 5.73
HSSC9E	28209	3/16 x 3-1/2" drill	1	\$ 6.30
HSSC29E	28229	13/64 x 3-5/8" drill	1	\$ 8.33
HSSC10E	28210	7/32 x 3-3/4" drill	1	\$ 8.88
HSSC11E	28211	15/64 x 3-7/8" drill	1	\$ 9.77
HSSC12E	28212	1/4 x 4" drill	1	\$ 10.62
HSSC13E	28213	17/64 x 4-1/8" drill	1	\$ 11.45
HSSC14E	28214	9/32 x 4-1/4" drill	1	\$ 12.55
HSSC15E	28215	19/64 x 4-3/8" drill	1	\$ 14.45
HSSC16E	28216	5/16 x 4-1/2" drill	1	\$ 15.53
HSSC17E	28217	21/64 x 4-5/8" drill	1	\$ 17.03
HSSC18E	28218	11/32 x 4-3/4" drill	1	\$ 19.65
HSSC19E	28219	23/64 x 4-7/8" drill	1	\$ 22.38
HSSC20E	28220	3/8 x 5" drill	1	\$ 23.43
HSSC21E	28221	25/64 x 5-1/8" drill	1	\$ 24.68
HSSC22E	28222	13/32 x 5-1/4" drill	1	\$ 26.38
HSSC23E	28223	27/64 x 5-3/8" drill	1	\$ 27.88
HSSC24E	28224	7/16 x 5-1/2" drill	1	\$ 29.03
HSSC25E	28225	29/64 5-5/8" drill	1	\$ 34.75
HSSC26E	28226	15/32 x 5-3/4" drill	1	\$ 35.45
HSSC27E	28227	31/64 x 5-7/8" drill	1	\$ 36.28
HSSC28E	28228	1/2 x 6" drill	1	\$ 37.35

Other sizes, materials and quantities available by request.


"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

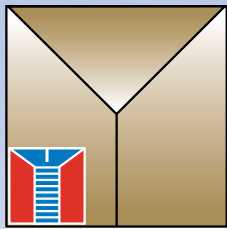

Metallics

Magnetic Bit Holder and Nut Setter Kits



[CONTRACTOR APPROVED]



- Each kit contains one of each of the following:
 - 1/4" x 1 5/8" magnetic nut setter,
 - 1/4" x 2 9/16" magnetic nut setter,
 - 1/4" x 4" magnetic nut setter,
 - 1/4" x 6" magnetic nut setter,
 - 5/16" x 1 5/8" magnetic nut setter,
 - 5/16" x 2 9/16" magnetic nut setter,
 - 5/16" x 4" magnetic nut setter,
 - 5/16" x 6" magnetic nut setter, and
 - 3/8" x 1 5/8" magnetic nut setter.
- The MTKQ10 also includes a 1/4" quick change drill chuck adapter.
- All pieces come in a handy X-Large 6 compartment poly box.

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MTKQ9	13246	9 Piece Magnetic Bit Holder and Nut Setter Kit	1	\$ 87.75
MTKQ10	13251	10 Piece Magnetic Bit Holder and Nut Setter Kit	1	\$ 92.25
DCA1	32764	1/4" Quick Change Drill Chuck Adapter	1	\$ 9.75


"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

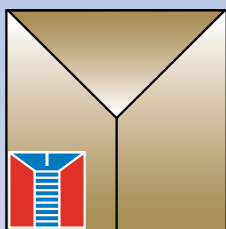


Metallics


Stop Guessing! Nut & Bolt Gauge

NEW!
2014-2015

MISTG1

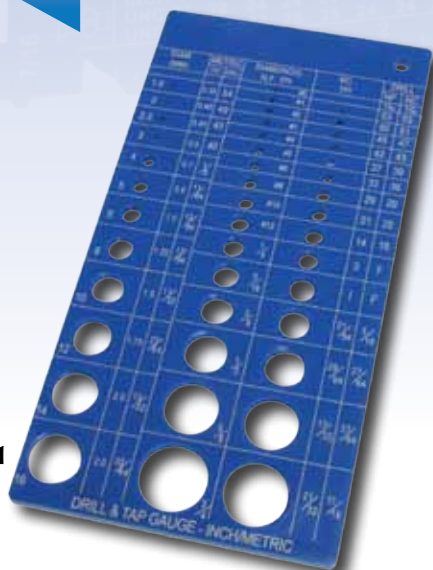

MNBG1

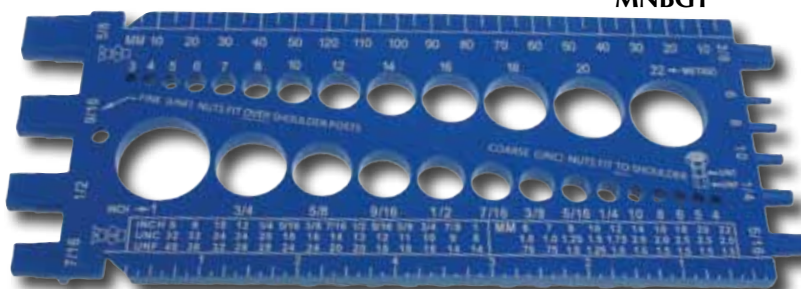

MNMG1

- Measures inch and metric bolts, nuts, screws, drill bits and washers.
- Inch and metric screw chart.

MISTG1

- Internal thread screw gauge measures inch and metric, coarse & fine.
- Tap drill chart for inch & metric.

**[CONTRACTOR
APPROVED]**

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MNMG1	16450	Nut & Bolt Gauge (Inch & Metric)	1	\$ 9.73
MISTG1	16452	Internal Thread Gauge (Inch & Metric)	1	\$ 10.40

"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • Fax 800-831-9358
Email sales@metallicsonline.com

Metallics West












 
 
 
651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • Fax 800-269-6278
Email saleswest@metallicsonline.com

TOOLS, DRILLS AND ACCESSORIES








POWER BITS AND HOLDERS PROFESSIONAL POWER TOOL ACCESSORY VISUAL PACKAGES

ALL BITS "XTRA-HARD"



STOCK NO.	UPC NO.	DESCRIPTION	LENGTH	QTY. PER PKG.	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
000P1X	25070	#1 Phillips Insert Bit	 1"	10	.18	12.08/ea pkg
000P2X	25074	#2 Phillips Insert Bit	 1"	10	.19	12.08/ea pkg
000P3X	25080	#3 Phillips Insert Bit	 1"	10	.19	12.08/ea pkg
000R2X	25055	#2 Square Drive Insert Bit	 1"	10	.19	14.40/ea pkg
0016X	25235	6-8 Slotted Insert Bit	 1"	10	.19	19.58/ea pkg
0018X	25240	8-10 Slotted Insert Bit	 1"	10	.19	19.58/ea pkg
00110X	25245	10-12 Slotted Insert Bit	 1"	10	.19	19.58/ea pkg
100P1X	25300	#1 Phillips Power Bit	 1 ⁵ / ₁₆ "	5	.19	14.20/ea pkg
100P2X	25305	#2 Phillips Power Bit	 1 ⁵ / ₁₆ "	5	.19	14.20/ea pkg
100P3X	25312	#3 Phillips Power Bit	 2"	5	.20	14.58/ea pkg
1008X	25415	8-10 Slotted Power Bit	 1 ⁵ / ₁₆ "	5	.21	22.53/ea pkg
10010X	25314	10-12 Slotted Power Bit	 1 ⁵ / ₁₆ "	5	.21	24.40/ea pkg
P2P2	25510	#2 Phillips Dbl Ended Bit	 1 ³ / ₄ "	2	.11	13.50/ea pkg
P2S8	25505	#2 Phillips Slotted Dbl End	 1 ¹ / ₂ "	2	.18	8.73/ea pkg

 MAGNETIZED

  



MT208	10870	1/4" Drill Chuck Nut Setter	 1 ⁵ / ₈ "	2	.15	14.78/ea pkg
MT208L	10875	1/4" Drill Chuck Long Nut Setter	 2 ⁹ / ₁₆ "	2	.20	17.88/ea pkg
MT210	10871	5/16" Drill Chuck Nut Setter	 1 ⁵ / ₈ "	2	.17	17.88/ea pkg
MT210L	10876	5/16" Drill Chuck Long Nut Setter	 2 ⁹ / ₁₆ "	2	.22	19.83/ea pkg
MT212	10872	3/8" Drill Chuck Nut Setter	 1 ⁷ / ₈ "	2	.18	19.63/ea pkg
MT212L	10877	3/8" Drill Chuck Long Nut Setter	 2 ⁹ / ₁₆ "	2	.25	22.93/ea pkg
M10	25250	1/4" Hex Insert Bit Holder	 2 ⁷ / ₈ "	1	.16	19.65/ea pkg

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES


BULK PACKAGED 1/4" HEX SHANK SCREWDRIVER POWER BITS AND HOLDERS

ORDER JUST WHAT YOU NEED

	STOCK NO.	UPC NO.	SCREW SIZE	POINT SIZE	OVERALL LENGTH	WT. EACH	SUGGESTED TRADE LIST PRICE PER
PHILLIPS INSERT & POWER BITS 	000P1B	25071	4-6	#1	1"	.01	1.10/ea
	000P2B	25076	8-10	#2	1"	.01	1.10/ea
	000P3B	25081	12-14	#3	1"	.01	1.10/ea
	001P2B	25085	8-10	#2	1 1/4"	.02	2.35/ea
	100P1B	25301	4-6	#1	2"	.02	2.53/ea
	100P2B	25306	8-10	#2	2"	.02	2.53/ea
	100P3B	25310	12-14	#3	2"	.02	2.30/ea
	125P1B	25315	4-6	#1	3"	.02	2.98/ea
	125P2B	25320	8-10	#2	3"	.04	3.33/ea
	125P3B	25325	12-14	#3	3"	.03	3.78/ea
	140P1B	25345	4-6	#1	4"	.04	4.20/ea
	140P2B	25350	8-10	#2	4"	.05	4.20/ea
	140P3B	25355	12-14	#3	4"	.05	4.20/ea
SLOTTED INSERT & POWER BITS 	0014B	25225	4-5	4-5	1"	.01	1.78/ea
	0016B	25236	6-8	6-8	1"	.01	1.78/ea
	0018B	25241	8-10	8-10	1"	.01	1.78/ea
	00110B	25206	10-12	10-12	1"	.01	1.78/ea
	0006B	25195	6-8	6-8	1 1/2"	.02	2.30/ea
	0008B	25200	8-10	8-10	1 1/2"	.03	2.30/ea
	00010B	25205	10-12	10-12	1 1/2"	.03	2.30/ea
	1004B	25400	4-5	4-5	2"	.02	3.75/ea
	1006B	25410	6-8	6-8	2"	.03	3.75/ea
	1008B	25416	8-10	8-10	2"	.03	4.20/ea
	10010B	25420	10-12	10-12	2"	.03	4.50/ea
	1256B	25440	6-8	6-8	3"	.04	5.30/ea
	1258B	25445	8-10	8-10	3"	.04	5.70/ea
	12510B	25450	10-12	10-12	3"	.05	7.85/ea
SQUARE DRIVE INSERT BITS 	000R1B	25050	4-6	#1	1"	.01	1.33/ea
	000R2B	25056	8-10	#2	1"	.01	1.33/ea
	000R3B	25060	12-14	#3	1"	.01	1.33/ea
	100R1B	25065	4-6	#1	2"	.01	2.60/ea
	100R2B	25072	8-10	#2	2"	.02	2.60/ea
	100R3B	25075	12-14	#3	2"	.02	2.60/ea
	125R1B	10149	4-6	#1	3"	.03	4.55/ea
	125R2B	10166	8-10	#2	3"	.04	4.55/ea
	125R3B	10167	12-14	#3	3"	.04	4.55/ea
	140R1B	10176	4-6	#1	4"	.04	6.53/ea
	140R2B	10177	8-10	#2	4"	.05	7.28/ea
	140R3B	10180	12-14	#3	4"	.05	7.28/ea
	160R2B	25352	8-10	#2	6"	.07	8.68/ea
	160R3B	25357	12-14	#3	6"	.07	8.68/ea
BIT HOLDER & NUT SETTERS 	180R2B	10193	8-10	#2	8"	.11	9.35/ea
	110R2B	10175	8-10	#2	12"	.12	10.45/ea
	P2P2B	10178	#2 Phil/#2 Phil		1 3/4"	.02	6.18/ea
	P2S8B	10179	#2 Phil/8-10 Slot		1 3/4"	.02	3.13/ea
	00SP6B	25027		#6	1"	.01	5.03/ea
	00SP8B	10195		#8	1"	.01	5.03/ea
	00SP10B	10196		#10	1"	.04	5.03/ea
	M1B	25260	1/4" Mag Bit Hldr		1 3/4"	.04	15.05/ea
	M10B	25255	1/4" Mag Bit Hldr		2 7/8"	.08	17.70/ea
	MT208B	10183	1/4" Mag Nut Setter		1 5/8"	.04	6.70/ea
	MT208LB	10186	1/4" Mag Nut Setter		2 9/16"	.06	8.10/ea
	MT210B	10184	5/16" Mag Nut Setter		1 5/8"	.05	7.53/ea
	MT210LB	10187	5/16" Mag Nut Setter		2 9/16"	.07	9.00/ea
	MT212B	10185	3/8" Mag Nut Setter		1 5/8"	.05	9.33/ea
	MT212LB	10188	3/8" Mag Nut Setter		2 9/16"	.08	10.63/ea

LONGER SIZES AVAILABLE!

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

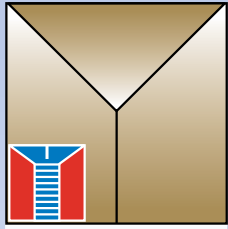

Metallics

Pull Rope

3 Strand Polypropylene

Don't Get Caught Short!



**[CONTRACTOR
APPROVED]**



PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
M3161200	17175	3/16" Three Strand Twisted Polypropylene Yellow Pull Rope 1200'	1	\$ 93.25
M14250	17235	1/4" Three Strand Twisted Polypropylene Yellow Pull Rope 250'	1	\$ 32.13
M14600	17237	1/4" Three Strand Twisted Polypropylene Yellow Pull Rope 600'	1	\$ 73.45
M141200	17240	1/4" Three Strand Twisted Polypropylene Yellow Pull Rope 1200'	1	\$ 146.86
M142400	17243	1/4" Three Strand Twisted Polypropylene Yellow Pull Rope 2400'	1	\$ 293.75
M145000	17247	1/4" Three Strand Twisted Polypropylene Yellow Pull Rope 5000'	1	\$ 612.00
M38250	17252	3/8" Three Strand Twisted Polypropylene Yellow Pull Rope 250'	1	\$ 71.75
M38600	17255	3/8" Three Strand Twisted Polypropylene Yellow Pull Rope 600'	1	\$ 164.00
M381200	17258	3/8" Three Strand Twisted Polypropylene Yellow Pull Rope 1200'	1	\$ 328.00
M382400	17262	3/8" Three Strand Twisted Polypropylene Yellow Pull Rope 2400'	1	\$ 656.00
M12250	17267	1/2" Three Strand Twisted Polypropylene Yellow Pull Rope 250'	1	\$ 125.75
M12600	17270	1/2" Three Strand Twisted Polypropylene Yellow Pull Rope 600'	1	\$ 287.38
M121200	17273	1/2" Three Strand Twisted Polypropylene Yellow Pull Rope 1200'	1	\$ 574.75

Other sizes, materials and quantities available by request.

"Growth Through Innovation"

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

SELECT-A-BIT KIT

10 Piece Kit

The Right Drive When You Need It!

KIT INCLUDES:

- 3 - Phillips Drive Bits
- 3 - Slotted Drive Bits
- 3 - Square Drive Bits
- 1 - Magnetic Holder for Power Driving.

Insert the Magnetic Holder into the star hole at the top of the bit case, and it becomes a screwdriver handle.



STOCK NO.	UPC NO.	STD. PKG.	WEIGHT EACH	SUGGESTED TRADE LIST PRICE PER
SAB10	28010	1 Kit	.24	29.88/ea

REPLACEMENT COMPONENTS FOR KIT


QUANTITY	DESCRIPTION	REPLACEMENT PART #
1	Bit Holder	M10B
1	#6-8 Slotted Bit	0016B
1	#8-10 Slotted Bit	0018B
1	#10-12 Slotted Bit	00110B
1	#1 Phillips Bit	000P1B
1	#2 Phillips Bit	000P2B
1	#3 Phillips Bit	000P3B
1	#1 Square Drive Bit	000R1B
1	#2 Square Drive Bit	000R2B
1	#3 Square Drive Bit	000R3B

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST


For PVC Plastic

CABLE SAW


FOR ALL PVC PIPE

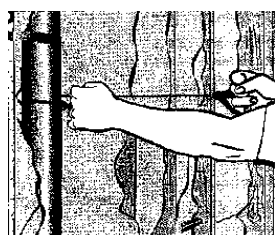

Between Joists

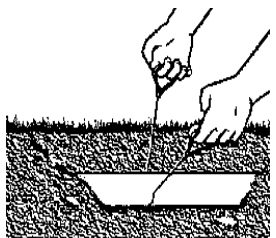

Buried

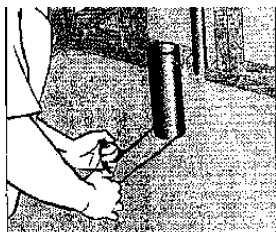

Closet Flanges and Floor

DIRECTIONS:

1. Secure PVC pipe for cutting. Loop cable around pipe at the location you wish to cut.
2. Apply pressure, while making short back and forth strokes to establish a starting cut or pilot groove in the pipe.
3. Using the middle third of the cable, make longer strokes to completely cut through PVC pipe.

- A WIRE CABLE SAW WITH VINYL COVERED HANDLES.
- SUITABLE FOR CUTTING PVC PLASTIC PIPE.



STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MCS26	71616	26" Cable Saw	0.07	1	18.68/ea
MCS46	71617	46" Cable Saw	0.07	1	20.68/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



SHARPIE® PERMANENT MARKER

PERMANENT MARKERS – SMEAR-PROOF, HEAT & WATER RESISTANT

- Sharpie® fine point permanent marker, perfect for labels, plastic or corrugated. Permanent ink smear proof, heat and water resistant.

STOCK NO.	UPC NO.	DESCRIPTION	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
30001	13721	Sharpie Fine Point Permanent Marker – black ink	12	39.96

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



SHARPIE® PERMANENT MARKERS

KING-SIZED MARKERS FOR YOUR TOUGHEST MARKING JOBS

- King Size permanent marker. Designed for the toughest marking jobs. Feature a long lasting felt chisel tip with high performance ink.
- Retractable fine tip marker. Quick drying and water resistant ink. AP certified nontoxic.

STOCK NO.	UPC NO.	DESCRIPTION	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
M15001	13781	Sharpie King-Size Marker – black ink	12	64.95
32701	13785	Sharpie Retractable Fine Tip Marker – black ink	1	10.45

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



MARKING CRAYONS

Weather resistant, fade resistant, lead free. For use on lumber (rough or smooth), cardboard, concrete, metal, paper, plastic and other surfaces. Each crayon 4-1/2" x 1/2".

STOCK NO.	UPC NO.	COLOR	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
LCB12	72600	Blue	.75	12	23.40/ea pkg
LCBLK12	72602	Black	.56	12	23.40/ea pkg
LCY12	72603	Yellow	.64	12	23.40/ea pkg
LCR12	72604	Red	.74	12	23.40/ea pkg

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST


CRAYON HOLDER



- Walnut holder fits both round or hexagonal marking crayons 1/2" in diameter.
- Walnut handle, metal chuck, hole for wrist strap.
- Aluminum holder is spring loaded and can be used with extension handle.
- Designed to hold Lumber Crayons and High Heat Metal Crayons 1/2" in diameter.

STOCK NO.	UPC NO.	DESCRIPTION	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WCH1	72599	Crayon Holder-Wood	.05	1	15.10/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

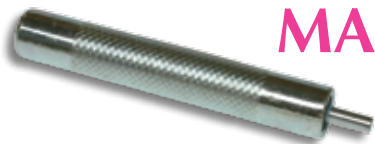

MACHINE SCREW ANCHOR SETTING TOOL

For setting Machine Screw Anchors

STOCK NO.	UPC NO.	SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
1402ST	17905	8-32	.07	1	4.20/ea
1403ST	17910	10-24	.08	1	5.03/ea
1404ST	17915	10-32	.14	1	5.03/ea
1406ST	17925	1/4-20	.17	1	5.58/ea
1407ST	17930	5/16-18	.27	1	5.95/ea
1408ST	17935	3/8-16	.38	1	6.28/ea
1409ST	17940	1/2-13	.58	1	12.13/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

HAND DRIVE TOOL


STEEL DROP-IN ANCHOR SETTING TOOL

For Setting DIA14, DIA12, DIA38 & DIA58



STOCK NO.	UPC NO.	SIZE	WT. PER EACH.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
DIA14T	12181	1/4-20	.18	1	3.85/ea
DIA38T	12182	3/8-16	.24	1	5.00/ea
DIA12T	12183	1/2-13	.41	1	6.18/ea
DIA58T	12184	5/8-11	.51	1	11.53/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

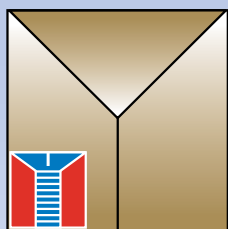

Metallics

Aviation Tin Snips

Heavy Duty Alloy Steel



**[CONTRACTOR
APPROVED]**



- Left cut – red handle
- Straight cut – yellow handle
- Right cut – green handle
- 10 inch length
- Serrated jaws
- Vinyl grips
- Safety latch
- Alloy steel construction

PART #	UPC #	DESCRIPTION	QTY / PKG	SUG. TRADE LIST / PKG
MAVSG	37468	Aviation Snip – Right Cut (Green)	1	\$ 17.25
MAVSR	37469	Aviation Snip – Left Cut (Red)	1	\$ 17.25
MAVSY	37470	Aviation Snip – Straight Cut (Yellow)	1	\$ 17.25

“Growth Through Innovation”

Metallics

229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

LAGMASTERTM *plus*

Patent Pending

Plug Into...
The electrician's only
multipurpose tool
for hanging...

- + WIRE
- + THREADED ROD
- + SMOOTH ROD
- + JACK CHAIN
- + SCREWS

...with
interchangeable
heads!

LAGMASTER PLUS™

The Lagmaster Plus™ is the electrician's pole tool. The unique plug-in heads make it the most efficient tool of it's kind. It increases safety by keeping your men on the floor. Use it to install ceiling wire, jack chain, threaded rod, smooth rod and overhead screw installation. Power the pole with any 3/8" or 1/2" battery operated or corded drill.



One pole...many applications!

Choose from two (2) different adjustable length models.

- MLMTA Triple 4' (18' ceilings)
- MLMT6 Triple 6' (24' ceilings)

Hang it up. (wire plug)




Lagmaster Plus™ wire plug hangs 12 or 9 guage wire. No need for ladders, scaffolding or scissor lifts.


Pre-wrapped wire on eye lags require a special plug (pre-wrapped plug).




Hang Wire. Move ring into the up position with set screw

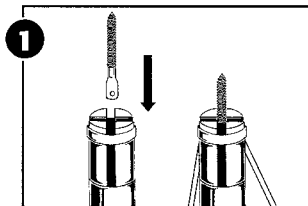


Insert the eye lag screw into secured wire plug. Insert the wire through the hole and bend the tails down.

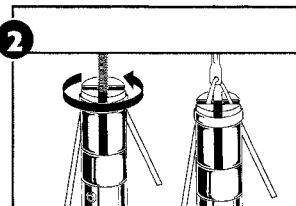


Adjust the pole to length and rotate the screw until it is seated. Pull down on the pole so that the wire is caught on the ring.

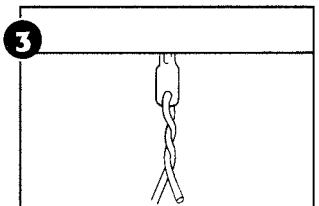


Rotate the pole again to twist the wire. Pull the wire through the plug to complete the installation.

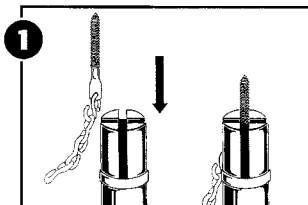

Secure a #1 1/2 "S" hook to an acoustical eye lag and to the proper size chain for your job. Insert it into the Lagmaster Plus™.

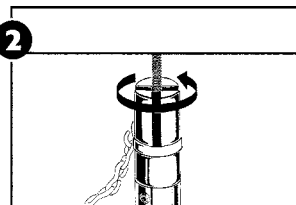

Secure the chain in the magazine so it does not whip when rotating the pole. Now rotate the eye lag screw until it is seated.

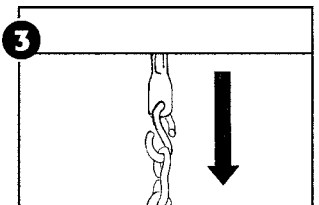

Lower the Lagmaster Plus™.



TOOLS, DRILLS AND ACCESSORIES

LAGMASTER PLUS™

DRIVE IT HOME. (socket plugs)


Install pre-cut threaded rod from the floor! Works with 3/8" or 1/4" threaded rod up to 10' long. Gets into tight spaces, vaulted ceilings, above stairwells or through ceiling grid easily.

Lagmaster Plus™ open-end socket plug-in heads work with Sammy Super Screws® and HangerMate® screws. Special twist out feature prevents over torquing and stripout even when installing from the floor.


Consult the screw manufacturer's literature for load specs and approvals on the screws.

The Lagmaster Plus™ base is the socket for HangerMate® 3/8" rod screws. The 3/8" socket plug-in works with HangerMate® 1/4" rod screws. The 5/8" socket plug-in works with Sammy Super Screws®.


Hang Threaded Rod:

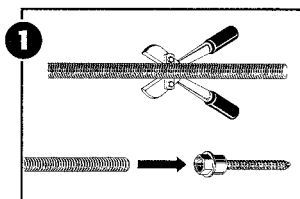


Cut threaded rod length and assemble to appropriate fastener.

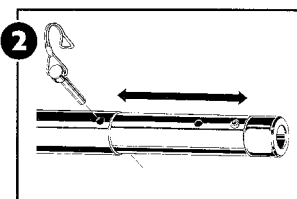

Adjust pole tool to length plug in the proper Lagmaster Plus™ head.

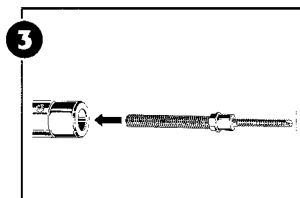

Load rod into Lagmaster pole tool. (The Lagmaster adjusting pin has to be 1/8" below the base or the pin may interfere with the rod.)

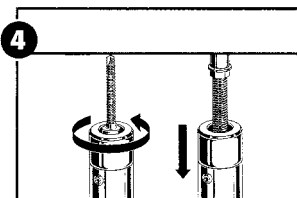

Install screw at proper site and pull down to remove the rod from the pole tool. The rod is now ready to receive hanger bracket.




(Patent # 5,154,104)


Turn your pole tool into a very long screwdriver. This Lagmaster Plus™ plug works with any 1/4" hex driver.

Install smooth rod with a Minerallac™ or Caddy™ spring clip assembly and screw. The Flash fastener is shown here.


Overhead Screw Applications: (1/4" hex plug)

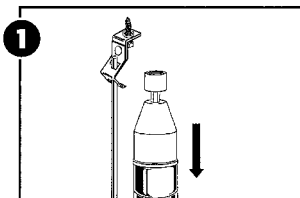

Plug in the Lagmaster Plus™ 1/4" hex head and insert the proper 1/4" driver. Adjust the Lagmaster pole tool to length.

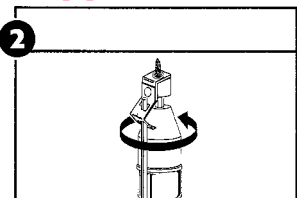

Push the smooth rod between the pole and the wire bale on the Lagmaster adjusting pin to keep the rod from whipping while turning in the screw for safety.

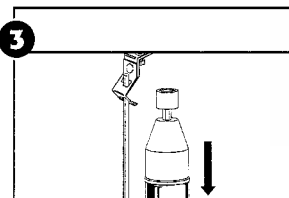

Turn in the screw cautiously being careful not to over torque or strip the screw. Remove the tool.



TOOLS, DRILLS AND ACCESSORIES

LAGMASTER PLUS™

One pole...many applications!



STOCK NO.	UPC NO.	DESCRIPTION	QTY. PKG.	SUGGESTED TRADE LIST PRICE PER
MLMT4	13329	Triple 4' Installation Tool 18' Ceiling	1	322.50/pkg.
MLMT6	13331	Triple 6' Installation Tool 24' Ceiling	1	372.50/pkg.

TOOLS, DRILLS AND ACCESSORIES

METALLICS KEYHOLE SAW WOODEN HANDLE

- Designed especially for plasterboard.
- Make cut-outs for electrical outlets, etc.
- Point sharpened for plunge cuts.



STOCK NO.	UPC NO.	LENGTH	BLADE EACH	WT. PKG.	SUGGESTED TRADE LIST PRICE PER
US6	31300	6	1.5 oz	.27	9.23/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

METALLICS HAND DRILLING HAMMER WOODEN HANDLE

- The old standby.

SAFETY GLASSES SHOULD BE WORN FOR ANY DRIVING APPLICATIONS. SEE THE NEW LINE OF SAFETY GLASSES ON PAGES 220-222.



STOCK NO.	UPC NO.	HEAD WEIGHT	OVERALL LENGTH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HAM3	18700	3.53	10"	1	40.38/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



CARBON STEEL TAPS

PLUG STYLE

A STRONG, DURABLE PRODUCT

STOCK NO.	UPC NO.	SIZE	USE DRILL SIZE	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
440CT	24900	4-40	#43	.05	5 Taps	20.83/ea pkg
632CT	24905	6-32	#36	.05	5 Taps	20.65/ea pkg
832CT	24910	8-32	#29	.07	5 Taps	20.83/ea pkg
1024CT	24915	10-24	#25	.10	5 Taps	21.83/ea pkg
1032CT	24920	10-32	#21	.10	5 Taps	21.83/ea pkg
1420CT	24925	1/4-20	#7	.15	5 Taps	23.85/ea pkg
516CT	24930	5/16-18	17/64	.16	5 Taps	26.00/ea pkg
3816CT	24935	3/8-16	5/16	.23	5 Taps	33.23/ea pkg
1213CT	24940	1/2-13	27/64	.46	5 Taps	43.48/ea pkg

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST, TAPER OR BOTTOMING TAPS AVAILABLE UPON REQUEST



TAP WRENCH T-HANDLE STYLE

STOCK NO.	UPC NO.	CAPACITY	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TWH1	24970	0 to 1/4	.15	1	14.50/ea
TWH2	24975	1/4 to 1/2	.39	1	23.98/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



CONCRETE SCREW INSTALLATION KIT

8 PIECE KIT
TOOLS AND DRIVING ACCESSORIES

KIT INCLUDES:

1 - Drill Driver 1 - Phillips Bit Holder
1 - Drill Adapter 2 - Phillips Bits
2 - Hex Drivers 1 - Allen Hex Key

DRILL BIT NOT INCLUDED

STOCK NO.	UPC NO.	DESCRIPTION	STD. PKG.	WT. EACH	SUGGESTED TRADE LIST PRICE PER
KIT					
IT1000	31200	Installation Tool (complete kit)	1	.95	110.10/ea
REPLACEMENT COMPONENTS FOR KIT					
MHD14	31205	1/4" Magnetic Hex Driver			30.55/ea
MHD56	31210	5/16" Magnetic Hex Driver			30.55/ea
PBH	31215	#2 & #3 Phillips Bit Holder			33.60/ea
ITSLEVE	31203	Drill/Driver Adapter			39.98/ea
PB2	31220	#2 Phillips Bit			1.53/ea
PB3	31225	#3 Phillips Bit			1.53/ea
HK1	31230	1/8" Allen Hex Key			1.53/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

CAN BE USED WITH
THE METALLICS
QUADRIE CONCRETE
SCREWS



MASONRY DRILLS FOR CONCRETE SCREWS

SPECIAL SIZE AND LENGTH
FOR USE WITH INSTALLATION TOOL ABOVE

STOCK NO.	UPC NO.	SIZE	SCREW DIA.	STD. PKG.	WT. EACH	SUGGESTED TRADE LIST PRICE PER
CD1	31250	5/32 x 3 1/2	3/16	1	.02	3.38/ea
CD2	31255	5/32 x 4 1/2	3/16	1	.02	3.98/ea
CD3	31260	5/32 x 5 1/2	3/16	1	.02	4.53/ea
CD5	31265	3/16 x 3 1/2	1/4	1	.02	3.45/ea
CD6	31270	3/16 x 4 1/2	1/4	1	.02	4.08/ea
CD7	31275	3/16 x 5 1/2	1/4	1	.03	5.78/ea
CD8	31280	3/16 x 6	1/4	1	.03	7.43/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



CAULKING GUN

PISTON ROD WITH DOUBLE FRICTION PLATE
QUICK-RELEASE LEVER

STOCK NO.	UPC NO.	TUBE SIZE	STD. PKG.	WT. EACH	SUGGESTED TRADE LIST PRICE PER
CG1	35020	10 oz	1	.90	7.55/ea
CG32	35050	32 oz	1	1.92	36.20/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES



HIGH-SPEED TWIST DRILLS

Jobber's Length

STOCK NO.	UPC NO.	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG. (DRILLS)	SUGGESTED TRADE LIST PRICE PER
NUMBERED SIZES 118° POINTS						
NHSD6	24806	#6	3 ³ / ₄	.40	10	37.58/ea pkg
NHSD7	24807	#7	3 ⁵ / ₈	.20	10	35.60/ea pkg
NHSD8	24808	#8	3 ⁵ / ₈	.21	10	31.58/ea pkg
NHSD9	24809	#9	3 ⁵ / ₈	.37	10	30.88/ea pkg
NHSD10	24810	#10	3 ⁵ / ₈	.22	10	29.55/ea pkg
NHSD11	24811	#11	3 ¹ / ₂	.22	10	29.55/ea pkg
NHSD20	24820	#20	3 ¹ / ₄	.25	10	24.18/ea pkg
NHSD21	24821	#21	3 ¹ / ₄	.14	10	24.85/ea pkg
NHSD22	24822	#22	3 ¹ / ₈	.13	10	21.83/ea pkg
NHSD25	24825	#25	3	.12	10	21.15/ea pkg
NHSD26	24826	#26	3	.11	10	21.15/ea pkg
NHSD28	24828	#28	2 ⁷ / ₈	.10	10	21.83/ea pkg
NHSD29	24829	#29	2 ⁷ / ₈	.10	10	21.83/ea pkg
NHSD30	24830	#30	2 ³ / ₄	.08	10	21.83/ea pkg
NHSD31	24831	#31	2 ³ / ₄	.08	10	21.83/ea pkg
NHSD35	24835	#35	2 ⁵ / ₈	.07	10	21.83/ea pkg
NHSD36	24836	#36	2 ¹ / ₂	.06	10	21.83/ea pkg
NHSD37	24837	#37	2 ¹ / ₂	.06	10	16.45/ea pkg
NHSD43	24843	#43	2 ¹ / ₄	.05	10	16.45/ea pkg
FRACTIONAL SIZES 118° POINTS						
HSD1	24300	1 ¹ / ₁₆	1 ⁷ / ₈	.03	10	15.80/ea pkg
HSD2	24305	5 ¹ / ₆₄	2	.04	10	15.80/ea pkg
HSD3	24310	3 ¹ / ₃₂	2 ¹ / ₄	.05	10	16.13/ea pkg
HSD4	24315	7 ¹ / ₆₄	2 ⁵ / ₈	.07	10	16.13/ea pkg
HSD5	24320	1 ¹ / ₈	2 ³ / ₄	.09	10	18.15/ea pkg
HSD6	24325	9 ¹ / ₆₄	2 ⁷ / ₈	.11	10	19.83/ea pkg
HSD7	24330	5 ¹ / ₃₂	3 ¹ / ₈	.14	10	20.15/ea pkg
HSD8	24335	11 ¹ / ₆₄	3 ¹ / ₄	.17	10	22.83/ea pkg
HSD9	24340	3 ¹ / ₁₆	3 ¹ / ₂	.21	10	26.53/ea pkg
HSD29	24345	13 ¹ / ₆₄	3 ⁵ / ₈	.26	10	30.23/ea pkg
HSD10	24350	7 ¹ / ₃₂	3 ³ / ₄	.26	10	31.90/ea pkg
HSD11	24355	15 ¹ / ₆₄	3 ⁷ / ₈	.35	10	34.90/ea pkg
HSD12	24360	1 ¹ / ₄	4	.41	10	40.98/ea pkg
HSD13	24365	17 ¹ / ₆₄	4 ¹ / ₈	.29	5	24.18/ea pkg
HSD14	24370	9 ¹ / ₃₂	4 ¹ / ₄	.28	5	28.40/ea pkg
HSD15	24375	19 ¹ / ₆₄	4 ³ / ₈	.32	5	30.23/ea pkg
HSD16	24380	5 ¹ / ₁₆	4 ¹ / ₂	.36	5	31.80/ea pkg
*HSD16R	24385	5 ¹ / ₁₆	3 ¹³ / ₁₆	.32	NOT INCLUDED	34.40/ea pkg
HSD17	24390	21 ¹ / ₆₄	4 ⁵ / ₈	.39	5	34.58/ea pkg
HSD18	24395	11 ¹ / ₃₂	4 ³ / ₄	.44	5	39.25/ea pkg
HSD19	24400	23 ¹ / ₆₄	4 ⁷ / ₈	.48	5	44.13/ea pkg
HSD20	24405	3 ¹ / ₈	5	.55	5	45.33/ea pkg
*HSD20R	24410	3 ¹ / ₈	4	.43	NOT INCLUDED	48.03/ea pkg
HSD21	24415	25 ¹ / ₆₄	5 ¹ / ₈	.60	5	48.68/ea pkg
HSD22	24420	13 ¹ / ₃₂	5 ¹ / ₄	.64	5	51.70/ea pkg
HSD23	24425	27 ¹ / ₆₄	5 ³ / ₈	.72	5	57.40/ea pkg
HSD24	24430	7 ¹ / ₁₆	5 ¹ / ₂	.82	5	61.28/ea pkg
*HSD24R	24435	7 ¹ / ₁₆	4 ¹¹ / ₁₆	.78	NOT INCLUDED	59.75/ea pkg
HSD25	24440	29 ¹ / ₆₄	5 ⁵ / ₈	.86	5	72.20/ea pkg
HSD26	24445	15 ¹ / ₃₂	5 ³ / ₄	.89	5	69.50/ea pkg
HSD27	24450	31 ¹ / ₆₄	5 ⁷ / ₈	1.00	5	74.03/ea pkg
HSD28	24455	1 ¹ / ₂	6	1.16	5	77.03/ea pkg
*HSD28R	24460	1 ¹ / ₂	4	.07	NOT INCLUDED	80.38/ea pkg

SEE PAGE
279

INCLUDED
IN HSCD1
DRILL
DISPLAY

NOT INCLUDED

NOT INCLUDED

NOT INCLUDED

NOT INCLUDED

* 1/4" Reduced Shank

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST



HIGH-SPEED DRILL COUNTER DISPLAY

An attractive, compact "Point of Purchase" Display, 15" wide X 13" high X 8" deep. Improve sales by providing speedy selection of your complete range of high-speed drills.

- Strong metal construction
- Transparent hinged cover with lock prevents theft

Display contains standard package quantities of all 29 HSD fractional drill sizes in jobber lengths, standard shank, a total of 210 drills.
SEE PAGE 278

FRACTIONAL DRILLS FOR HSCD1 COUNTER DISPLAY

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER EACH	STD. PKG.
HSCD1	24515	Display and 210 Assorted HSD drills	23.60	1 Display



SELECT-A-DRILL

SAD13 - 13 Piece Select-A-Drill Kit

Thirteen (13) high-speed jobber length drills from 1/16" to 1/4" by 64ths. Popular sizes in a unique rotating case

SAD21 - 21 Piece Select-A-Drill Kit

Twenty-one (21) high-speed jobber length drills from 1/16" to 3/8" by 64ths. Popular sizes in a unique rotating case

118° POINT



STOCK NO.	UPC NO.	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SAD13	24520	.32	1	33.23/ea kit
SAD21	24525	.98	1	85.65/ea kit



118° POINT

HIGH-SPEED DRILL KITS

IN METAL INDEX CASE

HSDK1 29 Drills
HSDK2 15 Drills
HSDK3 13 Drills

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
HSDK1	24510	29 Drills 1/16" thru 1/2" by 1/64ths	3.25	1	180.08/ea kit
HSDK2	24505	15 Drills 1/16" thru 1/2" by 1/32nds	2.08	1	95.15/ea kit
HSDK3	24500	13 Drills 1/16" thru 1/4" by 1/64ths	.80	1	31.20/ea kit

TOOLS, DRILLS AND ACCESSORIES



GOLD HIGH-SPEED DRILL KITS

GOLD SURFACE TREATED HEAVY DUTY DRILLS
13 PIECE KIT IN METAL INDEX CASE

HVAC SPECIAL DRILLS
LIGHT GAUGE SHEET METAL



135° SPLIT POINT



THREE FLATS ON SHANK

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER KIT	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
GDK13	24502	13 Drills $\frac{1}{16}$ " thru $\frac{1}{4}$ " x $\frac{1}{64}$ ths	.67	1	45.33/ea kit



HEX SHANK DRILL SET

5 PIECE SET

FOR DRILLS AND CORDLESS SCREWDRIVERS

118° POINT

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER KIT	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
DHS5	24530	5 Drills: $\frac{3}{32}$ " $\frac{7}{64}$ " $\frac{1}{8}$ " $\frac{9}{64}$ " $\frac{5}{32}$ "	.15	Set of 5 drills	29.28/ea

TO PROLONG DRILL LIFE USE CUTTING OIL FOR METAL.

TAP AND DRILL BIT SET

13 PIECE

- 6 Carbon Plug Taps - 4-40, 6-32, 8-32, 10-24, 10-32, $\frac{1}{4}$ -20
- 6 HSS Twist Drills - #43, #36, #29, #25, #21, #7
- 1 T-Handle Wrench



STOCK NO.	UPC NO.	WT. PER KIT	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TDS13	24945	.44	1	59.33/ea

SCREW EXTRACTOR AND DRILL BIT SET

10 PIECE

- Screw Extractors - #1, #2, #3, #4, #5
- Twist Drills - $\frac{5}{64}$ " $\frac{7}{64}$ " $\frac{5}{32}$ " $\frac{1}{4}$ " $\frac{17}{64}$ "

118° POINT

STOCK NO.	UPC NO.	WT. PER KIT	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SEDS10	25028	.47	1	48.80/ea



TOOLS, DRILLS AND ACCESSORIES



COMBINATION HIGH SPEED STEEL DRILL-TAP

FOR ALL METAL APPLICATIONS

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER KIT	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
DT632	24094	High Speed Steel 6-32 Drill-Tap	.02	1	31.63/ea
DT832	24095	High Speed Steel 8-32 Drill-Tap	.02	1	32.38/ea
DT1032	24096	High Speed Steel 10-32 Drill-Tap	.02	1	33.55/ea
DT1420	24097	High Speed Steel 1/4-20 Drill Tap	.03	1	39.18/ea
DT3816	24098	High Speed Steel 3/8-16 Drill-Tap	.08	1	54.78/ea
DT1213	24099	High Speed Steel 1/2-13 Drill-Tap	.13	1	76.88/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST



SHIP AUGER BITS

HEX SHANK
EXTRA HIGH QUALITY

- Single twist with single cutter and side up
- Machine ground hollows, deep throat for fast chip removal
- 7/16" shank for 3 jaw chucks
- Heat treated tool steel for strength and long life
- **E-Z to display packaging!**

SPECIFICALLY DESIGNED FOR WOOD PRODUCT CONSTRUCTION

STOCK NO.	UPC NO.	BORE DIAMETER	LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
AS916	24600	9/16	8	.25	1 Bit	27.83/ea
AS58	24601	5/8	8	.28	1 Bit	26.78/ea
AS1116	24602	11/16	8	.31	1 Bit	37.80/ea
AS34	24603	3/4	8	.43	1 Bit	45.08/ea
AS1316	24604	13/16	8	.42	1 Bit	45.18/ea
AS78	24605	7/8	8	.54	1 Bit	53.05/ea
AS1516	24606	15/16	8	.40	1 Bit	54.05/ea
AS1	24607	1	8	.45	1 Bit	57.38/ea
AS118	24608	1 1/8	8	.79	1 Bit	64.35/ea
AS114	24609	1 1/4	8	.55	1 Bit	74.18/ea
AS138	24610	1 3/8	8	.82	1 Bit	96.48/ea
AS112	24611	1 1/2	8	1.22	1 Bit	103.40/ea
AL916	24615	9/16	18	.65	1 Bit	58.30/ea
AL58	24616	5/8	18	.72	1 Bit	64.25/ea
AL1116	24617	11/16	18	.87	1 Bit	72.58/ea
AL34	24618	3/4	18	.71	1 Bit	73.80/ea
AL1316	24619	13/16	18	1.08	1 Bit	73.80/ea
AL78	24620	7/8	18	1.24	1 Bit	76.03/ea
AL1516	24621	15/16	18	1.36	1 Bit	70.70/ea
AL1	24622	1	18	1.54	1 Bit	73.68/ea
AL118	24623	1 1/8	18	1.42	1 Bit	105.70/ea
AL114	24624	1 1/4	18	2.35	1 Bit	113.00/ea
AL138	24625	1 3/8	18	2.94	1 Bit	126.73/ea
AL112	24626	1 1/2	18	3.30	1 Bit	133.70/ea

THE METALLICS SHIP AUGER BIT IS NOT SOLD AS A NAIL BITER. IT IS ONLY RECOMMENDED FOR WOOD PRODUCTS.

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

TOOLS, DRILLS AND ACCESSORIES




QUIK-BIT FLAT WOOD BORING BIT

PACKED IN VINYL POUCH
E-Z TO DISPLAY PACKAGING

STOCK NO.	UPC NO.	SIZE	OVERALL LENGTH	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
QB1	24701	1/4	6	.05	1 Bit	6.65/ea
QB2	24702	5/16	6	.06	1 Bit	6.28/ea
QB3	24703	3/8	6	.09	1 Bit	6.75/ea
QB4	24704	7/16	6	.06	1 Bit	6.75/ea
QB5	24705	1/2	6	.09	1 Bit	6.75/ea
QB6	24706	9/16	6	.09	1 Bit	7.08/ea
QB7	24707	5/8	6	.09	1 Bit	7.08/ea
QB8	24708	11/16	6	.09	1 Bit	7.33/ea
QB9	24709	3/4	6	.09	1 Bit	7.33/ea
QB10	24710	13/16	6	.10	1 Bit	7.43/ea
QB11	24711	7/8	6	.10	1 Bit	7.73/ea
QB12	24712	15/16	6	.11	1 Bit	8.28/ea
QB13	24713	1	6	.13	1 Bit	8.28/ea
QB14	24714	1 1/8	6	.13	1 Bit	11.35/ea
QB15	24715	1 1/4	6	.13	1 Bit	11.35/ea
QB16	24716	1 3/8	6	.14	1 Bit	11.48/ea
QB17	24717	1 1/2	6	.14	1 Bit	11.48/ea
QB22	24722	3/8	16	.27	1 Bit	20.50/ea
QB24	24724	1/2	16	.33	1 Bit	20.93/ea
QB26	24726	5/8	16	.28	1 Bit	22.83/ea
QB28	24728	3/4	16	.28	1 Bit	25.15/ea
QB29	24729	7/8	16	.32	1 Bit	25.15/ea
QB31	24731	1	16	.30	1 Bit	24.53/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

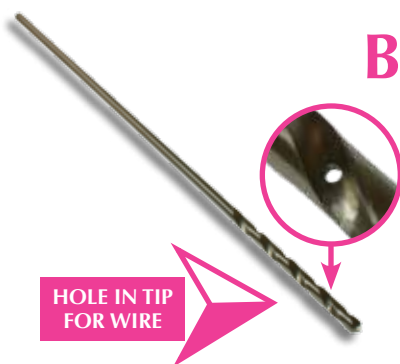

BELL HANGER'S DRILL

HIGH-GRADE STEEL
E-Z TO DISPLAY PACKAGING

- Specifically designed for wood product construction
- For all telephone, electrical, small wire, protective alarm and cable T.V. uses
- Resists damage during drilling if metal is encountered
- Not for masonry products

STOCK NO.	UPC NO.	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BHD5	26020	1/4	18	1/4	.26	1 Drill	33.03/ea
BHD6	26025	5/16	18	5/16	.40	1 Drill	36.68/ea
BHD7	26030	3/8	18	3/8	.56	1 Drill	39.55/ea
BHD8	26035	1/2	18	3/8	.90	1 Drill	45.13/ea
BHD9	26040	1/4	24	1/4	1.00	1 Drill	46.38/ea
BHD10	26045	5/16	24	5/16	.69	1 Drill	50.40/ea
BHD11	26050	3/8	24	3/8	.70	1 Drill	52.38/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

TOOLS, DRILLS AND ACCESSORIES



SDS-PLUS HAMMER DRILL

IDEAL FOR ROTARY AND PERCUSSION DRILLING
FOR ALL MASONRY PRODUCTS

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
SDS31645	24101	3/16" x 4-1/2" SDS-Plus Hammer Drill Bit	.08	16.38/ea
SDS31665	24102	3/16" x 6-1/2" SDS-Plus Hammer Drill Bit	.10	16.70/ea
SDS3168	24103	3/16" x 8" SDS-Plus Hammer Drill Bit	.10	23.53/ea
SDS1445	24104	1/4" x 4-1/2" SDS-Plus Hammer Drill Bit	.09	16.38/ea
SDS1465	24106	1/4" x 6-1/2" SDS-Plus Hammer Drill Bit	.11	16.70/ea
SDS149	24107	1/4" x 9" SDS-Plus Hammer Drill Bit	.14	23.53/ea
SDS3865	24108	3/8" x 6-1/2" SDS-Plus Hammer Drill Bit	.16	21.98/ea
SDS389	24109	3/8" x 9" SDS-Plus Hammer Drill Bit	.20	42.33/ea
SDS1265	24111	1/2" x 6-1/2" SDS-Plus Hammer Drill Bit	.22	29.98/ea
SDS129	24112	1/2" x 9" SDS-Plus Hammer Drill Bit	.34	48.43/ea
SDS5865	24113	5/8" x 6-1/2" SDS-Plus Hammer Drill Bit	.26	39.88/ea
SDS589	24114	5/8" x 9" SDS-Plus Hammer Drill Bit	.31	48.43/ea
SDS3465	24116	3/4" x 9" SDS-Plus Hammer Drill Bit	.45	80.58/ea

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

POWER BIT EXTENSIONS

FOR USE WITH QUIK-BITS, SHIP AUGER, AND POWER BITS



- Hex wrench included
- Two set screws
- E-Z TO DISPLAY PACKAGING

STOCK NO.	UPC NO.	SIZE	WT. EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BE1418	24875	1/4" x 18	.48	1	44.05/ea
BE5618	24880	5/16" x 18	1.50	1	41.23/ea
BE7612	24885	7/16" x 12	.86	1	43.28/ea
BE7618	24890	7/16" x 18	1.20	1	49.98/ea
BE7624	24891	7/16" x 24	1.56	1	61.48/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



SD34

MULTI STEP DRILLS

SELF STARTING TIP ELIMINATES NEED FOR PILOT HOLE DRILLING
GOOD IN ALL SHEET METALS UP TO 1/8" THICK



SD12

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SD12	24080	1/8-1/2" 2 FLUTE, 13 STEP	.06	1	55.10/ea
SD34	24082	1/4-3/4" 2 FLUTE, 9 STEP	.10	1	80.00/ea
SD78	24084	7/8 TO 1 1/8" 3 STEP	.16	1	123.08/ea
3 SET COMBO PACK					
SDCP3	24088	1/8 TO 1/2" 2 FLUTE, 13 STEP	.37	1	
		1/4 TO 3/4" 2 FLUTE, 9 STEP			
		7/8 TO 1 1/8" 3 STEP			

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

SAWTOOTH MULTISPUR WOOD DRILL BITS



PACKAGED INDIVIDUALLY
WITH EXTRA DOUBLE END
SCREWS AND WRENCH

E-Z TO DISPLAY
PACKAGING

REPLACEMENT SCREW POINTS

STOCK NO.	UPC NO.	SIZE	FITS
SP0001	23550	1/4"	1 1/4" - 2 9/16"
SP0002	23552	1/4"	3 - 4 5/16"

STOCK NO.	UPC NO.	DESCRIPTION	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
306MS0	23500	1 3/8" for 3/4" pipes	7/16"	.43	1	64.38/ea
306MS1	23505	1 1/2" for 1" pipes	7/16"	.46	1	64.38/ea
306MS2	23510	1 3/4" for 1 1/4" pipes	7/16"	.51	1	66.23/ea
306MS3	23515	2 1/8" for 1 1/2" pipes	7/16"	.74	1	66.23/ea
306MS4	23520	2 9/16" for 2" pipes	7/16"	.89	1	100.33/ea

EXTENSIONS FOR SHIP AUGERS & MULTISPUR

HEX WRENCH INCLUDED • TWO SET SCREWS • PACKAGED IN VINYL POUCH

BE7612	24885	7/16" x 12	.86	1	43.28/ea
BE7618	24890	7/16" x 18	1.20	1	49.98/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

BULK PACKAGED CARBIDE MASONRY DRILLS

The Five Most Popular Sizes



STOCK NO.	UPC NO.	DIAMETER	LENGTH	SHANK DIAMETER	QTY.	WT. PER PKG.	SUGGESTED TRADE LIST PRICE PER
BFRB12	37050	1/4"	4	1/4"	100	3.43	268.55/ea pkg
BFRB14	37055	5/16"	4	1/4"	75	3.08	254.28/ea pkg
BFRB16	37060	3/8"	4	1/4"	50	3.14	109.95/ea pkg
BFRB21	37065	1/2"	4	1/4"	25	2.64	39.45/ea pkg

OTHER SIZES AND QUANTITY AVAILABLE UPON REQUEST

FLEXIBLE FISH-BITS

- Unique flexible self-feeding bits up to 72" long suitable for drilling holes with the length of wall cavities and through hidden studs with no damage to wallboard plaster or any exterior finish.
- Bit has hole at tip and the shank which allows you to fish wire



STOCK NO.	UPC NO.	DESCRIPTION	SIZE	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFB1454	26455	FISH-BIT	1/4" x 54	3/16"	.65	1	64.30/ea
MFB3854	26459	FISH-BIT	3/8" x 54	3/16"	.65	1	67.60/ea
MFB1254	26451	FISH-BIT	1/2" x 54	3/16"	.65	1	70.70/ea
MFB1472	26457	FISH-BIT	1/4" x 72	3/16"	.75	1	68.18/ea
MFB3872	26461	FISH-BIT	3/8" x 72	3/16"	.75	1	69.08/ea
MFB1272	26453	FISH-BIT	1/2" x 72	3/16"	.65	1	71.30/ea
MSG1	26445	Steering Guide			.47	1	59.88/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

CARBIDE MASONRY DRILLS

IDEAL FOR ROTARY AND PERCUSSION DRILLING

BLACK



- Specially designed spirals for fast dust removal
- **E-Z TO DISPLAY PACKAGING**
- Slow spiral drills can be used with **either rotary or hammer drills** in hard brick, sandstone, bluestone, terracotta block and hard concrete

STOCK NO.	UPC NO.	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BFR10	24100	1/8	3	3/32	.02	1	2.98/ea
BFR11	24105	3/16	4	9/64	.03	1	2.98/ea
BFR12	24110	1/4	4	1/4	.04	1	2.98/ea
BFR13	24115	1/4	6	1/4	.06	1	4.35/ea
BFR14	24120	5/16	4	1/4	.05	1	3.75/ea
BFR15	24125	5/16	6	1/4	.08	1	5.40/ea
BFR16	24130	3/8	4	1/4	.07	1	4.88/ea
BFR17	24135	3/8	6	1/4	.11	1	6.05/ea
BFR18	24140	7/16	6	1/4	.15	1	6.15/ea
BFR21	24145	1/2	4	1/4	.11	1	7.00/ea
BFR19	24150	1/2	6	1/4	.20	1	8.23/ea
BFR20	24155	1/2	6	3/8	.20	1	8.23/ea
BTT22	24160	9/16	6	3/8	.31	1	15.80/ea
BTT23	24165	5/8	6	3/8	.31	1	22.10/ea
BTT25	24175	7/8	6	1/2	.58	1	22.48/ea
BTT26	24180	1	6	1/2	.75	1	29.50/ea
BTT1	24185	1/4	12	1/4	.15	1	11.28/ea
BTT2	24190	5/16	12	1/4	.22	1	11.43/ea
BTT4	24200	1/2	12	3/8	.44	1	15.88/ea
BTT5	24205	5/8	12	3/8	.62	1	21.03/ea
BTT6	24210	3/4	12	1/2	.91	1	33.23/ea
BTT7	24215	7/8	12	1/2	1.24	1	34.88/ea
BTT8	24220	1	12	1/2	1.53	1	47.33/ea

OTHER QUANTITIES AVAILABLE UPON REQUEST

EXTRA LONG MASONRY DRILLS



HEAVY-DUTY CARBIDE TIPPED

E-Z TO DISPLAY PACKAGING

STOCK NO.	UPC NO.	DIAMETER	LENGTH	SHANK DIAMETER	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
BTT9	24225	1/4	18	1/4	.22	1	19.58/ea
BTT11	24235	3/8	18	3/8	.45	1	21.50/ea
BTT12	24240	1/2	18	3/8	.64	1	25.18/ea
BTT13	24245	5/8	18	1/2	.94	1	29.90/ea
BTT14	24250	3/4	18	1/2	1.37	1	36.55/ea
BTT15	24255	7/8	18	1/2	1.79	1	71.40/ea
BTT16	24260	1	18	1/2	2.50	1	71.58/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

TOOLS, DRILLS AND ACCESSORIES

MASTER FLASH® COMPLETE ROOF JACK KIT



(Roof Jack Only)

Everything in ONE KIT!

- The Master Flash® Roof Jack
- UV Cable Tie
- Metalics Special Sealant
- 10 x 1 Indented Hex Tek Type Self-Drilling Screws
- Easy Installation Instructions

Universal Pipe Flashing System...

- Weather Resistant
- Adapts to Many Roof Surfaces
- Easily Installed
- Uniform Plumbing Code (UPC®) Listed

Numerous Applications...

- Plumbing, Heating/Air Conditioning Equipment
- Electrical Service Entrances
- TV Aerials
- Masts, Vents or Pipes Through Decks or Bulkheads



STOCK NO.	UPC NO.	FITS PIPE SIZES/ JACK BASE SIZE	DESCRIPTION OF CONTENTS	WEIGHT EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RJK1	31400	1/4" - 2" 4 1/2" Base	1 - Roof Jack, 1 - 25" Sealant Strip, 12 - Drive Screws, 1 - 11" Cable Tie	.51	1	30.08/ea
RJK2	31401	1/4" - 3" 6" Base	1 - Roof Jack, 1 - 35" Sealant Strip, 16 - Drive Screws, 1 - 15" Cable Tie	.77	1	34.95/ea
RJK3	31402	1/4" - 4" 8" Base	1 - Roof Jack, 1 - 45" Sealant Strip, 20 - Drive Screws, 1 - 21" Cable Tie	1.13	1	41.10/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

MASTER FLASH ROOF JACKS - BULK/UNPACKAGED

STOCK NO.	UPC NO.	FITS PIPE SIZES/ JACK BASE SIZE	DESCRIPTION OF CONTENTS	WEIGHT EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
RJK1B	31237	1/4" - 2" for 4 1/2" Base	1 - Roof Jack	.25	1	18.48/ea
RJK2B	31238	1/4" - 3" for 6" Base	1 - Roof Jack	.50	1	21.30/ea
RJK3B	31239	1/4" - 4" for 8" Base	1 - Roof Jack	.75	1	25.05/ea

OTHER SIZES AND QUANTITIES AVAILABLE UPON REQUEST

MASTER FLASH® IS A REGISTERED TRADEMARK

DAP® DOW CORNING® SILICONE SEALANT

Protect and seal with 100% silicone rubber. Waterproof and flexible. Non-paintable.
50 year manufacturer durability guarantee. Meets ASTM C-920, Class 25, Type S, Grade NS.



STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
WDSC10	71234	CLEAR - 10.1 oz.	.86	1	12.50/ea
WDSW10	71235	WHITE - 10.1 oz.	.78	1	12.78/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

DAP® DOW CORNING® ARE A REGISTERED TRADEMARK


GREY BUTYL TAPE FOR CAULKING

(SOLD IN PLASTIC BAGS)

STOCK NO.	UPC NO.	DESCRIPTION	WT. PER PKG.	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
TC1	31236	1/8" thick x 3/4" wide x 30' long.	1.08	1	24.23/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



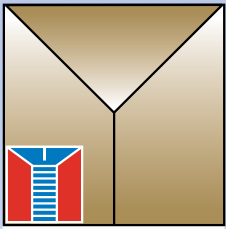

Metallics

Master Flash Complete Roof Jack Kit



**[CONTRACTOR
APPROVED]**

- New Packaging
- EZ to Display
- EZ to Store



PART #	UPC #	DESCRIPTION	FITS PIPE SIZE	JACK BASE SIZE	SUG. TRADE LIST / PKG
RJK1	31400	Roof Jack, Sealant Strip, Drive Screws and Cable Tie	1/4" - 2"	4 1/2" Base	\$ 30.08
RJK2	31401	Roof Jack, Sealant Strip, Drive Screws and Cable Tie	1/4" - 3"	6" Base	\$ 34.95
RJK3	31402	Roof Jack, Sealant Strip, Drive Screws and Cable Tie	1/4" - 4"	8" Base	\$ 41.10

"Growth Through Innovation"

Metallics


229 Cross Street, Bristol, CT 06010
Tel 800-243-8272 • **Fax** 800-831-9358
Email sales@metallicsonline.com

Metallics West

651 North Main Street, Mancos, CO 81328
Tel 800-269-5183 • **Fax** 800-269-6278
Email saleswest@metallicsonline.com

www.metallicsonline.com

TOOLS, DRILLS AND ACCESSORIES

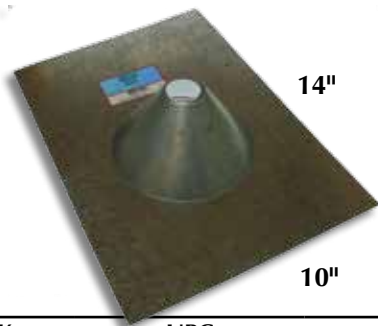


ROOF JACKS

26 GAUGE
10" x 14" Standard Base
Two-piece galvanized

STOCK NO.	UPC NO.	PIPE SIZE	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MF50	31410	1/2"	1.00	1	8.08/ea
MF75	31411	3/4"	1.05	1	8.08/ea
MF100	31412	1"	.95	1	8.08/ea
MF125	31413	1 1/4"	.95	1	8.08/ea
MF150	31414	1 1/2"	.95	1	8.08/ea

For 0/12 - 5/12 roof pitch

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

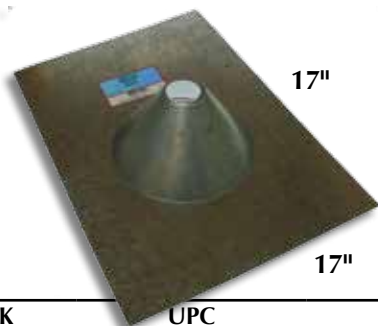


ROOF JACKS

26 GAUGE - FHA
17" x 17" Shingle Base
Two-piece galvanized

STOCK NO.	UPC NO.	PIPE SIZE	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFHA50	31416	1/2"	1.80	1	10.03/ea
MFHA75	31417	3/4"	1.80	1	10.03/ea
MFHA100	31418	1"	1.80	1	10.03/ea
MFHA125	31419	1 - 1/4"	1.80	1	10.03/ea
MFHA150	31420	1 - 1/2"	1.75	1	10.03/ea
MFHA200	31421	2"	1.75	1	10.03/ea

For 0/12 - 5/12 roof pitch

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

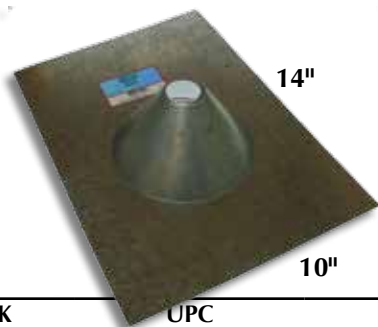

The Economical One! ROOF JACKS

26 GAUGE
One-Piece Spun Galvanized

STOCK NO.	UPC NO.	PIPE SIZE	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
SMF50	31422	1/2"	.75	1	6.95/ea
SMF75	31423	3/4"	.75	1	6.95/ea
SMF100	31424	1"	.75	1	6.95/ea
SMF125	31425	1 1/4"	.75	1	6.95/ea
SMF150	31426	1 1/2"	.75	1	6.95/ea
SMF200	31427	2"	.75	1	6.95/ea

For 0/12 - 5/12 roof pitch

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST

3-in-1 ROOF FLASHINGS

GALVANIZED BASE ROOF FLASHINGS
24 GAUGE WITH ELASTOMER COLLAR



Stock No. MRJ50

Fits pipe sizes: 1/2", 3/4", 1"

Fits base size: 8-3/4" x 12-1/2"

- Slides over pipe - for pitch to 45 degree.
- Rustproof, stamped galvanized 24 gauge.
- 18" x 18" base for code required areas.
- Rated 180°F continuous heat.
- Approved for Type B installations.



Stock No. MRJ125

Fits pipe sizes: 1-1/2", 2", 3"*

Fits base size: 10-3/4" x 12-1/2"

* Can be modified to fit 1-1/4" pipe

- Slides over pipe. Type of base determines pitch.
- Ring on collar tears off, allowing flashings to seal different pipe diameters.
- Non-fading, cracking and rusting bases and sealing collars.
- Rated 180°F continuous heat.
- Approved for Type B installations.

STOCK NO.	UPC NO.	PIPE SIZE	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MRJ50	31408	1/2" - 1"	.82	1	12.80/ea
MRJ125	31409	1-1/4" - 3"	1.16	1	15.78/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



FLOOR FLANGE

ZINC PLATED

PACKAGED IN POLY BAGS

STOCK NO.	UPC NO.	PIPE SIZE	ANCHOR HOLE	WT. PER EACH	STD. PKG.	SUGGESTED TRADE LIST PRICE PER
MFF25	16201	1/2"	1/4"	.27	1	5.70/ea
MFF75	16202	3/4"	1/4"	.49	1	6.75/ea
MFF100	16203	1"	1/4"	.65	1	8.65/ea
MFF125	16204	1 1/4"	1/4"	.88	1	11.80/ea
MFF150	16205	1 1/2"	1/4"	1.16	1	12.50/ea
MFF200	16206	2"	5/16"	1.55	1	16.60/ea

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST



**Metallics and Avanti
Screw, Inc.**
**Where
Manufacturing
Quality is Job
One!**

TOOLS, DRILLS AND ACCESSORIES



MASTER LOCK®

FULLY ADJUSTABLE 5/16" x 6' LOCKING VINYL COATED BRAIDED STEEL CABLE

Increased Security:

Cable length adjust to any position from 6' to 6'.

Application Flexibility:

Threads through places other cables cannot.

Cut Resistant:

5/16" (8mm) braided steel cable.

Scratch Resistant:

Vinyl coated cable and ABS plastic lock body.

Pick Resistant:

Reliable pin tumble mechanism.



Don't Just Tie It Down, Lock It Down!

STOCK NO.	UPC NO.	U/M	SUGGESTED TRADE LIST PRICE PER
PYLO1BLK	13080	1	24.33/ea.
PYLO1CAM	13085	1	27.83/ea.



RUBBER TARP STRAPS

STOCK NO.	UPC NO.	STRAP LENGTH MINUS HOOKS	WT.	SUGGESTED TRADE LIST PRICE PER	
RTS14	12060	10"	.19	2.31/ea.	NEW
RTS19	12062	15"	.24	2.81/ea.	NEW
RTS24	12064	21"	.25	3.56/ea.	NEW
RTS35	12066	31"	.33	4.44/ea.	NEW
RTS45	12068	41"	.40	6.13/ea.	NEW

OTHER SIZES AND QUANTITIES AVAILABLE BY REQUEST