

NEBO®

INNOVATIVE LIGHTING

2019



We are one of the world's best-selling lines of innovative, consumer-friendly flashlights and tools.

Ever-changing and never compromising, we create and see our products through every phase of development. From the concept to consumer, we offer quality and customer service guarantees that are unmatched.

6 million+ sold per year

With over 30,000 retail customers, we get instant market feedback on up-take and trends giving us unparalleled insight leading to the competitive edge in development.

Innovation & retail value

We bring cutting edge design with high lumen output to our line. Our established retails create a value proposition without jeopardising quality or product integrity.

International Patents

This secures our place in the market and brings protection to our customers and products from counterfeit threats.

Global distribution

NEBO® is a division of Alliance Sports Group (ASG), with headquarters in Grand Prairie, TX, USA. True Brands Ltd is a UK based wholly owned subsidiary of ASG, handling the global distribution and selling of NEBO® products throughout the world.

Top 5 Customers

Wal-Mart (30 yrs), Dicks Sporting Goods (4 yrs), Academy Sports (3 yrs), Bass Pro Shops (6 yrs), Sears Holding Corp. (25 yrs)

Proven business model

Solid dependable capacity working with some of the largest factories in the Far East delivering the highest quality.

NEBO® IN THE MARKET

As technology progresses, consumers are coming to expect better value for their money.

There is a focus on reducing energy consumption and a heavier focus on "green" living overall. High Powered LED's, lens technology and rechargeable flashlights are all utilities that we have incorporated into our assortment, and we are always learning and discovering other innovative ways to better our value at consumer level.

NEBO® flashlights deliver optimum performance. Products are of the highest quality, innovatively designed, with special features and patented technology. Eye-catching packaging, clever point of sale and interactive TRY ME features set them apart from many of the more expensive, less innovative major brands and the many sub-standard low cost brands. In this way, we have carved out market positioning that has enabled the brand to continually increase market share and grow into one of the largest flashlight brands in the world.



Patents



C•O•B (Chips on Board)

A new innovation in LED technology. C•O•B features smaller, easier clustered LED chips that are mounted directly to the circuit board. These LED chips work together as one lighting module. Because of the compact design, C•O•B outperforms traditional lighting by up to 50 times the light output per centimetre of light surface.



OPTIMISED CLARITY

Eliminating inconsistencies in light, the OC™ - Optimised Clarity Technology provides intense, clear, pristine light that is easy on the eyes. This technology allows the light beam to be as bright on the edge as it is in the center when used in flood mode.



ARCUS™

Shaping light like never before. Arcus is a new proprietary C•O•B LED technology that allows the shaping of light into full 3D patterns, giving optimal, bright, uniform light exactly where it's needed.



FLEX POWER™

FLEX-POWER™, technology allows the flexibility to use different quantities of batteries to power the light.

We are excited to introduce to you our latest line-up of new and innovative lighting products with counter top displays.

All of these high quality practical LED lighting products come complete with their own cleverly created point of sale displays, intended to sit directly on the countertop, near the till point - taking up as little space as possible and offering a unique and impulsive 'TRY & BUY' shopping experience.

The displays are designed to help you to sell as much stock as possible by encouraging your customers to interact, discover, and be impressed by the quality and brightness of these innovative and exciting NEBO® lighting products.



Bright Ideas is presented in language free eye catching, green and white euro-hook packaging that stands out from the competition.

The packs clearly show the product features through the use of internationally recognisable icons, enabling them to be sold worldwide.

All Bright Ideas product packs include a "TRY ME" feature to encourage your customers to interact, discover and be impressed by the quality and brightness of these innovative and exciting NEBO® lighting products.



The Bright Ideas products are well suited for retailers that sell from display hooks and Ideal for selling throughout the Outdoor, Camping, Travel, Auto, Garden, Home and Gift sectors.



iPROTEC flashlights are practical, enjoyable to own and far exceed expectations relative to their price.

They are "MADE TOUGH", ensuring each of our flashlights are rugged and highly dependable whilst also being compact and easy to pack away.

iPROTEC flashlights have lumen outputs that are equal to those of much more expensive products.



MADE TOUGH

REDLINE BIG DADDY™

The brightest flashlight ever created by NEBO is here – the Redline Big Daddy.

This completely waterproof (IPX7) flashlight features a powerful 2,000 lumen output, 4x adjustable zoom, 5 unique light modes and a convenient carry lanyard. The BIG DADDY is everything you could need in a flashlight, and then some!

- 5 LIGHT MODES
- HIGH (2000 lumens) - 3 hours / 346 meters
 - MEDIUM (800 lumens) - 6 hours / 219 meters
 - LOW (500 lumens) - 15 hours / 173 meters
 - STROBE (2000 lumens) - 6 hours / 346 meters
 - BEACON (2000 lumens) - 8 hours / 346 meters

- DESIGN
- Waterproof (IPX7)
 - Convex lens
 - Tactical edge
 - 4x adjustable zoom
 - Signature Red Ring®
 - Anodised aircraft-grade aluminum; impact-resistant
- OPERATION
- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology
- ACCESSORIES
- Lanyard included
- BATTERIES
- Powered by 9 AA batteries (included)
- SPECS
- 601g
 - Length: Compacted: 229mm / Extended: 248mm
 - Diameter: (Head) 57mm / (Barrel) 38mm
- PATENT
- 659,869 S



- Display holds 3 pieces - additional pieces included as replenishments.

DISPLAY DIMENSIONS
(H) 349mm x (W) 216mm x (D) 229mm



ITEM	DESCRIPTION	CASE PACK
NE6692	REDLINE® BIG DADDY	8 PIECES

REBEL™



The REBEL is a fully rechargeable task light that includes an adjustable head strap for use as a head lamp.

Small enough to fit in the palm of your hand, this powerful light rebels against its size with its impressive 600 lumen output. This bright light is also equipped with a rotating, removable steel clip and powerful magnetic base to provide even more hands-free lighting options.

4 LIGHT MODES

- HIGH (240 lumens) - 2 hours / 56 meters
- LOW (60 lumens) - 4.5 hours / 28 meters
- TURBO (600 lumens) - 40 seconds / 90 meters
- STROBE (600 lumens) - 2 hours / 90 meters

DESIGN

- Fully rechargeable
- Removable steel clip
- Anodised aircraft-grade aluminum; water and impact-resistant

OPERATION

- Top-positioned, ON/OFF button

ACCESSORIES

- Adjustable head strap; one size fits all
- Magnetic USB to Micro USB charging cable with charging indicator included

BATTERIES

- Powered by rechargeable battery (included)
(Recharge time: 1.5 - 2 hours)

SPECS

- 85g
- (H) 72.39mm x (W) 30mm x (D) 25mm



- Display holds 2 pieces in front for testing, additional pieces can be stored in the back as replenishments.

- Each REBEL™ comes with a gift box

- Product attaches securely to the display using the magnetic base.

DISPLAY DIMENSIONS

(H) 292mm x (W) 273mm" x (D) 349mm

GIFT BOX DIMENSIONS

(H) 133mm x (W) 82mm x (D) 62mm



ITEM	DESCRIPTION	CASE PACK
NE6691	REBEL 600 Lumen Task Light / Head Lamp	12 PIECES

The LEO™ is an amazingly versatile pocket light.

Fully dimmable and equipped with Memory Power Setting, the LEO's work light and spot light pivot and rotate to direct the light wherever you need it. A pocket clip, magnetic base and a kick stand / hanging hook give the LEO endless options of hands-free lighting.

- 2 LIGHT MODES**
- Work Light (220 lumens) - 5 hours / 22 meters
 - Spot Light (80 lumens) - 7 hours / 52 meters

- DESIGN**
- Rotating directional light
 - Non-slip rubber coating
 - Water and impact-resistant
 - Fully dimmable
 - Memory Power Setting
 - Pocket clip
 - Powerful magnetic base
 - Kick stand / hanging hook

- OPERATION**
- Top-positioned, ON/OFF button; hold to dim


- BATTERIES**
- Powered by 3 AAA batteries (included)

- SPECS**
- 87g
 - Length: 168mm / Extended: 247mm
 - Width: 19mm / Depth: 35mm



ASSORTED COLORS

Grey Black Orange

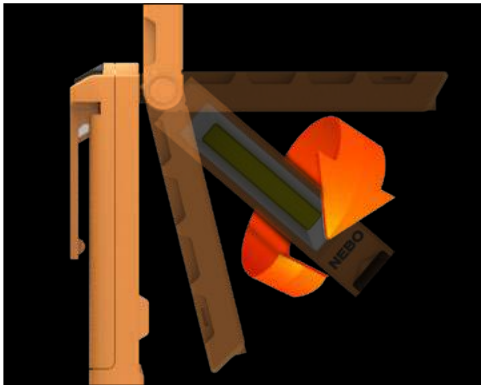

- Display showcases 3 pieces in front - additional pieces can be stored in the back of the display.
- Each LEO™ comes with a gift box.

DISPLAY DIMENSIONS
(H) 330mm x (W) 121mm x (D) 138mm

GIFT BOX DIMENSIONS
(H) 170mm x (W) 34mm x (D) 23mm

ITEM	DESCRIPTION	CASE PACK
NE6657	LEO Work Light and Spot Light	24 PIECES

ARC500

RECHARGEABLE BIKE LIGHT

The ARC500 Rechargeable Bike Light features 2 independently controlled light sources.

A 500 lumen spot light and a 120 lumen C•O•B flood light. The C•O•B flood light covers 250° using ARCUS LED Technology, which allows the user to be visible from multiple angles, enhancing the user's safety.

2 LIGHT MODES - SPOT LIGHT

- High (500 lumens) - 2.5 hours / 188 meters
- Low (170 lumens) - 3.25 hours / 105 meters

4 LIGHT MODES - C•O•B FLOOD LIGHT

- High (120 lumens) - 4.5 hours / 18 meters
- Low (60 lumens) - 7.5 hours / 13 meters
- Day Flash - 30 hours / 7 meters
- Night Flash - 6 hours / 14 meters

DESIGN

- Fully rechargeable
- Water and impact-resistant
- Mount allows light to swivel 90°
- Tool-free universal mounting system
- Quick-release mount design
- Battery charging indicator

OPERATION

- Top-positioned, independently controlled ON/OFF buttons for spot and flood light

ACCESSORIES

- USB to Micro USB charging cable (included)

BATTERIES

- Internal, rechargeable lithium-ion battery (Recharge time: 2 - 4 hours)

SPECS

- 181g
- (H) 122mm x (W) 41mm



Each ARC500 features 'TRY ME' packaging and comes with an instruction manual

DIMENSIONS
(H) 178mm x (W) 92mm x (D) 70mm



The BIG CRYKET™ is a versatile 3-in-1 LED light.

Featuring a 300 lumen C•O•B work light, a bright 300 lumen spot light and an intense red light. Its unique swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.

3 LIGHT MODES

- Spot Light (300 lumens) - 5 hours / 140 meters
- C•O•B Flood Light (300 lumens) - 5.5 hours / 20 meters
- Red (30 lumens) - 10 hours / 6 meters

DESIGN

- Fully dimmable
- Power memory setting
- Direct-to-red feature
- Anodised aircraft-grade aluminum; water and impact-resistant
- 90° swivel head
- Dual-direction steel belt/pocket clip
- Powerful magnetic base
- Rubberised non-slip grip

OPERATION

- Side-positioned, ON/OFF button

BATTERIES

- Powered by 3 AA batteries (included)

SPECS

- 255g
- (H) 138mm x (W) 46mm

PATENT PENDING



- Display holds 1 piece in front for consumer testing, additional pieces can be stored in the back as replenishments.
- Each BIG CRYKET™ comes with a gift box
- Product attaches securely to the display using the magnetic base.

DISPLAY DIMENSIONS
(H) 355mm x (W) 139mm x (D) 197mm

GIFT BOX DIMENSIONS
(H) 146 x (W) 80mm x (D) 66mm



ITEM	DESCRIPTION	CASE PACK
NE6641	ARC500 Rechargeable Bike Light	6 PIECES

ITEM	DESCRIPTION	CASE PACK
NE6666	BIG Cryket 300 Lumen Work Light	16 PIECES

TANGO™

The TANGO features 2 high power light sources, a 250 lumen spot light and 750 lumen C•O•B work light.

The TANGO is fully rechargeable and also serves as a power bank for your USB powered devices. A seven position 180° rotating arm functions as a hanging hook, carry handle, or a kickstand. Best of all, use Turbo mode to combine the spot light and work light for 1,000 lumens of intense illumination, after all, it takes two to TANGO.

3 LIGHT MODES

- **Work Light (750 lumens)** - 2 hours / 45 meters
- **Spot Light (250 lumens)** - 5 hours / 135 meters
- **TURBO MODE (1000 lumens)** - 2 minutes

DESIGN

- Fully rechargeable
- Power bank for your USB powered devices
- Full dimming
- Memory Power Setting
- Non-slip rubber coating
- Water and impact-resistant
- 180° pivoting base
- Battery charging indicator

OPERATION

- Rear-positioned, ON/OFF button; hold to dim

ACCESSORIES

- Micro USB to USB cable and AC adapter included

BATTERIES

- Powered by rechargeable battery (included)
(Recharge time: 5 - 6 hours)

SPECS

- 390g
- (H) 149mm x (W) 149mm x (D) 44mm

 **RECHARGEABLE**

 **C.O.B**
LED CHIP TECHNOLOGY



- Display holds 3 pieces - additional pieces included as replenishments.

DISPLAY DIMENSIONS
(H) 330mm x (W) 120mm x (D) 140mm



ITEM	DESCRIPTION	CASE PACK
NE6665	TANGO Work Light & Spot Light	10 PIECES

SLIM

The NEBO SLIM is a thin, ergonomic rechargeable pocket light that outputs 500 lumens of intense bright light.

Equipped with full dimming and Power Memory Recall, the SLIM also features a pocket clip, collapsible hanging hook and powerful magnetic base for convenient hands-free lighting.

1 LIGHT MODE - with Dimming
• 100% (500 lumens) - 2 hours / 58 meters
• 10% (50 lumens) - 10 hours / 18 meters

- DESIGN**
- Fully rechargeable
 - Full dimming
 - Anodised aircraft-grade aluminum; water and impact-resistant
 - Collapsible hanging hook
 - Belt/pocket clip
 - Memory Power Setting
 - Battery charging indicator
 - Powerful magnetic base
- OPERATION**
- Side-positioned, ON/OFF button; hold to dim
 - Lock-out mode to prevent accidental operation
- ACCESSORIES**
- Micro USB to USB charging cable included
- BATTERIES**
- Powered by rechargeable battery (included)
(Recharge time: 5 - 6 hours)
- SPECS**
- 145g
 - (H) 104mm x (W) 45mm x (D) 32mm



 **RECHARGEABLE**

ASSORTED COLORS
Silver Black Red



- Display showcases 3 pieces in front - additional pieces can be stored in the back of the display.
- Each SLIM comes with a gift box

DISPLAY DIMENSIONS
(H) 268mm x (W) 140mm x (D) 196mm

GIFT BOX DIMENSIONS
(H) 106mm x (W) 48mm x (D) 38mm



ITEM	DESCRIPTION	CASE PACK
NE6694	SLIM Rechargeable Pocket Light	12 PIECES



The next line of bug defence is
Z-Bug Lantern + Light.

Equipped with bug-attracting NUV LEDs and a 360° bug-zapping electric grid, this lantern & spot light combo will keep your outdoor excursions enjoyable and bug free!

The handle easily adjusts to conveniently serve both light modes. Z-Bug™ Lantern + Light includes Z-Bug Bulb™ sweeper to remove insect remains from the grid housing.

1 SPOT LIGHT MODE
• 120 lumens - 18 hours / 120 meters

3 LANTERN MODES
• White (250 lumens) - 6 hours / 10 meters
• White & NUV LEDs - 24 hours
• NUV LEDs (395nm) - 40 hours

- DESIGN**
- Fully dimmable
 - 360° insect-zapping rails (1,000 - 1,200V)
 - 360° protective cover for electric rails
 - Adjustable handle

- OPERATION**
- Side-positioned, ON/OFF button

- ACCESSORIES**
- Z-Bug Bulb™ Sweeper for easy cleaning

- BATTERIES**
- Powered by 3 AA batteries (included)

- SPECS**
- 333g
 - Height: Closed - 138mm / Open - 197mm
 - Diameter: 91mm



DISPLAY DIMENSIONS
(H) 330mm x (W) 139mm x (D) 196mm

GIFT BOX DIMENSIONS
(H) 122mm x (W) 76mm x (D) 59mm



ITEM	DESCRIPTION	CASE PACK
NE6587	Z-Bug™ Lantern + Light	12 PIECES

Pocket C.O.B task light with 40 lumens and 3 bits enclosed.

Equipped with three useful bits; Phillips, flat and Torx (T15) drivers. The powerful C.O.B light has 2 lighting modes; high (40 lumens) and low (11 lumens).
The Bitbrite also features a steel pocket clip and powerful magnetic base for convenient hands-free lighting. Made from durable aluminium, the Bitbrite is impact resistant up to 1 meter, so no problem if you drop it by accident.

- 2 LIGHT MODES**
- 40 lumens - 1.5 hours / 10 meters
 - 10 lumens - 8 hours / 5 meters



- DESIGN**
- 3x bits included
 - Magnetic base
 - Steel pocket clip

- OPERATION**
- Top-positioned, ON/OFF button

- ACCESSORIES**
- Phillips bit
 - Flat bit
 - Torx bit (T15)

- BATTERIES**
- Powered by 1 AAA batteries (included)

- SPECS**
- 65g
 - Height: 108mm
 - Diameter: 20mm

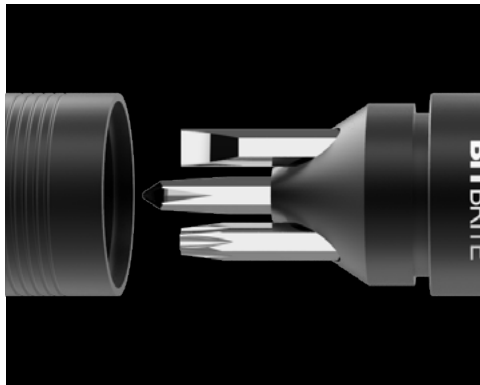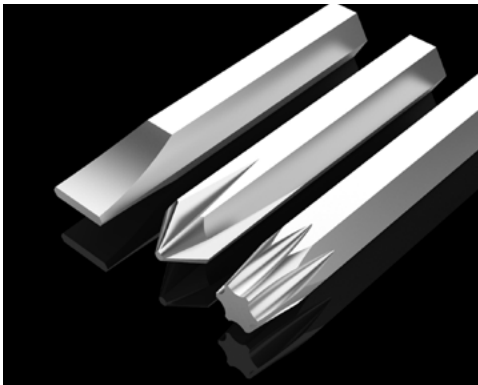

DISPLAY DIMENSIONS
(H) 255mm x (W) 152mm x (D) 10mm



ITEM	DESCRIPTION	CASE PACK
NE6706	Bitbrite C.O.B task light + Bits	12 PIECES

The BRIGHTEST Larry yet... The BIG Larry® PRO features a high-power, 500 lumen C•O•B work light and red hazard flasher.

Fully rechargeable and equipped with 2 magnetic charging stations, the BIG Larry® PRO is ready to handle any task at any time. The PRO also has a powerful magnetic base and adjustable steel clip for convenient hands-free lighting. When there is work to be done...bring a PRO!

- 3 LIGHT MODES**
- High (500 lumens) - 4.5 hours / 37 meters
 - Red (45 lumens) - 8 hours / 13 meters
 - Red hazard flasher - 24 hours / 13 meters


- DESIGN**
- Fully dimmable
 - Direct-to-Red
 - Anodised aircraft-grade aluminum; water and impact-resistant
 - Adjustable clip
 - Powerful magnetic base
 - Battery charging indicator

- OPERATION**
- Top-positioned, ON/OFF button

- ACCESSORIES**
- Two magnetic charging stations and cables




- BATTERIES**
- Powered by 1 Li-ion rechargeable battery (included) (Recharge time: 5 - 6 hours)

- SPECS**
- 215g
 - (H) 197mm x (W) 35mm x (D) 35mm

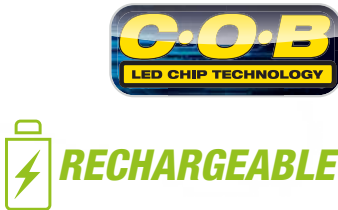

DISPLAY DIMENSIONS
(H) 394mm x (W) 140mm x (D) 197mm

GIFT BOX DIMENSIONS
(H) 242mm x (W) 131mm x (D) 44mm

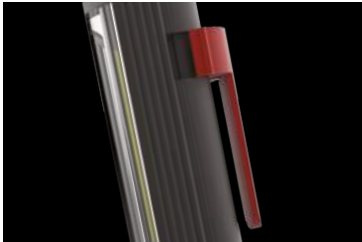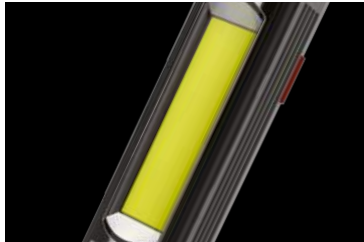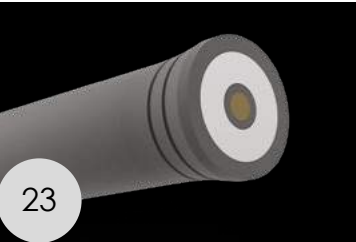

ITEM	DESCRIPTION	CASE PACK
NE6640	BIG Larry® PRO Power Work Light	12 PIECES

The new NEBO POPLITE is a versatile, compact light and lantern.

Its expandable design allows the POPLITE to easily change from flood light, to spot light, to lantern, by sliding the body of the light.

Small enough to fit on a key ring, the POPLITE also features a magnetic base and a detachable carabiner clip. To activate the light, just pop the carabiner clip from the light body and the POPLITE is ready to light the way!



- 3 LIGHT MODES**
- Spot Light (100 LUX) - 2.5 hours / 40 meters
 - Flood Light (20 lumens) - 2.5 hours / 11 meters
 - Lantern (20 lumens) - 2.5 hours / 6 meters



- DESIGN**
- 8x adjustable zoom
 - Anodised aircraft-grade aluminum; water and impact-resistant
 - Lantern diffuser
 - Carabiner clip
 - Powerful magnetic base

- OPERATION**
- Pop-on power; just remove carabiner cap

- BATTERIES**
- Powered by 3 LR44 batteries (included)

- SPECS**
- 36g
 - Length: Compacted: 64mm / Extended: 93mm
 - Diameter: 19mm



- AVAILABLE COLORS**
- Black
 - Silver
 - Red



DISPLAY DIMENSIONS
(H) 305 x (W) 178 x (D) 152mm

NE6557 Color Assortment:
Black, Silver & Red

GIFT BOX DIMENSIONS
(H) 67 x (W) 25 x (D) 19mm

Display includes area for testing magnetic base. 'TRY ME' purposes only, not intended for display.

With 1,400 lumens of high intensity light, this is a must have flashlight.

The BLAST is completely waterproof (IPX7) and ready for any weather condition.

Want more?
It can throw a spectacularly bright beam over 260 meters. How about a 4x zoom and 5 light modes (high, medium, low, defensive strobe & flashing beacon).



- 5 LIGHT MODES**
- High (1400 lumens) - 2.5 hours / 260 meters
 - Medium (560 lumens) - 7 hours / 180 meters
 - Low (140 lumens) - 30 hours / 90 meters
 - Strobe (1400 lumens) - 6 hours
 - Beacon (1400 lumens) - 120 hours

- DESIGN**
- Convex lens
 - Tactical edge
 - 4x adjustable zoom
 - Signature Red Ring®
 - Anodised aircraft-grade aluminum; waterproof (IPX7) and impact-resistant

- OPERATION**
- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

- ACCESSORIES**
- Lanyard (included)

- BATTERIES**
- Powered by 6 AA batteries (included)

- SPECS**
- 440g
 - Length: Compacted: 184 / Extended: 197mm
 - Diameter: 48mm

- PATENT**
- 659,869 S



DISPLAY DIMENSIONS
(H) 305 x (W) 152 x (D) 222mm

GIFT BOX DIMENSIONS
(H) 178 x (W) 51 x (D) 50mm

ITEM	DESCRIPTION	CASE PACK	ITEM	DESCRIPTION	CASE PACK
NE6557	POPLITE Lantern and Flashlight	48 PIECES	NE6542	REDLINE® BLAST 1400 Lumen Flashlight	12 PIECES

Equipped with a 120 lumen C•O•B LED work light and a 50 lumen flashlight, The Larry® TILT is adaptable for any work environment.

The TILT provides hands-free lighting in three different ways: a hanging hook, a 200° pivoting stand and a magnetic base. This new design features an **easy-to-activate push button**. Whether you are under the hood, under the sink or just out in the dark, the Larry® TILT is the perfect directional pocket work light!



- 2 LIGHT MODES**
- **Top Light (50 lumens)** - 3.5 hours / 27 meters
 - **Work Light (120 lumens)** - 3 hours / 19 meters



- DESIGN**
- Weather-proof (IPX4) and impact-resistant
 - Fully dimmable
 - Non-slip compact body design
 - Steel belt/pocket clip
 - 200° pivoting stand
 - Collapsible, hanging hook
 - Powerful magnetic base

- OPERATION**
- NEW rear-positioned ON/OFF button



- BATTERIES**
- Powered by 2 AAA batteries (included)

- SPECS**
- 74g
 - (H) 162mm x (W) 25mm x (D) 19mm



- DISPLAY DIMENSIONS**
(H) 381 x (W) 190 x (D) 203
- NE6539 Color Assortment:**
6 of each color
- GIFT BOX DIMENSIONS**
(H) 165 x (W) 29 x (D) 21mm

- ASSORTED COLORS**
- Camo
 - Red
 - Blue
 - Black



- AVAILABLE COLORS**
- Red
 - Dark Gray
 - Yellow
 - Green



- 4 LIGHT MODES**
- **C•O•B lantern**
 - HIGH (300 lumens)** – 7.5 hours / 15 meters
 - LOW (35 lumens)** – 40 hours / 6 meters
 - **Spot-light**
 - HIGH (120 lumens)** – 18 hours / 120 meters
 - LOW (90 lumens)** – 38 meters

- DESIGN**
- Fully dimmable
 - Rubberised body design; water and impact-resistant
 - Adjustable handle
 - Power memory setting

- OPERATION**
- Side-positioned, ON/OFF button

- BATTERIES**
- Powered by 3 AA batteries (included)

- SPECS**
- 300g
 - Height: Closed - 140mm / Open - 200mm
 - Diameter: 86mm



- DISPLAY DIMENSIONS**
(H) 330 x (W) 140 x (D) 197mm
- NE6555 Color Assortment:**
6 of each color
- GIFT BOX DIMENSIONS**
(H) 143 x (W) 89 x (D) 89mm



ITEM	DESCRIPTION	CASE PACK
NE6539	Larry® TILT Directional Pocket Work Light	24 PIECES

ITEM	DESCRIPTION	CASE PACK
NE6555	Poppy with Display	24 PIECES

With all of the features that you would expect from a SLYDE...and more!

The SLYDE™ KING is equipped with programmable memory settings for each light mode, a new C•O•B red light function, a 4x adjustable zoom and best of all...it's **rechargeable!**



4 LIGHT MODES

- Flashlight (330 lumens) - 2 hours / 123 meters
- C•O•B work light (250 lumens) - 4.25 hours / 22 meters
- Red light (40 lumens) - 4.75 hours / 7 meters
- Red flash - 24 hours

DESIGN

- Fully rechargeable
- Tactical edge
- Convex lens
- 4x adjustable zoom
- Fully dimmable
- Memory Power Setting
- Lock-out mode to prevent accidental operation
- Anodised aircraft-grade aluminum; water and impact-resistant
- Powerful magnetic base
- Battery charging indicator

OPERATION

- Side-positioned ON/OFF button
- Work light automatically turns ON when opened

BATTERIES

- Powered by 1 Li-ion rechargeable battery included (3-4 hour recharge time)

ACCESSORIES

- Micro USB to USB cable included

SPECS

- 364g
- Length: Compacted: 173mm / Extended: 225mm
- Diameter: (Head) 43mm

PATENT

- D 786,466 S



DISPLAY DIMENSIONS
(H) 292 x (W) 184 x (D) 197mm

GIFT BOX DIMENSIONS
(H) 178 x (W) 47.5 x (D) 47.5mm





 **RECHARGEABLE**



ITEM	DESCRIPTION	CASE PACK
NE6434	SLYDE™ KING with Display	12 PIECES

We took our best-selling SLYDE and improved it in every way imaginable.

The SLYDE™+ is equipped with programmable memory settings for each light mode, a new C•O•B red light function, a 4x adjustable zoom and instant slide on.



4 LIGHT MODES

- Flashlight (300 lumens) - 3 hours / 135 meters
- Work Light (200 lumens) - 3.5 hours / 21 meters
- Red (35 lumens) - 2 hours / 8 meters
- Red Flash (35 lumens) - 9 hours

DESIGN

- Convex lens
- Tactical edge
- 4x adjustable zoom
- Fully dimmable
- Direct-to-Red Feature (hold button and slide open)
- Memory Power Setting
- Lock-out mode to prevent accidental operation
- Powerful magnetic base
- Anodised aircraft-grade aluminum; weather-proof (IPX4) and impact-resistant

OPERATION

- Side-positioned, ON/OFF button; hold to dim
- C•O•B Work Light automatically turns ON when opened and OFF when closed

BATTERIES

- Powered by 4 AAA batteries (included)

SPECS

- 318g
- Length: Compacted: 172 / Extended: 230mm
- Diameter: (Head) 41mm / (Barrel) 35mm

PATENT

- D 786,466 S



DISPLAY DIMENSIONS
(H) 298 x (W) 184 x (D) 197mm

GIFT BOX DIMENSIONS
(H) 173 x (W) 44 x (D) 44mm

ITEM	DESCRIPTION	CASE PACK
NE6525	Slyde+ with display	16 PIECES

Introducing the newest member of the TWYST™ lineup...

The TWYST™Z features the same C•O•B lighting options as the original TWYST™: a high-power work light, lantern and flashlight. The TWYST™Z now features a 4x adjustable zoom. A powerful magnetic base also provides convenient hands-free lighting. TWYST™Z... shaping light like never before!



- 3 LIGHT MODES**
- C•O•B Work Light (75 lumens) - 10 hours / 11 metres
 - C•O•B Lantern (200 lumens) - 2 hours / 13 metres
 - Flashlight (200 lumens) - 2 hours / 107 metres

- DESIGN**
- 4x adjustable zoom
 - Enhanced C•O•B LED Technology
 - Fully dimmable beam
 - Anodised aircraft-grade Aluminium;
 - Water and impact-resistant
 - Powerful magnetic base

- OPERATION**
- Side-positioned ON/OFF button

- BATTERIES**
- Powered by 4 AAA batteries (included)

- SPECIFICATIONS**
- Weight with batteries - 250g
 - Length - 160mm (Compacted) / 172mm (Extended)
 - Diameter - 45mm (Head) / 25mm (Barrel)



- DISPLAY**
- Display holds 5 pieces - 1 'Try Me' and 4 in gift boxes; 11 additional pieces are included as replenishments.

- Each TWYST™Z comes with a gift box.

- Display allows product to be easily tested by consumers.

DISPLAY DIMENSIONS
(H) 216mm x (W) 235mm x (D) 178mm

GIFT BOX DIMENSIONS
(H) 165mm x (W) 476mm x (D) 476mm



The REDLINE® V is a powerful, 500 lumen flashlight, featuring OC™ optics.

The REDLINE® V is completely waterproof (IPX7) and is also equipped with a steel clip, powerful magnetic base, 4x zoom and 5 light modes (high, medium, low, defensive strobe & S.O.S.).

- 5 LIGHT MODES**
- High (500 lumens) - 2.5 hours / 170 meters
 - Medium (200 lumens) - 6 hours / 110 meters
 - Low (50 lumens) - 22 hours / 50 meters
 - Strobe (500 lumens) - 6 hours
 - S.O.S. (500 lumens) - 48 hours

- DESIGN**
- Convex lens
 - Tactical edge
 - 4x adjustable zoom
 - Signature Red Ring®
 - Anodised aircraft-grade aluminum; waterproof (IPX7) and impact-resistant
 - Steel belt/pocket clip
 - Powerful magnetic base

- OPERATION**
- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

- BATTERIES**
- Powered by 3 AAA batteries (included)

- SPECS**
- 154g
 - Length: Compacted: 127 / Extended: 140mm
 - Diameter: (Head) 35 / (Barrel) 32 mm

- PATENT**
- 659,869 S



- Display showcases 1 piece in front - additional pieces can be stored in the back of the display.
- Each REDLINE® V comes with a gift box.

DISPLAY DIMENSIONS
(H) 304 x (W) 152 x (D) 222 mm

GIFT BOX DIMENSIONS
(H) 131 x (W) 38 x (D) 38 mm



ITEM	DESCRIPTION	CASE PACK	ITEM	DESCRIPTION	CASE PACK
NE6372	TWYST-Z Work Light, Lantern & Flashlight	16 PIECES	NE6639	REDLINE™ V 500 Lumen Flashlight	16 PIECES

The LiL Larry™ knows how to light up a room!

Equipped with new C•O•B LED technology, the LiL Larry™ outputs 250 lumens of intense light. Secondary light modes include Low (95 lumens) and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodised aluminium body and recessed LED housing ensures that the LiL Larry™ can handle any situation. It's small size makes this flashlight extremely portable.





3 LIGHT MODES

- High (250 lumens) - 3 hours / 29 metres
- Low (95 lumens) - 10 hours / 17 metres
- Red Flash - 10 hours

LIGHT

- High-power 250 lumen C•O•B LED work light
- Low-power 95 lumen C•O•B LED work light
- High-power C•O•B LED emergency red flasher

DESIGN

- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Powerful magnetic base

OPERATION

- Top-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECIFICATIONS

- Weight with batteries - 89g
- Length - 151mm
- Diameter - 20mm (Head) 15mm (Barrel)



DISPLAY


- Display holds 18 pieces (5 red, 5 silver, 8 black); 3 in front for consumer testing, 15 additional pieces stored in the back as replenishments.
- Each LiL Larry™ comes with a gift box.
- Product attaches securely to the display using the magnetic base.

DISPLAY DIMENSIONS
(H) 250mm x (W) 140mm x (D) 190mm

ITEM	DESCRIPTION	CASE PACK
NE6373	LiL Larry™ Power C•O•B LED Work Light	18 PIECES



The BIG Larry™ knows how to light up a room!

Equipped with new C•O•B LED technology, the BIG Larry™ outputs 400 lumens of intense light. Secondary light modes include Low (160 lumens) and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodised aluminium body and recessed LED housing ensures that the BIG Larry™ can handle any situation.



3 LIGHT MODES

- High 400 lumen - 4.5 hours/29 meters
- Low 160 lumen - 15 hours/17 meters
- High C•O•B LED emergency red flasher - 40 meters



LIGHT

- High-power 400 lumen C•O•B LED work light
- Low-power 160 lumen C•O•B LED work light
- High-power C•O•B LED emergency red flasher

DESIGN

- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Powerful magnetic base

OPERATION

- Top-positioned, ON/OFF button

BATTERIES

- Powered by 3 AA batteries (included)

SPECIFICATIONS

- Weight with batteries - 211g
- L 188mm x W 28mm x D 28mm



DISPLAY

- Each BIG Larry™ comes with a gift box.
- Display holds 14 pieces; 2 in front for consumer testing, 12 additional pieces stored behind as replenishments.
- Assorted colour display: 7 black & 7 silver.
- Product attaches securely to the display using the magnetic base.

DISPLAY DIMENSIONS
(H) 304mm x (W) 139mm x (D) 139mm



ITEM	DESCRIPTION	CASE PACK
NE6306	BIG Larry™ Power C•O•B LED Work Light	14 PIECES

The Larry™C is now BRIGHTER THAN EVER!

Now, equipped with new C•O•B LED technology, the Larry™C outputs 170 lumens of intense light. The rotating magnetic clip gives you convenient hands-free lighting by attaching to virtually anything. The reinforced plastic body design is water and impact-resistant, making this light basically indestructible.



1 LIGHT MODE

- 170 lumen C•O•B LED work light
- 5.6 hours / 20 metres

LIGHT

- High-power 170 lumen C•O•B LED work light

DESIGN

- Water and impact-resistant
- Ergonomic non-slip grip
- 180° rotating magnetic clip
- Protective LED housing

OPERATION

- Top-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECIFICATIONS

- Weight - 67g
- Length - 160mm
- Width - 32mm
- Diameter - 16mm



DISPLAY DIMENSIONS
(H) 222 x (W) 152 x (D) 152mm

GIFT BOX DIMENSIONS
(H) 165 x (W) 38 x (D) 19mm

ASSORTED COLOURS

Black Red Yellow Blue



The newest rechargeable REDLINE® is the REDLINE® RC™ with MagDock.

The MagDock is a magnetic charging station that docks and charges your REDLINE®. Small enough to fit in the palm of your hand, the REDLINE® RC™ with MagDock is fully equipped with all of the features that make the REDLINE® series so popular.

- 4 LIGHT MODES**
- High (320 lumens) - 1 hour / 110 metres
 - Medium (125 lumens) - 2 hours / 70 metres
 - Low (32 lumens) - 9 hours / 35 metres
 - Strobe (320 lumens) - 2 hours / 110 metres

- LIGHT**
- High-power 320 lumen LED

- DESIGN**
- 4x adjustable zoom
 - Anodised aircraft-grade Aluminium
 - Water and impact-resistant
 - OC™ Technology
 - Convex lens
 - Signature Red Ring™
 - Steel belt/pocket clip
 - Ergonomic non-slip grip
 - Magnetic base
 - Protective LED housing
 - Charging indicator light

- OPERATION**
- Side-positioned, ON/OFF button

- ACCESSORIES**
- USB to Micro USB cable included
 - Lanyard included

- BATTERIES**
- Internal, rechargeable lithium-ion battery (Recharge time - up to 2 hours)

- SPECIFICATIONS**
- Weight - 94g
 - Length - 91mm (Compacted) 98mm (Extended)
 - Diameter - 31mm (Head) 27mm (Barrel)



DISPLAY DIMENSIONS
(H) 222 x (W) 152 x (D) 152mm

GIFT BOX DIMENSIONS
(H) 165 x (W) 38 x (D) 19mm



ITEM	DESCRIPTION	CASE PACK	ITEM	DESCRIPTION	CASE PACK
NE6327	LarryC	24 PIECES	NE6392	REDLINE® RC™ with MagDock	10 PIECES

Ideal for travel, the TRANSPORT DC® conveniently fits in your pocket, handbag, glove compartment or travel bag.

The TRANSPORT DC® is a compact, rechargeable flashlight that provides powerful bright light at your fingertips! Just plug directly into your car, van, boat or any other 12V outlet to charge your flashlight. The TRANSPORT DC® is compatible with any DC 12V socket. The reinforced plastic body design is water and impact-resistant, making this light basically indestructible.



1 LIGHT MODE

• ON (125 lumens) - 1 hour / 90 metres

LIGHT

• High-power 125 lumen LED

DESIGN

• Fully rechargeable
• Fits any 12V outlet (car cigarette lighter)
• Anodised aircraft-grade aluminium;
water and impact-resistant

OPERATION

• Top-positioned ON/OFF dial; twist to activate

BATTERIES

• Powered by 1 16340 Lithium Ion rechargeable battery (included)

SPECIFICATIONS

• Weight with battery - 85g
• L 94mm x W 30mm x D 30mm





DISPLAY

• Display holds 8 pieces + 1 piece is stored in the front of the display to show how product sits in 12V outlet
• Assorted colours: 12 black & 6 silver
• 9 additional pieces are included as replenishments

DISPLAY DIMENSIONS

(H) 184mm x (W) 193mm x (D) 158mm

ITEM	DESCRIPTION	CASE PACK
NE6311	TRANSPORT®DC	18 PIECES

Compact, handy and bright...the LUMO™ Clip Light by NEBO® is the perfect “whatever you need it to be” light.

Key chain light, purse light, backpack light, book light...the possibilities are endless. This compact 25 lumen light comes with a carabiner attachment to clip anywhere you need. The white top of the LUMO™ is a diffuser dome. This dome helps spread the light evenly to create a more omnidirectional light source. LUMO™ Clip Light...the brilliant clip light!





1 LIGHT MODE

• ON (25 lumens) - 5 hour / 3 metres

LIGHT

• High-power 25 lumen LED

DESIGN

• Anodised aircraft-grade Aluminium
• Water and impact-resistant
• Carabiner clip
• Glow-in-the-dark button
• Diffuser dome

OPERATION

• Rear-positioned glow-in-the-dark ON/OFF button

BATTERIES

• Powered by 3 LR44 batteries (included)

SPECIFICATIONS

• Weight with batteries - 25g
• L 50mm x W 19mm x D 19mm

DISPLAY

• Display holds 48 pieces total; 32 pieces on display and 16 additional pieces stored inside.
• Assorted colours: 12 of each colour.
• Display allows product to be easily tested by consumers.

DISPLAY DIMENSIONS

(H) 228mm x (W) 165mm x (D) 165mm



ITEM	DESCRIPTION	CASE PACK
NE6095	Lumo™	48 PIECES

REBEL™



The REBEL is a fully rechargeable task light that includes an adjustable head strap for use as a head lamp.

Small enough to fit in the palm of your hand, this powerful light rebels against its size with its impressive 600 lumen output. This bright light is also equipped with a rotating, removable steel clip and powerful magnetic base to provide even more hands-free lighting options.

ITEM	DESCRIPTION
NB6691	Rebel

- 4 LIGHT MODES**
- HIGH (240 lumens) - 2 hours / 56 meters
 - LOW (60 lumens) - 4.5 hours / 28 meters
 - TURBO (600 lumens) - 40 seconds / 90 meters
 - STROBE (600 lumens) - 2 hours / 90 meters

- DESIGN**
- Fully rechargeable
 - Removable steel clip
 - Anodised aircraft-grade aluminum; water and impact-resistant

- OPERATION**
- Top-positioned, ON/OFF button

- ACCESSORIES**
- Adjustable head strap; one size fits all
 - Magnetic USB to Micro USB charging cable with charging indicator included

- BATTERIES**
- Powered by rechargeable battery (included) (Recharge time: 1.5 - 2 hours)

- SPECS**
- 85g
 - (H) 72.39mm x (W) 30 x (D) 25



TRY ME Pack size
240mm x 120mm



LEO™

The LEO™ is an amazingly versatile pocket light.

Fully dimmable and equipped with Memory Power Setting, the LEO's work light and spot light pivot and rotate to direct the light wherever you need it. A pocket clip, magnetic base and a kick stand / hanging hook give the LEO endless options of hands-free lighting.

ITEM	DESCRIPTION
NE6657	Leo™

- 2 LIGHT MODES**
- Work Light (220 lumens) - 5 hours / 22 meters
 - Spot Light (80 lumens) - 7 hours / 52 meters

- DESIGN**
- Rotating directional light
 - Non-slip rubber coating
 - Water and impact-resistant
 - Fully dimmable
 - Memory Power Setting
 - Pocket clip
 - Powerful magnetic base
 - Kick stand / hanging hook

- OPERATION**
- Top-positioned, ON/OFF button; hold to dim

- BATTERIES**
- Powered by 3 AAA batteries (included)

- SPECS**
- 87g
 - Length: 168mm / Extended: 247mm
 - Width: 19mm / Depth: 35mm



TRY ME Pack size
240mm x 120mm



POPLITE

The new NEBO POPLITE is a versatile, compact light and lantern.

Its expandable design allows the POPLITE to easily change from flood light, to spot light, to lantern, by sliding the body of the light. Small enough to fit on a key ring, the POPLITE also features a magnetic base and a detachable carabiner clip. To activate the light, just pop the carabiner clip from the light body and the POPLITE is ready to light the way!

ITEM	DESCRIPTION
NB6557	Poplite


- 3 LIGHT MODES**
- Spot Light (100 LUX) - 2.5 hours / 40 meters
 - Flood Light (20 lumens) - 2.5 hours / 11 meters
 - Lantern (20 lumens) - 2.5 hours / 6 meters

- DESIGN**
- 8x adjustable zoom
 - Anodised aircraft-grade Aluminium
 - Water and impact-resistant
 - Lantern diffuser
 - Carabiner clip
 - Powerful magnetic base

- OPERATION**
- Pop-on power; just remove carabiner cap

- BATTERIES**
- Powered by 3 LR44 batteries (included)

- SPECS**
- 36g
 - Length: Compacted: 64mm / Extended: 93mm
 - Diameter: 19mm

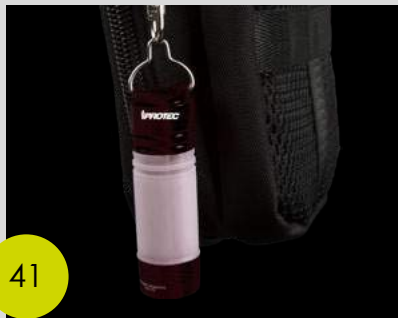

TRY ME Pack size
240mm x 120mm



SLIM

The NEBO SLIM is a thin, ergonomic rechargeable pocket light that outputs 500 lumens of intense bright light.

Equipped with full dimming and Power Memory Recall, the SLIM also features a pocket clip, collapsible hanging hook and powerful magnetic base for convenient hands-free lighting.



ITEM	DESCRIPTION
NE6694	SLIM

- 1 LIGHT MODE - with Dimming**
- 100% (500 lumens) - 2 hours / 58 meters
 - 10% (50 lumens) - 10 hours / 18 meters

- DESIGN**
- Fully rechargeable
 - Full dimming
 - Anodised aircraft-grade Aluminium
 - Water and impact-resistant
 - Collapsible hanging hook
 - Belt/pocket clip
 - Memory Power Setting
 - Battery charging indicator
 - Powerful magnetic base

- OPERATION**
- Side-positioned, ON/OFF button; hold to dim
 - Lock-out mode to prevent accidental operation

- ACCESSORIES**
- Micro USB to USB charging cable included

- BATTERIES**
- Powered by rechargeable battery (included)
(Recharge time: 5 - 6 hours)

- SPECS**
- 1g
 - (H) 104mm x (W) 45mm x (D) 32mm



TRY ME Pack size
240mm x 120mm



With all of the features that you would expect from a SLYDE...and more!

The SLYDE™ KING is equipped with programmable memory settings for each light mode, a new C•O•B red light function, a 4x adjustable zoom and best of all...it's rechargeable!

ITEM	DESCRIPTION
NB6434	SLYDE KING

- 4 LIGHT MODES
- Flashlight (330 lumens) - 2 hours / 123 metres
 - Work Light (250 lumens) - 4.25 hours / 22 metres
 - Red Light (40 lumens) - 4.75 hours / 7 metres
 - Red Flash - 24 hours

- LIGHT
- High-power 330 lumen LED flashlight
 - High-power 250 lumen C•O•B work light
 - High-power 40 lumen red light
 - High-power red hazard flasher

- DESIGN
- Fully rechargeable
 - Memory power setting
 - Convex lens
 - Tactical edge
 - 4x adjustable zoom
 - Anodised aircraft-grade aluminium; water and impact-resistant
 - Dimmable beam
 - Work light is concealed inside the flashlight body
 - Powerful magnetic base

- OPERATION
- Side-positioned ON/OFF button
 - Work light automatically turns ON when opened

- BATTERIES
- Powered by 1 Li-ion rechargeable battery included (3-4 hour recharge time)

- ACCESSORIES
- Micro USB to USB cable included

- SPECS
- 364g
 - Length: Compacted: 173mm
 - Length: Extended: 227.5mm
 - Diameter: (Head) 44.5mm / (Barrel) 32mm



Introducing the newest member of the TWYST™ lineup...TWYST™Z!

The TWYSTZ features the same C•O•B lighting options as the original TWYST: a high-power work light, lantern and flashlight! The TWYSTZ now features a 4x adjustable zoom. A powerful magnetic base also provides convenient hands-free lighting. TWYSTZ... shaping light like never before!

ITEM	DESCRIPTION
NE6372	TWYST-Z

- 3 LIGHT MODES
- C•O•B Work Light (75 lumens) - 10 hours / 11 metres
 - C•O•B Lantern (200 lumens) - 2 hours / 13 metres
 - Flashlight (200 lumens) - 2 hours / 107 metres


- LIGHT
- 75 Lumen C•O•B LED Work Light
 - 200 Lumen C•O•B LED Lantern
 - 200 Lumen Flashlight

- DESIGN
- 4x adjustable zoom
 - Enhanced C•O•B LED Technology
 - Fully dimmable beam
 - Anodised aircraft-grade Aluminium; water and impact-resistant
 - Powerful magnetic base

- OPERATION
- Side-positioned ON/OFF button

- BATTERIES
- Powered by 4 AAA batteries (included)

- SPECIFICATIONS
- Weight with batteries - 250g
 - Length - 160mm (Compacted) 172mm (Extended)
 - Diameter - 45mm (Head) 25mm (Barrel)

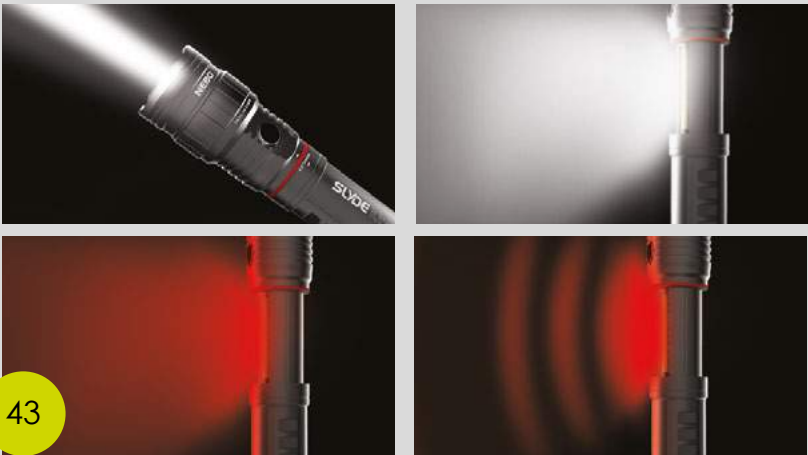


The BIG Larry™ knows how to light up a room!

Equipped with new C•O•B LED technology, the BIG Larry™ outputs 400 lumens of intense light. Secondary light modes include Low and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodised aluminium body and recessed LED housing ensures that the BIG Larry™ can handle any situation.

ITEM	DESCRIPTION
NB6306	Big Larry™

- 3 LIGHT MODES**
- High (400 lumens) - 4.5 hours / 29 m
 - Low (160 lumens) - 15 hours / 17 m
 - Red Flash - 40 hours

- LIGHT**
- High-power 400 lumen C•O•B LED work light
 - Low-power 160 lumen C•O•B LED work light
 - High-power C•O•B LED emergency red flasher
- DESIGN**
- Anodised aircraft-grade Aluminium
 - Water and impact-resistant
 - Powerful magnetic base
- OPERATION**
- Top-positioned, ON/OFF button
- BATTERIES**
- Powered by 3 AA batteries (included)
- SPECIFICATIONS**
- Weight with batteries - 211g
 - Length - 188mm
 - Diameter - 28mm (Head) 22mm (Barrel)

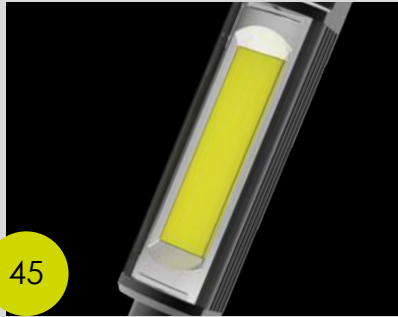

TRY ME Pack size
300mm x 120mm



TRY ME Pack size
240mm x 120mm



The LiL Larry™ knows how to light up a room!

Equipped with new C•O•B LED technology, the LiL Larry™ outputs 250 lumens of intense light. Secondary light modes include Low (95 lumens) and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodised aluminium body and recessed LED housing ensures that the LiL Larry™ can handle any situation. It's small size makes this flashlight extremely portable.

ITEM	DESCRIPTION
NE6373	LiL Larry™

- 3 LIGHT MODES**
- High (250 lumens) - 3 hours / 29 metres
 - Low (95 lumens) - 10 hours / 17 metres
 - Red Flash - 10 hours

- LIGHT**
- High-power 250 lumen C•O•B LED work light
 - Low-power 95 lumen C•O•B LED work light
 - High-power C•O•B LED emergency red flasher
- DESIGN**
- Anodised aircraft-grade Aluminium
 - Water and impact-resistant
 - Powerful magnetic base
- OPERATION**
- Top-positioned, ON/OFF button
- BATTERIES**
- Powered by 3 AAA batteries (included)
- SPECIFICATIONS**
- Weight with batteries - 89g
 - Length - 151mm
 - Diameter - 20mm (Head) 15mm (Barrel)



The newest rechargeable REDLINE® is the REDLINE® RC™ with MagDock.

The MagDock is a magnetic charging station that docks and charges your REDLINE®. Small enough to fit in the palm of your hand, the REDLINE® RC™ with MagDock is fully equipped with all of the features that make the REDLINE® series so popular.

ITEM	DESCRIPTION
NB6392	Magdock

- 4 LIGHT MODES
- High (320 lumens) - 1 hour / 110 metres
 - Medium (125 lumens) - 2 hours / 70 metres
 - Low (32 lumens) - 9 hours / 35 metres
 - Strobe (320 lumens) - 2 hours / 110 metres

- LIGHT
- High-power 320 lumen LED
- DESIGN
- 4x adjustable zoom
 - Anodised aircraft-grade Aluminium; water and impact-resistant
 - OC™ Technology
 - Convex lens
 - Signature Red Ring™
 - Steel belt/pocket clip
 - Ergonomic non-slip grip
 - Magnetic base
 - Protective LED housing
 - Charging indicator light
- OPERATION
- Side-positioned, ON/OFF button
- ACCESSORIES
- USB to Micro USB cable included
 - Lanyard included
- BATTERIES
- Internal, rechargeable lithium-ion battery (Recharge time - up to 2 hours)

- SPECIFICATIONS
- Weight - 94g
 - Length - 91mm (Compacted) 98mm (Extended)
 - Diameter - 31mm (Head) 27mm (Barrel)



We took our best-selling SLYDE Flashlight & Work Light and improved it every way imaginable.

The new SLYDE + is now equipped with programmable memory settings for each light mode, a new C•O•B red light function, a 4x adjustable zoom and instant slide on. And best of all? With all these new great features, the new SLYDE+ is still the same price!

ITEM	DESCRIPTION
NE6525	Slyde+™

- 4 LIGHT MODES
- Flashlight (300 lumens) - 3 hours / 135 metres
 - Work Light (200 lumens) - 3.5 hours / 21 metres
 - Red (35 lumens) - 2 hours / 8 metres
 - Red Flash (35 lumens) - 9 hours

- DESIGN
- Convex lens
 - Tactical edge
 - 4x adjustable zoom
 - Fully dimmable
 - Direct-to-Red Feature (hold button and slide open)
 - Memory Power Setting
 - Powerful magnetic base
 - Anodised aircraft-grade Aluminium; weather-proof (IPX4) and impact-resistant
- OPERATION
- Side-positioned, ON/OFF button; hold to dim
 - C•O•B Work Light automatically turns ON when opened and OFF when closed
- BATTERIES
- Powered by 4 AAA batteries (included)
- SPECS
- 318g
 - Length: Compacted: 172mm / Extended: 230mm
 - Diameter: (Head) 41mm / (Barrel) 35mm



SLIDE to reveal work light (automatically activates when opened)



TRY ME Pack size 320mm x 120mm



TRY ME Pack size 300mm x 120mm



DUO 250+ LUMEN HEADLAMP

This headlamp is the perfect hands-free light for working, hiking, camping and more!

The new NEBO® DUO Headlamp is an all-powerful, hands-free lighting solution. A push button allows you to easily cycle through the FOUR light modes: LED Spot Light, C•O•B Flood Light, RED C•O•B steady and RED beacon mode. The red LED is a low-signature light, which ensures stealth in the dark, enhances night vision and makes reading in little to no light possible.

ITEM	DESCRIPTION
NB6444	DUO HEADLAMP

- 4 LIGHT MODES
- Spot Light (250 lumens, Low 30) - 3.5 hours / 122 m
 - C•O•B Flood Light (80 lumens, Low 8) - 7 hours / 13 m
 - Red C•O•B (10 lumens, Low 2) - 8 hours / 4 m
 - Red Beacon - 48 hours / visible over 1 mile

- DESIGN
- Tough, lightweight, shock-proof
 - Fully dimmable
 - Programmable memory setting
 - Direct to red light feature
 - Water and impact resistant
 - Dual adjustable head straps

- OPERATION
- Power/dimmer button
 - 90° tilting headlamp
 - Top positioned On/Off button

- BATTERIES
- 3 AAA batteries included

- SPECS
- 75g, 100g with strap
 - Length: 60mm
 - Width: 40mm
 - Diameter: 49mm



CRYKET™

The CRYKET™ is a versatile 3-in-1 LED light.

Featuring a 240 lumen COB work light, a bright 250 lumen spot light and an intense red light. Its unique 90° swivel design allows the light's head to rotate into a forward-facing light, perfect for various working conditions. The magnetic base and steel clip provide convenient hands-free lighting.

ITEM	DESCRIPTION
NB6437	CRYKET™

- 5 LIGHT MODES
- Focused High 250 Lumens - 3.5 hours / 113 m
 - Focused Low 45 Lumens - 15 hours / 51 m
 - Work High 220 Lumens - 2.75 hours / 21 m
 - Work Low 30 Lumens - 22 hours / 7 m
 - RED 15 Lumens - 6.5 hours / 6 m

- LIGHT
- Dimmable white lights
 - 220 Lumens C•O•B LED ring flood light
 - 250 Lumens white LED focused light
 - 15 Lumens red ring light for night vision

- DESIGN
- Powerful hands-free magnetic base
 - Rubberised grip
 - Steel pocket / belt clip
 - Anodised aircraft-grade Aluminium
 - Water and impact-resistant design
 - Powered by 4 AAA batteries (included)

- SPECIFICATIONS
- Weight with batteries - 182g
 - Length - 125mm Diameter - 41mm



TRY ME Pack size
240mm x 120mm



TRY ME Pack size
240mm x 120mm



The Redline Zoom has a high-power LED that outputs an incredible 270 lumens of intense white light.

The Redline Zoom also features an impressive 6x zoom. Hard/Soft Touch Technology allows you to easily cycle through the five impressive light modes.

ITEM	DESCRIPTION
NB6380	Redline ZOOM+™

- 5 LIGHT MODES**
- High (270 lumens) - 2.5 hours / 180 m
 - Medium (112 lumens) - 6.5 hours / 126 m
 - Low (50 lumens) - 20 hours / 80 m
 - Strobe (270 lumens) - 24 hours / 180 m
 - S.O.S (270 lumens) - 20 hours / 180 m

- LIGHT**
- 5 light modes and 6 x zoom
- DESIGN**
- Flood light to spot light
 - Convex lens
 - Strong double steel clip
 - Anodised aircraft-grade aluminium
 - Water and impact-resistant
 - Powerful magnetic base
- OPERATION**
- Rear-positioned glow-in-the-dark ON/OFF button
- BATTERIES**
- Powered by 3 AAA batteries (included)
- SPECIFICATIONS**
- Weight with batteries - 148g
 - Length - 120mm
 - Diameter - 40mm (Head) 25mm (Barrel)



Compact, handy and bright...the LUMO™ Clip Light by NEBO® is the perfect “whatever you need it to be” light.

Key ring light, handbag light, travel light, book light...the possibilities are endless. This compact 25 lumen light comes with a carabiner attachment to clip anywhere you need. The white top of the LUMO is a diffuser dome. This dome helps spread the light evenly to create a more omni directional light source. LUMO Clip Light...the brilliant clip light!

ITEM	DESCRIPTION
NB6095	LUMO™

- 1 LIGHT MODE**
- 25 lumens - 5 hours / 3 metres

- LIGHT**
- High-power 25 lumen LED
- DESIGN**
- Anodised aircraft-grade aluminium
 - Water and impact-resistant
 - Carabiner clip
 - Glow-in-the-dark button
 - Diffuser dome
- OPERATION**
- Rear-positioned glow-in-the-dark ON/OFF button
- BATTERIES**
- Powered by 3 LR44 batteries (included)
- SPECIFICATIONS**
- Weight with batteries - 25g
 - Length - 50mm
 - Diameter - 15mm



TRY ME Pack size
240mm x 120mm



TRY ME Pack size
130mm x 90mm



The Larry™C is now BRIGHTER THAN EVER!

Now, equipped with new C•O•B LED technology, the Larry™C outputs 170 lumens of intense light. The rotating magnetic clip gives you convenient hands-free lighting by attaching to virtually anything. The reinforced plastic body design is water and impact-resistant, making this light tougher than ever.

ITEM	DESCRIPTION
NB6327	Larry C™

1 LIGHT MODE

- 170 lumen C•O•B LED work light
- 5.6 hours / 20 metres

LIGHT

- High-power 170 lumen C•O•B LED work light

DESIGN

- Water and impact-resistant
- Ergonomic non-slip grip
- 180° rotating magnetic clip
- Protective LED housing

OPERATION

- Top-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECIFICATIONS

- Weight with batteries - 67g
- Length - 160mm
- Width - 32mm
- Diameter - 16mm



TRY ME Pack size
240mm x 120mm



The Pro600Head+TaskRC is a fully rechargeable task light that includes an adjustable head strap for use as a head lamp.

Small enough to fit in the palm of your hand, this powerful light rebels against its size with its impressive 600 lumen output. This bright light is also equipped with a rotating, removable steel clip and powerful magnetic base to provide even more hands-free lighting options.

ITEM	DESCRIPTION
NB6691	PRO600HEAD+TASKRC

4 LIGHT MODES

- HIGH (240 lumens) - 2 hours / 56 meters
- LOW (60 lumens) - 4.5 hours / 28 meters
- TURBO (600 lumens) - 40 seconds / 90 meters
- STROBE (600 lumens) - 2 hours / 90 meters

DESIGN

- Fully rechargeable
- Removable steel clip
- Anodised aircraft-grade aluminum; water and impact-resistant

OPERATION

- Top-positioned, ON/OFF button

ACCESSORIES

- Adjustable head strap; one size fits all
- Magnetic USB to Micro USB charging cable with charging indicator included

BATTERIES

- Powered by rechargeable battery (included) (Recharge time: 1.5 - 2 hours)

SPECS

- 85g
- (H) 72.39 x (W) 30 x (D) 25mm



ITEM	DESCRIPTION
IP6657	PRO220TASK+SPOT

2 LIGHT MODES

- Work Light (220 lumens) - 5 hours / 22 meters
- Spot Light (80 lumens) - 7 hours / 52 meters

DESIGN

- Rotating directional light
- Non-slip rubber coating
- Water and impact-resistant
- Fully dimmable
- Memory Power Setting
- Pocket clip
- Powerful magnetic base
- Kick stand / hanging hook

OPERATION

- Top-positioned, ON/OFF button; hold to dim

BATTERIES

- Powered by 3 AAA batteries (included)

SPECS

- 87g
- Length: 168mm / Extended: 247mm
- Width: 19mm / Depth: 35mm



PACK SIZE
113mm x 194mm



PACK SIZE
94mm x 220mm



The new iProtec ProPopLite is
a versatile, compact light and lantern.

Its expandable design allows the PROPOPLITE to easily change from flood light, to spot light, to lantern, by sliding the body of the light. Small enough to fit on a key ring, the POPLITE also features a magnetic base and a detachable carabiner clip. To activate the light, just pop the carabiner clip from the light body and the POPLITE is ready to light the way!

ITEM	DESCRIPTION
NB6557	PROPOPLITE

4 LIGHT MODES

- Spot Light (100 LUX) - 2.5 hours / 40 meters
- Flood Light (20 lumens) - 2.5 hours / 11 meters
- Lantern (20 lumens) - 2.5 hours / 6 meters

DESIGN

- 8x adjustable zoom
- Anodised aircraft-grade aluminum; water and impact-resistant
- Lantern diffuser
- Carabiner clip
- Powerful magnetic base

OPERATION

- Pop-on power; just remove carabiner cap

BATTERIES

- Powered by 3 LR44 batteries (included)

SPECS

- 36g
- Length: Compacted: 64mm / Extended: 93mm
- Diameter: 19mm



iPROTEC™ MADE TOUGH
PRO2400LIGHT

The PRO2400LIGHT offers 2,400 lumens of high intensity light

Throwing a spectacularly bright beam over 346 meters. The PRO2400LIGHT is dust-proof, waterproof and ready for any weather condition. This light is packed with features including a 4x zoom, soft-touch button and 5 light modes (high, medium, low, defensive strobe & beacon).

ITEM	DESCRIPTION
IP6693	PRO2400LIGHT

5 LIGHT MODES

- High (2400 lumens) - 3 hours / 346 meters
- Medium (800 lumens) - 6 hours / 190 meters
- Low (240 lumens) - 15 hours / 110 meters
- Strobe (2400 lumens) - 6 hours / 346 meters
- Beacon (2400 lumens) - 8 hours / 346 meters

DESIGN

- Powerful 2400 lumens white LED light
- 5 light modes
- 4x Zoom
- Signature RED RING™
- Dust & Waterproof up to 1m deep (IP67)
- Lanyard included
- Glow in the dark reflector for low light
- Aluminium body

OPERATION




- Bottom-positioned, ON/OFF button

BATTERIES

- Powered by 9 AA batteries (included)

SPECS

- 627g
- Length: 241mm / Extended: 266mm
- Width: 55mm

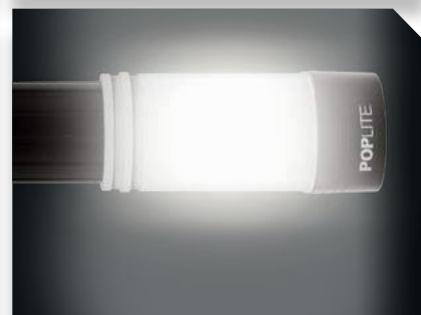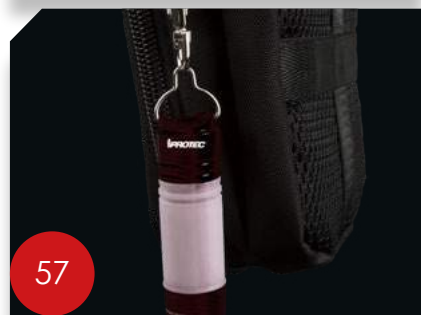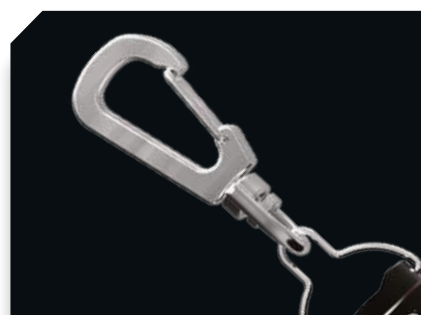

With 1400 lumens of high intensity light, this must-have flashlight can throw a spectacularly bright beam over 260 metres. The BLAST is completely waterproof and ready for any weather condition. Want more? How about a 4x zoom and 5 light modes (high, medium, low, defensive strobe & flashing beacon).

- High (1400 lumens) - 2.5 hours / 260 metres
- Medium (560 lumens) - 7 hours / 180 metres
- Low (140 lumens) - 30 hours / 90 metres
- Strobe (1400 lumens) - 6 hours
- Beacon (1400 lumens) - 120 hours

- Powerful 1400 lumens of white LED light
- 5 light modes
- Aluminium body
- Signature RED RING™
- Glow-in-the-dark reflector for low light
- Waterproof up to 1 metre deep (IPX7)
- Lanyard included
- Powered by 6 AA batteries (included)

- Bottom-positioned, ON/OFF button

- Powered by 6 AA batteries (included)

- Weight 440g
- Length - 184mm
- Diameter - 48mm



PACK SIZE
112mm x 265mm



The PRO500LIGHT is completely waterproof (IPX7) and is also equipped with a steel clip, powerful magnetic base, 4x zoom and 5 light modes (high, medium, low, defensive strobe & S.O.S.).

- High (500 lumens) - 2.5 hours / 170 metres
- Medium (200 lumens) - 6 hours / 110 metres
- Low (50 lumens) - 22 hours / 50 metres
- Strobe (500 lumens) - 6 hours
- S.O.S. (500 lumens) - 48 hours

- Convex lens
- Tactical edge
- 4x adjustable zoom
- Signature Red Ring®
- Anodised aircraft-grade aluminum; waterproof (IPX7) and impact-resistant
- Steel belt/pocket clip
- Powerful magnetic base

- Rear-positioned, glow-in-the-dark ON/OFF button with Soft Touch Technology

- Powered by 3 AAA batteries (included)

- Weight (product only) 115g
- Length: 127mm / Extended: 140mm
- Diameter: (Head) 37 / (Barrel) 32 mm

- 659,869 S



PACK SIZE
140mm x 343mm



IPROTEC MADE TOUGH

PRO400LIGHT

The PRO400LIGHT offers 400 lumens of high intensity light and can throw a spectacularly bright beam over 180 metres. The PRO400LIGHT is waterproof and ready for any weather condition. This light is packed with features including a 6x zoom, soft-touch button and 5 light modes (high, medium, low, defensive strobe & beacon).

5 LIGHT MODES

- HIGH - 400 Lumens, 2.5 hours, 180 metres
- MEDIUM - 160 Lumens, 6.5 hours, 120 metres
- LOW - 45 Lumens, 30 hours, 65 metres
- S.O.S - 400 Lumens 120 hours, 180 metres
- STROBE - 400 Lumens, 120 hours, 180 metres

ITEM	DESCRIPTION
IP6545	PRO400LIGHT

DESIGN

- Powerful 400 lumens of white LED light
- 5 light modes
- Aluminium body
- Signature RED RING™
- Glow-in-the-dark reflector for low light
- Waterproof up to 1 metre deep (IPX7)
- Lanyard included

OPERATION

- Bottom-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECS

- Weight with batteries - 173g
- Length - 115mm
- Diameter - 34mm (Head) 12mm (Barrel)



IPROTEC MADE TOUGH

PRO200LIGHT

The PRO200LIGHT offers 200 lumens of high intensity light and can throw a spectacularly bright beam over 228 metres. The PRO200LIGHT is waterproof and ready for any weather condition. This light is packed with features including a 6x zoom, glow-in-the-dark reflector and 2 light modes (high and low).

2 LIGHT MODES

- HIGH 200 Lumens, 9 hours, 228 metres
- LOW 100 Lumens - 18 hours, 156 metres

ITEM	DESCRIPTION
IP6544	PRO200LIGHT

DESIGN

- Powerful 200 lumens of white LED light
- 2 light modes
- Aluminium body
- Waterproof up to 1 metre deep (IPX7)
- Glow-in-the-dark reflector for low light
- Signature RED RING™
- Lanyard included

OPERATION

- Bottom-positioned, ON/OFF button

BATTERIES

- Powered by 2 AA batteries (included)

SPECS

- Weight with batteries - 206g
- Length - 150mm
- Diameter - 31mm (Head) 20mm (Barrel)



IPROTEC MADE TOUGH

TWYSTZ200

The TWYSTZ200 is shaping light like never before.

3 light modes - flashlight, work light and lantern; all can be used hands free using the magnetic base. A simple twist of the flashlight reveals a work light and lantern. Adjustable zoom and dimmable beam. Powered by 4 x AAA Batteries (included).



ITEM	DESCRIPTION
IP6372	TWYSTZ200

3 LIGHT MODES

- Flashlight (200 lumens) - 2 hours / 110 m
- Work Light (75 lumens) - 10 hours / 10 m
- Lantern (200 lumens) - 2 hours / 10 m

DESIGN

- 4x adjustable zoom
- ARCUS C+O•B LED Technology
- Tactical edge
- Fully dimmable beam
- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Powerful magnetic base

OPERATION

- Side-positioned ON/OFF button

BATTERIES

- Powered by 4 AAA batteries (included)

SPECS

- Weight with batteries - 250g
- Length - 160mm (Compacted) 172mm (Extended)
- Diameter - 45mm (Head) 25mm (Barrel)



The PRO250LIGHT has a high-power LED that outputs 250 lumens of intense white light.

The PRO250LIGHT also features a 6x adjustable zoom that changes from floodlight to spotlight. The magnetic base and steel belt clip provide convenient hands-free lighting.

ITEM	DESCRIPTION
IP6273	PRO250LIGHT
5 LIGHT MODES <ul style="list-style-type: none">• High 250 Lumens - 2.5 hours / 206 m• Medium - 6.5 hours / 140 m• Low - 20 hours / 87 m• Strobe - 24 hours / 206 m• S.O.S. - 24 hours / 206 m	
DESIGN <ul style="list-style-type: none">• Convex lens• Anodised aircraft grade aluminium• Water-resistant• Compact body design• Rear glow in the dark tactical button• 6X adjustable beam zoom• Steel clip• Impact resistant: 2 metres	
OPERATION <ul style="list-style-type: none">• Bottom-positioned, ON/OFF button	
BATTERIES <ul style="list-style-type: none">• Powered by 3 AAA batteries (included)	
SPECS <ul style="list-style-type: none">• Weight with batteries - 148g• Length - 112mm (Compacted) 123mm (Extended)• Diameter - 40mm (Head) 30mm (Barrel)	



250
LUMENS


One of the most versatile in the PROLIGHT series is the PRO320RC with MagDock.

The MagDock is a magnetic charging station that docks and charges your flashlight. Small enough to fit in the palm of your hand, the PRO320RC with MagDock is fully equipped with all of the features that make the PROLIGHT series so popular.

ITEM	DESCRIPTION
IP6392	PRO320RC
4 LIGHT MODES <ul style="list-style-type: none">• High (320 lumens) - 1 hour / 110 m• Medium (125 lumens) - 2 hours / 70 m• Low (32 lumens) - 9 hours / 35 m• Strobe (320 lumens) - 2 hours / 110 m	
DESIGN <ul style="list-style-type: none">• 4x adjustable zoom• Anodised aircraft-grade Aluminium• Water and impact-resistant• OCT™ Technology• Convex lens• Signature Red Ring™• Steel belt/pocket clip• Ergonomic non-slip grip• Magnetic base• Protective LED housing• Charging indicator light	
OPERATION <ul style="list-style-type: none">• Side-positioned, ON/OFF button	
BATTERIES <ul style="list-style-type: none">• Internal, rechargeable lithium-ion battery (Recharge time - up to 2 hours)	
SPECS <ul style="list-style-type: none">• Weight - 94g• Length - 91mm (Compacted) 98mm (Extended)• Diameter - 31mm (Head) 27mm (Barrel)	




320
LUMENS

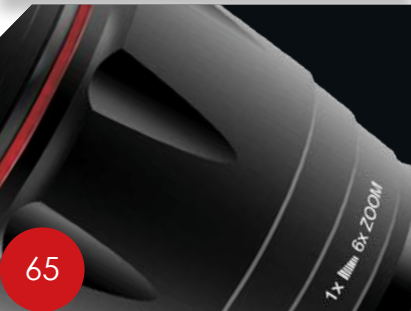

PACK SIZE
120mm x 185mm



PACK SIZE
120mm x 185mm

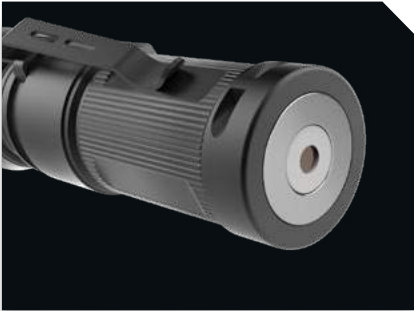

66

TASKLIGHT

The Task Light outputs 250 lumens of intense light. Secondary light modes include Low (95 lumens) and the Emergency Red Flash mode. This intense red light is perfect for distress signaling or roadside emergencies. The anodised aluminium body and recessed LED housing ensures that the Task Light can handle any situation. It's small size makes this flashlight extremely portable.

3 LIGHT MODES

- HIGH (250 lumens) - 3 hours / 29 metres
- LOW (95 lumens) - 10 hours / 17 metres
- RED Flash - 10 hours

ITEM	DESCRIPTION
IP6373	TASKLIGHT

DESIGN

- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Powerful magnetic base
- Top positioned ON/OFF button
- Powered by 3 AAA batteries (included)

OPERATION

- Top-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECS

- Weight with batteries - 89g
- Length - 151mm
- Diameter - 20mm (Head) 15mm (Barrel)



Compact, handy and bright...the LUMO™ Clip Light is the perfect “whatever you need it to be” light. Key chain light, purse light, backpack light, book light...the possibilities are endless. This compact 25 lumen light comes with a carabiner attachment to clip anywhere you need. The white top of the LUMO™ is a diffuser dome. This dome helps spread the light evenly to create a more omnidirectional light source.



PROLUMOLIGHT

1 LIGHT MODE

- HIGH power (25 lumens) - 5 hours / 3 metres

ITEM	DESCRIPTION
IP6095	PROLUMOLIGHT

DESIGN

- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Carabiner clip
- Glow-in-the-dark button
- Diffuser dome

OPERATION

- Rear-positioned glow-in-the-dark ON/OFF button

BATTERIES

- Powered by 3 LR44 batteries (included)

SPECS

- Weight with batteries - 25g
- Length - 50mm
- Diameter - 19mm

CHAMELEON

The Chameleon™ has a high-power, colour-changing LED that outputs white, green and red light. Hard/Soft Touch Technology allows you to easily cycle through the four impressive light modes.

4 LIGHT MODES

- WHITE - 100 Lumens, 4 hours, 80 metres
- GREEN - 90 Lumens, 5 hours, 70 metres
- RED - 85 Lumens, 7 hours, 50 metres
- STROBE - 5 hours, 80 metres

ITEM	DESCRIPTION
IP5905	CHAMELEON

DESIGN

- Anodised aircraft-grade aluminium
- Water and impact-resistant
- Convex lens
- 4x adjustable zoom
- Steel belt/pocket clip

OPERATION

- Rear-positioned ON/OFF button with Soft Touch Technology

BATTERIES

- 1 AA batteries included

SPECS

- Weight with batteries - 82g
- Length - 101mm
- Diameter - 25mm (Head) 19mm (Barrel)



PRO220LIGHT

The PRO220LIGHT has a high power LED that outputs 220 lumens of intense white light. It also features a 4x adjustable zoom that changes from floodlight to spotlight. The magnetic base and steel belt clip, provide convenient hands-free lighting options.



5 LIGHT MODES

- HIGH - 220 Lumens, 4 hours, 138 metres
- MEDIUM - 8 hours, 60 metres
- LOW - 15 hours, 27 metres
- S.O.S - 72 hours, 138 metres
- STROBE - 72 hours, 138 metres

ITEM	DESCRIPTION
IP5929	PRO220LIGHT

DESIGN

- Anodised aircraft grade aluminium
- Water-resistant
- Compact body design
- Rear glow in the dark tactical button
- Convex lens
- 4 X adjustable beam
- Powerful magnetic base for hands-free lighting
- Impact resistant: 2 metres, steel clip

OPERATION

- Rear-positioned, ON/OFF button

BATTERIES

- Powered by 3 AAA batteries (included)

SPECS

- Weight with batteries - 133g
- Length - 110mm (Compacted) 116mm (Extended)
- Diameter - 34mm

PRO180LIGHT

The PRO180LIGHT has a high-power LED that outputs 180 lumens of intense white light and it also features a tactical, self defense edge. Hard/Soft Touch Technology allows you to easily cycle through the two impressive light modes.

2 LIGHT MODES

- HIGH - 180 Lumens, 2 hours, 115 metres
- STROBE - 6 hours, 115 metres

ITEM	DESCRIPTION
IP6079	PRO180LIGHT

DESIGN

- Anodised aircraft grade aluminium
- Water-resistant
- Compact body design
- Rear glow-in-the-dark button
- Powerful magnetic base for hands-free lighting
- Convex lens

OPERATION

- Rear-positioned, ON/OFF button

BATTERIES

- Powered by 1 AA batteries (included)

SPECS

- Weight - 82g
- Length - 100mm (Compacted) 106mm (Extended)
- Diameter - 27mm



PRO100LIGHT

The PRO100LIGHT has a high power LED that outputs 100 lumens of intense white light and it also features a removeable, tactical self defense edge. Hard/Soft Touch Technology allows you to easily cycle through the two impressive light modes.

2 LIGHT MODES

- STEADY ON - 100 Lumens, 2 hours, 80 metres
- STROBE - 4.5 hours, 80 metres

ITEM	DESCRIPTION
IP6078	PRO100LIGHT

DESIGN

- Anodised aircraft grade aluminium
- Water-resistant
- Compact body design
- Removable chrome plated head, steel clip
- Rear glow-in-the-dark button - this button allows you to easily activate the light while maintaining constant control of the flashlight

OPERATION

- Rear-positioned ON/OFF button with Soft Touch Technology

BATTERIES

- 1 Duracell AA battery included

SPECS

- Weight with batteries - 65g
- Length - 102mm
- Diameter - 23mm



NEBO[®]

INNOVATIVE LIGHTING

2019



www.nebotools.co.uk
sales@true-brands.co.uk
+44(0)1202 768883

True Brands Ltd
Unit 2, The GP Centre
Yeomans Road,
Ringwood, BH24 3FF, UK