


Jumbo/ Oversize

- Ideal for covering broken plaster and irregularly cut holes in sheet rock or paneling around the box.
- Can be used to protect wall surrounding wiring devices thus reducing maintenance.
- Useful for replacement of plates in old work where a mark is left around the original plate.

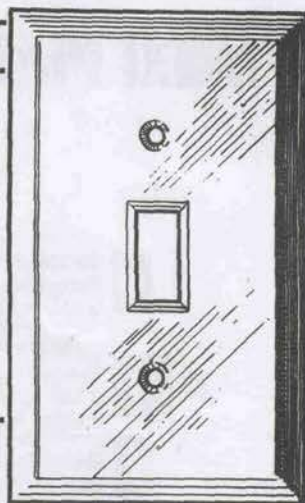

For color photos of finishes see inside front cover.

1 Gang	5.5" x 3.5"
2 Gang	5.5" x 5.5"
3 Gang	5.5" x 7.5"
4 Gang	5.5" x 9.5"
5 Gang	5.5" x 11.5"


STANDARD SHAPE

 listed 883C except where noted by asterisk(*).

See page A85 for ordering Custom Jumbo/Oversize Plates not found in this listing. Available to 20 gangs on special order.

	SPRAYED BRASS MATTE	BROWN SEMI- GLOSS	CHROME PLATED	IVORY SEMI- GLOSS	WHITE WRINKLE	WHITE SEMI- GLOSS
	Painted Steel (BA)	Painted Steel (BK)	Polished Steel (CA)	Painted Steel (IA)	Painted Steel (DW)	Painted Steel (WA)
 1 Toggle Switch (1T-SL)	81871	82871	83871	84871	85871	86871
 2 Toggle Switches (2T-SL)	81872	82872	83872	84872	85872	86872
 3 Toggle Switches (3T-SL)	81873	82873	83873	84873	85873	86873
 4 Toggle Switches (4T-SL)	81874	82874	83874	84874	85874	86874
 5 Toggle Switches (5T-SL)	81875	82875	83875	84875	85875	86875
 1 Duplex Receptacle (10DR-SL)	81801	82801	83801	84801	85801	86801
 2 Duplex Receptacles (20DR-SL)	81802	82802	83802	84802	85802	86802
 1 Single Recept. (1.405") (10R-SL)	81891	82891	83891	84891	85891	86891
 1 Blank (Box Mntg. 3.281") (1B-SL)	81851	82851	83851	84851	85851	86851
 2 Blanks (Box Mntg. 3.281") (2B-SL)	81852	82852	83852	84852	85852	86852
 3 Blanks (Box Mntg. 3.281") (3B-SL)	81853	82853	83853	84853	85853	86853
 One 5/8" ID Phone (Box Mntg. 3.281") (01-SL)*	81861	82861	83861	84861	85861	86861
 One Phone with .375" ID Grommet and Mounting Strap (Device Mntg. 2.375")*	81881	82881	83881	84881	85881	86881

Material Specifications

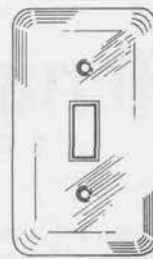

S = Standard Shape

P = Princess Shape



Listed 883C unless marked with asterisk(*).
Meets Federal Specification WP455A. All
plates supplied with matching screws.


Steel

(Preplated to Underwriters
Laboratories, Inc. specifications)


	Finish	Shape	Thickness	U.S. Bureau Standards Symbols	Finish Designator	Cat. Page #
Almond (ALM)	Smooth, Semi-Gloss	S	.030	—	44000	A14-20
Aluminum Paint (CDA)	Semi-Gloss	S	.030	—	88000	A21-27
Black Paint (BL)	Matte	S	.030	—	87000	A21-27
Brass Paint (BA)	Matte	S	.030	—	81000	A14-20
Brass Paint (BA-PRL)	Matte	P	.030	—	71000	A48-53
Brown Paint (BK)	Smooth, Semi-Gloss	S	.030	—	82000	A14-20
Brown Paint (DB)	Hard Baked, Wrinkle	S	.030	—	98000	A7-13
Brown Paint (DB-PRL)	Hard Baked, Wrinkle	P	.030	—	78000	A48-53
Chrome Plate (CA)	Mirror Polish	S	.030	—	83000	A7-13
Chrome Plate (CA-PRL)	Mirror Polish	P	.030	—	73000	A48-53
Gray	Smooth, Semi-Gloss	S	.030	—	58000	A21-27
Ivory (IA)	Smooth, Semi-Gloss	S	.030	—	84000	A14-20
Ivory (IA-PRL)	Smooth, Semi-Gloss	P	.030	—	74000	A48-53
Ivory (DI)	Hard Baked, Wrinkle	S	.030	—	99000	A7-13
Ivory (DI-PRL)	Hard Baked, Wrinkle	P	.030	—	79000	A48-53
Red (RA)	Smooth, Semi-Gloss	S	.030	—	51000	A21-27
White (WA)	Smooth, Semi-Gloss	S	.030	—	86000	A7-13
White (WA-PRL)	Smooth, Semi-Gloss	P	.030	—	76000	A48-53
White (DW)	Hard Baked, Wrinkle	S	.030	—	85000	A14-20
White (DW-PRL)	Hard Baked, Wrinkle	P	.030	—	75000	A48-53
Zinc Coat (AUNF)	Smooth, Dull	S	.030	—	89000	A21-27
Zinc Coat (AUNF-PRL)	Smooth, Dull	P	.030	—	80000	A42-47

WALL PLATE COLOR GUIDE

STANDARD SHAPE

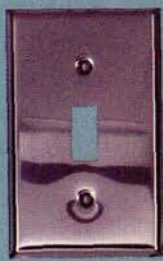


A

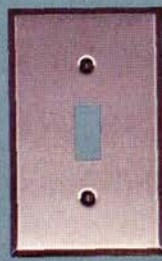

B



C

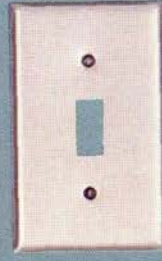

D



E




F




G




H

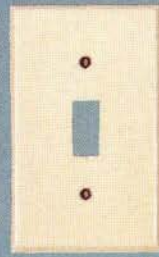

I

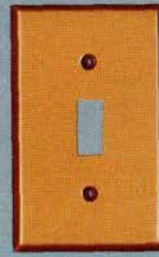


J

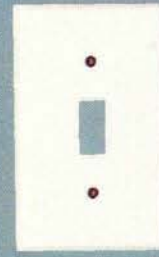

K




L

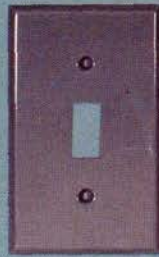

M



N

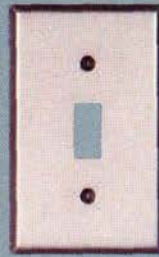

O



P



Q



R



S



T



U

- A. Polished Chrome (83000)
- B. Stainless Steel (97000, 93000, 70000)
- C. Polished Stainless (68000)
- D. Clear Anodized Aluminum (95000)
- E. Satin Aluminum (62000)
- F. Ivory Wrinkle (99000)

- G. Brown Wrinkle (98000)
- H. White Wrinkle (85000)
- I. Ivory Semi-Gloss (84000)
- J. Sprayed Brass Matte (81000)
- K. White Semi-Gloss (86000)
- L. Brown Semi-Gloss (82000)
- M. Gray Semi-Gloss (58000)

- N. Red Semi-Gloss (51000)
- O. Aluminum Painted Steel/Cadilite (88000)
- P. Black Matte (87000)
- Q. Satin Brass (94000, 96000)
- R. Bank Bronze (65000)
- S. Satin Bronze (66000)
- T. Statuary Bronze (69000)
- U. Polished Brass (64000)