

15, 20 & 30A 120/277V AC

LEVITON®

Industrial Grade, Back & Side Wired

10 YEAR LIMITED
WARRANTY

ELECTRICAL			
DIELECTRIC VOLTAGE	OVERLOAD UL 20 TEST	TEMP. RISE	ENDURANCE
Withstands 1500V for 1min	100 cycles of overload at 4.8 times rated current	30°C max at full rated current	UL 20/Fed Spec 50,000 cycles min., tungsten filament lamp load (Fed. Spec.) WS896E, SP, DP, 3-way, 4-way, Pilot Light, Illum., Key Lock

MECHANICAL			
TERMINAL I.D.	TERMINAL ACCOMM.	PRODUCT I.D.	TORQUE RANGE
Brass-Hot, Black-Hot, White-Neutral, Green-Grounding	#14-#10 AWG back wired #14-#12 AWG side wired	Ratings are permanently stamped on device strap	12-14 inch pounds

ENVIRONMENTAL	
FLAMMABILITY	OPERATING TEMP.
Rated V-2 per UL 94	-40°C to 65°C

STANDARDS & CERTIFICATION					
NEMA WD-1 & WD-6	ANSI C-73	UL 20	UL Fed Spec WS896E	CSA C22.2 No. 111	NOM
✓	✓	#E7458	#E7458	#152105	#057



1201-2W

1202-2L

1204-2

1224-2WL

3033-2I

AC HORSEPOWER RATINGS		
15 AMP	20 AMP	30 AMP
1/2@120V	1@120V	2@120V
2@240V	2@240V	2@240V
12 AMP MAX	16 AMP MAX	24 AMP MAX



Catalog No. 55500-PRT

HEAVY DUTY, INDUSTRIAL DEVICES HAVE NYLON TOGGLES, COLOR-CODED BODY COVERS, AUTOMATIC GROUND CLIP, COMBO-HEAD BRASS TERMINAL SCREWS AND BACK WIRED GROUND SCREW								
TOGGLE COLOR	SINGLE-POLE TOGGLE BACK WIRED	SINGLE-POLE LOCKING	DOUBLE-POLE TOGGLE	DOUBLE-POLE LOCKING	3-WAY TOGGLE BACK WIRED	3-WAY LOCKING	4-WAY TOGGLE	4-WAY LOCKING
15 AMP								
Brown	1201-2	1201-2L	1202-2	1202-2L	1203-2	1203-2L	1204-2	1204-2L
Ivory	1201-2I	1201-2IL	1202-2I	-	1203-2I	1203-2IL	1204-2I	-
White	1201-2W	-	1202-2W	-	1203-2W	-	1204-2W	-
Gray	1201-2GY	-	1202-2GY	-	1203-2GY	-	1204-2GY	-
Red	1201-2R	-	-	-	1203-2R	-	-	-
20 AMP								
Brown	1221-2	1221-2L	1222-2	1222-2L	1223-2	1223-2L	1224-2	1224-2L
Almond	1221-2A	-	-	-	-	-	-	-
Ivory	1221-2I	1221-2IL	1222-2I	1222-2IL	1223-2I	1223-2IL	1224-2I	1224-2IL
White	1221-2W	1221-2WL	1222-2W	-	1223-2W	1223-2WL	1224-2W	1224-2WL
Gray	1221-2GY	1221-2GL	1222-2GY	-	1223-2GY	1223-2GL	1224-2GY	1224-2GL
Red	1221-2R	1221-2RL	1222-2R	-	1223-2R	-	1224-2R	-
Ebony	1221-2E	-	1222-2E	-	1223-2E	-	1224-2E	-
30 AMP								
Brown	3031-2	3031-2L	3032-2	3032-2L	3033-2	3033-2L	-	-
Ivory	3031-2I	-	3032-2I	-	3033-2I	-	-	-
White	3031-2W	-	3032-2W	-	3033-2W	-	-	-



1221-SW

SPECCLASS

General Duty, Contractor Pack, Combo-Head Steel Terminal Screws, Back & Side Wired

TOGGLE COLOR	SINGLE-POLE TOGGLE	DOUBLE-POLE TOGGLE	3-WAY TOGGLE	4-WAY TOGGLE
20 AMP				
Brown	1221-S	1222-S	1223-S	1224-S
Ivory	1221-SI	1222-SI	1223-SI	1224-SI
White	1221-SW	1222-SW	1223-SW	1224-SW
Red	1221-SR	-	1223-SR	-
Gray	1221-SGY	1222-SGY	1223-SGY	1224-SGY

UL Fed. Spec.


2 YEAR LIMITED
WARRANTY




1241-I

LevSpec Industrial Grade Pigtail Switches


TOGGLE COLOR	SINGLE-POLE TOGGLE w/ 6" Leads	3-WAY TOGGLE w/ 6" Leads
15 AMP		
Ivory	1241-I	1242-I
White	1241-W	1242-W
20 AMP		
Ivory	1243-I	1244-I
White	1243-W	1244-W

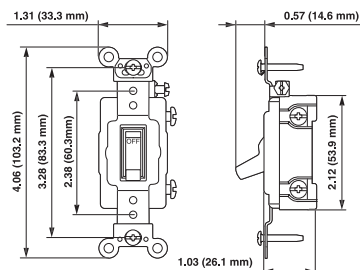

SINGLE-POLE

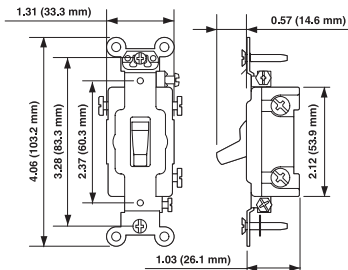

3-WAY

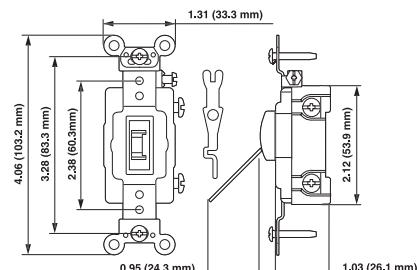

LOCKING

To learn more about Leviton devices or for answers to technical questions call our Techline at 1-800-824-3005 or visit us at www.leviton.com

Courtesy of Steven Engineering, Inc.-230 Ryan Way, South San Francisco, CA 94080-6370-Main Office: (650) 588-9200-Outside Local Area: (800) 258-9200-www.stevenengineering.com