



LED/CFL BULB PROGRAM REFERENCE GUIDE JULY 2018



RENAISSANCE

LIGHTING AND METAL FURNITURE FOR HOSPITALITY

www.RCLFinc.com

LED FILAMENT LAMPS

LED filament lamps

- LED with a traditional incandescent look and feel
- Omni-directional light source
- Dimmable
- Replaces up to 60 Watt lamps
- Damp location
- Approved for totally enclosed fixtures***
- c-UL-us listed
- Long life—up to 25,000 hours
- ENERGY STAR certified*
- 3 Year warranty



LED Filament Lamps



Item Number	Lamp Description	W	Bulb Type	Base	V	Finish	CCT	Lm	CRI	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9874*	4.5A15/CL/LED/E26/27K/ES/120V	4.5	A15	E26	120	Clear	2700K	450	80	3 3/8	15K	045923098741	24/6
S9875*	4.5A19/CL/LED/E26/27K/ES/120V	4.5	A19	E26	120	Clear	2700K	450	80	4 1/8	15K	045923098758	24/6
S9824	4.5A19/SW/LED/E26/27K/120V	4.5	A19	E26	120	Soft White	2700K	400	80	4 1/8	15K	045923098246	24/6
S9825	6.5A19/SW/LED/E26/27K/120V	6.5	A19	E26	120	Soft White	2700K	720	80	4 1/8	15K	045923098253	24/6
S9826†	6.5A19/SLV/LED/E26/27K/120V	6.5	A19	E26	120	Silver Crown	2700K	650	80	4 1/8	15K	045923098260	24/6
S9894	6.5A19/CL/LED/E26/30K/120V	6.5	A19	E26	120	Clear	3000K	800	80	4 1/8	15K	045923098949	24/6
S9876*	7A19/CL/LED/E26/27K/ES/120V	7	A19	E26	120	Clear	2700K	800	80	4 1/8	15K	045923098765	24/6
S8850	7A19/CL/LED/E26/40K/120V	7	A19	E26	120	Clear	4000K	800	80	4 1/8	15K	045923088506	24/6
S9845	9A19/CL/LED/E26/27K/120V	9	A19	E26	120	Clear	2700K	1100	80	4 1/2	15K	045923098451	24/6
S9846	9A19/CL/LED/E26/30K/120V	9	A19	E26	120	Clear	3000K	1100	80	4 1/2	15K	045923098468	24/6
90 CRI													
S9879**	8.5A19/CL/LED/E26/27K/90CRI	8.5	A19	E26	120	Clear	2700K	800	91	4	15K	045923098796	24/6
† Silver crown are 180° beam angle. ** Not rated for enclosed fixtures. *** See warranty for details.													

LED FILAMENT LAMPS




LED Globe Filament Lamps



Item Number	Lamp Description	W	Bulb Type	Base	V	Finish	CCT	Lm	CRI	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9870	2.5G16.5/LED/CL/27K/120V	2.5	G16 1/2	E12	120	Clear	2700K	200	80	3 3/16	15K	045923098703	24/6
S9871	3.5G16.5/LED/CL/27K/120V	3.5	G16 1/2	E12	120	Clear	2700K	350	80	3 3/16	15K	045923098710	24/6
S29563*	4.5G25/CL/LED/E26/27K/120V	4.5	G25	E26	120	Clear	2700K	450	80	4 3/8	20K	045923095634	24/6
S9827*	4.5G25/SW/LED/E26/27K/120V	4.5	G25	E26	120	Soft White	2700K	430	80	4 3/8	15K	045923098277	24/6
S9828†	4.5G25/SLV/LED/E26/27K/120V	4.5	G25	E26	120	Silver Crown	2700K	430	80	4 3/8	15K	045923098284	24/6
S9893	4.5G25/CL/LED/E26/30K/120V	4.5	G25	E26	120	Clear	3000K	550	80	4 3/8	15K	045923098932	24/6
S8849	4.5G25/CL/LED/E26/40K/120V	4.5	G25	E26	120	Clear	4000K	450	80	4 3/8	15K	045923088490	24/6
S9564	6.5G25/CL/LED/E26/27K/120V	6.5	G25	E26	120	Clear	2700K	810	80	4 3/8	15K	045923095641	24/6
S9565	4.5G40/CL/LED/E26/27K/120V	4.5	G40	E26	120	Clear	2700K	450	80	6 1/2	15K	045923095658	24/6
S9566	6.5G40/CL/LED/E26/27K/120V	6.5	G40	E26	120	Clear	2700K	800	80	6 1/2	15K	045923095665	24/6
90 CRI													
S9878	5G25/CL/LED/E26/27K/90CRI	5	G25	E26	120	Clear	2700K	380	90	4 3/8	15K	045923098789	24/6

† Silver crown are 180° beam angle. *** See warranty for details.

LED FILAMENT LAMPS

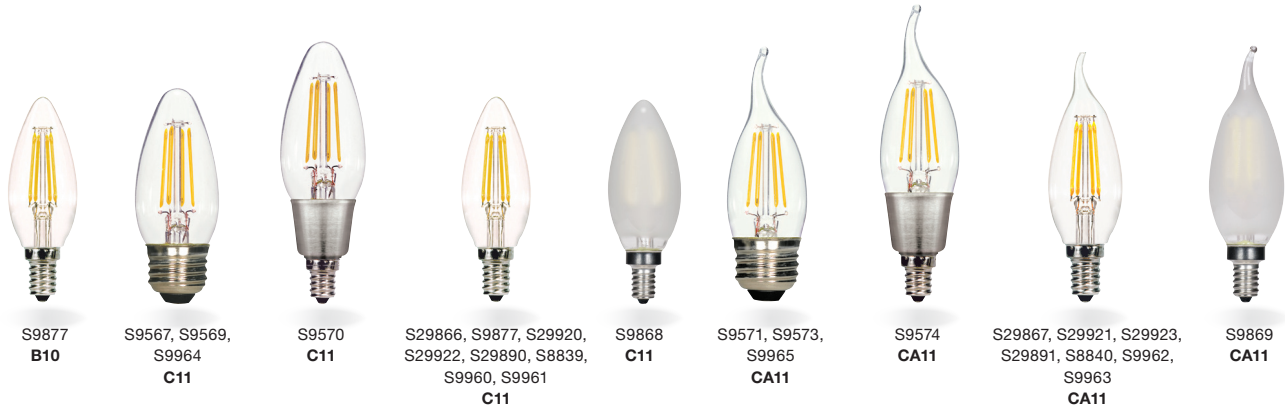


LED Decorative Filament Lamps



Item Number	Lamp Description	W	Bulb Type	Base	V	Finish	CCT	Lm	CRI	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9877**	4W CTC/LED/27K/CL/90CRI	4	B10	E12	120	Clear	2700K	300	94	3 5/8	15K	045923098772	24/6
S9567*	2.5W ETC/LED/27K/120V	2.5	C11	E26	120	Clear	2700K	250	80	3 1/2	25K	045923095672	24/6
S29920	2.5W CTC/LED/CL/27K/120V	2.5	C11	E12	120	Clear	2700K	200	80	3 7/8	15K	045923299209	24/6
S9868	3.5CTF/LED/FR/27K/120V	3.5	C11	E12	120	Frosted	2700K	350	80	4 5/16	15K	045923098680	24/6
S29922	4W CTC/LED/27K/CL/120V	4	C11	E12	120	Clear	2700K	350	80	3 7/8	15K	045923299223	24/6
S29890	4W CTC/LED/30K/CL/120V	4	C11	E12	120	Clear	3000K	350	80	3 7/8	15K	045923298905	24/6
S8839	4W CTC/LED/40K/CL/120V	4	C11	E12	120	Clear	4000K	350	80	3 7/8	15K	045923088391	24/6
S29866	4W CTC/LED/50K/CL/120V	4	C11	E12	120	Clear	5000K	350	80	4 5/16	15K	045923298660	24/6
S9569*	4.5W ETC/LED/27K/120V	4.5	C11	E26	120	Clear	2700K	450	80	3 1/2	15K	045923095696	24/6
S9570*	4.5W CTC/LED/27K/120V	4.5	C11	E12	120	Clear	2700K	450	80	4 5/16	20K	045923095702	24/6
S9960	5.5W CTC/LED/27K/CL/120V	5.5	C11	E12	120	Clear	2700K	500	80	3 7/8	15K	045923099601	24/6
S9961	5.5W CTC/LED/30K/CL/120V	5.5	C11	E12	120	Clear	3000K	500	80	3 7/8	15K	045923099618	24/6
S9964	5.5W ETC/LED/27K/CL/120V	5.5	C11	E26	120	Clear	2700K	500	80	3 1/2	15K	045923099649	24/6
S9571	2.5W EFC/LED/27K/120V	2.5	CA11	E26	120	Clear	2700K	250	80	4 5/16	15K	045923095719	24/6
S29921	2.5W CFC/LED/CL/27K/120V	2.5	CA11	E12	120	Clear	2700K	200	80	4 11/16	15K	045923299216	24/6
S9869	3.5CFF/LED/FR/27K/120V	3.5	CA11	E12	120	Frosted	2700K	350	80	5	15K	045923098697	24/6
S29923	4W CFC/LED/27K/CL/120V	4	CA11	E12	120	Clear	2700K	350	80	4 11/16	15K	045923299230	24/6
S29891	4W CFC/LED/30K/CL/120V	4	CA11	E12	120	Clear	3000K	350	80	4 11/16	15K	045923298912	24/6
S8840	4W CFC/LED/40K/CL/120V	4	CA11	E12	120	Clear	4000K	350	80	4 11/16	15K	045923088407	24/6
S29867	4W CFC/LED/50K/CL/120V	4	CA11	E12	120	Clear	5000K	350	80	5	15K	045923298677	24/6
S9573*	4.5W EFC/LED/27K/120V	4.5	CA11	E26	120	Clear	2700K	450	80	4 5/16	15K	045923095733	24/6
S9574	4.5W CFC/LED/27K/120V	4.5	CA11	E12	120	Clear	2700K	450	80	5	15K	045923095740	24/6
S9965	5.5W EFC/LED/27K/CL/120V	5.5	CA11	E26	120	Clear	2700K	500	80	4 5/16	15K	045923099656	24/6
S9962	5.5W CFC/LED/27K/CL/120V	5.5	CA11	E12	120	Clear	2700K	500	80	4 11/16	15K	045923099625	24/6
S9963	5.5W CFC/LED/30K/CL/120V	5.5	CA11	E12	120	Clear	3000K	500	80	4 11/16	15K	045923099632	24/6

** Not rated for enclosed fixtures. *** See warranty for details.

LED FILAMENT LAMPS

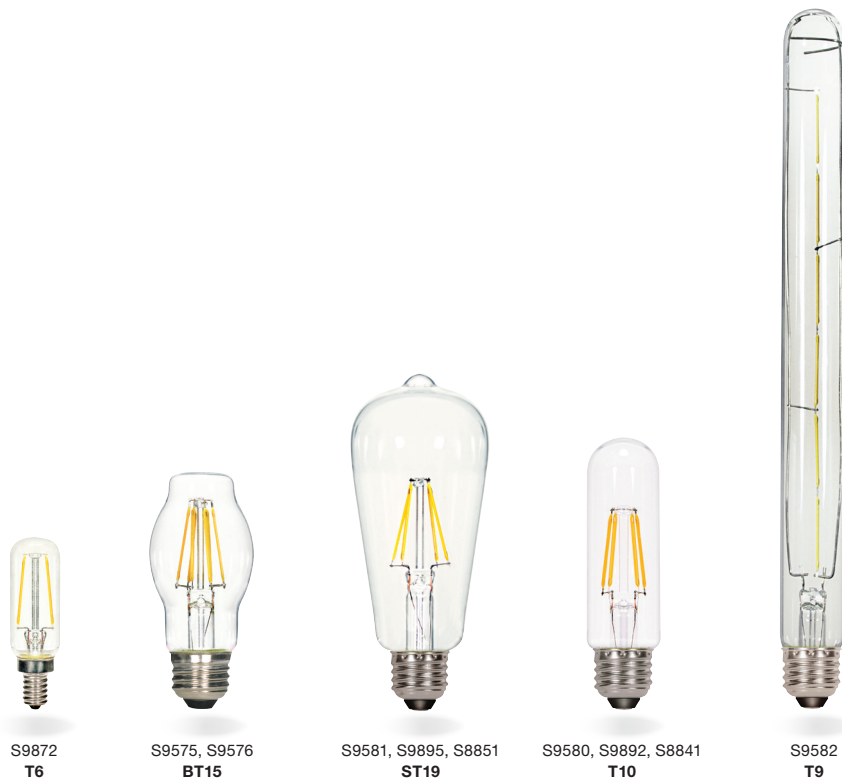

LED Specialty Filament Lamps




Item Number	Lamp Description	W	Bulb Type	Base	V	Finish	CCT	Lm	CRI	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9872	2.5T6/LED/CL/27K/E12/120V	2.5	T6	E12	120	Clear	2700K	200	80	3 3/16	15K	045923098727	24/6
S9575	4.5BT15/CL/LED/E26/27K/120V	4.5	BT15	E26	120	Clear	2700K	450	80	4 1/8	15K	045923095757	24/6
S9576	6.5BT15/CL/LED/E26/27K/120V	6.5	BT15	E26	120	Clear	2700K	800	80	4 1/8	15K	045923095764	24/6
S9581	6.5ST19/CL/LED/E26/27K/120V	6.5	ST19	E26	120	Clear	2700K	810	80	5 1/2	15K	045923095818	24/6
S9895	6.5ST19/CL/LED/E26/30K/120V	6.5	ST19	E26	120	Clear	3000K	810	80	5 1/2	15K	045923098956	24/6
S8851	6.5ST19/CL/LED/E26/40K/120V	6.5	ST19	E26	120	Clear	4000K	810	80	5 1/2	15K	045923088513	24/6
S9580	4.5T10/LED/E26/27K/120V	4.5	T10	E26	120	Clear	2700K	430	80	5	15K	045923095801	24/6
S9892	4.5T10/LED/E26/30K/120V	4.5	T10	E26	120	Clear	3000K	430	80	5	15K	045923098925	24/6
S8841	4.5T10/LED/E26/40K/120V	4.5	T10	E26	120	Clear	4000K	450	80	5	15K	045923088414	24/6
S9582	6.5T9/CL/LED/E26/27K/120V	6.5	T9	E26	120	Clear	2700K	800	80	12	15K	045923095825	24/6

*** See warranty for details.

OMNI-DIRECTIONAL LED A19 LAMPS

40W replacement omni-directional LED A19 lamps

- Direct replacement for 40 Watt incandescent lamps, uses only 6 Watts
- Indoor residential and commercial lighting
- Innovative design—smooth heat sink design to resemble traditional incandescent lamp
- 2700K, 3000K, 3500K, 4000K & 5000K options
- Damp location
- Dimmable and non-dimmable options
- Approved for totally enclosed fixtures**
- E26 & GU24 base options
- Long life—up to 25,000 hours
- ENERGY STAR certified*
- 3 Year warranty—15,000 hours
- 5 Year warranty—25,000 hours

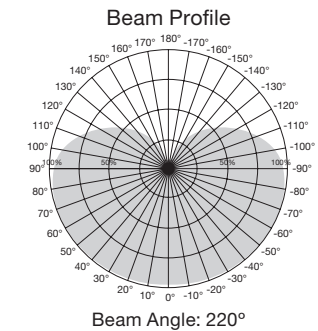

40W Replacement Omni-Directional A19 LED Lamps




Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
Dimmable											
S29830*	6A19/OMNI/220/LED/27K	6	120	80	2700K	480	220°	4 5/16	25K	045923298301	24/6
S29831*	6A19/OMNI/220/LED/30K	6	120	80	3000K	480	220°	4 5/16	25K	045923298318	24/6
S29832*	6A19/OMNI/220/LED/35K	6	120	80	3500K	480	220°	4 5/16	25K	045923298325	24/6
S29833*	6A19/OMNI/220/LED/40K	6	120	80	4000K	480	220°	4 5/16	25K	045923298332	24/6
S29834*	6A19/OMNI/220/LED/50K	6	120	80	5000K	480	220°	4 5/16	25K	045923298349	24/6
Non-Dimmable											
S9590*	6A19/LED/2700K/120V	6	120	80	2700K	480	220°	4 5/16	15K	045923095900	24/6
S9591*	6A19/LED/3000K/120V	6	120	80	3000K	480	220°	4 5/16	15K	045923095917	24/6
S9592*	6A19/LED/5000K/120V	6	120	80	5000K	480	220°	4 5/16	15K	045923095924	24/6

** See warranty for details.

OMNI-DIRECTIONAL LED A19 LAMPS

60W replacement omni-directional LED A19 lamps

- Direct replacement for 60 Watt incandescent lamps, uses only 8.5-10 Watts
- Indoor residential and commercial lighting
- Innovative design—smooth heat sink design to resemble traditional incandescent lamp
- 2700K, 3000K, 3500K, 4000K & 5000K options
- Damp location
- Dimmable and non-dimmable options
- Approved for totally enclosed fixtures**
- E26 & GU24 base options
- CEC/T20 Compliant options available
- Long life—up to 25,000 hours
- ENERGY STAR certified*
- 3 Year warranty—15,000 hours
- 5 Year warranty—25,000 hours

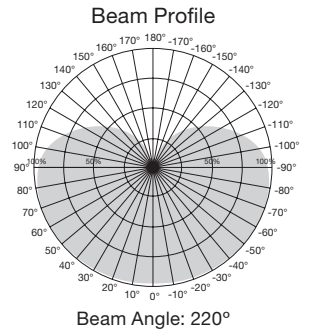

60W Replacement Omni-Directional A19 LED Lamps




Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/Hrs.	UPC	Pack
Dimmable											
S29835*	9.8A19/OMNI/220/LED/27K	9.8	120	80	2700K	800	220°	4 5/16	25K	045923298356	24/6
S29836*	9.8A19/OMNI/220/LED/30K	9.8	120	80	3000K	800	220°	4 5/16	25K	045923298363	24/6
S29837*	9.8A19/OMNI/220/LED/35K	9.8	120	80	3500K	800	220°	4 5/16	25K	045923298370	24/6
S29838*	9.8A19/OMNI/220/LED/40K	9.8	120	80	4000K	800	220°	4 5/16	25K	045923298387	24/6
S29839*	9.8A19/OMNI/220/LED/50K	9.8	120	80	5000K	800	220°	4 5/16	25K	045923298394	24/6
S29840*	9.8A19/OMNI/220/LED/27K/GU24	9.8	120	80	2700K	800	220°	4 5/16	25K	045923298400	24/6
S29841*	9.8A19/OMNI/220/LED/35K/GU24	9.8	120	80	3500K	800	220°	4 5/16	25K	045923298417	24/6
S29842*	9.8A19/OMNI/220/LED/40K/GU24	9.8	120	80	4000K	800	220°	4 5/16	25K	045923298424	24/6
90 CRI—CEC/T20—JA8-2016											
S9703*	10A19/OMNI/LED/27K/90CRI	10	120	90	2700K	800	220°	4 5/16	25K	045923097034	24/6
S9707*	10A19/OMNI/LED/27K/90CRI/GU24	10	120	90	2700K	800	220°	4 5/16	25K	045923097072	24/6
S9704*	10A19/OMNI/LED/3K/90CRI	10	120	90	3000K	800	220°	4 5/16	25K	045923097041	24/6
S9708*	10A19/OMNI/LED/3K/90CRI/GU24	10	120	90	3000K	800	220°	4 5/16	25K	045923097089	24/6
Non-Dimmable											
S9593*	9.5A19/LED/2700K/120V	9.5	120	80	2700K	800	220°	4 5/16	15K	045923095931	24/6
S9594*	9.5A19/LED/3000K/120V	9.5	120	80	3000K	800	220°	4 5/16	15K	045923095948	24/6
S9595*	9.5A19/LED/5000K/120V	9.5	120	80	5000K	800	220°	4 5/16	15K	045923095955	24/6
120-277V											
S8914*	8.5A19/LED/27K /120-277V	8.5	120-277	80	2700K	800	220°	4 5/16	25K	045923089145	24/6
S8915*	8.5A19/LED/30K /120-277V	8.5	120-277	80	3000K	800	220°	4 5/16	25K	045923089152	24/6
S8916	8.5A19/LED/40K /120-277V	8.5	120-277	80	4000K	800	220°	4 5/16	25K	045923089169	24/6
S8920	8.5A19/LED/50K /120-277V	8.5	120-277	80	5000K	800	220°	4 5/16	25K	045923089206	24/6

** See warranty for details.

OMNI-DIRECTIONAL LED A19 LAMPS

75W replacement omni-directional LED A19 lamps

- Direct replacement for 75 Watt incandescent lamps, uses only 11-13 Watts
- Indoor residential and commercial lighting
- Damp Location
- Approved for totally enclosed fixtures**
- Dimmable and non-dimmable options
- CEC/T20 Compliant options available
- Long life—25,000 hours
- ENERGY STAR certified*
- 3 Year warranty—15,000 hours
- 5 Year warranty—25,000 hours

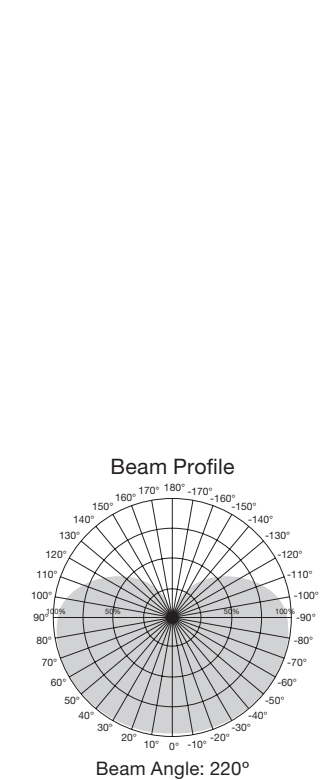

75W Replacement Omni-Directional LED A19 Lamps




Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
Dimmable											
S29810*	11A19/LED/2700K/1100L/120V/D	11	120	80	2700K	1100	220°	4 5/16	25K	045923298103	24/6
S29811*	11A19/LED/3000K/1100L/120V/D	11	120	80	3000K	1100	220°	4 5/16	25K	045923298110	24/6
S29812*	11A19/LED/4000K/1100L/120V/D	11	120	80	4000K	1100	220°	4 5/16	25K	045923298127	24/6
S29813*	11A19/LED/5000K/1100L/120V/D	11	120	80	5000K	1100	220°	4 5/16	25K	045923298134	24/6
S29814*	11A19/LED/2700K/120V/D/GU24	11	120	80	2700K	1100	220°	4 5/16	25K	045923298141	24/6
S29804*	11A19/LED/4000K/120V/D/GU24	11	120	80	4000K	1100	220°	4 5/16	25K	45923298042	24/6
90 CRI — CEC/T20 — JA8-2016											
S8650*	13A19/LED/2700K/90CRI	13	120	90	2700K	1100	220°	4 5/8	25K	045923086502	24/6
S8651*	13A19/LED/3000K/90CRI	13	120	90	3000K	1100	220°	4 5/8	25K	045923086519	24/6
Non-Dimmable											
S28765*	11.5A19/LED/27K/ND/120V	11.5	120	80	2700K	1100	220°	4 5/16	15K	045923287657	24/6
S28766*	11.5A19/LED/30K/ND/120V	11.5	120	80	3000K	1100	220°	4 5/16	15K	045923287664	24/6
S28767*	11.5A19/LED/40K/ND/120V	11.5	120	80	4000K	1100	220°	4 5/16	15K	045923287671	24/6
S28768*	11.5A19/LED/50K/ND/120V	11.5	120	80	5000K	1100	220°	4 5/16	15K	045923287688	24/6

** See warranty for details.

OMNI-DIRECTIONAL LED A19 & A21 LAMPS

100W replacement omni-directional LED A19, A21 lamps

- Direct replacement for 100 Watt incandescent lamps, uses only 15-18 Watts
- Indoor residential and commercial lighting
- Damp location
- Dimmable and non-dimmable options
- Approved for totally enclosed fixtures**
- CEC/T20 Compliant options available
- Long life—up to 25,000 hours
- ENERGY STAR certified*
- 3 Year warranty—15,000 hours
- 5 Year warranty—25,000 hours

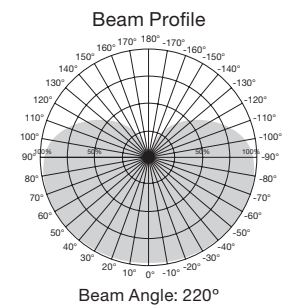

100W Replacement Omni-Directional LED A19 Lamps




Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
Dimmable											
S29815*	15A19/LED/2700K/1600L/120V/D	15	120	80	2700K	1600	220°	4 5/8	25K	045923298158	24/6
S29816*	15A19/LED/3000K/1600L/120V/D	15	120	80	3000K	1600	220°	4 5/8	25K	045923298165	24/6
S29817*	15A19/LED/4000K/1600L/120V/D	15	120	80	4000K	1600	220°	4 5/8	25K	045923298172	24/6
S29818*	15A19/LED/5000K/1600L/120V/D	15	120	80	5000K	1600	220°	4 5/8	25K	045923298189	24/6
S29819*	15A19/LED/27K/1600/120V/GU24	15	120	80	2700K	1600	220°	4 1/2	25K	045923298196	24/6
S29805*	15A19/LED/40K/1600/120V/GU24	15	120	80	4000K	1600	220°	4 1/2	25K	045923298059	24/6
90 CRI—CEC/T20—JA8-2016											
S8652*	18A21/LED/2700K/90CRI	18	120	90	2700K	1600	220°	5 5/8	25K	045923086526	24/6
S8653*	18A21/LED/3000K/90CRI	18	120	90	3000K	1600	220°	5 5/8	25K	045923086533	24/6
Non-Dimmable											
S28785*	15.5A19/LED/27K/ND/120V	15.5	120	80	2700K	1600	220°	4 5/8	15K	045923287855	24/6
S28786*	15.5A19/LED/30K/ND/120V	15.5	120	80	3000K	1600	220°	4 5/8	15K	045923287862	24/6
S28787*	15.5A19/LED/40K/ND/120V	15.5	120	80	4000K	1600	220°	4 5/8	15K	045923287879	24/6
S28788*	15.5A19/LED/50K/ND/120V	15.5	120	80	5000K	1600	220°	4 5/8	15K	045923287886	24/6

** See warranty for details.

OMNI-DIRECTIONAL 3-WAY LED LAMPS

3-way LED lamps

- Direct replacement for 30/70/100W 3-Way incandescent lamps, uses only 3/9/12W
- Indoor residential and commercial lighting
- 220° Omni-directional
- 2700K, 3000K, 4000K and 5000K options
- Damp location rated
- Approved for totally enclosed fixtures**
- ENERGY STAR certified*
- Long life—25,000 hours
- 3 Year warranty

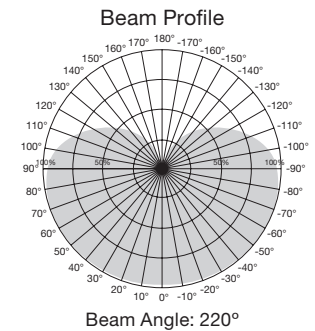

3-Way LED Lamps



Item Number	Lamp Description	W	V	CRI	CCT	Lumens	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9316*	3/9/12A19/3WAY LED/2700K/120V	3/9/12	120	80	2700K	280/950/1200	220°	4 5/8"	25K	045923093166	24/6
S9317*	3/9/12A19/3WAY LED/3000K/120V	3/9/12	120	80	3000K	280/950/1200	220°	4 5/8"	25K	045923093173	24/6
S9318	3/9/12A19/3WAY LED/4000K/120V	3/9/12	120	80	4000K	280/950/1200	220°	4 5/8"	25K	045923093180	24/6
S9319	3/9/12A19/3WAY LED/5000K/120V	3/9/12	120	80	5000K	280/950/1200	220°	4 5/8"	25K	045923093197	24/6

** See warranty for details.

LED replacements for Halogen G4, G9 and BA15S lamps

- Solid state LED lighting
- High efficacy
- Omni-directional light
- G9 Dimmable and non-dimmable
- Damp location
- Long life—15,000 hours
- 3 Year warranty



S9226, S9227,
S9228, S9229
G9



S9220,
S9221
G4



S9222,
S9223
BA15S



S9224,
S9225
G9




LED Replacements for Halogen G4, G9 and BA15S Lamps

Item Number	Lamp Description	W	V	Base	CRI	CCT	Lm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
G4 Bi-Pin											
S9220	LED/2.3W/JC/G4/3000K	2.3	12	G4	80	3000K	180	1 ¾	15K	045923092206	50/1
S9221	LED/2.3W/JC/G4/5000K	2.3	12	G4	80	5000K	180	1 ¾	15K	045923092213	50/1
BA15S											
S9222	LED/2.3W/BA15S/3000K	2.3	12	BA15S	80	3000K	180	2	15K	045923092220	50/1
S9223	LED/2.3W/BA15S/5000K	2.3	12	BA15S	80	5000K	180	2	15K	045923092237	50/1
G9											
S9226	LED/5.0W/G9/450L/3000K	5	120	G9	80	3000K	450	2 ½	15K	045923092268	20/1
S9227	LED/5.0W/G9/450L/5000K	5	120	G9	80	5000K	450	2 ½	15K	045923092275	20/1
Dimmable											
S9224*	LED/3.0W/G9/220L/3000K/DIM	3	120	G9	80	3000K	220	2 ½	15K	045923092244	50/1
S9225*	LED/3.0W/G9/220L/5000K/DIM	3	120	G9	80	5000K	220	2 ½	15K	045923092251	50/1
S9228*	LED/5.0W/G9/360L/3000K/DIM	5	120	G9	80	3000K	360	2 ½	15K	045923092282	20/1
S9229*	LED/5.0W/G9/360L/5000K/DIM	5	120	G9	80	5000K	360	2 ½	15K	045923092299	20/1

LED MR11 & MR16 LAMPS

1.6W & 3W, 12V MR11 LED lamps

- 20 Watt MR11 replacement, uses up to 3 Watts
- Indoor residential and commercial lighting
- Down lighting
- Accent lighting
- Pendant lighting
- Non-dimmable
- Damp location
- Approved for totally enclosed fixtures**
- Long life—25,000 hours
- 3 Year warranty

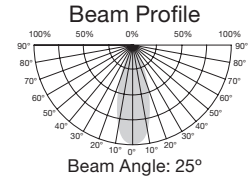

illumination	2700K	3000K	4000K	5000K
1m	700 lx in Center	730 lx in Center	760 lx in Center	800 lx in Center
2m	175 lx in Center	183 lx in Center	190 lx in Center	200 lx in Center

Beam Angle: 25°



1.6W & 3W, 12V MR11 LED Lamps With GU4 Base

Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/Hrs.	UPC	Pack
S9280	3MR11/LED/25/2700K/12V	3	12	80	2700K	210	25°	1 ½	25K	045923092800	12/1
S9281	3MR11/LED/25/3000K/12V	3	12	80	3000K	220	25°	1 ½	25K	045923092817	12/1
S9282	3MR11/LED/25/4000K/12V	3	12	80	4000K	230	25°	1 ½	25K	045923092824	12/1
S9283	3MR11/LED/25/5000K/12V	3	12	80	5000K	240	25°	1 ½	25K	045923092831	12/1

** See warranty for details.

MR16 GU10 LED lamps

- Down lighting
- Accent lighting
- Pendant lighting
- Dimmable
- Approved for totally enclosed fixtures**
- Long life—25,000 hours
- ENERGY STAR certified*
- 3 Year warranty



MR16 GU10 LED Lamps

Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/Hrs.	UPC	Pack
S9380*	4.5MR16/LED/40/30K/120V/GU10	4.5	120	80	3000K	370	40°	2 ¾	25K	045923093807	12/1
S9381	4.5MR16/LED/40/50K/120V/GU10	4.5	120	80	5000K	370	40°	2 ¾	25K	045923093814	12/1
S9382	6.5MR16/LED/40/27K/120V/GU10	6.5	120	80	2700K	500	40°	2 ¾	25K	045923093821	12/1
S9383*	6.5MR16/LED/40/30K/120V/GU10	6.5	120	80	3000K	500	40°	2 ¾	25K	045923093838	12/1
S9384	6.5MR16/LED/40/40K/120V/GU10	6.5	120	80	4000K	500	40°	2 ¾	25K	045923093845	12/1
S9385*	6.5MR16/LED/40/50K/120V/GU10	6.5	120	80	5000K	500	40°	2 ¾	25K	045923093852	12/1

** See warranty for details.

LED MR16 LAMPS

MR16 LED lamps

- Down lighting
- Accent lighting
- Pendant lighting
- Dimmable
- Approved for totally enclosed fixtures**
- Long life—25,000 hours
- ENERGY STAR certified*
- 3 Year warranty



S9490, S9491, S9492,
S9493, S9494, S9495,
S9496, S9497, S9498,
S9499, S9616



S8635, S8636, S8637,
S8638, S8639, S8640,
S8641, S8642, S8643,
S8644



S9552, S9553

MR16 LED Lamps



Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9552	LED/3MR16/40/3000K/12V/D	3	12	80	3000K	330	40°	2	25K	045923095528	20/1
S9553	LED/3MR16/40/5000K/12V/D	3	12	80	5000K	330	40°	2	25K	045923095535	20/1
S9490*	6.5MR16/LED/25/27K/12V	6.5	12	80	2700K	500	25°	1 3/4	25K	045923094903	12/1
S9491*	6.5MR16/LED/25/30K/12V	6.5	12	80	3000K	500	25°	1 3/4	25K	045923094910	12/1
S9492	6.5MR16/LED/25/35K/12V	6.5	12	80	3500K	500	25°	1 3/4	25K	045923094927	12/1
S9493	6.5MR16/LED/25/40K/12V	6.5	12	80	4000K	500	25°	1 3/4	25K	045923094934	12/1
S9494	6.5MR16/LED/25/50K/12V	6.5	12	80	5000K	500	25°	1 3/4	25K	045923094941	12/1
S9495*	6.5MR16/LED/40/27K/12V	6.5	12	80	2700K	500	40°	1 3/4	25K	045923094958	12/1
S9496*	6.5MR16/LED/40/30K/12V	6.5	12	80	3000K	500	40°	1 3/4	25K	045923094965	12/1
S9497*	6.5MR16/LED/40/35K/12V	6.5	12	80	3500K	500	40°	1 3/4	25K	045923094972	12/1
S9498*	6.5MR16/LED/40/40K/12V	6.5	12	80	4000K	500	40°	1 3/4	25K	045923094989	12/1
S9499*	6.5MR16/LED/40/50K/12V	6.5	12	80	5000K	500	40°	1 3/4	25K	045923094996	12/1
90 CRI—CEC/T20—JA8-2016											
S9616*	6.5MR16/LED/40/30K/12V/90CRI	6.5	12	90	3000K	450	40°	1 3/4	25K	045923094965	12/1
Single Optic - 75W Replacement											
S8635	8MR16/LED/15/27K/90CRI/12V	8	12	90	2700K	490	15°	1 7/8	25K	045923086359	12/1
S8636	8MR16/LED/15/30K/90CRI/12V	8	12	90	3000K	490	15°	1 7/8	25K	045923086366	12/1
S8637	8MR16/LED/15/35K/90CRI/12V	8	12	90	3500K	490	15°	1 7/8	25K	045923086373	12/1
S8638	8MR16/LED/15/40K/90CRI/12V	8	12	90	4000K	490	15°	1 7/8	25K	045923086380	12/1
S8639	8MR16/LED/15/50K/90CRI/12V	8	12	90	5000K	490	15°	1 7/8	25K	045923086397	12/1
S8640*	8MR16/LED/40/27K/90CRI/12V	8	12	90	2700K	490	40°	1 7/8	25K	045923086403	12/1
S8641*	8MR16/LED/40/30K/90CRI/12V	8	12	90	3000K	490	40°	1 7/8	25K	045923086410	12/1
S8642	8MR16/LED/40/35K/90CRI/12V	8	12	90	3500K	490	40°	1 7/8	25K	045923086427	12/1
S8643	8MR16/LED/40/40K/90CRI/12V	8	12	90	4000K	490	40°	1 7/8	25K	045923086434	12/1
S8644	8MR16/LED/40/50K/90CRI/12V	8	12	90	5000K	490	40°	1 7/8	25K	045923086441	12/1

All 12V MR16 lamps are compatible with electronic and magnetic transformers.
Visit www.satco.com for compatibility information and warranty details.

** See warranty for details.

OMNI-DIRECTIONAL A15 & DECORATIVE LED LAMPS


40W replacement omni-directional LED lamps

- Direct replacement for 40 Watt A15 incandescent lamps, uses only 5.5 Watts
- Indoor residential and commercial lighting
- Dimmable
- 2700K, 3000K, 4000K and 5000K options
- Damp location rated
- Approved for totally enclosed fixtures**
- Long life—25,000 hours
- ENERGY STAR certified*
- 3 Year warranty



E17 Base

E26 Base

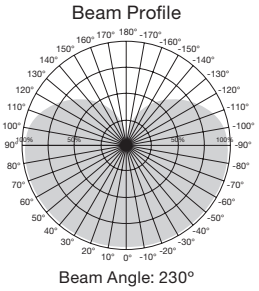

40W Replacement Omni-Directional LED Lamps

Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S9030*	5.5A15/LED/2700K/120V	5.5	120	80	2700K	450	230°	3 7/16	25K	045923090301	24/6
S9031*	5.5A15/LED/3000K/120V	5.5	120	80	3000K	450	230°	3 7/16	25K	045923090318	24/6
S9032	5.5A15/LED/4000K/120V	5.5	120	80	4000K	450	230°	3 7/16	25K	045923090325	24/6
S9033	5.5A15/LED/5000K/120V	5.5	120	80	5000K	450	230°	3 7/16	25K	045923090332	24/6
S9064	5.5A15/LED/2700K/E17/120V	5.5	120	80	2700K	450	230°	3 7/16	25K	045923090646	24/6
S9065	5.5A15/LED/3000K/E17/120V	5.5	120	80	3000K	450	230°	3 1/2	25K	045923090653	24/6
S9067	5.5A15/LED/4000K/E17/120V	5.5	120	80	4000K	450	230°	3 1/2	25K	045923090677	24/6
S9068	5.5A15/LED/5000K/E17/120V	5.5	120	80	5000K	450	230°	3 1/2	25K	045923090684	24/6

** See warranty for details.

Decorative LED lamps

- 25W candle replacement uses only 2.8 Watts
- 40W candle replacement uses only 4.5 Watts
- Accent lighting • Pendant lighting
- Dimmable • Damp location
- Approved for totally enclosed fixtures**
- Long life—25,000 hours
- ENERGY STAR certified*
- 3 Year warranty




S8951, S8952, S8950, S9618


S8953

S9200, S9201, S9202, S9203, S9619

Candle Beam Profile

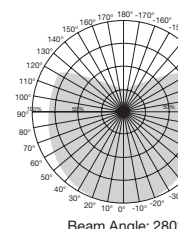

Globe Beam Profile

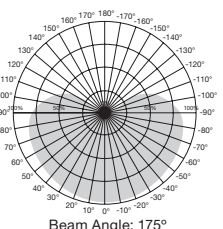

Decorative LED Lamps

Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S8950	2.8CTC/LED/3000K/E12/120V	2.8	120	80	3000K	165	280°	3 3/4	25K	045923089503	12/1
S8951*	4.5CTC/LED/2700K/E12/120V	4.5	120	80	2700K	300	280°	3 3/4	25K	045923089510	12/1
S8952*	4.5CTC/LED/3000K/E12/120V	4.5	120	80	3000K	300	280°	3 3/4	25K	045923089527	12/1
S8953*	4.5ETC/LED/3000K/E26/120V	4.5	120	80	3000K	300	280°	3 3/4	25K	045923089534	12/1

90 CRI — CEC/T20 — JA8-2016

S9618*	5CTC/LED/2700K/E12/120V	5	120	90	2700K	325	280°	3 3/4	25K	045923096181	12/1
--------	-------------------------	---	-----	----	-------	-----	------	-------	-----	--------------	------

** See warranty for details.

S9200*	6G25/LED/2700K/E26	6	120	80	2700K	450	175°	4 1/4	25K	045923090523	24/6
S9201*	6G25/LED/3000K/E26	6	120	80	3000K	450	175°	4 1/4	25K	045923090530	24/6
S9202	6G25/LED/4000K/E26	6	120	80	4000K	450	175°	4 1/4	25K	045923090691	24/6
S9203	6G25/LED/5000K/E26	6	120	80	5000K	450	175°	4 1/4	25K	045923092039	24/6

90 CRI

S9619*	6G25/LED/2700K/90/E26	6	120	90	2700K	390	175°	4 1/4	25K	045923096198	24/6
--------	-----------------------	---	-----	----	-------	-----	------	-------	-----	--------------	------

LED/CFL direct replacement lamps

4-pin (electronic ballasts) 2-pin (magnetic ballasts)

- 4-pin 26, 32, 42 Watt direct replacement
- 2-pin 26 Watt direct replacement
- 4-pin lamps fit G24q-3 & GX24q-3 and GX24q-4 sockets 2-pin lamps fit G24d-3 & GX24d-3 sockets
- No re-wiring needed
- Instant on to full brightness / no flickering
- Vertical and horizontal options
- Up to 70% energy saving
- DLC listed*
- c-UL-us Classified
- Long life—50,000 hours
- 5 Year warranty




S29858, S29859,
S29860, S29861
G24Q




S9862, S9863,
S9864, S9865
G24D

Rotates 270°
when installed

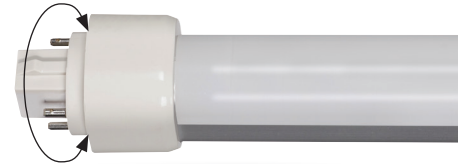

S29850, S29851, S29852, S29853
G24Q

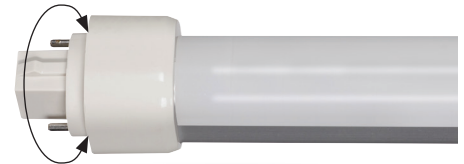

S9854, S9855, S9856, S9857
G24D

LED/CFL Replacement Lamps



Item Number	Lamp Description	W	Base Type	CCT	CRI	M.O.L. (Inches)	Lm	Life/Hrs.	UPC	Pack/Master
4-Pin Horizontal										
S29850*	9WPLH/LED/830/DR/4P	9	G24Q	3000K	82	6 5/8	850	50K	045923298509	50/10
S29851*	9WPLH/LED/835/DR/4P	9	G24Q	3500K	82	6 5/8	850	50K	045923298516	50/10
S29852*	9WPLH/LED/840/DR/4P	9	G24Q	4000K	82	6 5/8	900	50K	045923098529	50/10
S29853*	9WPLH/LED/850/DR/4P	9	G24Q	5000K	82	6 5/8	900	50K	045923298530	50/10
2-Pin Horizontal										
S9854	9WPLH/LED/830/DR/2P	9	G24D	3000K	82	6 5/8	850	50K	045923098543	50/10
S9855	9WPLH/LED/835/DR/2P	9	G24D	3500K	82	6 5/8	850	50K	045923098550	50/10
S9856	9WPLH/LED/840/DR/2P	9	G24D	4000K	82	6 5/8	900	50K	045923098567	50/10
S9857	9WPLH/LED/850/DR/2P	9	G24D	5000K	82	6 5/8	900	50K	045923098574	50/10
4-Pin Vertical										
S29858*	9WPLV/LED/830/DR/4P	9	G24Q	3000K	82	4 11/16	850	50K	045923298585	50/10
S29859*	9WPLV/LED/835/DR/4P	9	G24Q	3500K	82	4 11/16	850	50K	045923298592	50/10
S29860*	9WPLV/LED/840/DR/4P	9	G24Q	4000K	82	4 11/16	900	50K	045923298608	50/10
S29861*	9WPLV/LED/850/DR/4P	9	G24Q	5000K	82	4 11/16	900	50K	045923298615	50/10
2-Pin Vertical										
S9862	9WPLV/LED/830/DR/2P	9	G24D	3000K	82	4 11/16	850	50K	045923098628	50/10
S9863	9WPLV/LED/835/DR/2P	9	G24D	3500K	82	4 11/16	850	50K	045923098635	50/10
S9864	9WPLV/LED/840/DR/2P	9	G24D	4000K	82	4 11/16	900	50K	045923098642	50/10
S9865	9WPLV/LED/850/DR/2P	9	G24D	5000K	82	4 11/16	900	50K	045923098659	50/10

CFL LAMPS

13/15/18/20/23/26 Watt T2 ultra mini spirals

- Long life—10,000 hours
- All lamps offered in 2700K
- 13W standard lamps offered in 2700K, 3500K and 4100K
- Four color retail packaging
- c-UL-us listed



S7217

S7341

13/15/18/20/23/26 Watt T2 Ultra Mini Spirals



Item Number	Lamp Description	W	V	CRI	CCT	Lm	Base	M.O.L. (Inches)	Life/ Hrs.	UPC	Pack
S7217*	13T2/E26/2700K/120V/1PK	13	120	82	2700K	900	E26	4 1/8	12K	045923072178	12/1
S7218*	13T2/E26/4100K/120V/1PK	13	120	82	4100K	880	E26	4 1/8	12K	045923072185	12/1
S7219*	13T2/E26/5000K/120V/1PK	13	120	82	5000K	880	E26	4 1/8	12K	045923072192	12/1
S7221	15T2/E26/2700K/120V/1PK	15	120	82	2700K	1100	E26	4 3/8	12K	045923072215	12/1
S7222	15T2/E26/4100K/120V/1PK	15	120	82	4100K	1100	E26	4 3/8	10K	045923072222	12/1
S7223	15T2/E26/5000K/120V/1PK	15	120	82	5000K	1100	E26	4 3/8	10K	045923072239	12/1
S7224*	18T2/E26/2700K/120V/1PK	18	120	82	2700K	1200	E26	4 17/32	12K	045923072246	12/1
S7225	18T2/E26/4100K/120V/1PK	18	120	82	4100K	1200	E26	4 17/32	10K	045923072253	12/1
S7226	18T2/E26/5000K/120V/1PK	18	120	82	5000K	1200	E26	4 17/32	10K	045923072260	12/1
S7234	20T2/E26/2700K/120V/1PK	20	120	82	2700K	1330	E26	4 13/32	12K	045923072345	12/1
S7235	20T2/E26/4100K/120V/1PK	20	120	82	4100K	1300	E26	4 13/32	10K	045923072352	12/1
S7236	20T2/E26/5000K/120V/1PK	20	120	82	5000K	1300	E26	4 13/32	10K	045923072369	12/1
S7227*	23T2/E26/2700K/120V/1PK	23	120	82	2700K	1600	E26	4 7/8	12K	045923072277	12/1
S7228*	23T2/E26/4100K/120V/1PK	23	120	82	4100K	1600	E26	4 7/8	12K	045923072284	12/1
S7229*	23T2/E26/5000K/120V/1PK	23	120	82	5000K	1600	E26	4 7/8	12K	045923072291	12/1
S7231	26T2/E26/2700K/120V/1PK	26	120	82	2700K	1750	E26	5 1/16	12K	045923072314	12/1
S7232	26T2/E26/4100K/120V/1PK	26	120	82	4100K	1750	E26	5 1/16	10K	045923072321	12/1
S7233	26T2/E26/5000K/120V/1PK	26	120	82	5000K	1750	E26	5 1/16	10K	045923072338	12/1
Photocell & 3-Way CFL Spirals - E26 Medium Base											
S7341	12/20/26T4/E26/2700K/120V/1PK	12/20/26	120	82	2700K	1600	E26	6 5/16	10K	045923073410	12/1
S7342	12/20/26T4/E26/4100K/120V/1PK	12/20/26	120	82	4100K	N/A	E26	6 5/16	10K	045923073427	12/1
S7343	12/20/26T4/E26/5000K/120V/1PK	12/20/26	120	82	5000K	N/A	E26	6 5/16	10K	045923073434	12/1

CFL LAMPS

9/11/13/15/18/23/26 Watt CFL GU24 base

- Long life—10,000 hours
- All lamps offered in 2700K
- 13W standard lamps offered in 2700K, 3500K and 4100K
- Four color retail packaging
- c-UL-us listed



S8201



S8227

9/11/13/15/18/23/26 Watt CFL GU24 Base




Item Number	Lamp Description	W	V	CRI	CCT	Lm	Base	M.O.L. (Inches)	Life/ Hrs.		Pack
S8201	9T2/GU24/2700K/120V/1PK	9	120	82	2700K	500	GU24	3 15/32	10K	045923082016	12/1
S8202	11T2/GU24/2700K/120V/1PK	11	120	82	2700K	650	GU24	3 15/32	10K	045923082023	12/1
S8203*	13T2/GU24/2700K/120V/1PK	13	120	82	2700K	800	GU24	3 5/8	10K	045923082030	12/1
S8226	13T2/GU24/3500K/120V/1PK	13	120	82	3500K	900	GU24	3 5/8	10K	045923082269	12/1
S8208	13T2/GU24/4100K/120V/1PK	13	120	82	4100K	880	GU24	3 5/8	10K	045923082085	12/1
S8204	15T2/GU24/2700K/120V/1PK	15	120	82	5000K	1100	GU24	4 3/8	10K	045923082047	12/1
S8205	18T2/GU24/2700K/120V/1PK	18	120	82	2700K	1200	GU24	4 15/32	10K	045923082054	12/1
S8206*	23T2/GU24/2700K/120V/1PK	23	120	82	2700K	1600	GU24	4 7/16	10K	045923082061	12/1
S8207	26T3/GU24/2700K/120V/1PK	26	120	82	2700K	1750	GU24	5 3/32	10K	045923082078	12/1

13 & 18 Watt CFL GU24 Base Squat Spiral

S8227	13T2/SQUAT/GU24/2700K/120V/1PK	13	120	82	2700K	850	GU24	2 5/32	10K	045923082276	12/1
S8228	18T2/SQUAT/GU24/2700K/120V/1PK	18	120	82	2700K	1100	GU24	2 13/16	10K	045923082283	12/1

 QUAD TUBE CFL LAMPS



S8329



S8333




S8337

Quad Tube 4-Pin For Electronic & Dimming Ballasts

W	Bub	Base	Satco Product Number	Lamp Code	CCT	CRI	Mstr.	Pkg Type	Life/ Hrs.	Lm	M.O.L. (Inches)	UPC	Notes
13	T4	G24q-1	S8329	CFD13W/4P/827	2700K	82	50	Hang Box	12K	900	5 3/16	045923083297	2
			S6729	CF13DD/E/827	2700K	82	50	Box	12K	900	5 3/16	046135206825	2
			S8330	CFD13W/4P/830	3000K	82	50	Hang Box	12K	900	5 3/16	045923083303	2
			S6730	CF13DD/E/830	3000K	82	50	Box	12K	900	5 3/16	046135207211	2
			S8332	CFD13W/4P/835	3500K	82	50	Hang Box	12K	900	5 3/16	045923083327	2
			S6731	CF13DD/E/835	3500K	82	50	Box	12K	900	5 3/16	046135206719	2
			S8332	CFD13W/4P/841	4100K	82	50	Hang Box	12K	900	5 3/16	045923083327	2
			S6732	CF13DD/E/841	4100K	82	50	Box	12K	900	5 3/16	046135206672	2
18	T4	G24q-2	S8333	CFD18W/4P/827	2700K	82	50	Hang Box	12K	1250	5 13/16	045923083334	2
			S6733	CF18DD/E/827	2700K	82	50	Box	12K	1250	5 13/16	046135206832	2
			S8334	CFD18W/4P/830	3000K	82	50	Hang Box	12K	1250	5 13/16	045923083341	2
			S6734	CF18DD/E/830	3000K	82	50	Box	12K	1250	5 13/16	046135207242	2
			S8335	CFD18W/4P/835	3500K	82	50	Hang Box	12K	1250	5 13/16	045923083358	2
			S6735	CF18DD/E/835	3500K	82	50	Box	12K	1250	5 13/16	046135206726	2
			S8336	CFD18W/4P/841	4100K	82	50	Hang Box	12K	1250	5 13/16	045923083365	2
			S6736	CF18DD/E/841	4100K	82	50	Box	12K	1250	5 13/16	046135206689	2
26	T4	G24q-3	S8337	CFD26W/4P/827	2700K	82	50	Hang Box	12K	1825	6 1/2	045923083372	2
			S6737	CF26DD/E/827	2700K	82	50	Box	12K	1825	6 1/2	046135206849	2
			S8338	CFD26W/4P/830	3000K	82	50	Hang Box	12K	1825	6 1/2	045923083389	2
			S6738	CF26DD/E/830	3000K	82	50	Box	12K	1825	6 1/2	046135207228	2
			S8339	CFD26/4P/835	3500K	82	50	Hang Box	12K	1825	6 1/2	045923083396	2
			S6739	CF26DD/E/835	3500K	82	50	Box	12K	1825	6 1/2	046135206733	2
			S8340	CFD26W/4P/841	4100K	82	50	Hang Box	12K	1825	6 1/2	045923083402	2
			S6740	CF26DD/E/841	4100K	82	50	Box	12K	1825	6 1/2	046135206696	2

TRIPLE TUBE CFL LAMPS

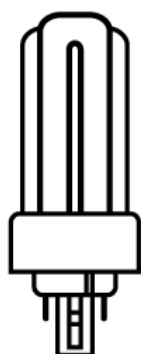

S8329



S8333



S8337

Triple Tube 4-Pin For Electronic & Dimming Ballasts

W	Bub	Base	Satco Product Number	Lamp Code	CCT	CRI	Mstr.	Pkg Type	Life/ Hrs.	Lm	M.O.L. (Inches)	UPC	Notes
13	T4	GX24q-1	S4369	CF13DT/E/827	2700K	82	50	Box	12K	900	4 3/16	046135208911	2
			S8396	CFT13W/4P/830	3000K	82	50	Hang Box	12K	900	4 3/16	045923083969	2
			S4730	CF13DT/3/830	3000K	82	50	Box	12K	900	4 3/16		2
			S8397	CFT13W/4P/835	3500K	82	50	Hang Box	12K	900	4 3/16	045923083976	2
			S4371	CF13DT/E/835	3500K	82	50	Box	12K	900	4 3/16		2
			S8398	CFT13W/4P/841	4100K	82	50	Hang Box	12K	900	4 3/16	045923083983	2
			S4372	CF13DT/E/841	4100K	82	50	Box	12K	900	4 3/16	046135208942	2
18	T4	GX24q-2	S6741	CF18DT/E/IN/827	2700K	82	50	Box	12K	1200	4 3/8	046135208751	2
			S8342	CFT18W/4P/830	3000K	82	50	Hang Box	12K	1200	4 3/8	045923083426	2
			S6742	CF18DT/E/IN/830	3000K	82	50	Box	12K	1200	4 3/8	046135208768	2
			S8343	CFT18W/4P/835	3500K	82	50	Hang Box	12K	1200	4 3/8	045923083433	2
			S6743	CF18DT/E/IN/835	3500K	82	50	Box	12K	1200	4 3/8	046135208775	2
			S8344	CFT18W/4P/841	4100K	82	50	Hang Box	12K	1200	4 3/8	045923083440	2
			S6744	CF18DT/E/IN/841	4100K	82	50	Box	12K	1200	4 3/8	046135208782	2
26	T4	GX24q-3	S6745	CF26DT/E/IN/827	2700K	82	50	Box	12K	1800	5	046135208799	2
			S8346	CFT26W/4P/830	3000K	82	50	Hang Box	12K	1800	5	045923083464	2
			S6746	CF26DT/E/IN/830	3000K	82	50	Box	12K	1800	5	046135208805	2
			S8347	CFT26W/4P/835	3500K	82	50	Hang Box	12K	1800	5	045923083471	2
			S6747	CF26DT/E/IN/835	3500K	82	50	Box	12K	1800	5	046135208812	2
			S8348	CFT26W/4P/841	4100K	82	50	Hang Box	12K	1800	5	045923083488	2
			S6748	CF26DT/E/IN/841	4100K	82	50	Box	12K	1800	5	046135208829	2



RENAISSANCE
LIGHTING AND METAL FURNITURE FOR HOSPITALITY

SATCO®

Copyright © 2018
Satco Products, Inc.
All Rights Reserved.
7/18 SA1963-2

Renaissance Contract Lighting & Furnishings, Inc.

2807 Mary Linda Avenue, N.E., Roanoke, VA 24012

Phone (540) 342-1548 Fax (540) 342-1417

www.RCLFinc.com