


Hi-Pro LED A21 lamps

High lumen, A21 lamps for industrial and commercial applications

Applications / Features

- For use in bollard and post top lighting
- High ceiling recessed lighting
- Replaces high lumen incandescent and CFL lamps
- Dimmable, 120V only*
- Saves over 80% on energy costs
- Advanced heat dissipation design
- Direct wire range voltage 120-277V options
- High efficiency—up to 150 LPW
- 2700 and 5000K options
- Base up, base down or horizontal operation
- Long life—25,000 hours
- 5 Year limited warranty

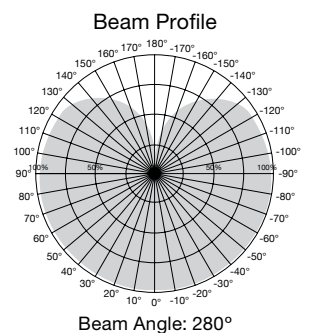

High Lumen A21 Industrial/Commercial LED Lamps



Item Number	Lamp Description	W	V	CRI	CCT	Lm	Bm	M.O.L. (Inches)	Life/Hrs.	UPC	Pack/Mstr.
S8735*	20WA21/LED/HID/2700K/120V/DIM/E26	20	120	80+	2700K	2900	280°	5	25K	045923087356	24/6
S8736*	20WA21/LED/HID/5000K/120V/DIM/E26	20	120	80+	5000K	3000	280°	5	25K	045923087363	24/6
S8737	20WA21/LED/HID/2700K/120-277V/E26	20	120-277	80+	2700K	2900	280°	5	25K	045923087370	24/6
S8738	20WA21/LED/HID/5000K/120-277V/E26	20	120-277	80+	5000K	3000	280°	5	25K	045923087387	24/6
Accessories											
92-406	Mog to Med Socket Reducer for S9750									045923924064	
80-929	Hard Wire Surge Protector									045923809293	