


BURNDY UNITAP™

A-46

CLEAR INSULATED MULTIPLE TAP CONNECTORS

Tap connections and in-line splice/reductions are made quickly and easily with the UNITAP™ line of connectors. UL486B Listed. Dual-rated AL9CU for any stranded copper or stranded aluminum applications. 600 Volt, 90° C.

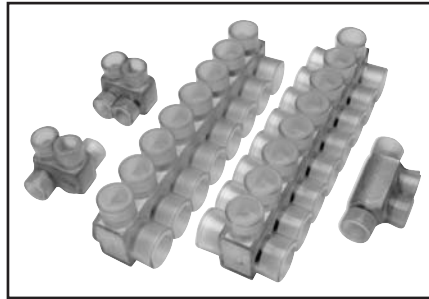

Features and Benefits

- Clear Plastisol covered AL6061-T6 aluminum body.
 - ◊ Saves time, lowers installation costs, eliminates taping.
- Clear Plastisol.
 - ◊ Allows visual confirmation that conductor is properly inserted.
- Oxide inhibitor pre-installed.
 - ◊ Inhibits moisture and contaminants from entering the contact area.
- Range-taking.
 - ◊ Reduces number of connectors carried in inventory.

2 PORT 1 or 2 Sided Entry

Catalog Number	# of Ports	Wire Range (AWG/kcmil)	L	W	H	Hex Key	Fig. No.
BIT4	2	#14 - #4	1.16	1.16	1.25	1/8	1
BITO4	2	#14 - #4	1.16	1.50	1.25	1/8	2
BIT2/0	2	#14 - 2/0	1.52	1.40	1.38	3/16	1
BITO2/0	2	#14 - 2/0	1.52	1.56	1.38	3/16	2
BIT250	2	#10 - 250	2.03	2.07	2.13	5/16	1
BITO250	2	#10 - 250	2.03	2.64	2.13	5/16	2
BIT350	2	#10 - 350	2.22	2.32	2.50	5/16	1
BITO350	2	#10 - 350	2.22	3.00	2.50	5/16	2
BIT600	2	#4 - 600	2.72	2.38	2.75	3/8	1
BITO600	2	#4 - 600	2.72	3.00	2.75	3/8	2
BIT750*	2	#2 - 750	2.87	2.70	3.00	3/8	1
BITO750*	2	#2 - 750	2.87	3.38	3.00	3/8	2

* Not UL Listed

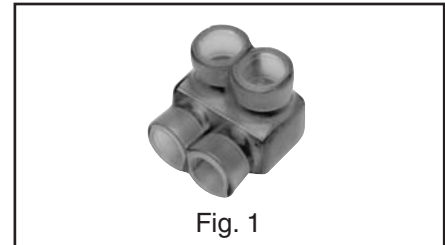


Fig. 1

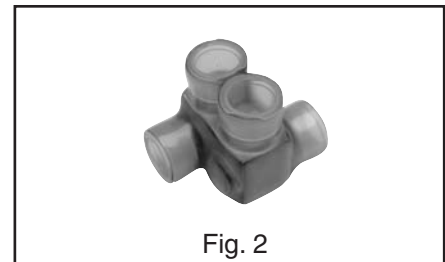


Fig. 2

IN-LINE SPLICER/REDUCER

Catalog Number	Wire Range (AWG/kcmil)	L	W	H	Hex Key
BISR2	#14 - 2	2.38	0.75	1.22	5/32
BISR1/0	#14 - 1/0	2.91	0.91	1.38	3/16
BISR250	#10 - 250	4.01	1.19	2.10	5/16
BISR350	#10 - 350	4.63	1.34	2.35	5/16
BISR500	#6 - 500	5.00	1.62	2.62	3/8

