
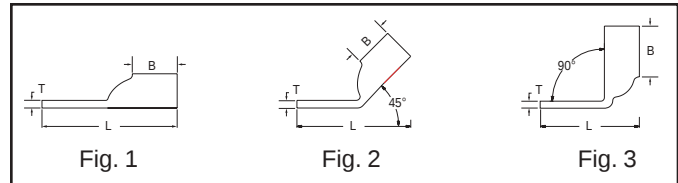


ONE HOLE HYLUG™ CODE CONDUCTOR STANDARD BARREL (Continued)

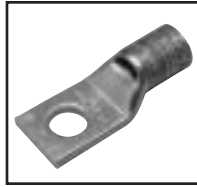

C-12

Catalog Number	Fig #	Conductor		Stud Hole Size	Tongue Width	Figure Dimensions		▲ Installation Tooling							Wire Strip Length
		AWG	*** MM²			(B)	(T)	(L)	Dieless (# of crimps)	Mechanical	Hydraulic		Color Code	Die Index	
										MD6, OUR840, MD7-34R	BCT500HS, Y500CTHS	Y35, Y39, Y750, Y46*, BAT750			
YA31L11	1	350 kcmil	185	3/8"	1.29"	1.06"	.18"	2.50"	Y644M (1)	W31VT (2)	W31VT (2) W31RT (2)	U31RT (2) U29ART (2)	Red	18	1-3/16"
YA31L11-45	2							2.42"							
YA31L11-90	3							1.40"							
YA31L36	1			7/8"	1.29"	1.06"	.18"	4.02"							
YA31L36-45	2							4.02"							
YA31L36-90	3							3.94"							
YA31L7	1			5/8"	1.29"	1.06"	.18"	3.00"							
YA31L7-45	2							3.00"							
YA31L7-90	3							1.90"							
YA31LNT38				3/8"	96"	1.06"	.18"	3.37"							
YA32L	1	400 kcmil		5/8"	1.38"	1.19"	.19"	3.18"		W32VT (2)	W32VT (2) W32RT (2)	U32RT (2) U30ART (2)	Blue	19	1-1/4"
YA32L-45	2							3.08"							
YA32L-90	3							1.95"							
YA32L1	1			1/2"	1.40"	1.19"	.19"	2.93"							
YA32L1-45	2							2.83"							
YA32L1-90	3							1.70"							
YA32L14	1			3/8"	1.38"	1.19"	.19"	2.68"							
YA32L14-45	2							2.58"							
YA32L14-90	3							1.45"							
YA32LTC78	1			7/8"	1.40"	1.19"	.19"	3.62"							
YA32LTC78-45	2							3.52"							
YA32LTC78-90	3							2.38"							
YA33L	1	450 kcmil		5/8"	1.48"	1.50"	.21"	3.57"		W33VT (2)	W33VT (2) W33RT (2)	U33RT (2)	Gray	326	1-9/16"
YA33L-45	2							3.30"							
YA33L-90	3							2.00"							
YA34L	1	500 kcmil	240	5/8"	1.55"	1.27"	.23"	3.37"		W34VT (2)	W34VT (2) W34RT (2)	U34RT (2) U31ART (2)	Brown	20	1-7/16"
YA34L-45	2							3.30"							
YA34L-90	3							2.03"							
YA34L20	1			1"	1.55"	1.27"	.23"	4.05"							
YA34L20-45	2							3.99"							
YA34L20-90	3							2.72"							
YA34L37	1			3/8"	1.55"	1.27"	.23"	2.87"							
YA34L37-45	2							2.80"							
YA34L37-90	3							1.53"							
YA34L6	1			1/2"	1.55"	1.27"	.23"	3.12"							
YA34L6-45	2							3.05"							
YA34L6-90	3							1.78"							
YA34L8	1			3/4"	1.55"	1.27"	.23"	3.55"							
YA34L8-45	2							3.49"							
YA34L8-90	3							2.22"							
YA34L9	1			7/8"	1.55"	1.27"	.23"	3.80"							
YA34L9-45	2							3.74"							
YA34L9-90	3							2.47"							
YA35L	1	550 kcmil		5/8"	1.65"	1.69"	.25"	3.81"		-	-	U35RT (2)	Yellow	21	1-3/4"
YA35L-45	2							3.67"							
YA35L-90	3							2.08"							
YA36L11	1	600 kcmil	300	1/2"	1.74"	1.38"	.27"	3.29"		-	-	U36RT (2)	Green	22	1-3/4"
YA36L	1			5/8"	1.74"	1.38"	.27"	3.72"							
YA36L-45	2							3.51"							
YA36L-90	3							2.11"							

* Use PUADP-1 adapter with "U" dies in Y46 HYPRESS™.
** P-RT die sets for use in Y46 HYPRESS™ only, PUADP-1 adapter not required.

*** The MM² conductor sizes listed are the recommendations for Class 2 conductor.
▲ See tooling section of this catalog for complete tool and die listings.

◆ For applications greater than 2000 Volts, consult cable manufacturer for voltage stress relief instructions.