

4" SQUARE (4S) BOXES & EXTENSION RINGS

WELDED

1-1/2" DEEP

21.0 Cu. In.

WITH RAISED GROUND EMBOSS (EXCEPT FOR BRACKETED AND EXTENSION BOXES)

METAL STUD BRACKET FEATURES

- ▶ U.S. Patent No.: 8,262,043
- ▶ Metal Stud (MS) Bracket engages on either side of metal stud
- **Model Revised Feb. 2008


BOXES WITH PIGTAIL FEATURES

7" Solid Cu. #12AWG Pigtail
Pre-assembled with Ground Emboss and 10-32 Ground Screw


NOTE

- ▶ *Available in Durable Red Powder Coat Finish (Pg. A24)
- ▶ **600V** MKO's and CKO's suitable for bonding without any additional bonding means up to 600V
- ▶ Acceptable for use in 2-hour rated walls
- ▶ Visit www.ul.com or QCIT Guide on page W1 for more information


Cat. No.	Bracket & Setback	Knockouts		Std. Pkg.
		Sides	Bottom	
4SB-50	-	12 - 1/2"	4 - 1/2"	50
4SB-50/75	-	8 - 1/2", 4 - 3/4"	2 - 1/2", 2 - 3/4"	50
*4SB-50/75-PT	-	8 - 1/2", 4 - 3/4"	2 - 1/2", 2 - 3/4"	50
4SB-75	-	8 - 3/4"	2 - 1/2", 2 - MKO	50
*4SB-MKO	-	8 - 1/2", 4 - MKO	2 - 1/2", 2 - MKO	50
4SB-MKO-PT	-	8 - 1/2", 4 - MKO	2 - 1/2", 2 - MKO	50
4SB-50-FB	FB, Flush	9 - 1/2"	5 - 1/2"	24
4SB-50/75-FB	FB, Flush	6 - 1/2", 3 - 3/4"	3 - 1/2", 2 - 3/4"	24
4SB-75-FB	FB, Flush	6 - 3/4"	1 - 1/2", 4 - 3/4"	24
4SB-MKO-FB	FB, Flush	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
*4SB-50/75-MS**	MS, Self-Gripping + Box Support Clip	6 - 1/2", 3 - 3/4"	3 - 1/2", 2 - 3/4"	24
4SB-MKO-MS**	MS, Self-Gripping + Box Support Clip	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
4SB-MKO-OB	OB, 1-5/16"	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
4SB-MKO-B	B, Flush	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
4SB-MKO-AB	AB, Flush	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
4SB-MKO-WB	WB, Flush	6 - 1/2", 3 - MKO	3 - 1/2", 2 - MKO	24
4SB-50-EXT	-	12 - 1/2"	-	50
4SB-50/75-EXT	-	8 - 1/2", 4 - 3/4"	-	50
*4SB-MKO-EXT	-	8 - 1/2", 4 - MKO	-	50
4SB-MKO-EHB	Extension Ring to Handy Box	8 - 1/2", 4 - MKO	-	50

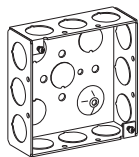


4SB-50

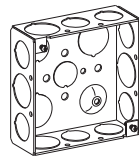


4SB-50/75

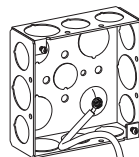


*4SB-50/75-PT

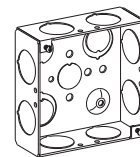


4SB-75

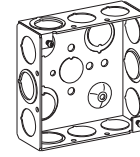


*4SB-MKO

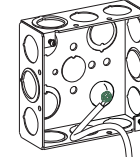


4SB-MKO-PT

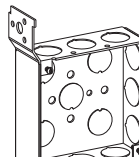


4SB-50-FB

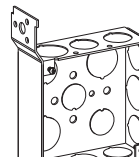


4SB-50/75-FB

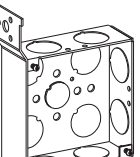


4SB-75-FB

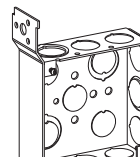


4SB-MKO-FB

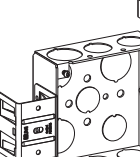


*4SB-50/75-MS**

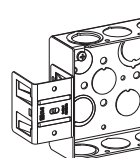


4SB-MKO-MS**

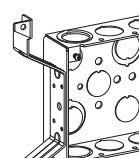


4SB-MKO-OB

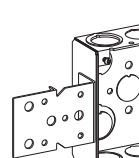


4SB-MKO-B

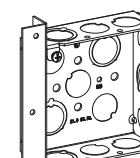


4SB-MKO-AB

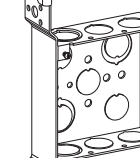


4SB-MKO-WB

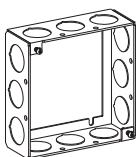


4SB-50-EXT

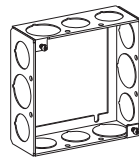

4SB-50/75-EXT

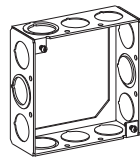

*4SB-MKO-EXT

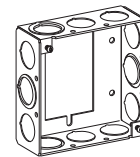

4SB-MKO-EHB