

CFL Ceiling Lampholder Solutions



Feature Driven to Meet Every Need

Leviton's line of Compact Fluorescent Ceiling Lampholders offers the ideal lighting source for closets and closed spaces. For energy-efficiency, fluorescent lighting is a smart alternative to incandescent fixtures. Our Fluorescent Ceiling Lampholders incorporate today's most desirable features and meet NFPA[®] 70, NEC[®] Section 410.16 requirements. Designed to reduce the risk of fire in closets, they can also be utilized in open spaces – a cost-saving solution for all areas of the home. Because needs vary, our Compact Fluorescent Ceiling Lampholders are available in three styles - Keyless, Pull Chain and Occupancy Sensor. Pigtail leads provide easy installation and multiple mounting holes are provided for multiple box configurations.

Applications

- Install in closets, garages, basements, storage rooms, utility rooms, workrooms and attics
- For indoor use only

Note: Not intended for use with Incandescent lamps, dimmers, occupancy sensors or lighted devices.



Features and Benefits

- 13W GU24 Squat Base Lamp
- Built of tough thermoplastic
- Pigtail leads provide easy installation
- Knockout holes on box enable multiple configurations
- Easy twist on/off lamp guard
- Backed by a Limited Two-Year Warranty on Lampholder and Guard

Keyless Lampholder – ON/OFF with Wall Switch

- Keyless Bi-Pin Compact Fluorescent Lampholder
- Wall switch turns lampholder ON/OFF

Pull Chain Lampholder – ON/OFF with Pull Chain



- Pull chain Bi-Pin Compact Fluorescent Lampholder
- Pull chain turns lampholder ON/OFF with no wall switch required

Occupancy Sensor Lampholder – ON/OFF automatically

- Occupancy Sensor Bi-Pin Compact Fluorescent Lampholder
- Light turns ON automatically when motion is detected and OFF after 3 minutes of inactivity
- 284° Field of View
- Green LED indicator light blinks when motion is detected
- Remote functionality with Vizia + Remote Switch (VPoSR-10)
- Ceiling mount only

Field of View:

Occupancy Sensor Lampholder (9863): Ceiling Mount Only

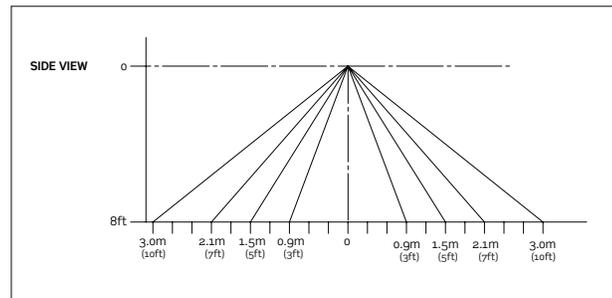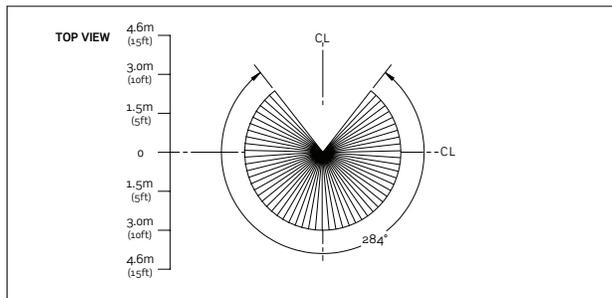

Agency Standards

- ENERGY STAR Qualified
- cULus Listed
- Meets NFPA 70, NEC Section 410.16 requirements
- Can be used in closets and open spaces
- Meets Canadian Electric Code requirements for use in closets with lamp guard

Ratings:

120W-250VAC, 60 Hz (Keyless and pull chain versions)
13W-120VAC, 60 Hz (Occupancy sensor version)

Specifications:

Lamp Output = 900 lumens
Lamp Color = 2700 K
Average Lamp Life = 10,000 hours**
Note: Supply conductors must have minimum 90°C rating

Fluorescent Ceiling Lampholder for use with Wall Switch

Cat. No.	Description	UPC Number	Standard Pack
001-9860-000*	Lampholder	07847731538 5	1/Box, 50/Carton
002-9860-00B	Lampholder with 13W Lamp	07847731539 2	1/Box, 50/Carton
006-9860-LHG	Lampholder with 13W Lamp and Lamp Guard	07847739388 8	1/Box, 36/Carton
C22-9860-0BL	Lampholder with 13W Lamp and Lamp Guard	07847736060 6	1/Clamshell, 3/Box, 18/Carton
004-9860-00L*	Lamp Guard	07847731555 2	1/Box, 50/Carton
000-9865-13W	13W Replacement Bulb	07847731546 0	1/Box, 20/Carton

Fluorescent Ceiling Lampholder with Pull Chain

Cat. No.	Description	UPC Number	Standard Pack
001-9862-PCH	Lampholder with 13W Lamp and Lamp Guard	07847745420 6	1/Box, 18/Carton
C20-9862-0PC	Lampholder with 13W Lamp and Lamp Guard	07847745524 1	1/Clamshell, 3/Box, 18/Carton

Fluorescent Ceiling Lampholder with Occupancy Sensor

Cat. No.	Description	UPC Number	Standard Pack
001-9863-OCC	Lampholder with 13W Lamp and Lamp Guard	07847750940 1	1/Box, 18/Carton
C20-9863-SEN	Lampholder with 13W Lamp and Lamp Guard	07847750941 8	1/Clamshell, 3/Box, 18/Carton

*Not Energy Star qualified

**Average rated bulb life based on 3 hour operating cycles. Rated bulb life will be lower for continuous (24/7) applications.

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747-3138
Telephone: 1-800-323-8920 FAX: 1-800-832-9538
Tech Line (8:30AM-7:00PM E.T. Monday-Friday): 1-800-824-3005

Visit our Website at: www.leviton.com
© 2012 Leviton Manufacturing Co., Inc. All rights reserved.



G-8683/B12-dp