

Wiha SoftGrip Pliers & Cutters

Wiha Pliers & Cutters, professional quality at competitive prices. A wide selection covering most applications in which pliers & cutters are required.



64HRC
Cutting
Edges


Precision formed

Heavy duty steel
riveted joints

Soft grips are
oil & solvent
resistant

Jaws and
cutters induction
hardened

High frequency induction hardened
body from C70 tool steel forgings

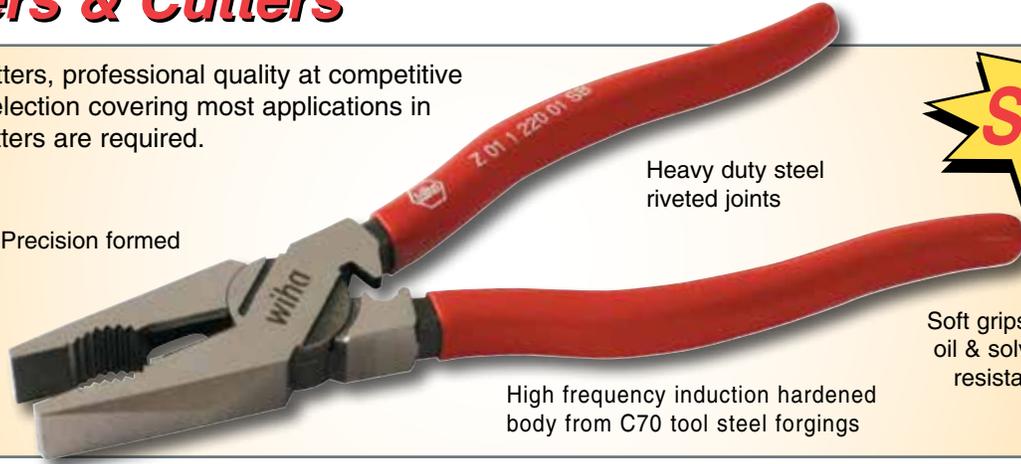

Lineman's Pliers With Crimpers

5-in-1 Lineman's Pliers



With Lower
Crimping Jaw

32616 Lineman's Pliers "5-in-1"
Professional Design Deep cut radius conduit jaws for non-slip gripping. Extra long induction hardened precision matched 64HRC cutting edges. Lower crimping jaw accepts most standard non-insulated electrical connectors. Large head with square anvil surface on each side. Premium C70 tool steel forgings.

Item	mm	Inch	Copper AWG	List	SALE
32616	225	9.0	#4	\$40.46	\$17.64

High Leverage Combination Pliers



326 High Leverage Heavy Duty Combination Pliers DIN ISO 5746

Extra long cutting edge for flat and round cables. Serrated jaws. Cutting edges additionally induction hardened to approx. 64HRC. C70 Special tool steel forgings. Use For gripping, pulling & holding as well as cutting soft, hard & piano wires and cables. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Copper AWG	List	SALE
32612	200	8.0	#4	\$26.32	\$15.92
32615	225	9.0	#4	\$28.96	\$17.14

Combination Pliers With Cutters



326 Combination Pliers With Cutters
DIN ISO 5746 Extra long cutting edge for flat and round cables. Serrated jaws. Cutting edges additionally induction hardened to approx. 64HRC. C70 Special tool steel. For gripping and holding as well as cutting soft & hard wires and cables. Soft vinyl grips, oil & solvent resistant.

Item	mm	Inch	Copper AWG	List	SALE
32603	160	6.3	#10	\$19.14	\$11.32
32606	180	7.0	#9	\$21.52	\$14.18
32609	200	8.0	#8	\$24.46	\$17.18

Soft Grip BiCut SuperCut

Cutting capacity up to 3mm
hardened piano wire



32636 Soft Grip BiCut SuperCut

For cutting various materials from soft to extremely hard, such as nails, screws, bolts, wire cables, spring wires, chains, etc.

Item	mm	Inch	Pkg.	lbs.	List	SALE
32636	200	8.0	1	.72	\$39.98	\$26.78



Double the power at the press of a button
BiCut does the job of two pairs of pliers
Up to 50% less hand strength required for cutting
Cutting force doubled for extremely hard materials
Switch between 2 strengths in one-handed operation



Soft Grip BiCut SuperCut & Screwdriver Set



32644 7 Pc. Soft Grip BiCut SuperCut & Screwdriver Set

Item No.	BiCut SuperCut:	List	SALE
32644	8.0"/200mm BiCut SuperCut		
1.78	Screwdrivers: Phillips: #0, #1, #2 Slotted: 3.0, 4.0, 6.5mm	\$89.98	\$44.99



Long Nose Pliers With Return Spring



32617 Long Nose Pliers With Cutters With Return Spring DIN ISO 5745 Long nose pliers. Extra long cutters for flat and round cables. Serrated Jaws. Cutting edges additionally induction hardened to approx. 64HRC. Special C70 tool steel forgings. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Copper AWG	List	SALE
32617	160	6.3	#12	\$29.98	\$19.20

Long Nose Pliers With Cutters



326 Long Nose Pliers With Cutters DIN ISO 5745 Long nose pliers. Extra long cutters for flat and round cables. Serrated Jaws. Cutting edges additionally induction hardened to approx. 64HRC. Special C70 tool steel forgings. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Copper AWG	List	SALE
32618	160	6.3	#10	\$17.96	\$12.98
32621	200	8.0	#8	\$22.36	\$16.30



Bent Long Nose Pliers With Cutters



326 Bent Long Nose Pliers With Cutters DIN ISO 5745 Long nose pliers angled 40°. Extra long cutters for flat and round wire. Partially Serrated Jaws. Cutting edges additionally induction hardened to approx. 64HRC. Special C70 tool steel forgings. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Copper AWG	List	SALE
32623	160	6.3	#10	\$18.60	\$13.32
32625	200	8.0	#8	\$22.34	\$14.48

Long Flat Nose Pliers



32630 Long Flat Nose Pliers DIN ISO 5745 Extra long head. Serrated Jaws are induction hardened. Special C70 tool steel forgings. Use for gripping and right-angled bending of wires and sheet metal parts. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Pkg.	lbs.	List	SALE
32630	160	6.3	1	.26	\$16.52	\$11.78

Long Round Nose Pliers



32633 Long Round Nose Pliers DIN ISO 5745 Extra long head. Serrated Jaws are induction hardened. Special C70 tool steel forgings. Use for gripping and uniform round bending of wires and sheet metal parts. Soft vinyl grips are oil & solvent resistant.

Item	mm	Inch	Pkg.	lbs.	List	SALE
32633	160	6.3	1	.25	\$16.42	\$11.72

High Leverage Cutters



DIN ISO 5749
326 High Leverage Cutters Semi-circular. Low wear lap joint, riveted and able to withstand high levels of load. Low force action, clean cutting. Long life is achieved through additional induction hardening of cutting edge to 64HRC. C70 special tool steel hardened & tempered.

Item	mm	Inch	Copper AWG	List	SALE
32646	160	6.3	#6	\$21.60	\$18.54
32649	180	7.0	#5	\$22.48	\$13.46
32652	200	8.0	#4	\$24.56	\$18.80



Cable Cutters



Long life is achieved through additional induction hardening of cutting edge to 64HRC

326 Cable Cutters Light, energy-saving & clean cutting with specially ground precision cutting edges. C70 special tool steel hardened & tempered. Soft vinyl grips. For cutting of copper & aluminum cables without crushing, also suitable for stripping. Not for steel cable, wires & copper conductors with hard coatings.

Item	Cutting Cap.				
No.	mm	Inch	Copper/Alum.	List	SALE
32600	160	6.3	16mm	\$20.94	\$13.72
32602	200	7.9	20mm	\$29.76	\$17.78

Diagonal Cutters



Special C70 tool steel hardened & tempered

326 Diagonal Cutters DIN ISO 5749 Low wear lap joint, riveted & able to withstand high levels of load. Low force cutting action, clean cutting. Long life edge is achieved through additional induction hardening to approx. 64HRC. For soft & medium hard wire. Soft vinyl grips.

Item	Cutting Cap.				
No.	mm	Inch	Copper AWG	List	SALE
32638	140	5.5	#6	\$19.06	\$13.68
32642	160	6.3	#6	\$21.60	\$15.48
32639	180	7.0	#6	\$23.32	\$13.84

Flush Cutting Mechanic's Diagonal Cutters

Special C70 tool steel hardened & tempered



Soft vinyl grips

Flush cutting, with return spring

326 Flush Cutting Mechanic's Diagonal Cutters With Return Spring DIN ISO 5749 Low wear lap joint, riveted and able to withstand high levels of load. Lightweight action, clean cutting. Long life edge is achieved through additional induction hardening to approx. 64HRC. Special C70 tool steel hardened and tempered. For flush cutting soft and semi-hard wires.

Item	Cutting Cap.				
No.	mm	Inch	Copper AWG	List	SALE
32613	127	5.0	#12	\$29.98	\$15.32

Diagonal Cutters

Flush cutting, with return spring



DIN ISO 5749

326 Flush Cutting Diagonal Cutters With Return Spring For Cutting Plastic Low wear lap joint, riveted and able to withstand high levels of load. Lightweight action, clean cutting. Long life edge is achieved through additional induction hardening to approx. 64HRC. Special C70 tool steel hardened & tempered. For flush cutting soft and semi-hard wires.

Item	Cutting Cap.					
No.	mm	Inch	Pkg.	lbs.	List	SALE
32607	127	5.0	1	.14	\$25.98	\$18.84
32614	160	6.3	1	.36	\$26.98	\$15.42

Soft Grip Crimping Pliers



326 Crimping Pliers DIN ISO 5743 Semi-circular profiles for secure connection between end sleeve and conductor. Long life is achieved through additional induction hardening to 64HRC. C70 special tool steel hardened & tempered. Soft vinyl grips.

Item	Cutting Cap.					
No.	Inch	mm2	AWG	List	SALE	
32604	5.75	0.25-2.5	14-32	\$22.14	\$13.58	
32605	7.0	0.25-16	6-32	\$26.38	\$16.66	

Stripping Pliers



32645 Stripping Pliers DIN ISO 5744 Heavy duty forged with induction hardened cutting edges for even stripping of insulation. Easy to use adjusting screw allows the stripping diameter to be set. Opening spring for effortless and sensitive handling of pliers. C70 special tool steel. 64HRC cutting edges. For Stripping up to Ø 5mm/#4 AWG conductor cross-section. Soft vinyl grips.

Item	Stripping Cap.				
No.	mm	Inch	Copper AWG	List	SALE
32645	160	6.3	#8 - #28	\$19.84	\$12.80





Wiha Soft Grip Nippers



326 High Leverage End Cutting Nippers

DIN ISO 5749 Low wear lap joint, riveted and able to withstand high levels of load. Low force action, clean cutting. Long life cutting edges are achieved through additional induction hardening to approx. 60 HRC. Special C70 tool steel forgings hardened and tempered. Soft vinyl grips are oil & solvent resistant.

Item	Cutting Cap.				List	SALE
No.	mm	Inch	Copper AWG			
32657	160	6.3	#6	\$20.92	\$11.96	
32658	180	7.0	#6	\$25.34	\$14.48	
32659	200	8.0	#6	\$29.76	\$19.04	



326 Carpenter's End Nippers

DIN ISO 9243 High cutting performance & reduced effort achieved through the precise formation of the cutting blade after assembly. Long life cutting edges achieved by additional induction hardening. Special C70 tool steel, hardened & tempered. Soft vinyl grips are oil & solvent resistant.

Item	Cutting Cap.		Pkg.	lbs.	List	SALE
No.	mm	Inch				
32671	180	7.0	1	.62	\$23.12	\$14.22
32672	200	8.0	1	.86	\$26.94	\$18.28



326 Mason Nippers DIN ISO 9243

High cutting performance and reduced effort achieved through the precise formation of the cutting blade after assembly. Long life induction hardened cutting edges. Special C70 tool steel, hardened & tempered. Soft vinyl Grips are oil & solvent resistant.

Item	Cutting Cap.				List	SALE
No.	mm	Inch	Hard Wire AWG			
32674	220	8.75	#12	\$25.54	\$15.46	
32676	250	10.0	#12	\$28.98	\$17.04	
32678	280	11.0	#12	\$30.30	\$22.64	
32680	300	12.0	#12	\$32.88	\$18.98	

Standard Adjustable Pliers



326 Adjustable Pliers - Box Type

DIN ISO 5745 10 different opening sizes provide optimal adjustment to objects being gripped. Long durability achieved through additional induction hardening of jaws to approx. 58-60 HRC. Chrome-vanadium tool steel, hardened and tempered. Soft vinyl grips are oil and solvent resistant.

Item	Capacities				List	SALE
No.	Inch	Round	Hex			
32660	7.0	1.25	1 1/2	\$25.34	\$16.82	
32661	10.0	1.75	2.0	\$29.58	\$20.94	
32663	12.0	2.0	2 1/4	\$39.66	\$26.70	



32670 3 Piece Adjustable Pliers Set

Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.

Item# 32670 lbs. 2.52

- 32660 - Adj. Pliers, Box Type - 7.0"
- 32661 - Adj. Pliers, Box Type - 10.0"
- 32663 - Adj. Pliers, Box Type - 12.0"

List \$91.54 **SALE \$61.24**

Rapid Adjustable - Push Button Pliers



- Fast push button jaw release
- Finger jam protection in all settings

326 Push Button Adjustable Water Pump Pliers - DIN ISO 8976

Extra narrow head for working in restricted spaces. Rapid and simple push button setting and locking. Long durability achieved by additional inductive hardening of gripper jaws to approx. 58-60 HRC. Finger jam protection in all settings ensures safe operation. Chrome-vanadium tool steel, hardened and tempered. Soft vinyl grips. For gripping and holding pipes and angular profiles such as hex nuts in the installation area.

Item	Capacities				List	SALE
No.	Inch	Round	Hex			
32664	7.0	1.25	1 1/2	\$28.66	\$18.74	
32665	10.0	1.75	2.0	\$35.26	\$19.87	
32667	12.0	2.0	2 1/4	\$44.08	\$27.82	



32669 3 Piece Push Button Set

Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.

- Item# 32669**
- Push Button Adj. Water Pump Pliers - 7.0"
 - Push Button Adj. Water Pump Pliers - 10.0"
 - Push Button Adj. Water Pump Pliers - 12.0"
- List \$104.32 **SALE \$59.66**

Wiha Soft Grip Pliers & Cutters Set



In roll-up pouch

32601 4 Pc. Pliers & Cutters Set

Drop-forged from C70 special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.

- Item# 32601**
- 32609 - Combination Pliers
 - 32618 - Long Nose Pliers
 - 32661 - Water Pump Pliers
 - 32642 - Diagonal Cutters
- List \$98.62 **SALE \$70.20**

Wiha Soft Grip Pliers & Cutters Sets



Wiha SoftGrip Pliers & Cutters



32648 2 Piece Pliers & Cutters Set
Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.
Item# 32648  lbs. .78
32621 - Long Nose Pliers With Cutters - 8.0"
32642 - Diagonal Cutters - 6.3"
List \$43.68 **SALE \$30.60**



32698 3 Piece Pliers & Cutters Set
Drop-forged from special tool steel, individually high frequency induction hardened. Precision formed. Soft vinyl grips, oil & solvent resistant.
Item# 32698  lbs. 1.4
32606 - Combination Pliers 32642 - Diagonal Cutters
32618 - Long Nose Pliers
List \$58.16 **SALE \$39.38**



Tool box set in blow molded tray

32679 9 Piece Pliers & Cutters Set In Tool Box Tray Pliers & cutters set in a light weight tool box tray.
Item
No. 9.0" Lineman's Pliers 8.0" Combo Pliers
32679 6.3" Long Nose Pliers 8.0" Cable Cutters
8.0" Long Nose Pliers 6.3" Stripping Pliers
 6.3" Diagonal Cutters 7.0" Crimping Pliers
lbs. 8.0" Diagonal Cutters
6.34 List \$237.48 **SALE \$143.24**



In canvas pouch
Pliers precision formed

32608 8 Pc. Pliers/Cutters Jaws & cutters induction hardened. Long life edge is achieved through additional induction hardening to approx. 60 HRC.
Item 6.3"/160mm Combination Pliers
No. 6.3"/160mm & 8.0"/200mm Long Nose Pliers
32608 6.3" / 160mm Diagonal Cutters
6.3" / 160mm Long Flat Nose Pliers
6.3" / 160mm Long Round Nose Pliers
 8.0" / 200mm High Leverage Cutters
lbs. 9.0" / 225mm High Leverage Combo Pliers
4.42 List \$164.38 **SALE \$115.52**

Wiha Soft Grip Belt Pack Pouch Sets

Durable Canvas Belt Pack Pouch



32653 3 Pc. Pliers/Cutters In Belt Pack Pouch Pliers precision formed. Jaws & cutters induction hardened. Soft vinyl grips are oil & solvent resistant.
Item No. Pliers & Cutters
32653 8.0"/200mm High Leverage Cutters
 8.0"/200mm Combo Pliers
lbs. 8.0"/200mm Long Nose Pliers
2.02 List \$84.36 **SALE \$57.52**

Durable Canvas Belt Pack Pouch



32655 5 Pc. Pliers/Cutters & Screwdrivers In Belt Pack Pouch Pliers precision formed. Jaws & cutters induction hardened. Soft vinyl grips are oil & solvent resistant. Screwdriver blades CVM tool steel, hardened, hard chromed. SoftFinish cushion grip drivers, multi-component.
Item No. Pliers & Cutters
32655 6.3"/160mm Diagonal Cutters
8.0"/200mm Long Nose Pliers
 **Cushion Grip Screwdrivers:**
lbs. Slotted: 3.0, 4.5mm / Phillips: #2
1.62 List \$70.74 **SALE \$52.70**

Wiha Soft Grip Electrician's shears



Soft Vinyl Grip

32610 Multipurpose Electrician's Heavy Duty Shears High alloy carbon steel, hardened, burnished surface. Sturdy model, straight, very robust, micro-toothed cutting.

Item						
No.	mm	Inch	Pkg.	lbs.	List	SALE
32610	145	5.75	1	.05	\$19.48	\$15.98



Comfort Grip

32611 Comfort Grip Electrician's And Craftsman Shears

Item						
No.	mm	Inch	Pkg.	lbs.	List	SALE
32611	145	5.75	1	.05	\$22.16	\$17.70





Retaining Ring Pliers - Internal



326 Straight Internal Retaining Ring Pliers DIN ISO 5256 Shape C, straight tips. Die forged cylindrical precision formed. Chrome-vanadium special tool steel. For inserting & removing internal retaining rings.

Item No.	←→ Inch	↺↻ Inch	● Tip mm	Inch/mm	List	SALE
32681	5.5	5/16-1/2	8-13	.035/9	\$23.08	\$13.74
32682	5.5	1/2-1	12-25	.050/1.3	\$23.20	\$12.82
32683	7.0	3/4-2 3/8	19-60	.070/1.5	\$24.72	\$14.46
32684	8.9	1 1/2-4	40-100	.090/2.3	\$30.74	\$17.94
32654	12.2	3.5-5.5	85-140	.126/3.2	\$39.12	\$23.16

90° Angle Retaining Ring Pliers - Internal



326 90° Angle Internal Retaining Ring Pliers DIN ISO 5254 Shape D, 90° angled tips. Die forged cylindrical precision formed. CV Special tool steel. For inserting & removing internal retaining rings. Soft vinyl grips.

Item No.	←→ Inch	↺↻ Inch	● Tip mm	Inch/mm	List	SALE
32685	5.5	5/16-1/2	8-13	.035/9	\$25.22	\$13.98
32686	5.5	1/2-1	12-25	.050/1.3	\$25.22	\$13.74
32687	7.0	3/4-2 3/8	19-60	.070/1.5	\$25.72	\$16.34
32688	8.9	1 1/2-4	40-100	.090/2.3	\$31.56	\$18.30
32656	12.2	3.5-5.5	85-140	.126/3.2	\$37.80	\$22.92

Forged Retaining Ring Pliers



32693 8 Pc. Straight Retaining Ring Pliers Set Straight tips. For inserting & removing internal and external retaining rings.

Item# 32693	↔ lbs. 3.65
Internal-Shape C	External-Shape A
32681 8-13mm/tip .035	32689 3-10mm/tip .035
32682 12-25mm/tip .050	32690 10-25mm/tip .050
32683 19-60mm/tip .070	32691 19-60mm/tip .070
32684 40-100mm/tip .090	32692 40-100mm/tip .090
List \$211.72	SALE \$122.44


Retaining Ring Pliers - External



326 Straight External Retaining Ring Pliers DIN ISO 5254 Shape A, straight tips. Die forged cylindrical precision formed. For fitting & removing external retaining rings. CV special tool steel.


Item No.	←→ Inch	↺↻ Inch	● Tip mm	Inch/mm	List	SALE
32689	5.5	1/8-3/8	3-10	.035/9	\$25.22	\$13.90
32690	5.5	3/8-1	10-25	.050/1.3	\$25.22	\$13.84
32691	7.0	3/4-2 3/8	19-60	.070/1.5	\$26.20	\$16.36
32692	8.9	1 1/2-4	40-100	.090/2.3	\$30.74	\$17.96
32662	12.2	3.5-5.5	85-140	.126/3.2	\$39.12	\$23.26

90° Angle Retaining Ring Pliers - External

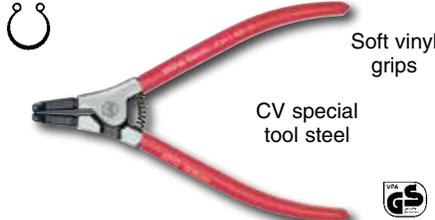


326 90° Angled External Retaining Ring Pliers DIN ISO 5254 Shape B, 90° angled tips. Die forged cylindrical precision formed. For fitting & removing external retaining rings. CV special tool steel.

Item No.	←→ Inch	↺↻ Inch	● Tip mm	Inch/mm	List	SALE
32694	5.5	1/8-3/8	3-10	.035/9	\$25.20	\$14.32
32695	5.5	3/8-1	10-25	.050/1.3	\$25.20	\$14.06
32696	7.0	3/4-2 3/8	19-60	.070/1.5	\$27.46	\$15.98
32697	8.9	1 1/2-4	40-100	.090/2.3	\$32.72	\$18.76
32666	12.2	3.5-5.5	85-140	.126/3.2	\$39.12	\$22.58

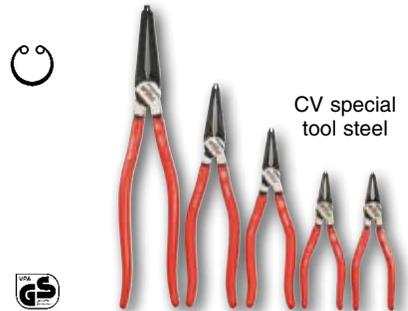


32626 5 Piece Straight Internal Ring Pliers Set Shape C, straight tips. Die forged cylindrical precision formed. For inserting & removing internal retaining rings. CV special tool steel.

Item# 32626	↔ lbs. 2.52
32681 8-13mm / tip .035	32684 40-100mm / tip .090
32682 12-25mm / tip .050	32654 85-140mm / tip .126
32683 19-60mm / tip .070	
List \$129.98	SALE \$79.98

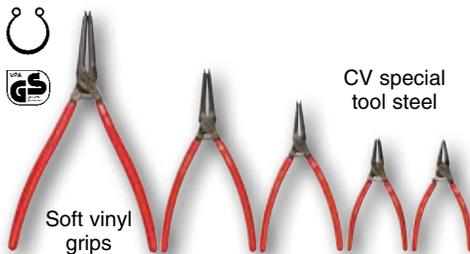


32628 5 Piece Straight External Ring Pliers Set Shape A, straight tips. Die forged cylindrical precision formed. For fitting & removing external retaining rings. CV special tool steel.

Item# 32628	↔ lbs. 2.68
32689 3-10mm / tip .035	32692 40-100mm / tip .090
32690 10-25mm / tip .050	32662 85-140mm / tip .126
32691 19-60mm / tip .070	
List \$138.98	SALE \$79.98

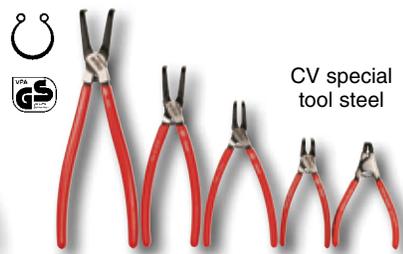

32629 5 Pc. 90° Angle External Ring Pliers Set Shape B, 90° angled tips. Die forged cylindrical precision formed. Fitting & removing external retaining rings. Soft vinyl grips. CV special tool steel.

Item# 32629	↔ lbs. 2.60
32694 3-10mm / tip .035	32697 40-100mm / tip .090
32695 10-25mm / tip .050	32666 85-140mm / tip .126
32696 19-60mm / tip .070	
List \$143.98	SALE \$79.98

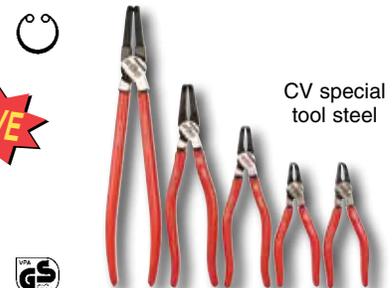

32627 5 Piece 90° Angle Internal Ring Pliers Set Shape D, 90° angled tips. Die forged cylindrical precision formed. CV Special tool steel. For inserting & removing internal retaining rings. Soft vinyl grips.

Item# 32627	↔ lbs. 2.56
32685 8-13mm / tip .035	32688 40-100mm / tip .090
32686 12-25mm / tip .050	32656 85-140mm / tip .126
32687 19-60mm / tip .070	
List \$132.98	SALE \$79.98



SAVE NOW!

Wiha MagicTip Safety Ring Pliers

“MagicTips”



High performance precision notched tips for maximum stability & secure holding (Safety notched on .070, .090 & .126)

Hardened MagicTips are notched to hold rings securely on .070, .090 & .126 sizes



Safety Notched

Tips made of premium quality hardened CVM tool steel, HRC 64



No Dropped Rings!

Heavy duty forged pliers with soft vinyl grips

- **Faster & Easier Application**
- **Fewer Lost Rings**
- **Safer To Use**
- **Saves Time & Money**



Patents Pending

SALE

MagicTip Safety Ring Pliers-External

MagicTip Safety Ring Pliers - Internal



Soft vinyl grips



Soft vinyl grips

346 MagicTip Straight Internal Safety Ring Pliers DIN ISO 5256 Shape C, straight tips. Precision machined tips of CV special tool steel. For inserting & removing internal retaining rings.

Item	↔	⊖	⊕	●	Tip	List	SALE
34610	7.1	3/4-2 3/8	19-60	.070/1.5	\$26.84	\$15.60	
34611	8.7	1 1/2-4	40-100	.090/2.3	\$31.16	\$18.00	
34612	12.0	3.5-5.5	85-140	.126/3.2	\$48.46	\$28.22	

346 MagicTip Straight External Safety Ring Pliers DIN ISO 5254 Shape A, straight tips. Precision machined tips of Chrome-vanadium special tool steel. For fitting & removing external retaining rings.

Item	↔	⊖	⊕	●	Tip	List	SALE
34620	7.3	3/4-2 3/8	19-60	.070/1.5	\$27.66	\$16.08	
34621	9.5	1 1/2-4	40-100	.090/2.3	\$31.68	\$18.34	
34622	11.8	3.5-5.5	85-140	.126/3.2	\$49.58	\$28.90	

MagicTip 90° Angle Safety Ring Pliers - Internal



Soft vinyl grips

346 MagicTip 90° Angle Internal Safety Ring Pliers DIN ISO 5254 Shape D, 90° angled tips. Precision machined tips of Chrome-vanadium Special tool steel. For inserting & removing internal retaining rings.

Item	↔	⊖	⊕	●	Tip	List	SALE
34615	7.1	3/4-2 3/8	19-60	.070/1.5	\$27.36	\$15.82	
34616	8.7	1 1/2-4	40-100	.090/2.3	\$31.68	\$18.32	
34617	12.0	3.5-5.5	85-140	.126/3.2	\$49.06	\$27.42	

MagicTip 90° Angle Safety Ring Pliers - External



Soft vinyl grips

346 MagicTip 90° Angled External Safety Ring Pliers DIN ISO 5254 Shape B, 90° angled tips. Precision machined tips of Chrome-vanadium special tool steel. For fitting & removing external retaining rings.

Item	↔	⊖	⊕	●	Tip	List	SALE
34625	7.3	3/4-2 3/8	19-60	.070/1.5	\$28.18	\$16.28	
34626	9.5	1 1/2-4	40-100	.090/2.3	\$32.20	\$18.62	
34627	11.8	3.5-5.5	85-140	.126/3.2	\$50.20	\$28.10	




In Canvas Roll-Up Pouch

Soft vinyl grips

34699 12 Pc. Straight And 90° Internal & External Ring Pliers Set Precision machined tips of CV special tool steel. For inserting & removing retaining rings.

Item#	↔	⊖	⊕	●	Tip	List	SALE
34610	19-60mm	/ tip .070					
34611	40-100mm	/ tip .090					
34612	85-140mm	/ tip .126					
34615	19-60mm	/ tip .070					
34616	40-100mm	/ tip .090					
34617	85-140mm	/ tip .126					
34620	19-60mm	/ tip .070					
34621	40-100mm	/ tip .090					
34622	85-140mm	/ tip .126					
34625	19-60mm	/ tip .070					
34626	40-100mm	/ tip .090					
34627	85-140mm	/ tip .126					
List						\$450.94	SALE \$258.76

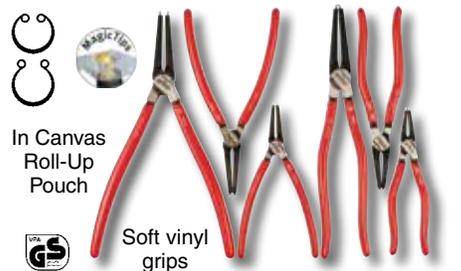


In Canvas Roll-Up Pouch

Soft vinyl grips

34697 6 Pc. Straight Internal & External Ring Pliers Set Precision machined tips of Chrome-vanadium special tool steel. For inserting & removing retaining rings.

Item#	↔	⊖	⊕	●	Tip	List	SALE
34610	19-60mm	/ tip .070					
34611	40-100mm	/ tip .090					
34612	85-140mm	/ tip .126					
34620	19-60mm	/ tip .070					
34621	40-100mm	/ tip .090					
34622	85-140mm	/ tip .126					
List						\$223.76	SALE \$128.44

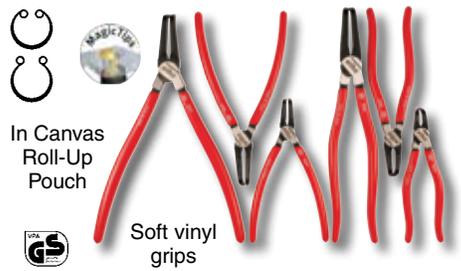

In Canvas Roll-Up Pouch

Soft vinyl grips

34698 6 Pc. 90° Angle Internal & External Ring Pliers Precision machined tips of CV tool steel. For Inserting & removing retaining rings.

Item#	↔	⊖	⊕	●	Tip	List	SALE
34610	19-60mm	/ tip .070					
34611	40-100mm	/ tip .090					
34612	85-140mm	/ tip .126					
34620	19-60mm	/ tip .070					
34621	40-100mm	/ tip .090					
34622	85-140mm	/ tip .126					
List						\$227.18	SALE \$130.16



All Steel Narrow Profile Pipe Wrenches

Easy access 20%
Narrower profile
heads



Comfortable
handle profile

Rapid adjusting nut
with acme thread

Extra heavy duty hardened CV
steel, induction hardened jaws

Safe & secure grip with back raked serrated jaws



32995 3 Piece Pipe Wrench Sets

Hardened chrome-vanadium steel, induction hardened jaws. Safe and secure grip on pipes, flat work-pieces and nuts.

Item No.	32995	Weight	lbs.
32970 - 12.60" S-Jaws		32978 - 12.20" 90° Jaws	5.60
32974 - 12.36" 45° Jaws			
List \$194.98			SALE \$162.98



32996 3 Piece Narrow Style 90° Pipe Wrench Sets

Narrow shape angled 90°. Safe and secure grip angled jaw teeth. Comfortable handle profile. Rapid adjusting nut.

Item No.	32996	Weight	lbs.
32978 - 12.20" Narrow Style 90°		32979 - 16.54" Narrow Style 90°	
32980 - 22.05" Narrow Style 90°			
10.80		List \$288.28	SALE \$246.98

Distributed by:



1348 Dundas Circle
Monticello, MN 55362

(800)494-6104
fax: (800)494-7456
cservice@wihatools.com

Pipe Wrenches Narrow Style / S-Jaw



329 Pipe Wrenches Narrow Style / S-Jaw

S-Jaw shape angled 45°. Self clamping gripping of pipes and hex nuts at 3 points. Comfortable handle profile. Rapid adjusting nut. Hardened CV steel, induction hardened jaws. Safe & secure grip on pipes & hex nuts.

Item No.	Inch OAL	Max. pipe dia.	Max. grip jaw opening	maximum	List	SALE
32970	12.6	1	40mm(1.5")	\$69.22	\$53.56	
32971	16.4	1.5	55mm(2.1")	\$97.16	\$73.48	
32972	21.1	2	67mm(2.6")	\$151.66	\$131.28	

Pipe Wrenches Narrow Style - 45°



329 Pipe Wrenches Narrow Style - 45°

Narrow shape angled 45°. Safe and secure grip angled jaw teeth. Comfortable handle profile. Rapid adjusting nut. Hardened CV steel, induction hardened jaws. Safe & secure grip on pipes, flat work-pieces & nuts.

Item No.	Inch OAL	Max. pipe dia.	Max. grip jaw opening	maximum	List	SALE
32974	12.4	1	40mm(1.5")	\$69.22	\$49.38	
32975	16.8	1.5	55mm(2.1")	\$92.12	\$59.55	
32976	22.4	2	67mm(2.6")	\$141.94	\$94.80	

Pipe Wrenches Narrow Style - 90°



329 Pipe Wrenches Narrow Style - 90°

Narrow shape angled 90°. Safe and secure grip angled jaw teeth. Comfortable handle profile. Rapid adjusting nut. Hardened CV steel, induction hardened jaws. Safe and secure grip on pipes, flat work-pieces & nuts.

Item No.	Inch OAL	Max. pipe dia.	Max. grip jaw opening	maximum	List	SALE
32978	12.2	1	40mm(1.5")	\$69.22	\$55.76	
32979	16.5	1.5	55mm(2.1")	\$95.20	\$77.34	
32980	22.1	2	67mm(2.6")	\$145.98	\$119.24	



Wiha Ratchet Crimpers

Ratchet End Sleeve Crimper



5 die nests side
entry crimp

Factory set
auto release
at end of
crimp cycle

43612 Ratchet End Sleeve Crimper

Crimps Insulated & non-insulated end sleeves. 6 crimp positions range AWG 26-18, 18-16, 14, 12, 10, 8. Soft grip non-slip handles.

Item No.	Inch Length	AWG Range	Weight	List	SALE
43612	8.6"	26-8	1.18	\$204.30	\$132.80

Ratchet Crimper For Standard Connectors



Crimp
Profile

Factory set auto release
at end of crimp cycle

Soft grip non-slip

43618 Ratchet Crimper For Standard Connectors

Crimps Insulated & non-insulated connectors. 3 crimp positions range AWG 20-18 red, 16-14 blue, 12-10 yellow.

Item No.	Inch Length	AWG Range	Weight	List	SALE
43618	8.6"	20-10	1.06	\$204.30	\$118.14

Ratchet Crimper Push On Terminals



Crimp Profile
"F"/"B"

Factory set auto
release at end of
crimp cycle

Soft grip non-slip

43624 Ratchet Crimper Push On Terminals

Crimps Insulated & non-insulated terminals. 4 crimp positions range AWG 24-20, 20-18, 16-14, 12-10. Soft grip non-slip handles.

Item No.	Inch Length	AWG Range	Weight	List	SALE
43624	8.6"	24-10	1.06	\$204.30	\$132.60

Ratchet Crimper For Eye Terminals



Self
adjusting
side entry
crimp

Factory set auto
release at end of
crimp cycle

Soft grip non-slip

43643 Ratchet Crimper For Eye Terminals

Crimps Insulated & non-insulated terminals. 4 crimp positions range AWG 26-22, 20-18, 12-10, 8-6.

Item No.	Inch Length	AWG Range	Weight	List	SALE
43643	8.6"	26-6	1.02	\$204.30	\$118.38