

KICHLER®



LANDSCAPE LIGHTING

At-A-Glance | 2018

Designed to enhance your reputation

For more than 25 years we've made it our commitment to continually offer one of the most comprehensive professional landscape lighting lines in the industry: one that's built for design flexibility, superior efficiency and rock-solid performance. You can install a system that's exactly what you and your clients want from day one – for a landscape lighting effect that's beautiful, capturing and functional for years to come.





12V INTEGRATED LED Kichler Technology

When we first entered the landscape lighting category more than 25 years ago, we had a simple goal: make things better.

Today, that history of innovation still drives everything we do. It's why Kichler® offers one of the largest landscape lighting portfolios on the market. This commitment to innovation means you never have to compromise on performance, design, quality or dependability. You can always trust you're getting the latest and best LED technologies available and backed by one of the finest warranties in the industry.

We invite you to explore all of the products we have to offer, including our high-performance integrated LED fixtures and our newest and most advanced technology: Variable Lumen Output (VLO). We think you'll agree, our integrated LED options assure you get the best in custom optics and light output, for the utmost in design versatility and flexibility.

12V LED Accent Light Solutions			
	12V Integrated LED Accent with VLO	12V Integrated LED Accent	12V LED Lamp and Fixture
			
Design	Integrated LED fully potted and sealed for protection of electrical components to ensure optimal all-weather performance	Integrated LED fully potted and sealed for protection of electrical components to ensure optimal all-weather performance	Unsealed separate fixture with accessible/upgradeable lamp options
LED Style	Single high output chip-on-board or discrete LEDs provide single focal point	Multiple discrete LEDs	Multiple discrete LEDs
Beam Quality & Uniformity	Optimal center-to-edge uniformity	Optimal center-to-edge uniformity	Standard center-to-edge uniformity
Light Output	Custom optics that provide 100% light output and no cut-off	100% light output and no cut-off	Cowls and lenses may alter beam spread and decrease lumen output
Stated Lifetime (L70)	50K hours (based on 5 hours of use a day)	40K hours (based on 5 hours of use a day)	30K hours (based on 5 hours of use a day)
Adjustable Lumen Output	Yes	No	No
Surge Protection	6kV protection	4kV protection	None
Warranty	15 years	10 years	6 years

Visit www.Kichler.com/Warranty for full warranty and limitations.

Lighting Design Tips

The color of your light sets the tone.

Did you know that not all white light is created equal? Many of our integrated LED fixtures and LED retrofit lamps come in a variety of color temperatures – from warm white to pure white to cool white – that can enhance the colors in your home's exterior and landscape. Known as Kelvin (K) temperature, consider these suggestions for placement:



WARM WHITE - 2700K

- Surroundings with warmer colors, like brown and cedar
- Natural colored walls or stonework
- Foliage that is red, orange or yellow (ex: highlighting oak trees)



PURE WHITE - 3000K

- Surroundings with dark materials, like deep slate, black or gray
- Foliage that is blue or purple (ex: highlighting blue spruce trees)



BRIGHT WHITE - 4000K-4200K


- Ultra contemporary homes and structures
- Commercial applications
- 120V-277V only

Beam spreads...focus light where it's needed.


Kichler® integrated LED fixtures are available in a variety of beam spreads that allow your lighting professional to tailor the light to your specific application – creating the perfect end effect you desire.




Tall, thin beam of light ideal for grazing trees and column features.

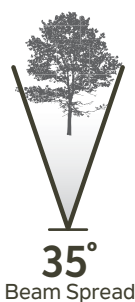

Medium height and width beam of light suited for general accent lighting.

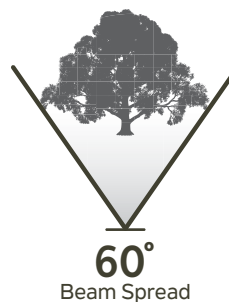

Short and wide beam of light useful for broad trees and wide structures.

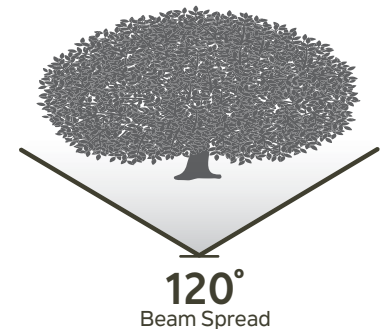

Ideal for wall washing, grazing, and short yet wide, objects.

Our commitment to quality goes beyond product.

With professional landscape lighting projects, there's no room for do-overs. That's why we don't just think of ways to make our products better; we look for ways to make your entire Kichler® experience superior.

- Our exclusive **Advanced Product Solutions (APS) and Layout Team** is a free service that can answer your installation questions or assist with property designs and layouts.
- Every product we offer is competitively priced and backed by our domestic network of sales and service.
- Our inventory levels allow us to fill orders within 24 hours: when your installation crews need the product most.



Our Advanced Product Solutions and Layout Team employees average 14+ years with Kichler, giving them a level of pride and professionalism that you can count on at every turn. Our entire team is also Certified Low Voltage Lighting Technician (CLVLT) certified.

Landscape lighting products used in the image above:

Front yard: LED Accent with VLO 16016AZT27, LED In-Ground Light 16032BBR27, LED Path Shallow Shade 15806BKT27R



Accent Lighting
with VLO



In-Ground Lighting
with LED


LAYOUT DESIGN SERVICES

Get to solutions faster & increase sales.

From answering questions to creating detailed layouts to delivering a full bill of materials – Kichler's Advanced Product Support Team is your link to getting the job done. This FREE service takes the guesswork out of any lighting need you have: determining the scope of materials required, installing a product correctly, even creating a full wiring and product layout.

Contact us at layouts@kichler.com and we'll get you started:

- 1 Email us a completed Design Request Form (available at [Kichler.com/APS](https://www.kichler.com/APS)) along with any drawings or pictures related to the project.
- 2 We'll create a bill of materials (BOM) and email it back to you that same day (for all requests received by 3:00 pm EST).
- 3 Once you confirm the BOM and pricing, we'll return a completed layout design **within 48 hours or less**.

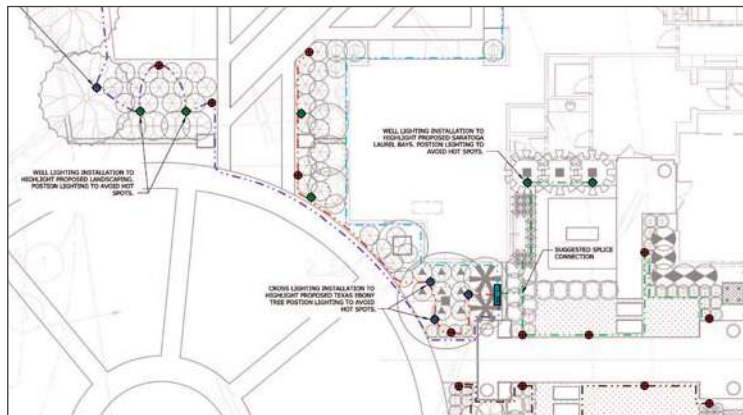

Landscape | Lighting Systems

ADVANCED PRODUCT SUPPORT

No question is too complex.


Installation issue? Building code question? Regulatory stumper? If you've got a challenging question – we've got you covered. Our Advanced Product Support Team receives additional classroom and in-field training on all Kichler products, so you can get your question answered quickly. To take advantage of this free service, call our dedicated Advanced Product Support line at **844-KICHLER (844-542-4537)** or email techsupport@kichler.com.

Lighting Techniques

Wall-Wash Lighting

Directs the eye to the textures, shapes and/or height differences of items in beds, adding depth and ambiance.

Recommended fixtures: 12V LED Accent with VLO 16017 & 16020. Also 120V-277V C-Series 16210-16211, 16213-16214, 16218-16225.

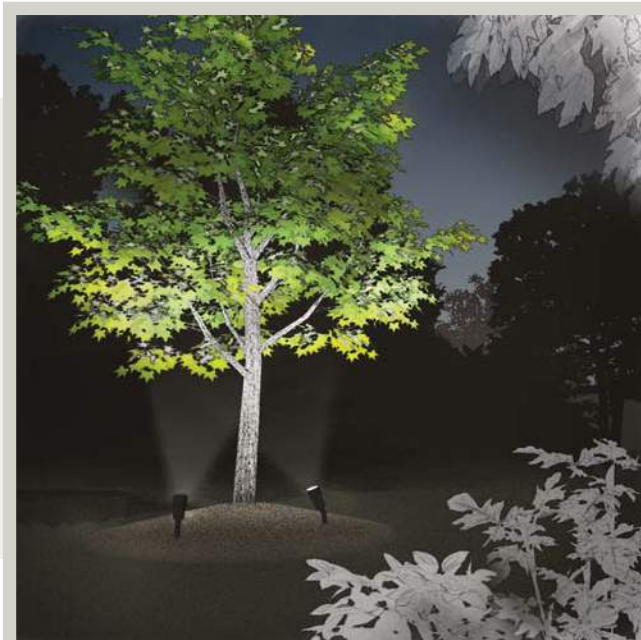

Cross Lighting

Using two beams of light, it creates 360-degree visual interest on large trees, statues or other tall features.

Recommended fixtures: 12V LED Accent with VLO 16015-16016, 16018-16019. Also 120V-277V C-Series 16209-16210, 16212-16213, 16215-16216, 16218-16219.

Get the most out of a project with these professional landscape lighting techniques.

Accent Uplighting

Shines light upward to illuminate an object or surface for dramatic, attention-getting visuals.

Recommended fixtures: 12V LED Accent with VLO 16015-16020. Also 120V-277V C-Series 16209-16220.



Grazing

Adds depth and dimension to stucco, brick, stonework or architectural features of a home or building.

Recommended fixtures: 12V LED Accent with VLO 16017 & 16020. Also 120V-277V C-Series 16210-16211, 16213-16214, 16218-16225.

Lighting Techniques

Shadowing

A technique that projects the look of a tree or yard art onto a surface behind the object.

Recommended fixtures: 12V LED Accent with VLO 16015-16020. Also 120V-277V C-Series 16209-16220.



Silhouette Lighting

Draw attention to an interesting shape by lighting a vertical surface behind the object to accent that unique shape.

Recommended fixtures: 12V LED Accent with VLO 16015-16020. Also 120V-277V C-Series 16209-16220.

Mirror Lighting

Create dream-like water scenes by strategically lighting background areas around bodies of water that reflect the landscape off of the water.

Recommended fixtures: 12V LED Accent with VLO 16015-16020. Also 120V-277V C-Series 16209-16220.



Moon Lighting

Placing a lower lumen fixture high in a tree catches the details of branches and leaves, emulating the look of moonlight.

Recommended fixtures: 12V LED Accent with VLO 16016-16017, 16019-16020. Also 120V-277V C-Series 16210-16211, 16213-16214, 16218-16225.

Lighting Techniques

In-Ground Lighting

Deliver light to permanent and semi-permanent installations such as sidewalks, large mature trees, walls and flagpoles.

Recommended fixtures: 12V LED In-Ground 16030-16038.



Underwater & Water Accent Lighting

Enhance and highlight flowing water in waterfalls, streams and fountains. Create a magical mirroring effect on still waters.

Recommended fixture: 12V LED Water Accent 15711SS.

Flagpole Lighting

Two to three directional accent lights are often needed to properly illuminate the pole and the entire flag. Use the pole height and flag size to determine the right fixtures.

- The fixtures should be placed 180° apart if using two and 120° apart if using three.
- The fixtures should be located 6" to 3' from the flagpole in low-voltage (12V) residential applications. For large residential, commercial and line voltage applications (120V), fixtures should be from 12" to 3' from the base of the pole.
- Aim the fixture at the ball at the top of the flagpole.



Pole Height	Typical Flag Size	# of Fixtures	Lamp Wattage	Beam Spread	12V LED Option	120V LED Option
12' - 20'	3' x 5'	2	20W	NSP 10° to 15°	16015 (Level 2)	--
25'	4' x 6'	2	35W	NSP 10° to 15°	16015 (Level 3)	16209
30'	5' x 8'	2	35W	NSP 10° to 15°	16018 (Level 1)	16209
35'	6' x 10'	3	35W	NSP 10° to 15°	16018 (Level 1)	16209
35' +	10' +	3	50W	NSP 10° to 15°	16018 (Level 2 or 3)	16212



Xeriscape Lighting

Cacti, grasses and the stone used in xeriscape designs can benefit from a lower lumen illumination than traditional landscaping.


Recommended fixtures: 2700K fixtures, 12V LED Path 15811, 12V LED Accent with VLO 16015-16017.

Lighting Techniques

Path & Spread Lighting

Illuminate sidewalks, stone pathways and lawn walkways while adding a hint of intrigue to boulders and plant beds.

Recommended fixtures: 12V LED Path Fundamentals 16120, Llena 15820 or Dome 15810.

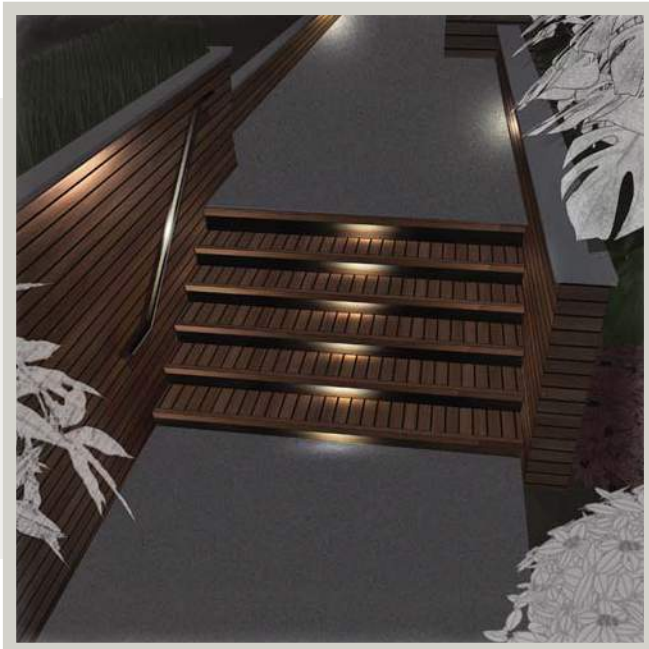

Hardscape Lighting

Highlight stone features, retaining walls, outdoor kitchens, steps, handrails, benches and more.

Recommended fixture: 12V 3 LED Fixture 15745.

Deck & Patio Lighting

Accentuate all of the beauty and details of decks, patios, outdoor kitchens, steps, handrails and more.

Recommended fixtures: 12V LED Half Moon 15764 (top) and 12V LED Brick Light 15773 (bottom).





1



Arrange pendant fixtures in clusters - for a stylish statement and ambient light.

Argyle
Outdoor Pendant
(49747 WZC)

2



Outdoor ceiling fans bring light and added temperature control to sitting areas.

Rana™ LED Ceiling Fan
60"
(310155 NI)

3



The right hardscape lighting helps guide guests at night. Choose small ...

LED Hardscape Lighting
3 LED
(15745 BBR27)



Bring it all together.

Bring life to outdoor spaces after dark with the right combination of lighting pieces.

Get the look shown here by incorporating integrated LED landscape lighting fixtures along with Kichler® decorative options designed for outdoor use. Homeowners get a beautiful and functional space they can use 24/7; you get a project that shows your design sensibility.

4



... or large fixtures to match the space.

LED Hardscape Lighting
9 LED
(15756 GRY27)

5



A built-in Bluetooth® speaker allows homeowners to wirelessly add music to gatherings.

Lyndon™ LED
Portable Lantern
(49500 BKTLED)

6



Select Kichler integrated fixtures allow you to adjust the light output easily, for long-term flexibility.

LED Accent Light
with VLO
(16016 AZT27)

Accent



Name	Small Accent with VLO		Large Accent with VLO	
SKU & Finish	16015 AZT27 - 15° Spot 16015 BKT27 - 15° Spot 16015 CBR27 - 15° Spot 16016 AZT27 - 35° Flood 16016 BKT27 - 35° Flood 16016 CBR27 - 35° Flood 16016 WHT27 - 35° Flood 16017 AZT27 - 60° Wide Flood 16017 BKT27 - 60° Wide Flood 16017 CBR27 - 60° Wide Flood	16015 AZT30 - 15° Spot 16015 BKT30 - 15° Spot 16015 CBR30 - 15° Spot 16016 AZT30 - 35° Flood 16016 BKT30 - 35° Flood 16016 CBR30 - 35° Flood 16016 WHT30 - 35° Flood 16017 AZT30 - 60° Wide Flood 16017 BKT30 - 60° Wide Flood 16017 CBR30 - 60° Wide Flood	16018 AZT27 - 15° Spot 16018 BKT27 - 15° Spot 16018 CBR27 - 15° Spot 16019 AZT27 - 35° Flood 16019 BKT27 - 35° Flood 16019 CBR27 - 35° Flood 16019 WHT27 - 35° Flood 16020 AZT27 - 60° Wide Flood 16020 BKT27 - 60° Wide Flood 16020 CBR27 - 60° Wide Flood	16018 AZT30 - 15° Spot 16018 BKT30 - 15° Spot 16018 CBR30 - 15° Spot 16019 AZT30 - 35° Flood 16019 BKT30 - 35° Flood 16019 CBR30 - 35° Flood 16019 WHT30 - 35° Flood 16020 AZT30 - 60° Wide Flood 16020 BKT30 - 60° Wide Flood 16020 CBR30 - 60° Wide Flood
Watt/VA	Level 1 = 2W/3.5VA, 100 lm, 50 lm/W Level 2* = 3.5W/5.5VA, 200 lm, 57 lm/W Level 3 = 5.5W/7.5VA, 300 lm, 55 lm/W		Level 1* = 5.25W/8.5VA, 400 lm, 76 lm/W Level 2 = 8.5W/12.5VA, 600 lm, 70 lm/W Level 3 = 12W/17VA, 835 lm, 69 lm/W	
Kelvin & Lumens	2700K - Warm White (see Wattage for lumen info.)	3000K - Pure White (see Wattage for lumen info.)	2700K - Warm White (see Wattage for lumen info.)	3000K - Pure White (see Wattage for lumen info.)
*Factory setting		*Factory setting		



Name	LED Accent - 2.5W, 3.5W, 7W					
SKU & Finish	16150 AZT27 - 10° Spot 16150 BKT27 - 10° Spot 16150 CBR27 - 10° Spot 16151 AZT27 - 35° Flood 16151 BKT27 - 35° Flood 16151 CBR27 - 35° Flood 16152 AZT27 - 60° Wide Flood 16152 BKT27 - 60° Wide Flood 16152 CBR27 - 60° Wide Flood	16150 AZT30 - 10° Spot 16150 BKT30 - 10° Spot 16150 CBR30 - 10° Spot 16151 AZT30 - 35° Flood 16151 BKT30 - 35° Flood 16151 CBR30 - 35° Flood 16152 AZT30 - 60° Wide Flood 16152 BKT30 - 60° Wide Flood 16152 CBR30 - 60° Wide Flood	16153 AZT27 - 10° Spot 16153 BKT27 - 10° Spot 16153 CBR27 - 10° Spot 16154 AZT27 - 35° Flood 16154 BKT27 - 35° Flood 16154 CBR27 - 35° Flood 16155 AZT27 - 60° Wide Flood 16155 BKT27 - 60° Wide Flood 16155 CBR27 - 60° Wide Flood	16153 AZT30 - 10° Spot 16153 BKT30 - 10° Spot 16153 CBR30 - 10° Spot 16154 AZT30 - 35° Flood 16154 BKT30 - 35° Flood 16154 CBR30 - 35° Flood 16155 AZT30 - 60° Wide Flood 16155 BKT30 - 60° Wide Flood 16155 CBR30 - 60° Wide Flood	16156 AZT27 - 10° Spot 16156 BKT27 - 10° Spot 16156 CBR27 - 10° Spot 16157 AZT27 - 35° Flood 16157 BKT27 - 35° Flood 16157 CBR27 - 35° Flood 16158 AZT27 - 60° Wide Flood 16158 BKT27 - 60° Wide Flood 16158 CBR27 - 60° Wide Flood	16156 AZT30 - 10° Spot 16156 BKT30 - 10° Spot 16156 CBR30 - 10° Spot 16157 AZT30 - 35° Flood 16157 BKT30 - 35° Flood 16157 CBR30 - 35° Flood 16158 AZT30 - 60° Wide Flood 16158 BKT30 - 60° Wide Flood 16158 CBR30 - 60° Wide Flood
Watt/VA	2.5W, 3.5VA		3.5W, 5.25VA		7W, 10VA	
Kelvin & Lumens	2700K - Warm White 200 lm, 80 lm/W	3000K - Pure White 200 lm, 80 lm/W	2700K - Warm White 300 lm, 86 lm/W	3000K - Pure White 300 lm, 86 lm/W	2700K - Warm White 500 lm, 71 lm/W	3000K - Pure White 500 lm, 71 lm/W

Accent & In-Ground



Name	Wall Wash	
SKU & Finish	16070 AZT27R 16070 BBR27R 16070 BKT27R	16070 AZT30R 16070 BBR30R 16070 BKT30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W
Beam spread vertical of 80°, horizontal of 100°.		



Wall Wash Accent	
SKU & Finish	15861 AZT27R 15861 BBR27R 15861 BKT27R
SKU & Finish	15861 AZT30R 15861 BBR30R 15861 BKT30R
Watt/VA	4.3W/5.8VA
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W
Kelvin & Lumens	3000K - Pure White 302 lm, 73 lm/W
Beam spread vertical of 108°, horizontal of 111°.	



LED In-Ground - 4W	
SKU & Finish	16030 BBR27 - 10° 16031 BBR27 - 35° 16032 BBR27 - 60°
SKU & Finish	16030 BBR30 - 10° 16031 BBR30 - 35° 16032 BBR30 - 60°
Watt/VA	4W/5.8VA
Kelvin & Lumens	2700K - Warm White 146 lm, 37 lm/W
Kelvin & Lumens	3000K - Pure White 170 lm, 43 lm/W



LED In-Ground - 6.5W	
SKU & Finish	16033 BBR27 - 10° 16034 BBR27 - 35° 16035 BBR27 - 60°
SKU & Finish	16033 BBR30 - 10° 16034 BBR30 - 35° 16035 BBR30 - 60°
Watt/VA	6.5W/9.3VA
Kelvin & Lumens	2700K - Warm White 306 lm, 47 lm/W
Kelvin & Lumens	3000K - Pure White 348 lm, 54 lm/W



LED In-Ground - 14W	
SKU & Finish	16036 BBR27 - 10° 16037 BBR27 - 35° 16038 BBR27 - 60°
SKU & Finish	16036 BBR30 - 10° 16037 BBR30 - 35° 16038 BBR30 - 60°
Watt/VA	14W/18.5VA
Kelvin & Lumens	2700K - Warm White 520 lm, 37 lm/W
Kelvin & Lumens	3000K - Pure White 590 lm, 42 lm/W



LED Well Light - 4.5W	
SKU & Finish	15767 BKT - 10° 15768 BKT - 35° 15769 BKT - 60°
Watt/VA	4.5W/7.5VA
Kelvin & Lumens	3000K - Pure White 150 lm, 33 lm/W



LED In-Ground - 8.5W	
SKU & Finish	15728 BKT - 10° 15747 BKT - 35° 15748 BKT - 60°
Watt/VA	8.5W/12.2VA
Kelvin & Lumens	3000K - Pure White 310 lm, 36 lm/W



LED In-Ground - 12.4W	
SKU & Finish	15729 BKT - 10° 15757 BKT - 35° 15758 BKT - 60°
Watt/VA	12.4W/16.7VA
Kelvin & Lumens	3000K - Pure White 460 lm, 37 lm/W



2-in-1 Water Accent		
SKU & Finish	15711 SS27	15711 SS
SKU & Finish		15711 SS42
Watt/VA	3.4W/4.9VA	
Kelvin & Lumens	2700K - Warm White 135 lm, 40 lm/W	3000K - Pure White 150 lm, 44 lm/W
Kelvin & Lumens		4200K - Cool White 180 lm, 53 lm/W

Path & Spread



Name	Decorative Hammered Roof	
SKU & Finish	15843 CO27 15843 TZT27	15843 CO 15843 TZT
Watt/VA	3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 48 lm/W	3000K - Pure White 182 lm, 49 lm/W



Name	Cast Hammered Roof	
SKU & Finish	15871 BBR27 15871 TZT27	15871 BBR 15871 TZT
Watt/VA	3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 48 lm/W	3000K - Pure White 182 lm, 49 lm/W



Name	Fundamentals™	
SKU & Finish	15839 CO27R 15839 TZT27R	15839 CO30R 15839 TZT30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector



Name	Fundamentals™	
SKU & Finish	16120 AZT27 16120 BBR27 16120 BKT27	16120 AZT30 16120 BBR30 16120 BKT30
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector



Name	Copper Hat	
SKU & Finish	15850 CO27R	15850 CO30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector



Name	Forged	
SKU & Finish	15803 AZT27R	15803 AZT30R
Watt/VA	3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 49 lm/W



Name	Pyramid	
SKU & Finish	15802 TZT27R	15802 TZT30R
Watt/VA	3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 49 lm/W



Name	Ripley™	
SKU & Finish	15800 AZT27R 15800 BBR27R	15800 AZT30R 15800 BBR30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W



Name	Shallow Shade Small	
SKU & Finish	15805 BKT27R	15805 BKT30R
Watt/VA	4W/5.8VA	
Kelvin & Lumens	2700K - Warm White 126 lm, 31 lm/W	3000K - Pure White 140 lm, 35 lm/W



Name	Shallow Shade Large	
SKU & Finish	15806 BKT27R	15806 BKT30R
Watt/VA	4W/5.8VA	
Kelvin & Lumens	2700K - Warm White 126 lm, 31 lm/W	3000K - Pure White 140 lm, 35 lm/W



Name	Broad Roof	
SKU & Finish	15833 AZT27R	15833 AZT30R
Watt/VA	4W/5.8VA	
Kelvin & Lumens	2700K - Warm White 126 lm, 31 lm/W	3000K - Pure White 140 lm, 35 lm/W



Name	Side Mount	
SKU & Finish	15815 AZT27R 15815 BKT27R	15815 AZT30R 15815 BKT30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W



Name	Side Mount Cast Brass	
SKU & Finish	15827 BBR27R	15827 BBR30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W



Center Mount	
15826 AZT27R	15826 AZT30R
15826 BKT27R	15826 BKT30R
4.3W/5.8VA	
2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector

Glass & Metal	
15817 AZT27R	15817 AZT30R
15817 BN27R	15817 BN30R
4.3W/5.8VA	
2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W



Name	6" Dome	
SKU & Finish	15870 AZT27R 15870 BBR27R 15870 BKT27R	15870 AZT30R 15870 BBR30R 15870 BKT30R
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector

8" Dome	
15810 AZT27R	15810 AZT30R
15810 BBR27R	15810 BBR30R
15810 BKT27R	15810 BKT30R
4.3W/5.8VA	
2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector

8" Dome Short Stem	
15811 AZT27R	15811 AZT30R
4.3W/5.8VA	
2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector

Name	Llena™	
SKU & Finish	15820 AZT27 15820 BBR27 15820 CO27	15820 AZT 15820 BBR 15820 CO
Watt/VA	3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 49 lm/W



Llenita™	
15821 AZT27	15821 AZT
15821 BBR27	15821 BBR
15821 CO27	15821 CO
3.8W/4.95VA	
2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 49 lm/W



Tiki	
15801 TZT27R	15801 TZT30R
3.8W/4.95VA	
2700K - Warm White 168 lm, 48 lm/W	3000K - Pure White 182 lm, 49 lm/W



Name	Four Corners	
SKU & Finish	16121 AZT27 16121 BKT27 16121 TZT27	16121 AZT30 16121 BKT30 16121 TZT30
Watt/VA	4.3W/5.8VA	
Kelvin & Lumens	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W

Includes **FM128296BKT** Glare Guard Reflector

Overlay	
16122 AZT27	16122 AZT30
3.8W/4.95VA	
2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 46 lm/W



Perforated	
16123 AZT27 16123 CO27 16123 TZT27	16123 AZT30 16123 CO30 16123 TZT30
3.8W/4.95VA	
2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 46 lm/W

Path & Spread



Name	Round Tiered		Flare		Petal	
SKU & Finish	16124 AGZ27 16124 BKT27 16124 CW27	16124 AGZ30 16124 BKT30 16124 CW30	16125 AZT27 16125 BBR27 16125 CO27	16125 AZT30 16125 BBR30 16125 CO30	16126 AZT27	16126 AZT30
Watt/VA	3.8W/4.95VA		4.3W/5.8VA		3.8W/4.95VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 46 lm/W	2700K - Warm White 294 lm, 68 lm/W	3000K - Pure White 302 lm, 70 lm/W	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 46 lm/W

Includes **FM128296BKT** Glare Guard Reflector



Name	Pierced Dome		Shepherd's Crook		Louvered Bollard	
SKU & Finish	15857 AZT27R	15857 AZT30R	15807 AZT27R 15807 BBR27R	15807 AZT30R 15807 BBR30R	16130 AZT28 16130 BKT28	
Watt/VA	3.8W/4.95VA		4.3W/5.8VA		3.5W/5.67VA	
Kelvin & Lumens	2700K - Warm White 168 lm, 46 lm/W	3000K - Pure White 182 lm, 49 lm/W	2700K - Warm White 294 lm, 67 lm/W	3000K - Pure White 302 lm, 73 lm/W	2800K - Warm White 224 lm, 64 lm/W	



Name	Tee Bollard		Side Throw Bollard		Mission Bollard	
SKU & Finish	16131 AZT28 16131 BKT28		16132 AZT28 16132 BKT28		16133 AZT28 16133 BKT28	
Watt/VA	3.5W/5.67VA		3.5W/5.67VA		3.5W/5.67VA	
Kelvin & Lumens	2800K - Warm White 224 lm, 64 lm/W		2800K - Warm White 224 lm, 64 lm/W		2800K - Warm White 224 lm, 64 lm/W	



Deck & Patio



Name	Vintage Park™	
SKU & Finish	15750 TZT27R	15750 TZT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Decorative Hammered Roof	
SKU & Finish	15763 TZT27R	15763 TZT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Mini Deck Light	
SKU & Finish	15765 AZT27R 15765 BBR27R 15765 BKT27R 15765 WHT27R	15765 AZT30R 15765 BBR30R 15765 BKT30R 15765 WHT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Half Moon	
SKU & Finish	15764 AZT27R 15764 BBR27R 15764 WHT27R	15764 AZT30R 15764 BBR30R 15764 WHT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Fundamentals™	
SKU & Finish	16110 AZT27 16110 BBR27 16110 BKT27 16110 CO27 16110 GRY27 16110 SD27	16110 AZT30 16110 BBR30 16110 BKT30 16110 CO30 16110 GRY30 16110 SD30
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Four Corners	
SKU & Finish	16111 AZT27 16111 BKT27 16111 TZT27	16111 AZT30 16111 BKT30 16111 TZT30
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Overlay	
SKU & Finish	16112 AZT27	16112 AZT30
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Perforated	
SKU & Finish	16113 AZT27 16113 CO27 16113 TZT27	16113 AZT30 16113 CO30 16113 TZT30
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Brick Light (with Louvers)	
SKU & Finish	15773 AZT27R	15773 AZT30R
Watt/VA	1.72W/3.72VA	
Kelvin & Lumens	2700K - Warm White 82 lm, 100 lm/W	3000K - Pure White 86 lm, 102 lm/W



Name	Brick Light (without Louvers)	
SKU & Finish	15774 AZT27R	15774 AZT30R
Watt/VA	1.72W/3.72VA	
Kelvin & Lumens	2700K - Warm White 82 lm, 100 lm/W	3000K - Pure White 86 lm, 102 lm/W



Name	Mini Step Light (with Louvers)	
SKU & Finish	15782 AZT27R 15782 BBR27R 15782 BKT27R 15782 CO27R 15782 WHT27R	15782 AZT30R 15782 BBR30R 15782 BKT30R 15782 CO30R 15782 WHT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W



Name	Mini Step Light (without Louvers)	
SKU & Finish	15780AZT27R	15780 AZT30R
Watt/VA	.86W/1.86VA	
Kelvin & Lumens	2700K - Warm White 41 lm, 50 lm/W	3000K - Pure White 43 lm, 51 lm/W

Portable Lantern with Bluetooth®



Name	South Hope™ LED
SKU & Finish	49473 RZLED
Watt/VA	7W
Kelvin & Lumens	3000K - Pure White 250 lm



Name	Lyndon™ LED
SKU & Finish	49500 BKTLED
Watt/VA	7W
Kelvin & Lumens	3000K - Pure White 250 lm


Hardscape



Name	1 LED Fixture (with Bracket) - 3" L			
SKU & Finish	15744 AZT27 15744 BBR27 15744 CO27	15744 GRY27 15744 SD27 15744 WHT27	15744 AZT30 15744 BBR30 15744 CO30	15744 GRY30 15744 SD30 15744 WHT30
Watt/VA	.19W/.28VA			
Kelvin & Lumens	2700K - Warm White 8.4 lm, 44 lm/W		3000K - Pure White 8.6 lm, 45 lm/W	



Name	3 LED Fixture (with Bracket) - 6.9" L			
SKU & Finish	15745 AZT27 15745 BBR27 15745 CO27	15745 GRY27 15745 SD27 15745 WHT27	15745 AZT30 15745 BBR30 15745 CO30	15745 GRY30 15745 SD30 15745 WHT30
Watt/VA	.75W/1.3VA			
Kelvin & Lumens	2700K - Warm White 34.7 lm, 46 lm/W		3000K - Pure White 44.5 lm, 59 lm/W	

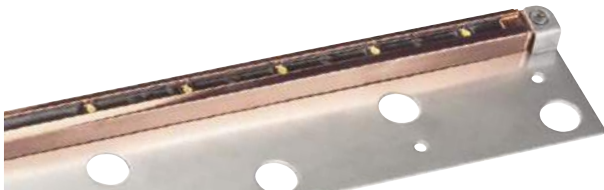

Name	6 LED Fixture (with Bracket) - 12.9" L			
SKU & Finish	15746 AZT27 15746 BBR27 15746 CO27	15746 GRY27 15746 SD27 15746 WHT27	15746 AZT30 15746 BBR30 15746 CO30	15746 GRY30 15746 SD30 15746 WHT30
Watt/VA	1.4W/2.4VA			
Kelvin & Lumens	2700K - Warm White 69.5 lm, 49 lm/W		3000K - Pure White 88 lm, 63 lm/W	



Name	9 LED Fixture (with Bracket) - 18.9" L			
SKU & Finish	15756 AZT27 15756 BBR27 15756 CO27	15756 GRY27 15756 SD27 15756 WHT27	15756 AZT30 15756 BBR30 15756 CO30	15756 GRY30 15756 SD30 15756 WHT30
Watt/VA	2.2W/3.7VA			
Kelvin & Lumens	2700K - Warm White 104.2 lm, 47 lm/W		3000K - Pure White 132 lm, 60 lm/W	

Hardscape



Name	1 LED Fixture (without Bracket) - 3" L	
SKU & Finish	15734 AZT30 15734 BBR30 15734 CO30	15734 GRY30 15734 SD30 15734 WHT30
Watt/VA	.19W/.28VA	
Kelvin & Lumens	3000K - Pure White 8.6 lm, 45 lm/W	



Name	3 LED Fixture (without Bracket) - 6.9" L	
SKU & Finish	15735 AZT30 15735 BBR30 15735 CO30	15735 GRY30 15735 SD30 15735 WHT30
Watt/VA	.75W/1.3VA	
Kelvin & Lumens	3000K - Pure White 44..5 lm, 59 lm/W	



Name	6 LED Fixture (without Bracket) - 12.9" L	
SKU & Finish	15736 AZT30 15736 BBR30 15736 CO30	15736 GRY30 15736 SD30 15736 WHT30
Watt/VA	1.4W/2.4VA	
Kelvin & Lumens	3000K - Pure White 88 lm, 61 lm/W	



Name	9 LED Fixture (without Bracket) - 18.9" L	
SKU & Finish	15755 AZT30 15755 BBR30 15755 CO30	15755 GRY30 15755 SD30 15755 WHT30
Watt/VA	2.2W/3.7VA	
Kelvin & Lumens	3000K - Pure White 132 lm, 62 lm/W	

Accessories

Hardscape



Name	1 LED Flat Mount Bracket
SKU & Finish	15716 SS
Notes	Mounting hardware included



Name	3 LED Flat Mount Bracket
SKU & Finish	15717 SS
Notes	Mounting hardware included



Name	6 LED Flat Mount Bracket
SKU & Finish	15718 SS
Notes	Mounting hardware included



Name	9 LED Flat Mount Bracket
SKU & Finish	15719 SS
Notes	Mounting hardware included

Design Pro LED Controller



Name	Design Pro LED Controller		Design Pro LED Controller	Design Pro LED Controller
SKU	15DC100		15DC200	15DC300
Watt/VA	100W		200W	300W
AC or DC & Output Voltage	Direct current (DC), 15V constant DC		Direct current (DC), 15V constant DC	Direct current (DC), 15V constant DC
	Up to 2 independently controlled zones		Up to 4 independently controlled zones	Up to 6 independently controlled zones

Accessories

Design Pro LED Controller



Name	Remote	Range Extender	#14-2 Wire	#16-2 Wire
SKU	16080 BK	16081 WH	16088 BK	16089 BK
Descr.	Allows the user to independently control lighting zones based on pre-defined programs. This enables the homeowner to temporarily override schedules on individual zones by turning the lights on/off at any given time. Can also be used as a secondary programmer.	Allows for wireless range extension (additional 300') between wireless devices (ex: power supply to power supply). Plugs into any standard 120V outlet (dry location). Compatible with Vera™ Plus and Edge Gateways.	Now 14 and 16 gauge direct burial wire can now be used with Kichler's Design Pro LED Controller. Available in 250' EZ Pull boxes for added convenience. To be used only with the Kichler DesignPro LED Controller. See Kichler DC voltage drop calculator to calculate wire runs.	



Name	Vera™ Edge	Vera™ Plus
SKU	16082 BK	16083 BK
Descr.	50-75 controllable devices; works with smartphone, tablet or computer. Wi-Fi compatible and works with Z-Wave® Plus.	75-125 controllable devices; works with smartphone, tablet or computer. Requires hardwire ethernet connection and works with Z-Wave® Plus.

Low-Voltage Transformers

						
Name	Professional Series		Pro. Series	Pro. Series 2-in-1	Contractor Series	Contractor Series
SKU & Finish	15PR100SS 15PR200SS 15PR300SS	15PR600SS 15PR900SS 15PR1200SS	15PR75SS	15PRD600SS	15CS75SS	15CS150SS 15CS300SS 15CS600SS 15CS900SS 15CS1200SS
Wattage	100W - 1200W		75W	600W	75W	150W - 1200W
Descr.	Output voltage taps 12/13/14/15 Volts		Output voltage tap is 15 Volt only	Output voltage taps 12/13/14/15 Volts	Output voltage taps 12/15 Volts	Output voltage taps 12/13/14/15 Volts

							
Name	Plus Series		Plus Series	Manual Series		Economy Series	In-Ground
SKU & Finish	15PL100AZT 15PL200AZT 15PL300AZT	15PL600AZT 15PL900AZT	15PL75AZT	15M100AZT 15M200AZT	15M300AZT 15M600AZT	15E60BK 15E120BK	15IGT100 15IGT300 15IGT600
Wattage	100W - 900W		75W	100W - 600W		60W, 120W	100W, 300W, 600W
Descr.	Output voltage taps 12/13/14/15 Volts		Output voltage tap is 15 Volt only	Output voltage taps 12 Volts only for 100W-200W. 12/13/15 Volts for 300W & 600W.		Output voltage taps 12/13/14/15 Volts	Output voltage taps 12/13/14/15 Volts

Accessories

Transformers

					
Name	Mechanical Transformer Timer	Plug-in Transformer Photocell	Digital Transformer Timer	Synchronizer Device	Plug-in Transformer Remote Photocell
SKU & Finish	15557 BK	15565 BK	15556 WH	15511 BK	15534 BK
Descr.	Plug-in timer suitable for outdoor temperatures when enclosed in an outdoor transformer enclosure.		Battery backup included. Straight-forward programming and easy daylight savings change over.	Synchronize all transformers used in a landscape setting so they turn on and off at the same time. Jumper wire (not included) should be a min. of 24-gauge.	Plug-in photocell with 10' cord

Compatible with all Professional Series, Contractor Series and Plus Series transformers.

Accent



Name	Mini Accent		MR8 Accent	MR11 Accent
SKU & Finish	15384 AZT 15384 AZT24 15384 BKT	15384 BKT24 15384 CBR 15384 CO	15483 CBR	15484 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen		2W MR8 (18150-18157) Compares up to 15W Halogen	2.5W MR11 (18158-18165) Compares up to 20W Halogen



Name	Long Cowl Mini Accent	Architectural - Grade Adjustable	Micro Accent MR11
SKU & Finish	15484 AZT	15397 AZT	15398 AZT
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	2.5W MR11 (18150-18165)



Name	Accent	Accent	Composite
SKU & Finish	15309 AZT 15309 AZT12 15309 BKT	15374 AZT 15374 AZT20L 15374 AZT20L24	15374 BKT 15374 BKT20L 15374 BKT20L24
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen



Name	MR16 Accent Fixed Socket Adjustable Cowl	MR16 Accent Fixed Socket	Solid Brass Accent
SKU & Finish	15485 CBR	15517 CBR	15475 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen



Name	MR16	Bi-Pin	PAR36 Uplight
SKU & Finish	15381 AZT 15381 AZT6 15381 BBR 15381 BKT	15383 AZT	15487 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen 2W T3/G4 Bi-Pin (18206, 18207) Compares up to 20W Halogen	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18028) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen



Name	PAR36	Adjustable Wide Flood	Miniature Hooded Adjustable Wide Flood
SKU & Finish	15390 AZT	15395 AZT	15396 AZT
LED Lamp Options	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18029) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen	1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen	1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen

Accent



Name	Hooded Adjustable Wide Flood	Solid Brass Mini Wall Wash	Adjustable Wall Wash
SKU & Finish	15385 AZT	15476 CBR	15361 AZT 15361 BKT
LED Lamp Options	1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen	2W T5 Wedge (18120, 18121) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen	2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton 2W S8 Wedge (18203, 18203) Compares up to 20W Krypton



Name	MR16 Downlight	MR16 Mini Downlight	MR16 Mini Downlight
SKU & Finish	15486 CBR	15087 AZT	15093 WHT
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 35W Halogen



Name	Long Cowl Mini Downlight	Solid Hanging Light	Twinkler Hanging Light
SKU & Finish	15494 AZT	15500 CBR	15501 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 35W Halogen	2W MR8 (18150-18157) Compares up to 15W Halogen 2.5W MR11 (18158-18165) Compares up to 20W Halogen 4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen 1.2W Micro Ceramic (18200, 18201) Compares up to 10W Halogen 2W T3/G4 Bi-Pin (18206, 18207) Compares up to 20W Halogen	2W MR8 (18150-18157) Compares up to 15W Halogen 2.5W MR11 (18158-18165) Compares up to 20W Halogen 4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen 1.2W Micro Ceramic (18200, 18201) Compares up to 10W Halogen 2W T3/G4 Bi-Pin (18206, 18207) Compares up to 20W Halogen

In-Ground



Name	MR8 Recessed Basic Trim	MR8 Recessed Louvered	MR8 Recessed with Cowl
SKU & Finish	15490 CBR	15492 CBR	15491 CBR
LED Lamp Options	2W MR-8 (18150-18157) Compares to 15W Halogen	2W MR-8 (18150-18157) Compares to 15W Halogen	2W MR-8 (18150-18157) Compares to 15W Halogen



Name	Brass Trim In-Ground	Brass Beacon In-Ground	Brass Rock Guard In-Ground
SKU & Finish	15495 CBR	15498 CBR	15497 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen



Name	Brass Cowl In-Ground	Brass Side Throw In-Ground	PAR36 Well Brass Trim
SKU & Finish	15496 CBR	15499 CBR	15507 CBR
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18028) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen

In-Ground



Name	PAR36 Well Rock Guard	Solid Brass In-Ground	PAR36 Well
SKU & Finish	15508 CBR	15481 CBR	15088 BK 15088 BK12 Yoke Held Rubber Boot
LED Lamp Options	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18028) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen	4W PAR36 (18126-18133) Compares up to 20W Halogen 5W PAR36 (18134-18141) Compares up to 35W Halogen 7W PAR36 (18142-18149) Compares up to 50W Halogen	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18028) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen



Name	Enclosed PAR36 In-Ground	MR16 Mini In-Ground	MR16 Mini In-Ground with Cowl
SKU & Finish	15194 AZ	15190 BK	15192 BK
LED Lamp Options	4W PAR36 (18166-18173) Compares up to 20W Halogen 6W PAR36 (18174-18181) Compares up to 35W Halogen 10W PAR36 (18182-18189) Compares up to 50W Halogen 11W PAR36 (18021-18028) Compares up to 50W Halogen 14W PAR36 (18190-18197) Compares up to 75W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen

Water Accent



Name	MR16 Well	Underwater
SKU & Finish	15092 BKT	15191 BK
LED Lamp Options	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen	4W MR16 (18126-18133) Compares up to 20W Halogen 5W MR16 (18134-18141) Compares up to 35W Halogen 7W MR16 (18142-18149) Compares up to 50W Halogen

Path & Spread



Name	Adjustable Height Small
SKU & Finish	15502 CBR
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Adjustable Height Large
SKU & Finish	15503 CBR
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Small Hat Brass
SKU & Finish	15506 CBR
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Small Hat Copper
SKU & Finish	15504 CO
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Medium Hat Copper
SKU & Finish	15505 CO
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Solid Brass Traditional
SKU & Finish	15478 CBR
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Solid Brass Missionary
SKU & Finish	15480 CBR
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	6" Dome
SKU & Finish	15470 AZT 15470 BKT 15470 CBR
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	8" Dome
SKU & Finish	15310 AZT 15310 BKT 15310 AZT6
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Dome
SKU & Finish	15410 AZT
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Large Eclipse™
SKU & Finish	15336 BKT 15336 Tzt
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen



Name	Eclipse™
SKU & Finish	15323 AZT 15323 BKT 15323 Tzt
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen

Path & Spread



Name	Side Mount Eclipse™	Side Mount	Center Mount
SKU & Finish	15423 AZT 15423 BKT	15315 AZT 15315 BKT	15326 AZT 15326 BKT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge Mini (18202, 18203) Compares up to 20W Halogen



Name	Large Center Mount	One Tier	Three Tier
SKU & Finish	15328 AZT	15011 AZT	15005 AZT 15005 BKT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge Mini (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen





Name	Galaxy	Adjustable Copper	Decorative Hammered Roof
SKU & Finish	15318 AZT	15350 CO	15443 CO 15443 OB 15443 OB12 15443 TZT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen



Name	Cast Hammered Roof	Fundamentals™	Ribbed Roof
SKU & Finish	15471 BBR 15471 TZT	15439 CO 15439 OB 15439 TZT	15418 AZT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Glass & Metal	Simplicity Side Mount	Mica Mission
SKU & Finish	15317 AZT 15317 BN	15360 AZT	15450 TZT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Thatched Roof	Gate House™	Single-Tier Leaf
SKU & Finish	15401 AZT	15379 OZ	15314 AZT 15314 MST
LED Lamp Options	2W G4/T3 (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen



Path & Spread



Name	Pierced Dome	Pierced Scrollwork	Cotswold™ Convertible-Height Tiki
SKU & Finish	15457 AZT	15437 TZT	15421 AGZ
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Round Lantern	Concord Lantern	Traditional Marine Lantern
SKU & Finish	15367 TZT	15334 OB	15438 OB 15438 OZ
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18202, 18203) Compares up to 20W Halogen



Name	Cross Creek™ Lantern	Intaglio Brass Crook Neck	Lafayette™ Lantern
SKU & Finish	15322 AGZ	15436 OZ	15313 TZG
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Larkin Estate™	Mission Lantern	Zen Garden
SKU & Finish	15444 OZ	15319 PZ	15391 OZ
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 2W T5 Wedge (18204, 18205) Compares up to 20W Halogen



Name	Cathedral
SKU & Finish	15429 TZT
LED Lamp Options	2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton



Name	Almeria™
SKU & Finish	15426 BKT
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon



Name	Tulip
SKU & Finish	15349 MST
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton



Name	Adjustable Crescent
SKU & Finish	15330 OZ
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton



Name	Kentucky
SKU & Finish	15393 OZ
LED Lamp Options	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 16W Xenon



Name	Vintage Park™
SKU & Finish	15369 TZT
LED Lamp Options	2W S8 Wedge (18036, 18037) Compares up to 18.5W Krypton 2W S8 Wedge (18122, 18123) Compares up to 18.5W Krypton



Name	Cotswold™
SKU & Finish	15422 AGZ
LED Lamp Options	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 16W Xenon



Name	Cotswold™ Lantern
SKU & Finish	15420 AGZ
LED Lamp Options	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen 2W T5 Wedge (18204, 18205) Compares up to 16W Xenon



Name	Mission Bollard
SKU & Finish	15458 OZ
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Zen Garden Bollard
SKU & Finish	15392 OZ
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen



Name	Cathedral™ Bollard
SKU & Finish	15449 TZT
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen

Deck & Patio



Name	Mini Deck Light		Full Back Mini Deck Light	Brass Deck Light
SKU & Finish	15065 AZT 15065 BBR	15065 BKT 15065 WHT	15045 AZT	15477 CBR
LED Lamp Options	2W T5 Wedge (18120, 18121) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>		2W T5 Wedge (18120, 18121) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>	2W T5 Wedge (18120, 18121) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen



Name	Half Moon Deck Light		Mini Deck Light	Oak Trail™ Accent
SKU & Finish	15064 AZT 15064 BBR	15064 WHT	15165 AZ	15047 OZ
LED Lamp Options	2W G4/T3 Bi-Pin (18124, 18125) Compares up to 20W Halogen 1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>		2W T5 Wedge (18120, 18121) Compares up to 16W Xenon 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>



Name	Zen Garden™ Deck Post		Larkin Estate™ Deck Post	Adjustable Under Deck Rail
SKU & Finish	15071 OZ		15474 OZ	15077 AZT
LED Lamp Options	2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen <i>Light distribution may be affected by location of sockets</i>		2W T5 Wedge (18039, 18040) Compares up to 16W Xenon 1.2W T3/G4 (18200, 18201) Compares up to 10W Halogen 2W T3/G4 (18206, 18207) Compares up to 20W Halogen <i>Light distribution may be affected by location of sockets</i>	2W S8 Wedge (18202, 18203) Compares up to 20W Halogen




Name	Louvered Down Deck Rail	Up/Down Accent Deck Light	Barbecue Light
SKU & Finish	15066 AZT 15066 WHT	15079 AZT	15123 BK
LED Lamp Options	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen	1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen	2.5W MR11 (18158-18165)



Name	Louvered Brick Light	Acrylic Lens Brick Light	Mini Louvered Step Light	Mini Acrylic Lens Step Li
SKU & Finish	15073 AZT	15074 AZT	15072 AZT 15072 WHT	15070 AZT
LED Lamp Options	2W G4/T3 Bi-Pin (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen 2W T3/G4 Bi-Pin (18206, 18207) <i>Light distribution may be affected by location of sockets</i>	2W G4/T3 Bi-Pin (18042, 18043) Compares up to 20W Halogen 1.2W T3/G4 Bi-Pin (18200, 18201) Compares up to 10W Halogen 2W T3/G4 Bi-Pin (18206, 18207) <i>Light distribution may be affected by location of sockets</i>	2W T5 Wedge (18204, 18205) Compares to 20W Halogen 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>	2W T5 Wedge (18204, 18205) Compares to 20W Halogen 1.2W T5 Wedge (18198, 18199) Compares up to 10W Halogen <i>Light distribution may be affected by location of sockets</i>

Accessories

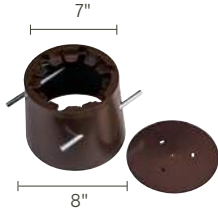

Name	Concrete Installation Kit
------	---------------------------

SKU & Finish	16501 BBRP
--------------	------------


Notes	For use with fixtures 4W, 6.5W & 14W – 16030, 16031, 16032, 16033, 16034, 16035, 16036, 16037, 16038
-------	--



Fixture Mounting Stems	.25-18 NPSM Thd.	.5" Dia. Overall
------------------------	------------------	------------------

15651 AZT, BKT	12"
15652 AZT, BKT	18"
15653 AZT, BKT	24"

Notes	.5-14 NPSM stems will require additional Coupler (15649) or Elbow (15647) for accent light use
-------	--

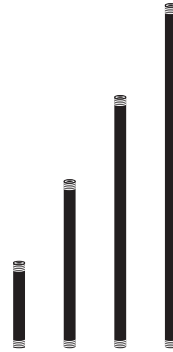

Fixture Mounting Stems	.5-14 NPSM Thd.	.75" Dia. Overall
------------------------	-----------------	-------------------

15645 AZT, BBR, BKT	6"
15656 AZT, BBR, BKT	12"
15657 AZT, BBR, BKT	18"
15658 AZT, BBR, BKT	24"

Notes	.5-14 NPSM stems will require additional Coupler (15649) or Elbow (15647) for accent light use
-------	--



Adjustable Height Stems

15570 AZT, BKT

Notes	.5-14 NPSM stems will require additional Coupler (15649) or Elbow (15647) for accent light use. Extends from 18" to 33".
-------	--



Name	Bollard Mounting Kit
------	----------------------

15665 AZT, BKT	18"
15666 AZT, BKT	24"
15667 AZT, BKT	36"

Notes	For use with fixtures: 15005, 15011, 15205, 15211
-------	---



Bollard Template Kit

15671 ST

Notes	For use with fixtures: 16130, 16131, 16132, 16133
-------	---



Bollard Mounting Stake

15578 BK	23" H
----------	-------

Notes	For use with fixtures: 16130, 16131, 16132, 16133
-------	---



Polymeric Support Stakes

15575 BK	8" H in-ground stake
15576 BK	14" H in-ground stake

Notes	
-------	--



Name	Elbow
------	-------

15647 AZT	
15647 BBR	
15647 BKT	

Notes	1.18" W x 2.09" H x 1.35" L
-------	-----------------------------



Stem Coupler

15649 AZT	
15649 BBR	
15649 BKT	

Notes	1.5" x .5-14 NPSM Thd. For use with .5" NPSM stems.
-------	---



Surface Mounting Flange

15601 AZT	15601 BKT
15601 BBR	15601 WHT

Notes	4" Dia. x .5-14 NPSM Thd.
-------	---------------------------



Flange Mounting Nipple

15602 AL

Notes	1" x .5-14 NPSM Thd.
-------	----------------------



Name	Surface Mounting Bracket
------	--------------------------

15607 AZT	15607 BKT
15607 BBR	15607 WHT

Notes	1.5" x 2.5" x 1" .5-14 NPSM Thd.
-------	----------------------------------



Out of Water Bracket

15577 SS

Notes	2.52" W For use with fixture: 15711 SS
-------	--



Multi-Fixture Weighted Base

15776 BK

Notes	3.375" W For use with fixture: 15711 SS
-------	---



Single Fixture Weighted Base

15778 BK

Notes	3.375" W For use with fixture: 15711 SS
-------	---



Name	Junction Box Mounting Bracket		Gutter Mount	3" Round Mounting Base	Male/Female Riser	
SKU & Finish	15609 AZT 15609 BKT	15609 CBR 15609 WHT	15489 CBR	15493 CBR	15509 CBR 15510 CBR 15511 CBR 15512 CBR 15513 CBR	3" 6" 12" 18" 24"
Notes	2.39" W x 5.56" H		2.75" W x .75" H x 4" L		No couplers needed	



Name	90° Elbow	Two Fixture Mount	Surface/Tree Bracket	Amber Lens
SKU & Finish	15514 CBR	15515 CBR	15516 CBR	16071 AMB 16072 AMB 15875 AMB
Notes	.5" W x .5" H x 2.75" L	2" W x 1" H x 2" L	1.5" W x 1.25" H x 6" L	For use with: 16015-16017 16018-16020 16150-16158 For integrated LED fixtures



Name	Green Foliage Lens	Frosted Lens	Frosted Lens	Red Lens
SKU & Finish	16071 GRN 16072 GRN 15885 GRN	For use with: 16015-16017 16018-16020 16150-16158 16071 FRO 16072 FRO 15895 FRO	For use with: 16015-16017 16018-16020 16150-16158 15672 FRO 15676 FRO 15633 FRO 15643 FRO 15691 FRO 16079 FRO	For use with: 16015-16017 16018-16020 16150-16158 15382 15092, 15384, 15484, 15494 15398 15374 15381 15361, 15861 16071 RD 16072 RD 15875 RD
Notes	For integrated LED fixtures	For integrated LED fixtures	For retrofit fixtures	For integrated LED fixtures



Name	Holiday Green Lens	Blue Lens	Linear Lens
SKU & Finish	16071 HGRN 16072 HGRN 15875 HGRN	For use with: 15398 15374 15382 15092, 15384, 15484, 15485, 15494 15381 15397 15631 BL 15641 BL 15673 BL 15686 BL 15687 BL 15693 BL	For use with: 15382 15092, 15384, 15484, 15494 15398 15374 15381 15674 LN 15675 LN 15632 LN 15642 LN 15692 LN
Notes	For integrated LED fixtures	For retrofit fixtures	For retrofit fixtures

Accessories




Name	Polycarbonate Lens		Heat-Resistant Lens		Cowl - Polycarbonate		Cowl - Cast Brass	
SKU & Finish	15677 CLR 15695 CLR	For use with: 15827 (Int. LED) 15315 (Retrofit)	15659 AZT 15689 BK	For use with: 15079 15088, 15388	16050 BBRP	For use with: 16030-16038	16050 BBR	For use with: 16030-16038
Notes					2.5" H		2.5" H	



Name	Small Long Cowl		Large Long Cowl		Small 360° Cowl		Large 360° Cowl	
SKU & Finish	16067 AZT 16067 BKT 16067 CBR	For use with: 16015-16017	16068 AZT 16068 BKT 16068 CBR	For use with: 16018-16020	16069 AZT 16069 BKT 16069 CBR	For use with: 16015-16017	16074 AZT 16074 BKT 16074 CBR	For use with: 16018-16020
Notes	2.4" H		5.75" H		1.8" H		4.4" H	



Name	Long Cowl		Rock Guard - Polycarbonate		Rock Guard - Cast Brass		Rock Guard	
SKU & Finish	16076 AZT 16076 BKT 16076 CBR	For use with: 16150-16158	16051 BBRP	For use with: 16030-16038	16051 BBR	For use with: 16030-16038	15787 BK	For use with: 15767, 15769, 15728, 15748, 15729, 15757, 15758
Notes	2.4" H						5.9" Dia., 1.686" H For Integrated LED fixtures	

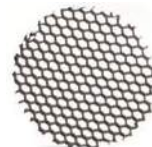

Name	Rock Guard		Rock Guard		Rock Guard - Solid Brass with Clear Lens		Hexcell Louver	
SKU & Finish	15694 AZ	For use with: 15194, 15268	15690 BK	For use with: 15088, 15388	15482 CBR	For use with: 15481	15634 BK 15644 BK 15679 BK 15680 BK 15683 BK	For use with: 15398 15374 15092, 15384, 15484, 15494 15381 15397
Notes	6.97" Dia., 1.29" H For retrofit fixtures		5.9" Dia., 1.686" H For retrofit fixtures		4.5" Dia., 1" H For retrofit fixtures		For retrofit fixtures	



Name	Hexcell Louver	Hexcell Louver	Low-Voltage Cable	Gel-Filled Wire Connectors
SKU & Finish	16073 BK 16075 BK	For use with: 16015-16017 16018-16020 FM127265	For use with: 15810, 15811, 15826, 15839, 15850, 15870, 16120, 16121, 16125 15501 BK 100' 12-gauge 15502 BK 250' 12-gauge 15503 BK 250' 8-gauge 15504 BK 250' 10-gauge 15505 BK 500' 12-gauge 15506 BK 1000' 12-gauge	15579 BK 8 & 10-gauge cable 15589 BK 12-gauge
Notes	For integrated LED fixtures	For use with path lights utilizing the downward module		



Name	QUICK DISC® Connector	Pro Series Wire Connector	Low-Voltage Power Conditioner (LVPC)	Kichler Landscape Flag Marker	Corrosion Preventative Compound
SKU & Finish	15509 BK	15529 BL	16059 BK	15507 ONG	15670 BK
Notes	For use with #12-2 or #10-2 low-voltage cable only	Bulk pack of 100 connectors, packed in sealed bags of 10.	Master pack of 5		



LED Lamps

LAMP	ITEM #	BASE/ LAMP TYPE	WATTS	KELVIN/LUMENS (lm for Bare Lamps)	BEAM ANGLE/ITEM #			
					15° Spot	25° Narrow Flood	40° Flood	60° Wide Flood
	18150, 18152, 18154, 18156	MR8 Bi-Pin Damp Location D	2W, 3.1VA Compares up to 15W Halogen	2700K - Warm White 140 lm	18150	18152	18154	18156
	18151, 18153, 18155, 18157			3000K - Pure White 150 lm	18151	18153	18155	18157
	18158, 18160, 18162, 18164	MR11 Bi-Pin Damp Location D	2.5W, 3.8VA Compares up to 20W Halogen	2700K - Warm White 180 lm	18158	18160	18162	18164
	18159, 18161, 18163, 18165			3000K - Pure White 180 lm	18159	18161	18163	18165
	18126, 18128, 18130, 18132	MR16 Damp Location D	4W, 5.4VA Compares up to 20W Halogen	2700K - Warm White 285 lm	18126	18128	18130	18132
	18127, 18129, 18131, 18133			3000 - Pure White 285 lm	18127	18129	18131	18133
	18134, 18136, 18138, 18140	MR16 Damp Location D	5W, 6.6VA Compares up to 35W Halogen	2700K - Warm White 365 lm	18134	18136	18138	18140
	18135, 18137, 18139, 18141			3000K - Pure White 365 lm	18135	18137	18139	18141
	18142, 18144, 18146, 18148	MR16 Damp Location D	7.2W, 9.9VA Compares up to 50W Halogen	2700K - Warm White 615 lm	18142	18144	18146	18148
	18143, 18145, 18147, 18149			3000K - Pure White 615 lm	18143	18145	18147	18149
	18166, 18168, 18170, 18172	PAR36 Wet Location W	4.2W, 6.3VA Compares up to 20W Halogen	2700K - Warm White 290 lm	18166	18168	18170	18172
	18167, 18169, 18171, 18173			3000K - Pure White 290 lm	18167	18169	18171	18173
	18174, 18176, 18178, 18180	PAR36 Wet Location W	6W, 8.5VA Compares up to 35W Halogen	2700K - Warm White 475 lm	18174	18176	18178	18180
	18175, 18177, 18179, 18181			3000K - Pure White 475 lm	18175	18177	18179	18181
	18182, 18184, 18186, 18188	PAR36 Wet Location W	10W, 13.2VA Compares up to 50W Halogen	2700K - Warm White 700 lm	18182	18184	18186	18188
	18183, 18185, 18187, 18189			3000K - Pure White 700 lm	18183	18185	18187	18189
	18021, 18024, 18027	PAR36/AR111 Wet Location W	10W, 13.2VA Compares up to 50W Halogen	2700K - Warm White 620 lm	18021	18024	18027	--
	18022, 18025, 18028			3000K - Pure White 620 lm	18022	18025	18028	--
	18190, 18192, 18194, 18196	PAR36 Wet Location W	14W, 19.2VA Compares up to 75W Halogen	2700K - Warm White 1090 lm	18190	18192	18194	18196
	18191, 18193, 18195, 18197			3000K - Pure White 1090 lm	18191	18193	18195	18197

LAMP	ITEM #	BASE/ LAMP TYPE	WATTS	KELVIN/LUMENS (lm for Bare Lamps)	BEAM ANGLE/ITEM #s	
					300° Omni-Directional	
	18036	S8 Wedge Wet Location 	2W, 2.9VA	2700K - Warm White / 95 lm	18036	
	18037		Compares up to 18.5W Krypton	3000K - Pure White / 95 lm	18037	
	18039	T5 Wedge Wet Location 	2W, 2.9VA	2700K - Warm White / 95 lm	18039	
	18040		Compares up to 16W Xenon	3000K - Pure White / 95 lm	18040	
	18042	G4/T3 Bi-Pin Wet Location 	2W, 2.9VA	2700K - Warm White / 95 lm	18042	
	18043		Compares up to 20W Halogen	3000K - Pure White / 95 lm	18043	
					120° Beam Angle	
	18122	S8 Wedge* Wet Location 	1.5W, 2.4VA	2700K - Warm White / 130 lm	18122	
	18123		Compares up to 18.5W Krypton	3000K - Pure White / 130 lm	18123	
	18120	T5 Wedge* Wet Location 	1.5W, 2.4VA	2700K - Warm White / 130 lm	18120	
	18121		Compares up to 16W Xenon	3000K - Pure White / 130 lm	18121	
	18124	G4/T3 Bi-Pin* Wet Location 	1.5W, 2.4VA	2700K - Warm White / 130 lm	18124	
	18125		Compares up to 20W Halogen	3000K - Pure White / 130 lm	18125	
LAMP	ITEM #	BASE/ LAMP TYPE	WATTS	KELVIN/LUMENS (lm for Bare Lamps)	BEAM ANGLE/ITEM #s	
					180°	300°
	18198	T5 Wedge Mini Ceramic Wet Location 	1W, 1.2VA	2700K - Warm White / 85 lm	18198	--
	18199		Compares up to 10W Halogen	3000K - Pure White / 85 lm	18199	--
	18200	T3/G4 Bi-Pin Micro Ceramic Wet Location 	1W, 1.2VA	2700K - Warm White / 85 lm	18200	--
	18201		Compares up to 10W Halogen	3000K - Pure White / 85 lm	18201	--
	18204	T5 Wedge High Lumen Mini Wet Location 	2.3W, 3.3VA	2700K - Warm White / 215 lm	--	18204
	18205		Compares up to 20W Halogen	3000K - Pure White / 215 lm	--	18205
	18202	S8 Wedge High Lumen Mini Wet Location 	2.3W, 3.3VA	2700K - Warm White / 215 lm	--	18202
	18203		Compares up to 20W Halogen	3000K - Pure White / 215 lm	--	18203
	18206	T3/G4 Bi-Pin High Lumen Mini Wet Location 	2.3W, 3.3VA	2700K - Warm White / 215 lm	--	18206
	18207		Compares up to 20W Halogen	3000K - Pure White / 215 lm	--	18207
	18208	BA15 Single Contact High Lumen Mini Wet Location 	2.3W, 3.3VA	2700K - Warm White / 215 lm	--	18208
	18209		Compares up to 20W Halogen	3000K - Pure White / 215 lm	--	18209

Accent & Flood



Name	C-Series Small Accent - 5.3W	
SKU & Finish	16209 AZT30 - 15° Spot 16209 BKT30 - 15° Spot 16210 AZT30 - 40° Flood 16210 BKT30 - 40° Flood 16211 AZT30 - 55° Wide Flood 16211 BKT30 - 55° Wide Flood	16209 AZT40 - 15° Spot 16209 BKT40 - 15° Spot 16210 AZT40 - 40° Flood 16210 BKT40 - 40° Flood 16211 AZT40 - 55° Wide Flood 16211 BKT40 - 55° Wide Flood
	5.3W/.9pf	
Kelvin & Lumens	3000K - Pure White 478 lm, 93 lm/W	4000K - Cool White 514 lm, 100 lm/W



Name	C-Series Small Accent - 10W	
SKU & Finish	16212 AZT30 - 15° Spot 16212 BKT30 - 15° Spot 16213 AZT30 - 40° Flood 16213 BKT30 - 40° Flood 16214 AZT30 - 55° Wide Flood 16214 BKT30 - 55° Wide Flood	16212 AZT40 - 15° Spot 16212 BKT40 - 15° Spot 16213 AZT40 - 40° Flood 16213 BKT40 - 40° Flood 16214 AZT40 - 55° Wide Flood 16214 BKT40 - 55° Wide Flood
	10W/.9pf	
Kelvin & Lumens	3000K - Pure White 831 lm, 82 lm/W	4000K - Cool White 942 lm, 91 lm/W



Name	C-Series Large Accent - 14.3W	
SKU & Finish	16215 AZT30 - 15° Spot 16215 BKT30 - 15° Spot 16216 AZT30 - 33° Flood 16216 BKT30 - 33° Flood 16217 AZT30 - 55° Wide Flood 16217 BKT30 - 55° Wide Flood	16215 AZT40 - 15° Spot 16215 BKT40 - 15° Spot 16216 AZT40 - 33° Flood 16216 BKT40 - 33° Flood 16217 AZT40 - 55° Wide Flood 16217 BKT40 - 55° Wide Flood
	14W/.9pf	
Kelvin & Lumens	3000K - Pure White 1263 lm, 90 lm/W	4000K - Cool White 1374 lm, 96 lm/W



Name	C-Series Large Accent - 21W	
SKU & Finish	16218 AZT30 - 15° Spot 16218 BKT30 - 15° Spot 16219 AZT30 - 33° Flood 16219 BKT30 - 33° Flood 16220 AZT30 - 55° Wide Flood 16220 BKT30 - 55° Wide Flood	16218 AZT40 - 15° Spot 16218 BKT40 - 15° Spot 16219 AZT40 - 33° Flood 16219 BKT40 - 33° Flood 16220 AZT40 - 55° Wide Flood 16220 BKT40 - 55° Wide Flood
	21W/.9pf	
Kelvin & Lumens	3000K - Pure White 2015 lm, 97 lm/W	4000K - Cool White 2111 lm, 99 lm/W



Name	Small Accent - 12.5W	
SKU & Finish	16200 BBR30 - 10° 16201 BBR30 - 35° 16206 BBR30 - 60°	16200 BBR40 - 10° 16201 BBR40 - 35° 16206 BBR40 - 60°
	12.5W/.13VA/.85pf	
Kelvin & Lumens	3000K - Pure White 590 lm, 47 lm/W	4250K - Cool White 646 lm, 52 lm/W



Name	Large Accent - 19.5W	
SKU & Finish	16202 BBR30 - 10° 16203 BBR30 - 35° 16207 BBR30 - 60°	16202 BBR40 - 10° 16203 BBR40 - 35° 16207 BBR40 - 60°
	19.5W/.18VA/.90pf	
Kelvin & Lumens	3000K - Pure White 947 lm, 49 lm/W	4250K - Cool White 993 lm, 51 lm/W



Name	Large Accent - 29W	
SKU & Finish	16204 BBR30 - 10° 16205 BBR30 - 35° 16208 BBR30 - 60°	16204 BBR40 - 10° 16205 BBR40 - 35° 16208 BBR40 - 60°
	29W/.27VA/.90pf	
Kelvin & Lumens	3000K - Pure White 1131 lm, 39 lm/W	4250K - Cool White 1368 lm, 47 lm/W

120V only. Cast brass housing.

120V only. Cast brass housing.

120V only. Cast brass housing.



Name	C-Series Small Flood - 12W		C-Series Small Flood - 23W	
SKU & Finish	16221 AZT30 - Knuckle Mount 16221 BKT30 - Knuckle Mount 16221 AZT30TR - Trunnion Mount 16221 BKT30TR - Trunnion Mount 16221 AZT30SL - Slip-Fit Mount 16221 BKT30SL - Slip-Fit Mount	16221 AZT40 - Knuckle Mount 16221 BKT40 - Knuckle Mount 16221 AZT40TR - Trunnion Mount 16221 BKT40TR - Trunnion Mount 16221 AZT40SL - Slip-Fit Mount 16221 BKT40SL - Slip-Fit Mount	16222 AZT30 - Knuckle Mount 16222 BKT30 - Knuckle Mount 16222 AZT30TR - Trunnion Mount 16222 BKT30TR - Trunnion Mount 16222 AZT30SL - Slip-Fit Mount 16222 BKT30SL - Slip-Fit Mount	16222 AZT40 - Knuckle Mount 16222 BKT40 - Knuckle Mount 16222 AZT40TR - Trunnion Mount 16222 BKT40TR - Trunnion Mount 16222 AZT40SL - Slip-Fit Mount 16222 BKT40SL - Slip-Fit Mount
Watt/pf	12W/.9pf		23W/.9pf	
Kelvin & Lumens	3000K - Pure White 1120 lm, 89 lm/W	4000K - Cool White 1210 lm, 100 lm/W	3000K - Pure White 2050 lm, 86 lm/W	4000K - Cool White 2080 lm, 89 lm/W

NEMA 6x5 beam with 88° vertical beam, 126° horizontal beam.



Name	C-Series Medium Flood - 33.5W		C-Series Medium Flood - 52W		C-Series Large Flood - 85W	
SKU & Finish	16223 AZT30 - Knuckle Mount 16223 BKT30 - Knuckle Mount 16223 AZT30TR - Trunnion Mount 16223 BKT30TR - Trunnion Mount 16223 AZT30SL - Slip-Fit Mount 16223 BKT30SL - Slip-Fit Mount	16223 AZT40 - Knuckle Mount 16223 BKT40 - Knuckle Mount 16223 AZT40TR - Trunnion Mount 16223 BKT40TR - Trunnion Mount 16223 AZT40SL - Slip-Fit Mount 16223 BKT40SL - Slip-Fit Mount	16224 AZT30 - Knuckle Mount 16224 BKT30 - Knuckle Mount 16224 AZT30TR - Trunnion Mount 16224 BKT30TR - Trunnion Mount 16224 AZT30SL - Slip-Fit Mount 16224 BKT30SL - Slip-Fit Mount	16224 AZT40 - Knuckle Mount 16224 BKT40 - Knuckle Mount 16224 AZT40TR - Trunnion Mount 16224 BKT40TR - Trunnion Mount 16224 AZT40SL - Slip-Fit Mount 16224 BKT40SL - Slip-Fit Mount	16225 AZT30 - Knuckle Mount 16225 BKT30 - Knuckle Mount 16225 AZT30TR - Trunnion Mount 16225 BKT30TR - Trunnion Mount 16225 AZT30SL - Slip-Fit Mount 16225 BKT30SL - Slip-Fit Mount	16225 AZT40 - Knuckle Mount 16225 BKT40 - Knuckle Mount 16225 AZT40TR - Trunnion Mount 16225 BKT40TR - Trunnion Mount 16225 AZT40SL - Slip-Fit Mount 16225 BKT40SL - Slip-Fit Mount
Watt/pf	33W/.9pf		50W/.9pf		85W/.9pf	
Kelvin & Lumens	3000K - Pure White 3285 lm, 99 lm/W	4000K - Cool White 3495 lm, 104 lm/W	3000K - Pure White 4496 lm, 89 lm/W	4000K - Cool White 4795 lm, 92 lm/W	3000K - Pure White 7529 lm, 89 lm/W	4000K - Cool White 8613 lm, 102 lm/W

NEMA 7x5 beam with 88° vertical beam, 131° horizontal beam.

NEMA 7x6 beam with 110° vertical beam, 131° horizontal beam.

DLC: +10% lm / +3% lm/W

Outdoor



Name	Outdoor Up & Down Lantern	Outdoor Lantern	Outdoor Wall
SKU & Finish	11251 AZT30 11251 BKT30	11250 AZT30 11250 BKT30	11077 AZT 11077 BKT
Watt/VA	15W	11W	15W
Kelvin & Lumens	3000K - Pure White 550 lm, 37 lm/W	3000K - Pure White 350 lm, 32 lm/W	3000K - Pure White 400 lm, 27 lm/W

Accent



Name	Small Accent	Medium Accent	Large Accent
SKU & Finish	15231 AZT 15231 BKT	15241 AZT 15241 BKT	15251 AZT 15251 BKT
LED Lamp Options	7W PAR20 Wet (18081-18086) Compares up to 35W Halogen	12W PAR30L Wet (18111-18116) Compares up to 50W Halogen	17W PAR38 Wet (18093-18098) Compares up to 75W Halogen



Name	Small Compact	Large Compact	Downlight
SKU & Finish	15230 AZT	15250 AZT	15255 AZT
LED Lamp Options	N/A (Incandescent: 35W Max. PAR20 Metal Halide or 50W Max. PAR20 Incandescent)	12W PAR30L Wet (18111-18116) Compares up to 50W Halogen	17W PAR38 Wet (18093-18098) Compares up to 75W Halogen

In-Ground



Name	In-Ground PAR38	Small In-Ground PAR20/PAR30	In-Ground 70W MH Quad-Tap
SKU & Finish	15295 AZ	15268 AZ	15266 AZ
LED Lamp Options	7W PAR20 Wet (18081-18086) Compares up to 35W Halogen 12W PAR30 Wet (18087-18092) Compares up to 50W Halogen 12W PAR30L Wet (18111-18116) Compares up to 50W Halogen 17W PAR38 Wet (18093-18098) Compares up to 75W Halogen	7W PAR20 Wet (18081-18086) Compares up to 35W Halogen 12W PAR30 Wet (18087-18092) Compares up to 50W Halogen 12W PAR30L Wet (18111-18116) Compares up to 50W Halogen	7W PAR20 Wet (18081-18086) Compares up to 35W Halogen 12W PAR30 Wet (18087-18092) Compares up to 50W Halogen 12W PAR30L Wet (18111-18116) Compares up to 50W Halogen

Path & Spread



Name	Three Tier
SKU & Finish	15205 AZT 15205 BKT
LED Lamp Options/ Notes	A19 Damp Location. Available as stem mount, deck mount or as a bollard. Mounting stems and bollard kits sold separately.



Name	Large One Tier
SKU & Finish	15211 AZT 15211 BKT
LED Lamp Options/ Notes	A19 Damp Location. Available as stem mount, deck mount or as a bollard. Mounting stems and bollard kits sold separately.



Name	Eclipse™
SKU & Finish	15236 BKT 15236 TZT
LED Lamp Options/ Notes	A19 Damp Location



Name	Cross Creek™ Lantern
SKU & Finish	15232 AGZ
LED Lamp Options	A19 Damp Location



Name	Traditional Marine Lantern
SKU & Finish	15239 OZ
LED Lamp Options	A19 Damp Location

Outdoor



Name	Outdoor Wall
SKU & Finish	6051 AZ 6051 WH
LED Lamp Options	12W PAR30 Wet (18087-18092) Compares up to 50W Halogen 12W PAR30L Wet (18111-18116) Compares up to 50W Halogen 17W PAR38 Wet (18093-18098) Compares up to 75W Halogen




Name	Outdoor Wall 2-Light
SKU & Finish	6052 AZ 6052 WH
LED Lamp Options	12W PAR30 Wet (18087-18092) Compares up to 50W Halogen 12W PAR30L Wet (18111-18116) Compares up to 50W Halogen 17W PAR38 Wet (18093-18098) Compares up to 75W Halogen

Accessories



Name	Concrete Installation Kit
SKU & Finish	15608 AZ For use with: 15262, 15263, 15266, 15295, 151GT100, 151GT300, 151GT600
Notes	7" D x 5.19" H

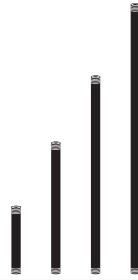

Name	Fixture Mounting Stems .5-14 NPSM Thd. .75" Dia. Overall
SKU & Finish	15645 AZT, BBR, BKT 6" 15656 AZT, BBR, BKT 12" 15657 AZT, BBR, BKT 18" 15658 AZT, BBR, BKT 24"
Notes	.5-14 NPSM stems will require additional Coupler (15649) or Elbow (15647) for accent light use



Name	Power Post®
SKU & Finish	15276 BK For use with: 15205 AZT, 15205 BKT, 15211 AZT, 15211 BKT, 15232 AGZ, 5236 BKT, 15236 TZ, 15239 OB, 15239 OZ and all other .5" NPSM threaded fixtures
Notes	2.25" W x 19" H x 4.375" L



Name	Bollard Mounting Stake
SKU & Finish	15578 BK For use with all bollard mounting kits on 12V and 120V fixtures: 15005, 15205, 15211
Notes	23" H



Name	Bollard Template Kit
SKU & Finish	15671 ST For use with all bollard mounting kits on 12V and 120V fixtures: 15005, 15205, 15211
Notes	



Name	Surface Mounting Flange
SKU & Finish	15601 AZT 15601 BBR 15601 BKT 15601 WHT
Notes	4" D .5-14 NPSM Thd.



Name	Flange Mounting Nipple
SKU & Finish	15602 AL
Notes	.5-14 NPSM Thd.



Name	Junction Box Mounting Bracket
SKU & Finish	15609 AZT 15609 BKT 15609 CBR 15609 WHT
Notes	2.39" W x 5.56" H



Name	Gel Encapsulant
SKU & Finish	15616 WH10 10-pack
Notes	



Name	Blue Lens
SKU & Finish	15623 BL For use with: 15231
Notes	



Name	Well Light Blue Lens Filter
SKU & Finish	15626 For use with: 15262, 15263, 15266, 15295
Notes	



Name	45° Hexcell Louver
SKU & Finish	15638 BK For use with: 15241
Notes	



Name	Rock Guard
SKU & Finish	15688 AZ For use with: 15263, 15264, 15265, 15295
Notes	9.63" Dia. x 1.29" H



Name	LED Long Cowl
SKU & Finish	16060 BBR 16062 BBR For use with 12.5W fixtures: 16200, 16201, 16206 For use with 19.5W & 29W fixtures: 16202, 16203, 16204, 16205, 16207, 16208
Notes	5.8" H



Name	LED 360° Short Cowl
SKU & Finish	16061 BBR 16063 BBR For use with 12.5W fixtures: 16200, 16201, 16206 For use with 19.5W & 29W fixtures: 16202, 16203, 16204, 16205, 16207, 16208
Notes	16061: 3" Dia. x 2.5" H 16063: 4.5" Dia. x 3.25" H







Name	PAR20 Medium Cowl
SKU & Finish	15620 AZT 15620 BKT For use with: 15231
Notes	3.32" L

								
Name	PAR20 Long Cowl		PAR30 Medium Cowl		PAR30 Long Cowl		PAR38 Medium Cowl	
SKU & Finish	15628 AZT 15628 BKT	For use with: 15231	15640 AZT 15640 BKT	For use with: 15241	15648 AZT 15648 BKT	For use with: 15241	15660 AZT 15660 BKT	For use with: 15251, 15255
Notes	7.45" L		3.87" L		8.99" L		4.92" L	

								
Name			PAR20 Cowl			PAR38 Cowl		
SKU & Finish			15630 AZT			15650 AZT		
For use with:			15251, 15255			15230		
Notes			12" L			3.58" L		

120V-277V LED Lamps

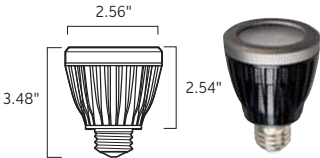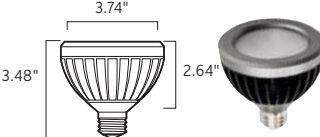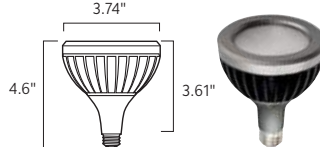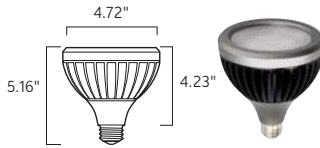LAMP	BASE / LAMP TYPE	WATTS	KELVIN / LUMENS	BEAM ANGLE/ITEM #	
				25° Spot	40° Flood
 2.56" 3.48" 2.54"	PAR20 Wet Location W	7W Compares up to 35W Halogen	2700K – Warm White 310 lm	18081	18084
			3000K – Pure White 330 lm	18082	18085
			4200K – Cool White 350 lm	18083	18086
 3.74" 3.48" 2.64"	PAR30 Wet Location W	12W Compares up to 50W Halogen	2700K – Warm White 580Lm	18087	18090
			3000K – Pure White 610Lm	18088	18091
			4200K – Cool White 640Lm	18089	18092
 3.74" 4.6" 3.61"	PAR30 Longneck Wet Location W	12W Compares up to 50W Halogen	2700K – Warm White 580Lm	18111	18114
			3000K – Pure White 610Lm	18112	18115
			4200K – Cool White 640Lm	18113	18116
 4.72" 5.16" 4.23"	PAR38 Wet Location W	17W Compares up to 75W Halogen	2700K – Warm White 800Lm	18093	18096
			3000K – Pure White 850Lm	18094	18097
			4200K – Cool White 900Lm	18095	18098

W Wet location versions designed and listed for use in an enclosed or open fixture.
Using lamp in enclosed fixtures can result in up to 30-40% loss in lumen output based on test data.

Outdoor Chandeliers & Pendants



Lyndon™

OZ (Olde Bronze™), BA (Brushed Aluminum)



Riverwood™

WZC (Weathered Zinc)



Wright

WZC (Weathered Zinc)



Westington™

OZ (Olde Bronze™)



Halleron™

LD (Londonderry)



Vandalia™

BKT (Textured Black)



Palisades

OZCW (Olde Bronze™, Chestnut Wicker),
OZNW (Olde Bronze™, Natural Wicker)



Outdoor Ceiling Fans



54" Seaside™ LED

AIR PERFORMANCE

Airflow Cubic Ft. Per Minute on High	Power Usage Watts on High (Excludes Lights)	Airflow Efficiency Cubic Ft. Per Minute Per Watt
5627	60	93



60" Rana™ LED

AIR PERFORMANCE

Airflow Cubic Ft. Per Minute on High	Power Usage Watts on High (Excludes Lights)	Airflow Efficiency Cubic Ft. Per Minute Per Watt
8536	70	121



60" Szepló™ II LED (Available in Multiple Sizes)

AIR PERFORMANCE

Airflow Cubic Ft. Per Minute on High	Power Usage Watts on High (Excludes Lights)	Airflow Efficiency Cubic Ft. Per Minute Per Watt
7154	32	225



52" Canfield™ Climates™ (Available in Multiple Sizes and Blade Sets)

AIR PERFORMANCE

Airflow Cubic Ft. Per Minute on High	Power Usage Watts on High (Excludes Lights)	Airflow Efficiency Cubic Ft. Per Minute Per Watt
6231	73	86

Outdoor Wall Lanterns & Posts



River Path™ LED

BKT, OZ



Northland™

BA, BKT



Wayland

WZC



Mill Lane™

AVI



Argyle

WZC



South Hope™

RZ



Ashland Bay

WZC




Andover

WZC

Finishes Guide



AGZ
Aged Bronze

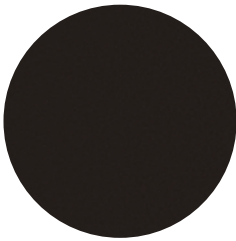

AZ
Architectural
Bronze



AZT
Textured
Architectural Bronze



BBR
Bronzed Brass



BK
Black



BKT
Textured Black



BN
Brushed Nickel



CBR
Centennial Brass




CO
Copper



CW
Crimson Wood



GRY
Textured Gray

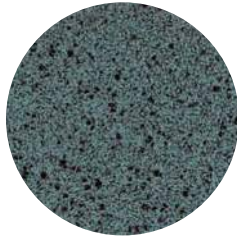

MST
Textured Midnight
Spruce



OB
Olde Brick



OZ
Olde Bronze



PZ
Patina Bronze




SD
Textured Sand



SS
Stainless Steel



TZG
Tannery Bronze
with Gold Accents

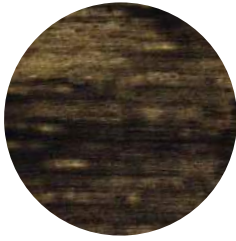

TZT
Textured
Tannery Bronze



WHT
Textured White

Symbols Guide

D **Damp Rating:** Used in sheltered areas that are protected from direct contact with rain, snow or excessive moisture.

W **Wet Rating:** Suitable for direct contact with rain, snow or excessive moisture (such as fog or ocean spray).

LE **Line Extension:** Additional product added to an existing product line.

Dark Sky compliant: Aligns with the International Dark-Sky Association (IDA) standards of reducing light pollution, protecting the night skies for present and future generations.



016 Title 24, Part 6: A document that contains the California Building Energy Efficiency Standards as regulated by the California Energy Commission. Products marked with this logo and labelled as JA8-2016 or JA8-2016-E have been found to meet the requirements stated in 2016 T24, Part 6. For more information, visit www.energy.ca.gov/title24.

FCC Federal Communications Commission devices designated with this logo comply with part 15 of the FCC Rules.

Ceiling Fans Iconography:



1: DC Fan 2: LED Light Kit 3: Climates finish



4: Damp-Rated 5: Wet-Rated 6: ENERGY STAR®



All electrical products are UL/CSA/ or ETL Listed and Certified to UL/CSA Standards for use in U.S.A. and Canada except where noted.



Kichler is a member of the American Lighting Association (ALA), a trade association representing the residential lighting and ceiling fan industries in the United States and Canada. Its membership includes leading lighting and fan manufacturers, showrooms (retailers), manufacturers representatives and designers. ALA members are dedicated to providing the public with the proper application of quality residential lighting.

To serve you better, Kichler® reserves the right to make improvements to products in this catalog. Therefore, some products may change during the life of the catalog and the product information contained in this catalog may also have changed.

CONNECT WITH US



Like us: [facebook.com/Kichler.Lighting](https://www.facebook.com/Kichler.Lighting)

Follow us: twitter.com/KichlerLight

Watch us: [youtube.com/KichlerLighting](https://www.youtube.com/KichlerLighting)

Join us: [houzz.com/pro/KichlerLighting/Kichler](https://www.houzz.com/pro/KichlerLighting/Kichler)

Find us: [pinterest.com/KichlerStyle](https://www.pinterest.com/KichlerStyle)

Follow us: [instagram.com/KichlerLighting](https://www.instagram.com/KichlerLighting)

Kichler

7711 East Pleasant Valley Road
P.O. Box 318010
Cleveland, Ohio 44131-8010
U.S.A.

To find an Authorized Dealer, visit Kichler.com/Landscape

Abbreviation Key

ACAlternating Current

ADAAmericans with Disabilities Act

ANSIAmerican National Standards Institute

AWGAmerican Wire Gauge system

CBCPCenter Beam Candlepower

CLRClear

CRIColor Rendering Index

DDepth

DCDirect Current

FC, fcFoot-candles

FLFlood Light

FROFrosted

HHeight

hrs.Hours

HzHertz

IDInside Diameter

KKelvin temperature

kVKilovolt

LLength

LEDLight Emitting Diode

lmLumens

lm/WLumens per Watt

lpwLumens per Wat

LVPCLow Voltage Power Conditioner

Max.Maximum

NFLNarrow Flood Light

NSPNarrow Spot Light

NPSMNational Pipe & Thread - Straight, Male

ODOutside Diameter

pfPower Factor

SPSpot Light

VVolt

VAVolt-Amp

VNSPVery Narrow Spot Light

VWFLVery Wide Flood Light

WWatt, when directly next to a number

WWidth, when paired with L and/or H

WFLWide Flood Light

Thd.Thread

Kichler.com/Landscape

Our Vision

At Kichler, everything we do, every single day, is with the intention of creating and delivering products that allow people to see what matters most to them. We will do that by relentlessly pursuing ever-better quality, ensuring continued innovation, always going one step further in our commitment to exceptional customer service and education, as well as creating on-trend designs that are both stylish and “life-stylish,” promising to deliver project success for you.

Get inspired at **Kichler.com**

Featured on Front Cover: LED Path Shallow Shade 15806 BKT27 | Page 20

Catalog No. K318 | Printed in USA, 17LD4584-90M | For more information call: 866-558-5706

© The L.D. Kichler Co. All rights reserved. Kichler®. The majority of newer Kichler fixtures are U.S. and Canadian Patent Pending.