



**LED  
Undercabinet  
Lighting**

Commercial Indoor

## Additional Ways to use LED Undercabinet Lighting to Enhance Your Space



\*Add Dimension to Shelves



\*Draw Attention to Merchandising



\*Accent Glass Cabinets



\*Instantly Update Ambiance

## LED Cabinet Lighting Product Images & Features

LED Cabinet lighting can be used for task and accent in a multitude of residential, commercial, retail and hospitality space. Our new and improved cabinet lighting provides higher lumen output, smoother illumination and increased energy efficiency. Use cabinet lighting to create a warm and welcoming ambiance with thoughtful accent lighting, increase productivity in your kitchen or office space with bright task lighting, make sure your trophy case doesn't go unnoticed or set up your in-store merchandising to glow.



### UCEL LED Linkable Cabinet Light

- 388 – 1603 lumens
- 12", 24", 36" and 48" lengths
- Low-profile steel housing in white finish
- On/Off rocker switch



### UCLD LED Linkable Cabinet Light

- 413 – 740 lumens
- 12", 18" and 24" lengths
- Swivel head allows light to be directed to desired area
- Low-profile aluminum housing in white, bronze or brushed nickel finish



### Rayzer™ Modular LED Lighting System

- 324 – 958 lumens
- 9", 12", 18" and 24" lengths
- Can be flush mounted or angled at 30° using included clips
- Slim, low-profile aluminum housing with frosted acrylic diffuser

Each of the cabinet lighting series are easy to install and can be direct wired or powered by cord-and-plug. Create a continuous lighting effect and eliminate shadows by connecting up to 10 feet of fixtures.



## Motion Sensors

### Make Your Work Area Even More Efficient

Gain more efficiency when you add the UC PIR Motion Sensor to the UCLD and UCEL LED Undercabinet lights. With the PIR Motion Sensor, your work space will light up automatically when you need it, and turn off 300 seconds after the last motion is detected. That means you have instant bright task lighting when the area is in use, and reliable energy savings when it is unoccupied.

- Compatible with UCLD and UCEL LED Undercabinet Lights
- Power on warm up time: 15 seconds nominal
- PIR Motion Sensor active during day and night
- Light stays on for 300 seconds nominal after last motion is detected
- Maximum detection range is 15 feet at 90 degree detection angle

Accessories: Order as separate catalog number

UC PIR

PIR Motion Sensor

## UCLD LED Linkable Cabinet Light

### Ordering Information

For shortest lead times, configure products using **bolded options**.

**EXAMPLE:** UCLD 12IN 30K 90CRI SWR BN

UCLD LED					
Series	Length	Color temperature	CRI	Options	Finish
<b>UCLD</b>	<b>12IN</b> 1' Nominal	40K 4000K <sup>1</sup>	<b>90CRI</b> >90	<b>SWR</b> ON/OFF Rocker Switch	<b>WH</b> White
Premium LED Undercabinet	<b>18IN</b> 1.5' Nominal	35K 3500K <sup>2</sup>			<b>BN</b> Brushed Nickel
	<b>24IN</b> 2' Nominal	<b>30K</b> 3000K			
		27K 2700K <sup>2</sup>			


Accessories: Order as separate catalog number.

- UC 5FT POWERCORD WH White 5' cord and plug
- UC 5FT POWERCORD BL Black 5' cord and plug
- UCD JB White Junction/Splice box - allows for quick and easy direct wiring
- UCD JB BL Black Junction/Splice box - allows for quick and easy direct wiring
- UC ERC White 7/8" row connector for end-to-end connections (1 included with each WH fixture)
- UC ERC BL Black 7/8" row connector for end-to-end connections (1 included with each BN fixture)
- UC ERC24 White 24" connector cord for longer length connections between fixtures or splice box (required for splice box to first fixture)
- UC ERC24 BL Black 24" connector cord for longer length connections between fixtures or splice box (required for splice box to first fixture)

### Notes

- 60-day lead time for non-stock color temperatures; minimum 50 order quantity
- 90-day lead time for non-standard color temperatures; minimum 50 order quantity

### Installation

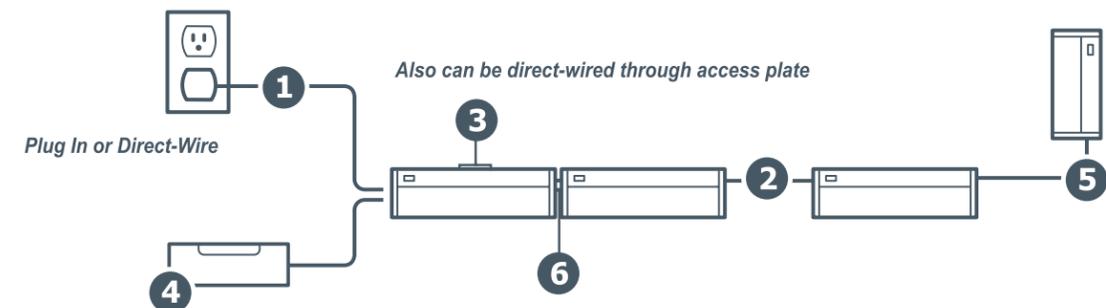

### Included



### Accessories (sold separately)



# UCEL LED Linkable Cabinet Light

## Ordering Information

For shortest lead times, configure products using **bolded options**.

**EXAMPLE:** UCEL 12IN 30K 90CRI SWR WH

UCEL LED					
Series	Length	Color temperature	CRI	Options	Finish
<b>UCEL</b>	<b>12IN</b> 1' Nominal	40K 4000K <sup>1</sup>	<b>90CRI</b> >90	<b>SWR</b> ON/OFF Rocker Switch	<b>WH</b> White
Economy LED Under Cabinet	24IN 2' Nominal	35K 3500K <sup>2</sup>			
	36IN 3' Nominal	<b>30K 3000K</b>			
	48IN 4' Nominal	27K 2700K <sup>2</sup>			


Accessories: Order as separate catalog number.

UC SFT POWERCORD WH	White 5' cord and plug
UCD JB	White Junction/Splice box - allows for quick and easy direct wiring (UC ERC24 also required for splice box to first fixture)
UC ERC	White 7/8" row connector for end-to-end connections (1 included with each fixture)
UC ERC24	White 24" connector cord for longer length connections between fixtures or splice box (required for splice box to first fixture)


### Notes

- 60-day lead time for non-stock color temperatures; minimum 50 order quantity
- 90-day lead time for non-standard color temperatures; minimum 50 order quantity


## Installation

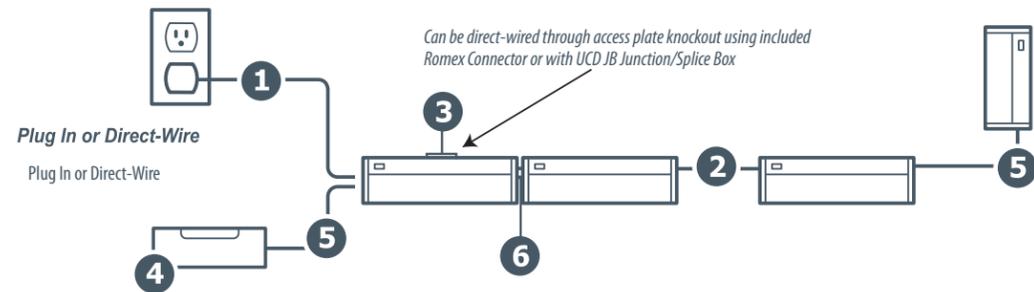

## Included

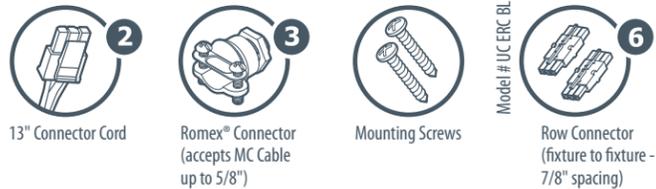

## Accessories (sold separately)

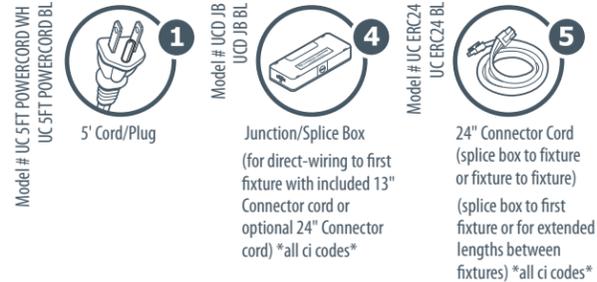

# Rayzer™ Modular LED Lighting System

## Ordering Information

For shortest lead times, configure products using **bolded options**.


**EXAMPLE:** RAZ 12IN 30K 90CRI

Rayzer Modular LED				
Series <sup>1,2</sup>	Length	Color temperature	CRI	Finish
<b>RAZ</b>	<b>9IN</b> 9' Nominal	40K 4000K <sup>1</sup>	<b>90CRI</b> >90	<b>(blank)</b> Brushed Nickel
Rayzer Low Profile LED Undercabinet	12IN 1' Nominal	35K 3500K <sup>2</sup>		
	18IN 1.5' Nominal	<b>30K</b> 3000K		
	24IN 2' Nominal	27K 2700K <sup>2</sup>		

- Notes**
- Link up to 10' of modular system to one transformer
  - Transformer is required for operation

## Accessories/Replacement Parts<sup>1,2</sup>

RAZTRANS24 120	24v transformer - 120v power source, includes 5' cord and plug and 24" connector cord (for linking to first fixture)	RAZ ERC	End row connector (fixture to fixture, 1 3/8" fixture spacing, 2 connectors per pack)
RAZTRANS24 MVOLT	24v transformer - Multi-Volt power source, includes integrated direct-wire junction box and 24" connector cord (for linking to first fixture)	RAZ PHD	Power hub distributor, allows for additional fixture run
RAZDIM	Step dimmer with remote touch pad, 10' cord length on remote touchpad	RAZ INLS26	In-line power switch (transformer to linking cord, 26" cord length)
RAZ CC121	121" Linking cord (fixture to fixture)	UCD JB	Splice box - white (required for 120V direct wire)
RAZ CC24	24" linking cord (fixture to fixture)	UCD JB BL	Splice box - black (required for 120V direct wire)
RAZ CC3	3" linking cord (fixture to fixture)	UC ERC24	24" connector cord - white (required for 120V direct wire for splice box to transformer connection)
RAZLVCC	Low voltage linking cord (cord to cord), to connect multiple linking cords	UC ERC24 BL	24" connector cord - black (required for 120V direct wire for splice box to transformer connection)

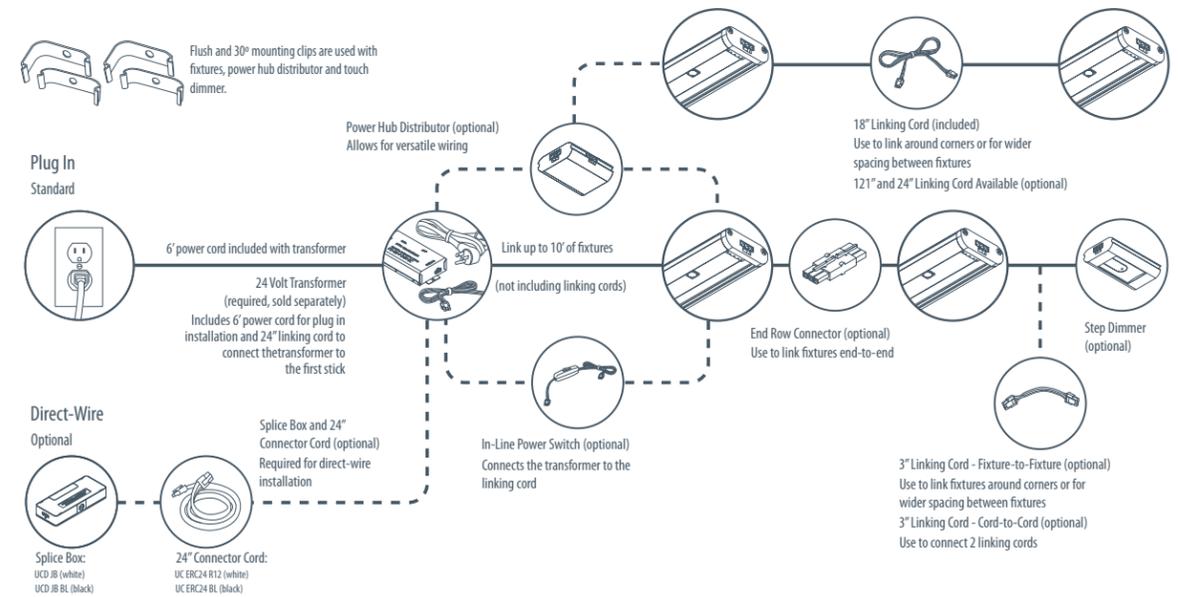



**Lithonia Lighting®** is a member of the Acuity Brands portfolio of lighting, controls and daylighting solutions.

Lithonia Lighting offers one of the industry's broadest lighting portfolios for commercial and industrial lighting applications. Our LED, fluorescent and HID lighting are recognized for their quality, reliability and solid performance, making Lithonia Lighting one of the most specified brands in the lighting industry.

[www.lithonia.com](http://www.lithonia.com)