
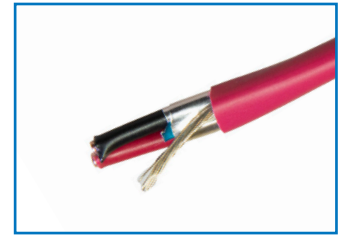
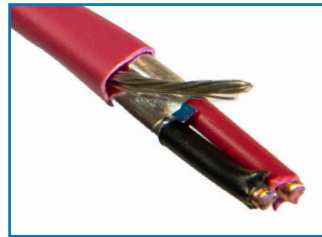


Power Limited-Type FPLP-Plenum Rated, 75°C-300 Volt, Shielded

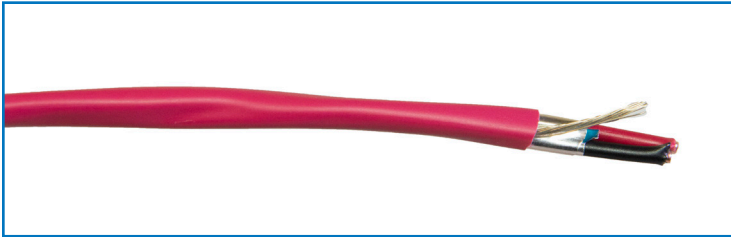

Product Construction

Conductor:

- Solid bare copper

Insulation:

- Color coded OMNIPLEN

Assembly:

- Conductors cabled together

Shield:

- Overall aluminum/polyester shield and drain wire

Jacket:

- Red Omniplen

Applications

- Fire alarm systems
- Smoke detectors
- Burglar alarms
- Dedicated Fire Protective Circuits

Standards

- UL Listed Type FPLP

Part #	AWG	Conductors	Insulation Thickness	Jacket Thickness	Nom. O.D.	Lbs./M'
H11802	18	2	.006"	.016"	.146"	20
H11804	18	4	.006"	.019"	.174"	33
H11806	18	6	.006"	.016"	.204"	48
H11808	18	8	.006"	.019"	.220"	60
H11602	16	2	.008"	.019"	.182"	27
H11604	16	4	.008"	.019"	.210"	52
H11402	14	2	.009"	.019"	.212"	47
H11404	14	4	.009"	.019"	.246"	79
H11202	12	2	.013"	.019"	.242"	68

Note: The data shown is approximate and subject to standard industry and manufacturer tolerances.