


Type			
	-09	-20	-33
P3311	☐	☐	☐
P3312	☐	☐	☐

Catalog No.	Finish			Lamping	Dimensions (Inches)	
	Brushed Nickel	Antique Bronze	Cobblestone		A	B
P3311	-09	-20	-33	1 (m) 60w	12	7
P3312	-09	-20	-33	2 (m) 60w	15-3/4	8-1/4

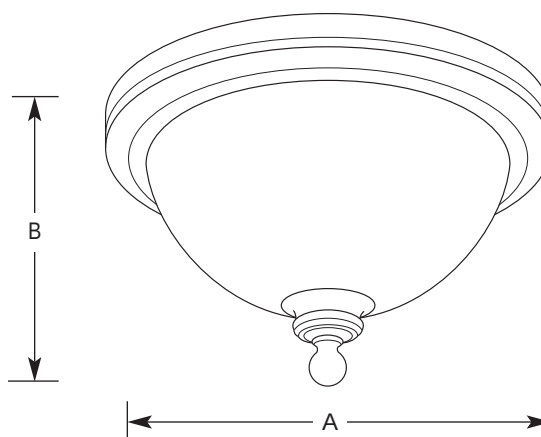

Specifications:

General

- Etched glass
P3311 glass 10" dia. x 4" tall
P3312 glass 13-3/8" dia. x 5" tall
- Hand painted finishes Antique Bronze (-20), Cobblestone (-33)
- Plated finish Brushed Nickel (-09)
- Steel construction
- Center lock up glass
- Companion fixtures: hall & foyer, wall bracket, chandelier

Mounting

- Flush mount ceiling
- Covers outlet box
- Mounting strap for outlet box included

Electrical

- Ceramic sockets
- Pre-wired

Labeling

- UL-CUL damp location listed