



Outdoor Patio Fan

With classic looks, four sizes and an astonishing array of options, the Outdoor Patio Fan is the ideal choice for al fresco entertaining.


FEATURES

Heavy Duty, 3-Speed Reversible Motor
Dual Mount
3" and 6" Downrods (Included)
Limited Lifetime Warranty
Blades Sold Separately
Outdoor Light Kit Adaptable (Optional)
Suitable for Wet Locations

SPECS

Blade Sweep Options. 44", 52", 54", 56"
Number of Blades..... 5
Blade Pitch..... 14°
Motor Size (MM) 188 x 15
AMPS (HI Speed) <1
Shipping Wt. (lbs.)..... 19.4
CU. FT. in Carton 1.53
Airflow*
(Cubic Feet Per Minute)..... 5,522
Watts (HI Speed) 61
Airflow Efficiency*
(CFM Per Watt) 91

CEILING DROP DIMENSIONS

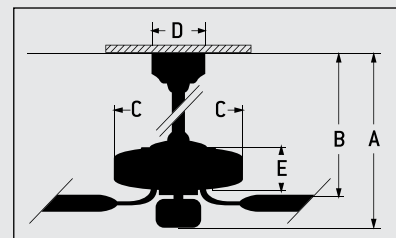

A: 3" DR - 13.5"
A: 6" DR - 15.5"
C: 11.5"
E: 4.5"

B: 3" DR - 10.75"
B: 6" DR - 13.75"
D: 5.125"
DR = Downrod

*Compare: 36" to 48" ceiling fans have airflow efficiencies ranging from approximately 71 to 86 cubic feet per minute per watt at high speed.

*Compare: 49" to 60" ceiling fans have airflow efficiencies ranging from approximately 51 to 176 cubic feet per minute per watt at high speed.



Blades Sold Separately



 
- A

Galvanized Outdoor Patio Fan
Model**OPXL52GV**
Blade**B554T-OLOK-Outdoor
Tropic Isle Light Oak**
Light.**OLK13CFL-GV-Shown,
Sold Separately**
Location.**Suitable for Wet
Locations**
- B

Flat Black Outdoor Patio Fan
Model**OPXL52FB**
Blade**B554PR-DOK-Premier
Rustic Dark Oak**
Light.**OLK3CFL-FB-Shown,
Sold Separately**
Location.**Suitable for Wet
Locations**
- C

Rustic Iron Outdoor Patio Fan
Model**OPXL52RI**
Blade**B552S-ORI-Outdoor
Standard Rustic Iron**
Light.**OLK124CFL-RI-Shown,
Sold Separately**
Location.**Suitable for Wet
Locations**
- D

White Outdoor Patio Fan
Model**OPXL52W**
Blade**B552S-OWH-Outdoor
Standard White**
Light.**OLK3CFL-W-Shown,
Sold Separately**
Location.**Suitable for Wet
Locations**

AVAILABLE FINISHES	BLADE OPTIONS	LIGHT KIT OPTIONS
AW Antique White BR Brown FB Flat Black GV Galvanized Steel RI Rustic Iron W White	Type 1 Blades* (See Pages 354-359)  Type 3 Blades (See Pages 365-366) 	Outdoor Light Kits (see pages 380-381) 
*For Damp Location Only		
FAN CONTROL OPTIONS Not Available		