

GULLIVER



P400158-141 shown with P860041-000 shade

Arching and delicate details curve to create an airy design in new Gulliver options. Dual toned frame color combinations are Galvanized with antique white accents and Graphite with weathered gray accents. The hand painted wood grained texture complements Coastal and Farmhouse home décor. Accessory shades are available in Natural Burlap or Flax Linen options.

FINISHES

- Galvanized Finish - 141
- Graphite - 143

PAIR WITH

Briarwood
Conestee

ALSO AVAILABLE

Complete collection at
progresslighting.com



P350117-141



P350117-141
shown as semi-flush



P500157-141



P400159-141
shown with
P860042-000
shade



P400158-141



P500158-141

SEMI-FLUSH CONVERTIBLE

P350117-141 Galvanized Finish
Hanging and ceiling mount
hardware included.
14-7/8" dia., 12-5/8" ht.,
Overall ht. w/chain 53"; wire 120".
Four candelabra base lamps,
each 60w max.

FIVE-LIGHT CHANDELIER

P400158-141 Galvanized Finish
26" dia., 30" ht.,
Overall ht. w/chain 105-1/2"; wire 180".
Five candelabra base lamps,
each 60w max.

NINE-LIGHT CHANDELIER

P400159-141 Galvanized Finish
35-1/4" dia., 40-1/2" ht.,
Overall ht. w/chain 163-1/2"; wire 180".
Nine candelabra base lamps,
each 60w max.

FOUR-LIGHT FOYER

P500157-141 Galvanized Finish
17" dia., 26-1/4" ht.,
Overall ht. w/chain 102-1/2"; wire 180".
Four candelabra base lamps,
each 60w max.

EIGHT-LIGHT FOYER

P500158-141 Galvanized Finish
21" dia., 33-3/4" ht.,
Overall ht. w/chain 108-1/2"; wire 180".
Eight candelabra base lamps,
each 60w max.

ACCESSORY SHADE

P860041-000 Natural Burlap
1" uno-style candle fitter
6" dia., 5-1/8" ht.

ACCESSORY SHADE

P860042-000 Flax Linen
1" uno-style candle fitter
6" dia., 5-1/8" ht.



P860041-000



P860042-000



P400158-143 shown with P860042-000 shade



P350117-143



P350117-143
shown as semi-flush



P500157-143



P400159-143
shown with
P860041-000
shade



P400158-143



P500158-143

GULLIVER

SEMI-FLUSH CONVERTIBLE

P350117-143 Graphite
Hanging and ceiling mount
hardware included.
14-7/8" dia., 12-5/8" ht.,
Overall ht. w/chain 53"; wire 120".
Four candelabra base lamps,
each 60w max.

FIVE-LIGHT CHANDELIER

P400158-143 Graphite
26" dia., 30" ht.,
Overall ht. w/chain 105-1/2"; wire 180".
Five candelabra base lamps,
each 60w max.

NINE-LIGHT CHANDELIER

P400159-143 Graphite
35-1/4" dia., 40-1/2" ht.,
Overall ht. w/chain 163-1/2"; wire 180".
Nine candelabra base lamps,
each 60w max.

FOUR-LIGHT FOYER

P500157-143 Graphite
17" dia., 26-1/4" ht.,
Overall ht. w/chain 102-1/2"; wire 180".
Four candelabra base lamps,
each 60w max.

EIGHT-LIGHT FOYER

P500158-143 Graphite
21" dia., 33-3/4" ht.,
Overall ht. w/chain 108-1/2"; wire 180".
Eight candelabra base lamps,
each 60w max.

ACCESSORY SHADE

P860041-000 Natural Burlap
1" uno-style candle fitter
6" dia., 5-1/8" ht.

ACCESSORY SHADE

P860042-000 Flax Linen
1" uno-style candle fitter
6" dia., 5-1/8" ht.



P860041-000



P860042-000

GULLIVER



P500023-143



Three circular bands wrap together to create an open design for Gulliver. Dual toned frame color combinations are hand painted Galvanized with antique white accents or Graphite with weathered gray accents. A hand painted wood grained texture complements Rustic and Modern Farmhouse home décor, as well as Urban Industrial and Coastal interior settings.

FINISH

- Galvanized - 141
- Graphite - 143

PAIR WITH

- Ridge
- Trestle



P350049-141



P350049-143



P500022-141




P710031-141



P400097-141



P710031-143

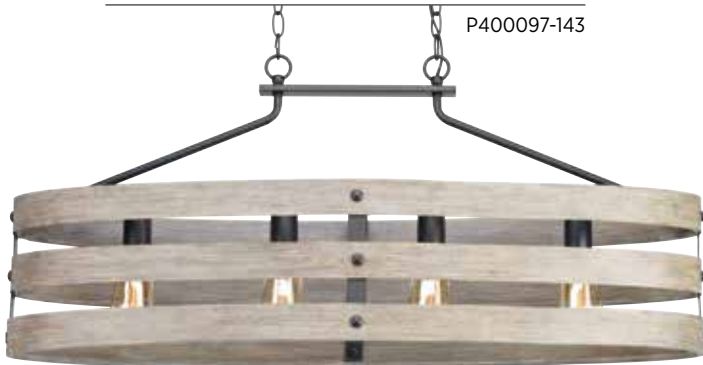

P400097-143



P500090-143



P500090-141

SEMI-FLUSH CONVERTIBLE

P350049-141 Galvanized

P350049-143 Graphite

Hanging and ceiling mount hardware included.

17" dia., 13-1/2" ht.

Overall ht. w/chain 52-1/2", wire 10'.

Three medium base lamps, each 75w max.

FOUR-LIGHT LINEAR CHANDELIER

P400097-141 Galvanized

P400097-143 Graphite

38-1/2" W., 10-1/2" L., 17" ht.

Overall ht. w/chain 91-1/2", wire 15'.

Extends 10-1/2".

Four medium base lamps, each 75w max.

MINI-PENDANT

P500022-141 Galvanized

P500022-143 Graphite

8-1/12" dia., 10" ht.

Overall ht. w/chain 85", wire 10'.

One medium base lamp, 75w max.

FOUR-LIGHT PENDANT

P500023-141 Galvanized

P500023-143 Graphite

21-5/8" dia., 18-1/4" ht.

Overall ht. w/chain 93-1/2", wire 10'.

Four medium base lamps, each 75w max.

FIVE-LIGHT PENDANT

P500090-141 Galvanized

P500090-143 Graphite

27-3/4" dia., 22-3/4" ht.

Overall ht. w/chain 93-1/2", wire 10'.

Five medium base lamps, each 75w max.

WALL BRACKET

P710031-141 Galvanized

P710031-143 Graphite

6" dia., 12" ht.

Extends 7". H/CTR 9-3/8".

One medium base lamp, 75w max.

Fixtures shown with P7825-01 vintage lamps

GULLIVER



P300124-141

Three circular bands wrap together to create an open design for Gulliver. Dual toned frame color combinations are Galvanized with antique white accents or Graphite with weathered gray accents. A hand painted wood grained texture complements Rustic and Modern Farmhouse home décor, as well as Urban Industrial and Coastal interior settings.

ONE-LIGHT BATH
P710031-141 Galvanized
6" dia., 12" ht.
Extends 7". H/CTR 9-3/8".
One medium base lamp, 75w max.

TWO-LIGHT BATH
P300124-141 Galvanized
15-1/2" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Two medium base lamps, 60w max.

THREE-LIGHT BATH
P300125-141 Galvanized
24" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Three medium base lamps, 60w max.

FOUR-LIGHT BATH
P300126-141 Galvanized
32-7/8" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Four medium base lamps, 60w max.



P710031-141



P300125-141
mounted down



P300126-141

FINISHES

- Galvanized - 141
- Graphite - 143

ALSO AVAILABLE IN

Fixture Collections
See complete collection:
ProgressLighting.com



P300124-143
mounted down



P300124-143



P300125-143
mounted down



P710031-143



P300125-143



P300126-143
mounted down



P300126-143

ONE-LIGHT BATH
P710031-143 Graphite
6" dia., 12" ht.
Extends 7". H/CTR 9-3/8".
One medium base lamp, 75w max.

TWO-LIGHT BATH
P300124-143 Graphite
15-1/2" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Two medium base lamps, 60w max.

THREE-LIGHT BATH
P300125-143 Graphite
24" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Three medium base lamps, 60w max.

FOUR-LIGHT BATH
P300126-143 Graphite
32-7/8" W., 8-1/2" ht.
Extends 5". H/CTR 6-1/8".
Four medium base lamps, 60w max.

*Fixtures shown with P7825-01
vintage lamps*

Fixtures mount up or down.

GULLIVER



P250012-141-22 shown with Antique White Wood

P250012-141-22
Galvanized



Antique White Wood

P250012-143-22
Graphite



Gray Wood



Three circular bands wrap together to create an open design for Gulliver. Fan blades enclosed within a stylish cage design gives the rustic charm of a pendant combined with the functionality of a ceiling fan. Dual toned frame color combinations of Galvanized with antique white accents or Graphite with weathered gray accents. A hand painted wood grained texture complements Rustic and Modern Farmhouse home decor, as well as Urban Industrial and Coastal interior settings.

FEATURES

- Limited lifetime warranty
- Dual Mount (flat or sloped ceiling-18.5°)
- AC motor
- Remote control with batteries is included

SIZE

23" dia., 18-1/8" ht.
80" lead wires

FINISHES

- Galvanized -141
- Graphite - 143

ENERGY INFORMATION AT HIGH SPEED

AIRFLOW:	1,297 cubic feet per minute
ELECTRICITY USE:	39 watts (excludes lights)
AIRFLOW EFFICIENCY:	33 cubic feet per minute per watt

LAMPING INFORMATION

Three LED medium base vintage lamps, 2200K, 80 CRI, 5.5w max each, included. (dimnable)



Three-Speed Remote Included
Full-range dimming for light
Three-speed fan operation



Canada



Fan



Damp

Indoor/Outdoor