



Staples

Gardner Bender™ provides a complete line of staple and fastening solutions for all industries, including industrial, residential, construction, or manufacturing. From low voltage wire to service entrance cables, professionals rely on Gardner Bender™ for quality fastening products.



Category 3 & 5 Data Staples.....	159
Coaxial Cable Staples.....	159
Conduit Straps.....	158
Fiber-Insulated Staples	160
Insulated Metal Staples.....	156
Low Voltage Wire Staples.....	158, 160
Masonry Staples	159, 160
Metal Staples	156
MultiCable Staples	157
Plastic Staples	157
Roofing Staples	160
Service Entrance Staples	157
Service Entrance Straps.....	158
Staple Gun	155



INNOVATION

Staples

155

NEW Cable Boss® Staple Gun

- Secures 120V & low-volt cable: Romex®, Coaxial & CAT 5 from the same tool.
- Comfort grip areas for 2-handed operation.
- Easy trigger force.
- Ergonomic handle.
- Secures round and flat cable.
- 3 sizes covering: NM, Coax, Voice/Data, Low Volt.

Patented



Part #	Pkg Qty
MSG-501	1/clam



Size	Part #	Pkg Qty	Color	Application
5/16"	MPS-2080	250/box	Blue	Voice/Data: CAT 5e Speaker Wire: 16/2, 16/4, 12/2 (standard and in-wall styles) Security Wire: 18/4
3/8"	MPS-2100	200/box	White	Coax: RG-6 Voice/Data: CAT 6 NM Cable: 14/2, 14/3, 12/2
1/2"	MPS-2125	200/box	Black	Coax: RG-6 Quad Shield NM Cable: 10/2, 12/3 Structured Cabling: Siamese CAT 5e, Siamese CAT 5e and 16/4 Speaker wire



Low-Volt Staple Gun

- Heavy-duty stainless steel design.
- Safety handle for compact storage.
- Staples cover wide range of wire applications.
- Easy loading.

Part #	Pkg Qty
MSG-301	1/clam



Size	Part #	Pkg Qty	Application
5/32"	MMS-3101	625/box	Use with alarm, bell, intercom, security, speaker, and thermostat wires
1/4"	MMS-3102	625/box	Use with television, CAT 5e, CAT 6, RG-59, and computer wires

IMPROVED Metal Staples

Secures Romex® wire and other types of non-metallic (NM) cable.

- Recessed head drives faster and protects cable insulation.
- Pointed legs drive in straight; will not split wood.
- Preferred length.
- Virtually "Oil-Free" for cleaner handling.
- Sharper tips for easy starting.



Dims W x L	Part #	Pkg Qty	Application
1/2"	MS-1550T	24/card	14/2, 12/2, 10/2
	MS-1555	50/card	
	MS-150	100/box	
	MS-500J	500/jar	
	MS-550	500/box	
	MS-950B	5,000/bucket	
	MS-950BU	10,000/bucket	

Dims W x L	Part #	Pkg Qty	Conductor
9/16"	MS-1575T	18/card	14/3, 12/3, 10/3
	MS-1577	50/card	
	MS-175	100/box	
	MS-450J	450/jar	
	MS-575	500/box	
	MS-975B	5,000/bucket	

Insulated Metal Staples

Secures and protects non-metallic (NM), BX, MC, AC and UF cable.

- Insulator made from durable polyethylene.
- Plastic insulator protects cables and helps prevent arc faults.



Dims W x L	Part #	Pkg Qty	Application
1/2"	MSI-1525T	15/card	14/2 & 12/2 cable
	MSI-50B	50/bag	
	MSI-150	100/box	
	MSI-200JT	200/jar	
	MSI-550	500/box	
	MSI-950B	4,000/bucket	

Dims W x L	Part #	Pkg Qty	Application
9/16"	MSI-1575	15/card	14/3, 12/3, 10/3 cable
	MSI-75	50/bag	
	MSI-1755	175/jar	

Service Entrance Staples

Secures service entrance cables.

- Pointed offset legs drive in straight.
- Will not split wood.

Dims W x L	Part #	Pkg Qty	Application
1 ³ / ₁₆ " x 1 ³ / ₈ "	GSE-15310	10/card	SEU #6/3 with ground
	GSE-5310	25/box	
	GSE-310	100/box	
1 ¹ / ₈ " x 1 ¹ / ₂ "	GSE-15410	10/card	4/3 and 2/3 SE cable
	GSE-4310	25/box	
	GSE-410	100/box	
1 ⁵ / ₈ " x 2 ¹ / ₈ "	GSE-710	100/box	4/0 SE, Large BX, Romex®, Greenfield



Staples

Plastic Staples

Secures Romex®, UF and other types of non-metallic (NM) cable.

- Fast and easy to install – both zinc-plated nails drive together without splitting wood.
- Nail heads are recessed for minimum exposure.
- Smooth saddles prevent damage to insulation.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.



14 Gauge

Size	Part #	Pkg Qty	Color	Application
1/2"	PS-1550T	15/card	White	14/2, 12/2, 10/2
	PS-50	50/bag	White	
	PS-150	100/box	White	
	PS-150Z	100/bag	White	
	PS-150ZJ	100/jar	White	
	PS-225J	225/jar	White	
	PS-250N	250/bag	White	
	PS-550	500/box	White	
	PS-750B	2,000/bucket	White	

Size	Part #	Pkg Qty	Color	Application
3/4"	PS-1575T2	15/card	White	14/3, 12/3, 10/3
	PS-75	50/bag	White	
	PS-175	100/box	White	
	PS-175ZN	100/bag	White	
	PS-175J	175/jar	White	
	PS-275N	250/bag	White	
	PS-575	500/box	White	



INNOVATION

NEW MultiCable Staples

Organizes and secures multiple cable runs on a stud.

- Secures NM/Romex®, coaxial and CAT 5 all on the same st
- Snap lock gate quickly and easily secures all cables.
- Self-centering tab guides perfect placement on the stud.
- Secures with a nail or staple for wood studs, a screw for metal studs.



Patented

Part #	Pkg Qty	Stud Type	Cable Combinations
MCS-20W	20/box	Wood/Metal	(8) NM-B Flat 14-2
MCS-100W	100/box	Wood/Metal	(8) NM-B Flat 12-2
			(4) NM-B Flat 10-2
			(2) NM-B Round 14-3
			(2) NM-B Round 12-3
			(10) RG-59
			(8) RG-6
			(10) CAT-5



Clip-on Plastic Staples

Secures Romex®, UF and other type-NM cable.

- Fast and easy to install – both zinc-plated nails drive together.
- Hardened nails can penetrate cement block, mortar or plaster surfaces.
- Nail heads are recessed for minimum exposure.
- Smooth saddles prevent damage to cable insulation.
- UV-protected polyethylene saddle resists rot, rust and deterioration.




Size	Part #	Pkg Qty	Type	Application
1/2"	PSM-1550T	25/clam	Masonry	14/2, 12/2, 10/2
	PS-50M	50/bag		
	PS-225JM	225/jar		

Size	Part #	Pkg Qty	Type	Application
3/4"	PS-75M	50/bag	Masonry	14/3, 12/3, 10/3
	PS-175JM	175/jar		

Service Entrance Cable Straps

Plastic insulated straps quickly and easily secure service entrance cable.

- Electro-zinc plated nails provide strength and durability.
- Polyethylene straps stabilized against UV rays and extreme cold; withstand deterioration and breakage.

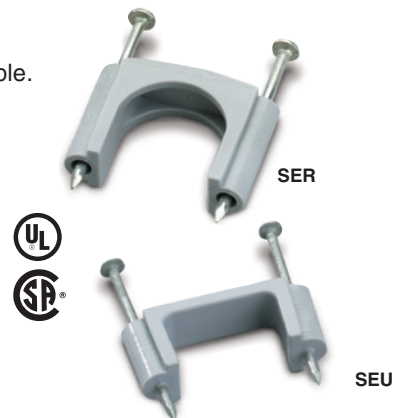

Part #	Pkg Qty	Application	Part #	Pkg Qty	Application
GSE-105	5/card	#6 SEU	GSE-304	4/card	#2 SER
GSE-115	10/box		GSE-314	10/box	
GSE-170	70/box		GSE-330	30/box	
GSE-205	5/card	#2 SEU	GSE-402	2/card	#4/0 SEU
GSE-215	10/box		GSE-505	5/card	#6 SER
GSE-250	50/box		GSE-515	10/box	

Conduit Plastic Straps

Enables secure fastening of plastic electrical conduit, schedule 40 PVC, copper tubing, etc.

- Heavy-duty polyethylene resists deterioration from UV rays and breakage from extreme cold.



Size Dia.	Part #	Pkg Qty	Application
.840"	GCC-120	6/card	1/2" conduit
1.05"	GCC-220	20/bag	3/4" conduit
1.315"	GCC-310	10/bag	1" conduit

Size Dia.	Part #	Pkg Qty	Application
1.66"	GCC-410	10/bag	1 1/4" conduit
1.9"	GCC-510	10/bag	1 1/2" conduit
2.375"	GCC-610	10/bag	2" conduit

Coaxial Cable Staples - Low Voltage

Secures RG-59 and RG-6 coaxial cables.

- UV-resistant polyethylene saddle.
- For indoor and outdoor applications.
- Zinc-plated nails resist rust and corrosion.



Size	Part #	Pkg Qty	Color
1/4"	PSB-1650T	25/card	Black
	PSW-1650T	25/card	White
	PSB-165	50/card	Black
	PSW-165	50/card	White
	PSB-100	100/box	Black
	PSW-100	100/card	White
	PSW-200JN	200/jar	White

Size	Part #	Pkg Qty	Color
1/4"	PCC-1525	25/clam	Black
	PCC-300T	300/jar	Black
7/16"*	PSG-15	15/card	Gray
	PSG-50	50/box	Gray
	PSG-100	100/bag	Gray
	PR-50	50/bag	White

*For RG-8, triaxial and up to 25 pairs UTP cable

Plastic Staples - Low Voltage

Secures bell, speaker, thermostat and telephone wire.

- For inside and outside applications.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Size	Part #	Pkg Qty	Color
3/16"	PLW-1525L1	25/clam	White*
	PMB-1525	25/card	Black*
	PMW-100	100/box	White*
3/16"	PSB-1600T	25/card	Black
	PSW-1600T	25/card	White
	PSB-160	100/card	Black
	PSW-160	100/card	White

*Indicates clip on staples

Masonry Staples - Low Voltage

Secures bell, speaker, thermostat and telephone wire.

- Hardened nails can penetrate cement block, mortar or plaster surfaces.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Size	Part #	Pkg Qty	Color
3/16"	PMC-1525WT	25/clam	White

Category 3 & 5 Data Staples Low Voltage

Secures RJ-11, RJ-12, RJ-45, Category 3 and Category 5 wire.

- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Part #	Pkg Qty	Color
PTP-25T	25/clam	Blue
PTP-100	100/bag	Blue
PTP-250JT	300/jar	Blue



Masonry Category 3 & 5 Data Staples - Low Voltage

Secures and protects RJ-11, RJ-12, RJ-45, Category 3 and Category 5 wire.

- Hardened nails can penetrate cement block, mortar or plaster surfaces.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Part #	Pkg Qty	Color
PTM-25	25/clam	Blue
PTP-100M	100/bag	Blue



Coaxial Masonry Staples - Low Voltage

Secures RG-59 and RG-6 coaxial cables.

- Hardened nails can penetrate cement block, mortar or plaster surfaces.
- UV-Protected.



Size	Part #	Pkg Qty	Color
1/4"	PCS-1525	25/card	Black
	PCS-100	100/box	Black
	PCS-100B	100/bag	Black
	PCS-1600T	25/clam	Black
	PCS-300B	300/jar	Black

Double Coaxial Staples - Low Voltage

Secures multiple RG-59, RG-59 quad shield, RG-6 and RG-6 quad shield wire.

- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Size	Part #	Pkg Qty	Color
1/4"	PDS-1525BT	25/clam	Black

Coaxial Roofing Staples - Low Voltage

Secures RG-59 and RG-6 coaxial cables

- Extra-long nail accommodates roofing applications.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.
- Zinc-plated nails resist rust and corrosion.



Size	Part #	Pkg Qty	Color
1/4"	PSR-25	25/card	Black

Double Coaxial Masonry Staples - Low Voltage

Secures multiple RG-59, RG-59 quad shield, RG-6 and RG-6 quad shield wire.

- Hardened nails can penetrate cement block, mortar and plaster surfaces.
- UV-resistant polyethylene saddles will not rust, rot or deteriorate.



Size	Part #	Pkg Qty	Color
1/4"	PDC-1525BT	25/clam	Black

Fiber Insulated Staples - Low Voltage

Secures bell, speaker, telephone and thermostat wire.

- Insulates and protects cable.



Size	Part #	Pkg Qty	Color
1/8"	MSB-1540	40/card	Brown
	MSW-1540	40/card	White

Kwik Mount Staples - Low Voltage

Fastens and guides wires.

- Wires easily snap in or out of two usable sides.
- Accommodates Category 5 wire.
- Use to secure holiday light sets, sound system wires, etc.



Size	Part #	Pkg Qty
7/8" X 3/16" X 1/4"	PWS-1525	25/card