
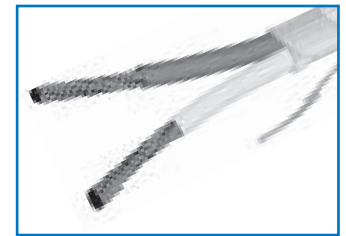


Non-shielded Conductors, Plenum

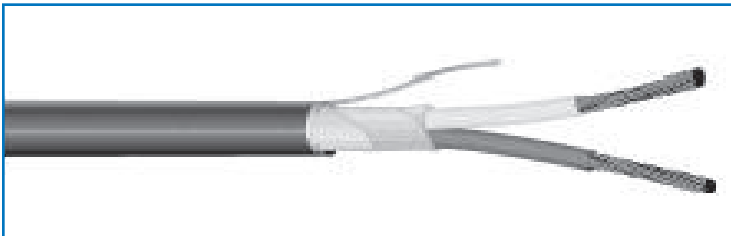

Product Construction

Conductor:

- Stranded Bare Copper

Insulation:

- Plenum

Shield:

- None

Jacket:

- Plenum

Applications

- Power limited control circuits
- Wiring of the following systems:
 - -Intercom
 - -Security
 - -Audio
- Suggested Voltage Rating: 300 Volts

Standards

- NEC Article 725-CL3P, CMP, MPP

COLOR CODE CHART

Cond. #	Color	Cond. #	Color
1	Black	7	Orange
2	Red	8	Yellow
3	White	9	Purple
4	Green	10	Gray
5	Brown	11	Pink
6	Blue	12	Tan

Part #	AWG	Conductors	Insulation Thickness	Jacket Thickness	Nom O.D.	Lbs./M'
G121802	18	2	.008"	.015"	.156"	16
G121803	18	3	.008"	.015"	.166"	23
G121804	18	4	.008"	.015"	.187"	30
G121805	18	5	.008"	.015"	.200"	36
G121806	18	6	.008"	.015"	.216"	43
G121808	18	8	.008"	.015"	.235"	58.2
G121810	18	10	.008"	.015"	.268"	70.6
G121812	18	12	.008"	.015"	.278"	83.2
G121602	16	2	.008"	.015"	.174"	21
G121603	16	3	.008"	.015"	.185"	21
G121604	16	4	.008"	.015"	.205"	38

Note: The data shown is approximate and subject to standard industry and manufacturer tolerances.

Selling Exclusively Through Electrical Distribution Since 1977 | phone: (800) 292-OMNI | website: omnicable.com

Atlanta • Boston • Charlotte • Chicago • Denver • Houston • Los Angeles • Philadelphia • San Francisco • Seattle • St. Louis • Tampa