



Nothing but **HEAVY DUTY.**



THE FASTEST GROWING LITHIUM-ION CORDLESS SYSTEM

The fast growing M18™ LITHIUM-ION cordless system delivers more torque, more power, and longer run-time than the competition, and is backed by an exclusive 5 Year Warranty. Patented technologies and electronics, innovative motor design, and superior ergonomics provide the most efficient combination of power, weight and performance.



M18™ Cordless 1/2" High Performance Hammer Drill Driver Kit

2611-24 (Bare tool 2611-20)

Specifications:

Peak Torque	650 in-lbs
RPM	450 / 1,800
BPM	0 – 28,000
Chuck Type	1/2" Metal Single Sleeve w/ Carbide Jaws
Length	9-1/4"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Side Handle, Carrying Case

M18™ Cordless 1/2" High Performance Drill Driver Kit

2610-24 (Bare tool 2610-20)

Specifications:

Peak Torque	650 in-lbs
RPM	450 / 1,800
Chuck Type	1/2" Metal Single Sleeve w/ Carbide Jaws
Weight	5.53 lbs
Length	9-1/4"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Side Handle, Carrying Case

M18™ Cordless 1/2" Hammer Drill Driver Kit

2602-22 (Bare tool 2602-20)

Specifications:

Peak Torque	550 in-lbs
RPM	450 / 1,700
BPM	0 – 29,000
Chuck Type	1/2" Metal Single Sleeve w/ Carbide Jaws
Length	8-1/2"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries*, 1-Hour Charger, Carrying Case

M18™ Cordless 1/2" Hammer Drill Driver Kit

2602-22CT (Bare tool 2602-20)

Specifications:

Peak Torque	450 in-lbs
RPM	450 / 1,700
BPM	0 – 29,000
Chuck Type	1/2" Metal Single Sleeve w/ Carbide Jaws
Length	8-1/2"



Includes (2) M18™ Compact LITHIUM-ION Batteries*, 30-Minute Charger, Carrying Case

M18™ Cordless Compact Drill Driver Kit

2601-22 (Bare tool 2601-20)

Specifications:

Peak Torque	400 in-lbs
RPM	350 / 1,400
Chuck Type	1/2" Single Sleeve
Weight	3.9 lbs
Length	7-3/4"
Weight	3.9 lbs



Includes (2) M18™ Compact LITHIUM-ION Batteries*, 30-Minute Charger, Carrying Case

M18™ Cordless 3/4" High Torque Impact Wrench Kit

2664-22 (Bare tool 2664-20)

Specifications:

Peak Torque	525 ft-lbs
RPM / IPM	1,900 / 2,200
Anvil	3/4" Friction Ring
Weight	6.8 lbs
Length	9"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Carrying Case

M18™ Cordless 1/2" High Torque Impact Wrench Kit

2663-22 (Bare tool 2663-20)

Specifications:

Peak Torque	450 ft-lbs
RPM / IPM	1,900 / 2,200
Anvil	1/2" Friction Ring
Weight:	6.7 lbs
Length:	8-7/8"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Carrying Case





Nothing but **HEAVY DUTY.**®

M18™ Cordless 1/2" High Torque Impact Wrench Kit 2662-22 (Bare tool 2662-20)

Specifications:

Peak Torque	450 ft-lbs
RPM / IPM	1,900 / 2,200
Anvil	1/2" Pin Detent
Weight:	6.7 lbs
Length:	8-7/8"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Carrying Case

M18™ Cordless 7/16" Hex High Torque Impact Wrench Kit 2665-22 (Bare tool 2665-20)

Specifications:

Peak Torque	350 ft-lbs
RPM / IPM	1,900 / 2,200
Anvil	7/16" Hex
Weight	7 lbs
Length	9-1/2"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Carrying Case

M18™ Cordless 1/2" Compact Impact Wrench Kit 2652-22 (Bare tool 2652-20)

Specifications:

Peak Torque	2,200 in-lbs
RPM / IPM:	2,200 / 3,200
Anvil:	1/2" Pin Detent
Weight:	4.1 lbs
Length:	5-3/4"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries*, 1-Hour Charger, Belt Hook, Carrying Case

M18™ Cordless 3/8" Compact Impact Wrench Kit 2651-22 (Bare tool 2651-20)

Specifications:

Peak Torque	2,000 in-lbs
RPM / IPM	2,200 / 3,200
Anvil	3/8" Friction Ring
Weight	4.1 lbs
Length	5-3/4"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries*, 1-Hour Charger, Belt Hook, Carrying Case

M18™ Cordless 1/4" Hex Compact Impact Driver Kit 2650-22 (Bare tool 2650-20)

Specifications:

Peak Torque	1,400 in-lbs
RPM / IPM	2,200 / 3,200
Anvil	1/4" Hex
Weight	4.1 lbs
Length	5-3/4"



Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries*, 1-Hour Charger, Belt Hook, Carrying Case

M18™ Cordless 1/4" Hex Compact Impact Driver Kit 2650-21 (Bare tool 2650-20)

Specifications:

Peak Torque	1,400 in-lbs
RPM / IPM	2,200 / 3,200
Anvil	1/4" Hex
Weight	3.5 lbs
Length	5-3/4"



Includes (2) M18™ Compact LITHIUM-ION Batteries*, 30-Minute Charger, Belt Hook, Carrying Case




THE POWER OF DPM

When it comes to providing maximum cordless power on the jobsite, nothing comes close to LITHIUM-ION and nothing is better than Milwaukee's M18™ LITHIUM-ION batteries with DPM – Digital Power Management.



DPM Features

- **Overload Protection**
Prevents user from damaging their cordless power tool investment in abusive situations
- **Temperature Management System**
Keeps battery in ideal temperature range to provide maximum life
- **Individual Cell Voltage Monitoring**
Ensures optimal charge and discharge for maximum life
- **Discharge Protection**
Prevents cell damage from over-discharge
- **Battery Fuel Gauge**
Displays remaining run-time

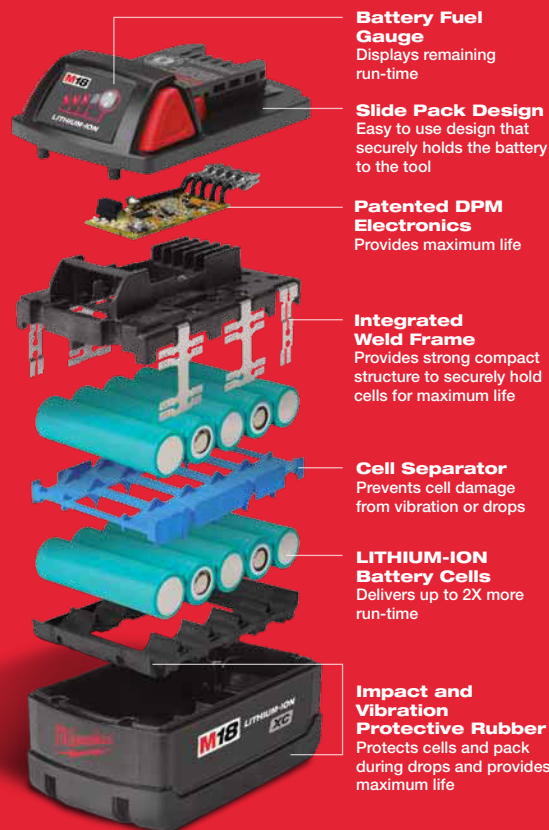

M18™ TOOLS

*Compatible with M18™ XC High Capacity LITHIUM-ION Batteries or M18™ Compact LITHIUM-ION Batteries

SAWZALL® M18™ Cordless Recip Saw Kit

2620-22/2620-21 (Bare tool 2620-20)

Specifications:

SPM	0 – 3,200
Stroke Length	1"
Weight	7.9 lbs
Blade Clamp	Lever Action QUIK-LOK®
Anti-Vibration	YES

Includes

2620-22: (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, SAWZALL® Blade, Carrying Case
2620-21: (1) M18™ XC High Capacity LITHIUM-ION Battery, 1-Hour Charger, SAWZALL® Blade, Carrying Case



M18™ Cordless Band Saw Kit

2629-22 (Bare tool 2629-20)

Specifications:

SFPM	480
Capacity	3-1/4" x 3-1/4"
Weight	10.25 lbs
Material Guide	Tool-Free
Blade Ejection System	YES

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Blade, Carrying Case



HACKZALL® M18™ Cordless One-Handed Recip Saw Kit

2625-21 (Bare tool 2625-20)

Specifications:

SPM	0 – 3,000
Stroke Length	3/4"
Weight	5.6 lbs
Blade Clamp	QUIK-LOK®
Anti-Vibration	YES

Includes (1) M18™ XC High Capacity LITHIUM-ION Battery*, 1-Hour Charger, SAWZALL® Blade, Contractor Bag



HACKZALL® M18™ Cordless One-Handed Recip Saw Kit

2625-21CT (Bare tool 2625-20)

Specifications:

SPM	0 – 3,000
Stroke Length	3/4"
Weight	5.0 lbs
Blade Clamp	QUIK-LOK®
Anti-Vibration	YES

Includes (1) M18™ Compact LITHIUM-ION Battery*, 30-Minute Charger, SAWZALL® Blade, Contractor Bag



M18™ Cordless 6-1/2" Circular Saw Kit

2630-22 (Bare tool 2630-20)

Specifications:

RPM	3,500
Bevel Capacity	50°
Arbor	5/8"
Blade Guards	Magnesium
Shoe	Aircraft Aluminium

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Circular Saw Blade, Rip Fence, Wrench, Contractor Bag



M18™ Cordless 4-1/2" Cut-Off/Grinder Kit

2680-22 (Bare tool 2680-20)

Specifications:

RPM	9,000
Switch	Paddle
Guard Adjustment	Tool-Free
Overload Protection	YES
Handle Positions	3

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Type 1 Guard, Type 27 Guard, Type 1 Cut-Off Wheel, Spanner Wrench, Side-Handle, Contractor Bag



M18™ Cordless Jig Saw Kit

2645-22 (Bare tool 2645-20)

Specifications:

SPM	2,200
Stroke Length	1"
Orbital Settings	5
Blade Clamp	Tool-Free
Bevel Adjustment	45° Tool-Free

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Jig Saw Blade, Non-Marring Shoe, Carrying Case



ProPEX® M18™ Cordless Expansion Tool Kit

2632-22 (Bare tool 2632-20)

Specifications:

Speed	45 SPM
Head Rotation	Built-in Auto Rotator
Capacity	3/8" – 1-1/2"
Compatibility	3/8" – 1" M12, 1" – 1-1/2" M18/Uponor
LED light	YES

Includes (2) M18™ Compact LITHIUM-ION Batteries*, 30-Minute Charger, 1" Expansion Head, 1-1/4" Expansion Head, 1-1/2" Expansion Head, Carrying Case, Grease



ProPEX® is a registered trademark of Uponor, Inc.



**AVAILABLE
FALL 2010**

M18™ ProPEX® Accessory Heads

Specifications:

49-16-2608	M18™ 1" Expansion Head
49-16-2610	M18™ 1-1/4" Expansion Head
49-16-2612	M18™ 1-1/2" Expansion Head

Compatible with M18™ ProPEX® Expansion Tools Only





Nothing but **HEAVY DUTY.**®

Jobsite Radio

2790-20

Specifications:

Powered By	M12™, M18™, M28™, 12V-18V NiCd, AC Outlet
Tuner	Digital Reception with Signal Processor
Speakers	4" High Performance Poly
Display	Digital
Auxiliary Input	1/8" Stereo Jack
Equalizer	Customizable Bass and Treble



Includes 1/8" Auxiliary Input Cord, (2) AA Batteries (For Memory Backup).
Battery and Charger Sold Separately*

M18™ Cordless LED Work Light

2735-20

Specifications:

Light	160 Lumen LED
Optics	Faceted Reflector
Head Rotation	135°
Hands Free	Integrated Hook



Battery and Charger Sold Separately*

M18™ Cordless Work Light

49-24-0171

Specifications:

Bulb	High Intensity Xenon
Optics	Faceted Reflector
Head Rotation	135°
Hands Free	Integrated Hook



Battery and Charger Sold Separately*

RELATED ACCESSORY

LED Upgrade 49-81-0090
Compatible with Milwaukee® M12™, M18™, M28™
and most other power tool work lights



M18™ Cordless Compact LITHIUM-ION Battery

48-11-1815

Specifications:

Battery Type	LITHIUM-ION
Warranty	2-years



M18™ Cordless XC High Capacity LITHIUM-ION Battery

48-11-1828

Specifications:

Battery Type	LITHIUM-ION
--------------	-------------



M18™ Cordless Wet/Dry Vacuum

0880-20

Specifications:

Material	Wet/Dry
Capacity	2 gallons
Max Air Flow	45 cu ft/min
Sealed Suction in Water	32"
Height	11-1/2"



Includes Filter Assembly, Crevice Tool, Wide Utility Nozzle, Hose.
Batteries and Charger Sold Separately*

M18™ LITHIUM-ION Battery Charger

48-59-1801

Specifications:

Charge Time	(48-11-1815) 30-Minutes (48-11-1828) 1-Hour
-------------	--



M18™ AC/DC WALL and Vehicle Charger

2710-20

Specifications:

Charge Time	(48-11-1815) 30-Minutes (48-11-1828) 1-Hour
-------------	--



M18™ Cordless 1/2" Hammer Drill Driver Kit - AC/DC Charger

2602-22DC

Tools included:

1/2" Hammer Drill Driver	2602-20
AC/DC Charger	2710-20

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2695-22

Tools included:

1/2" Hammer Drill Driver	2602-20
HACKZALL® Recip Saw	2625-20

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger,
(1) SAWZALL® Blade, Contractor Bag



*Compatible with M18™ XC High Capacity LITHIUM-ION Batteries or M18™ Compact LITHIUM-ION Batteries

milwaukeeeetool.com 11

M18™ TOOLS



Nothing but **HEAVY DUTY.**®

M18™ Cordless 4-Tool Combo Kit

2690-24

Tools included:

1/2" High Performance Hammer Drill Driver	2611-20
SAWZALL® Recip Saw	2620-20
Circular Saw	2630-20
Work Light	49-24-0171

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, (1) SAWZALL® Blade, (1) Circular Saw Blade, Rip Fence, Wrench, Side Handle, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2690-22

Tools included:

1/2" High Performance Hammer Drill Driver	2611-20
SAWZALL® Recip Saw	2620-20

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, (1) SAWZALL® Blade, Side Handle, Contractor Bag



M18™ Cordless 4-Tool Combo Kit

2692-24

Tools included:

1/2" High Performance Hammer Drill Driver	2611-20
1/4" Hex Impact Driver	2650-20
SAWZALL® Recip Saw	2620-20
Work Light	49-24-0171

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Side Handle, (1) SAWZALL® Blade, Belt Hook, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2694-22

Tools included:

1/2" Hammer Drill Driver	2602-20
SAWZALL® Recip Saw	2620-20

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, (1) SAWZALL® Blade, Contractor Bag



M18™ Cordless 4-Tool Combo Kit

2694-24

Tools included:

1/2" Hammer Drill Driver	2602-20
SAWZALL® Recip Saw	2620-20
Circular Saw	2630-20
Work Light	49-24-0171

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Side Handle, (1) SAWZALL® Blade, (1) Circular Saw Blade, Rip Fence, Wrench, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2697-22

Tools included:

1/2" Hammer Drill Driver	2602-20
1/4" Hex Impact Driver	2650-20

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Belt Hook, Contractor Bag



M18™ Cordless 3-Tool Combo Kit

2696-23

Tools included:

1/2" High Torque Impact Wrench	2663-20
3/8" Compact Impact Wrench	2651-20
Work Light	49-24-0171

Includes (2) M18™ XC High Capacity LITHIUM-ION Batteries, 1-Hour Charger, Belt Hook, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2691-22

Tools included:

1/2" Compact Drill Driver	2601-20
1/4" Hex Impact Driver	2650-20

Includes (2) M18™ Compact LITHIUM-ION Batteries, 30-Minute Charger, Belt Hook, Carrying Case



M18™ Cordless 3-Tool Combo Kit

2691-23

Tools included:

3/8" Compact Impact Wrench	2651-20
1/2" Compact Drill Driver	2601-20
Work Light	49-24-0171

Includes (2) M18™ Compact LITHIUM-ION Batteries, 30-Minute Charger, Belt Hook, Contractor Bag



M18™ Cordless 2-Tool Combo Kit

2693-22

Tools included:

3/8" Compact Impact Wrench	2651-20
Work Light	49-24-0171

Includes (2) M18™ Compact LITHIUM-ION Batteries, 30-Minute Charger, Belt Hook, Contractor Bag





Nothing but **HEAVY DUTY.**®

AVAILABLE FALL 2010



THE LARGEST HIGH VOLTAGE LITHIUM-ION CORDLESS SYSTEM

When superior power and run-time is a necessity, the full line of Milwaukee® M28™ LITHIUM-ION cordless products will provide the performance of corded tools in a durable and reliable cordless package. The patented Digital Power Management (DPM) is the only system that will allow you to perform heavy duty applications without compromising durability or run-time.



M28™ Cordless 1/2" Hammer Drill Driver Kit

0726-22 (Bare tool 0726-20)

Specifications:

Peak Torque	750 in-lbs
RPM (High)	0 – 1,800
RPM (Low)	0 – 450
BPM (High)	0 – 28,800
Chuck Type	1/2" Metal Single Sleeve w/ Carbide Jaws



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, Side-Handle, Carrying Case

M28™ Cordless Band Saw Kit

0729-21 (Bare tool 0729-20)

Specifications:

SFPM (low)	0 – 225
SFPM (high)	0 – 350
Capacity	4-3/4" x 4-3/4"
LED Light	YES



Includes (1) M28™ LITHIUM-ION Battery, 1-Hour Charger, Carrying Case

M28™ Cordless 1" Compact SDS Rotary Hammer Kit

0756-22 (Bare tool 0756-20)

Specifications:

BPM	0 – 4,700
RPM	0 – 1,400
Solid Bit Capacity	1"
Thin Wall Core Bit Capacity	2-1/2"
Tool Weight	9.5 lbs



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, Depth Gauge, Side Handle, Carrying Case

M28™ Cordless 6-1/2" Circular Saw Kit

0730-22 (Bare tool 0730-20)

Specifications:

RPM	4,200
Blade Size	6-1/2"
Blade Guard	Magnesium
Shoe	Aircraft Aluminum
Weight	9.8 lbs



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, Circular Saw Blade, Rip Fence, Wrench, Carrying Case

M28™ Cordless 1/2" Right Angle Drill Kit

0721-21 (Bare tool 0721-20)

Specifications:

Chuck Type	1/2" Keyed
RPM	0 – 400 / 0 – 1,000
Torque	1,081 in-lbs
Tool Weight	10.9 lbs



Includes (1) M28™ LITHIUM-ION Battery, 1-Hour Charger, Chuck Key, Side Handle, Carrying Case

M28™ Cordless Metal Cutting Saw Kit

0740-22 (Bare tool 0740-20)

Specifications:

RPM	3,200
Blade Size	6-7/8"
Shoe	Steel
Blade Guard	Magnesium
Weight	9.4 lbs



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, Circular Saw Blade, Wrench, Carrying Case

SAWZALL® M28™ Cordless Recip Saw Kit

0719-22 (Bare tool 0719-20)

Specifications:

SPM	0 – 2,000 / 0 – 3,000
Stroke Length	1-1/8"
Blade Clamp	QUIK-LOK®
Trigger	Variable
Weight	9.8 lbs



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, (2) SUPER SAWZALL® Blades, Carrying Case



M28™ TOOLS



Nothing but **HEAVY DUTY.**

M28™ Cordless 1/2" High Torque Impact Wrench Kit 0779-22 (Bare tool 0779-20)

Specifications:

Torque	325 ft-lbs
RPM/IPM	0 – 1,450 / 0 – 2,450
Anvil	1/2" Pin Detent
Length	12-1/8"
Trigger	Variable



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, Hanger Bracket w/Steel Ring, Carrying Case

M28™ Cordless LED Work Light 49-24-0187

Specifications:

Light	180 Lumen LED
Optics	Faceted Reflector
Head Rotation	135°
Hands Free	Integrated Hook



Battery and Charger Sold Separately

M28™ Cordless 7/16" Hex High Torque Impact Wrench 0799-20

Specifications:

Torque	325 ft-lbs
RPM/IPM	0 – 1,450 / 0 – 2,450
Anvil	7/16" Hex
Length	12-1/8"
Trigger	Variable



Includes Hanger Bracket w/ Steel Ring. Battery and Charger Sold Separately

M28™ Cordless Work Light 49-24-0185

Specifications:

Bulb	High Intensity Xenon
Optics	Faceted Reflector
Head Rotation	135°
Hands Free	Integrated Hook



Battery and Charger Sold Separately

RELATED ACCESSORY

LED Upgrade 49-81-0090
Compatible with Milwaukee® M12™, M18™, M28™ and most other power tool work lights



M28™ Cordless 4-1/2" Cut-Off/Grinder Kit 0725-21 (Bare tool 0725-20)

Specifications:

RPM	8,000
Trigger	Slide On
Guard	Tool-Free
Overload Protection	YES
Weight	6.8 lbs



Includes (1) M28™ LITHIUM-ION Battery, 1-Hour Charger, Side Handle, Spanner Wrench, Type 1 Cut-Off Wheel & Guard, Type 27 Grinding Wheel & Guard, Contractor Bag

M28™ Cordless Wet/Dry Vacuum 0780-20

Specifications:

Material	Wet/Dry
Capacity	2 Gallons
Air Flow	45 Cu. ft/min
Sealed Suction in Water	32"
Height	11-1/2"



Includes Filter Assembly, Crevice Tool, Wide Utility Nozzle, Hose
Battery and Charger Sold Separately

M28™ Cordless 4-Tool Combo Kit 0928-29

Tools included:

1/2" Hammer Drill Driver	0726-20
SAWZALL® Recip Saw	0719-20
Circular Saw	0730-20
Work Light	49-24-0185



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, (2) SAWZALL® Blades, (1) Circular Saw Blade, Rip Fence, Side Handle, Contractor Bag

M28™ Cordless LITHIUM-ION Battery Pack 48-11-2830

Specifications:

Battery Type	LITHIUM-ION
--------------	-------------



M28™ Cordless 3-Tool Combo Kit 0928-23

Tools included:

1/2" Hammer Drill Driver	0726-20
SAWZALL® Recip Saw	0719-20
Work Light	49-24-0185



Includes (2) M28™ LITHIUM-ION Batteries, 1-Hour Charger, (2) SAWZALL® Blades, Side Handle, Contractor Bag

M28™ LITHIUM-ION Battery Charger 48-59-2819

Specifications:

Charge Time	1 Hour
-------------	--------

