

Hold Tight



4" Clamp-Style Remodel Housing

Economical housing simplifies remodeling

The Juno 4" clamp-style remodel housing is the ideal solution for remodel applications with non-insulated ceilings. This economical 4", 120V housing is designed for fast, simple installation and features factory-installed, screw-driven remodel clamps and a prewired junction box. It installs tightly into 1/8" to 5/8" thick ceilings and won't shift or turn during trim installation or removal. The shallow housing fits easily in 2x6 construction and accepts a wide range of beautiful Juno round or square trims, and can even be used with Juno Basic Series™, 4RLA and 4RLD Retrofit LED trims, which offer energy-cost savings of up to 80%.

Save up to
80%
in energy costs!

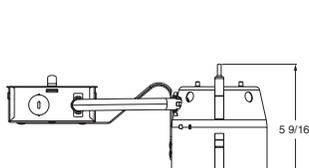
Install with Juno®
Basics Series™
Retrofit LED Trims

Juno®

Juno® 4" Clamp-Style Remodel Housing

The Juno 4" clamp-style remodel housing installs quickly and easily from below in non-insulated ceilings, requiring no access from above. It holds tight during installation of Juno trims, including baffle, cone, decorative, lensed, and square styles.

TC1RC W N Trim Style

Downlight		Lensed		Max. Lamp Rating	
 14 Baffle Series	 17 Cone Series	 13 Pinhole	 11 Drop Opal Series	 12 Frosted Perimeter Lens Series	50W PAR20
Adjustable/Wall Wash					
 10 Flush Gimbal Series	 18 Mini Eyeball Series	 440 Flush Gimbal Series	 445 Slot Aperture Series	 446 Adjustable Scoop Series	 448 Eyeball Series
					10 Series: 50W PAR20, 18 Series: 60W PAR16, 440, 445, 446 and 448 Series: 50W MR16, PAR16, ES16 120V GU10 Base (Requires GU10WHIP)
Decorative					
 4101 Beveled Dome Lensed Series	 4102 Beveled Lensed Series	 4103 Beveled Cylinder Series	 4104 Beveled Cone Series	 4150 Cylinder Series	50W PAR20
Square					
 17SQ Square Downlight Series	 13SQ Square Pinhole Series	 440SQ Square Flush Gimbal Series	 12SQ Square Perimeter Lens Series	17SQ, 13SQ, 12SQ: 50W PAR20, 440SQ: 50W MR16 120V GU10 Base (Requires GU10WHIP)	
VuLite					
 V4034 Baffle Series	 V4017 Clear Cone	 V4010 Flush Gimbal Ring	 V4012 Stippled Opal Lens Shower	V4034, V4017, V4010 and V4012: 50W PAR20, V4018: 60W PAR16, V4040, V4041, V4048: 50W MR16, PAR16, ES16 120V GU10 Base (Requires GU10WHIP)	
 V4018 White Eyeball	 V4040 Gimbal Ring	 V4041 Stippled Opal Lens	 V4048 Eyeball with Baffle		
Retrofit					
 4RLD G2 Basics Series™ Retrofit LED Downlight	 4RLA Basics Series™ Retrofit LED Adjustable				
				<h3>Accessories</h3>  	



©2017 Acuity Brands Lighting, Inc. The marks appearing in this catalog are trademarks of Acuity Brands Lighting, Inc. Products shown in this brochure may be covered by U.S. and international patents and patents pending. Specifications subject to change without notice. Printed in the U.S.A.