


UTILITY STRIP LIGHT (Motion Sensor)

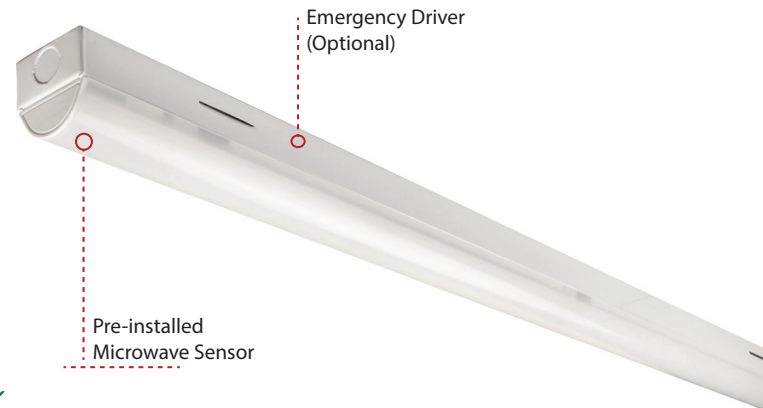

naturaLED® USL with motion sensor provides the perfect solution for your lighting needs. The LED utility strip light maximizes energy savings and is designed for multiple applications including new construction. The LED Utility Strip Light can be used for warehouse, parking garages, stairwells, offices, hallways and many other applications in industrial, commercial and residential. Types of installation include ceiling, wall, chain or cable mounting. Our 4-foot Utility Strip Light is very versatile, efficient and is available in 40-watt, with option and availability for pre-installed motion sensor.



Features & Benefits

- ▶ DLC Qualified
- ▶ L70 Rated Chip for over 100,000 projected life hours
- ▶ Uniform and consistent color: ANSI C78.377-2017
- ▶ UL Damp
- ▶ Easy installation with multiple mounting options
- ▶ Mounting brackets and clips included for ceiling, wall, cable and chain
- ▶ 2KV Surge Protection
- ▶ Material: Aluminum and Opaque lens

Specifications

- ▶ Input line voltage: 120-277V
- ▶ Power Factor: >0.9
- ▶ THD: <20%
- ▶ Dimmable: 0-10V
- ▶ Beam: Flood
- ▶ Operating temperature: -4°F - 131°F
- ▶ Finish: White

Applications



- ▶ Warehouses
- ▶ Pathway Lighting
- ▶ Parking Garage
- ▶ Stairwells and Hallways
- ▶ Retail Lighting

Mountings




Ordering Information

*P= DLC Premium / S = Standard DLC


Code	Description	CCT	Watt	Lumen	Equiv Wattage	Size	Beam Angle	Voltage	Rated Hrs		
9253	LED-FXUSL40/48FR/840/MV-SEN	4000K	40	4,387	Replaces 2 32W T8	2.5"x 48"	110°	120-277	50,000	•	S
7593	LED-FXUSL40/48FR/840/MV	4000K	40	4,387		2.5"x 48"	110°	120-277	50,000	•	S
7594	LED-FXUSL40/48FR/850/MV	5000K	40	4,518		2.5"x 48"	110°	120-277	50,000	•	S

Accessories (available for purchase)

Sensor	Box
<p>P10091 SEN-UM05/ANT5 (Motion Sensor)</p> 	<p>K154091 PLT/MC05 (Kit with MC05 Motion Sensor)</p> <p>P10154: Mount Sensor Box + P10091: Motion Sensor</p> 
<p>7334 BAEM15-48BC-MV-A (Emergency Battery Backup)</p> 	

Photometric Data


40 Watt-5000K-Motion Sensor

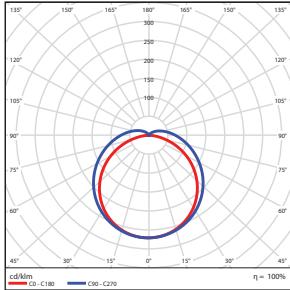


Zonal Lumen Summary

Zone	Lumens	% Luminaire
0-30	935.88	21.30
0-40	1547.93	35.20
0-60	2826.69	64.30
60-80	930.82	21.20
70-80	399.49	9.10
90-120	327.13	7.40
90-180	375.12	8.50
0-180	4397.57	100.00

Total Luminaire Efficiency = 100.00%

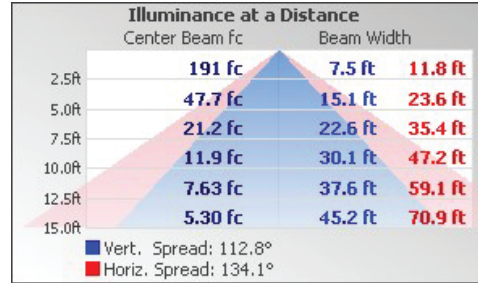


40 Watt-4000K

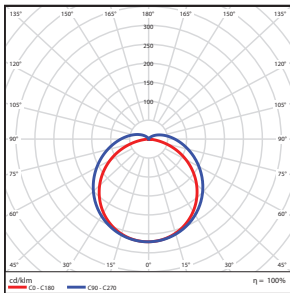


Zonal Lumen Summary

Zone	Lumens	% Luminaire
0-30	935.88	21.30
0-40	1547.93	35.20
0-60	2826.69	64.30
60-80	930.82	21.20
70-80	399.49	9.10
90-120	327.13	7.40
90-180	375.12	8.50
0-180	4397.57	100.00

Total Luminaire Efficiency = 100.00%

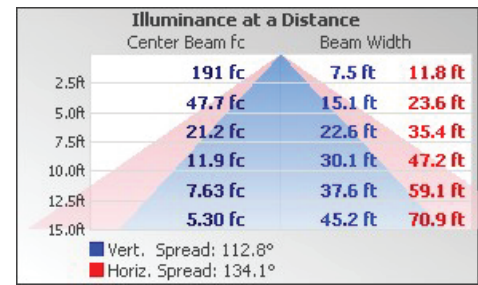


40 Watt-5000K

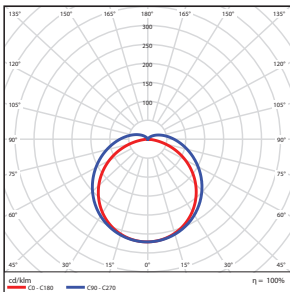

Zonal Lumen Summary

Zone	Lumens	% Luminaire
0-30	935.88	21.30
0-40	1547.93	35.20
0-60	2826.69	64.30
60-80	930.82	21.20
70-80	399.49	9.10
90-120	327.13	7.40
90-180	375.12	8.50
0-180	4397.57	100.00


Total Luminaire Efficiency = 100.00%

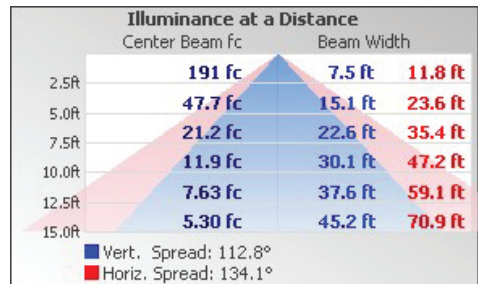

Product Dimensions

4ft

Weight: 3.85 lbs

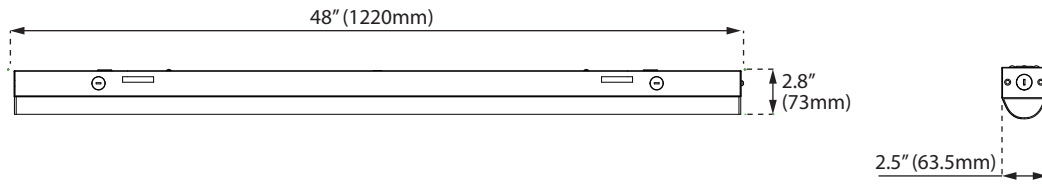

Package

