



Tenant Main Circuit Breakers for GE Meter Mod* III Modular Metering



Your guide to GE's Tenant Main Circuit Breakers

GE tenant main circuit breakers are typically used in residential and light commercial **group metering applications**. This product category offers **2 or 3 pole configurations** with amperage ranging from 60 to 225A, suitable for 125A, 200A or 225A sockets.

Circuit Breaker Specifications


- Up to 42kAIC ratings for 2P
125A sockets at 120/240V
- Up to 100kAIC ratings for 2P
200A sockets at 120/240V
- Up to 100kAIC ratings for 2P &
3P 225A sockets at 240V

Certifications

- UL 489
- CSA 22.2 No. 5



Nomenclature

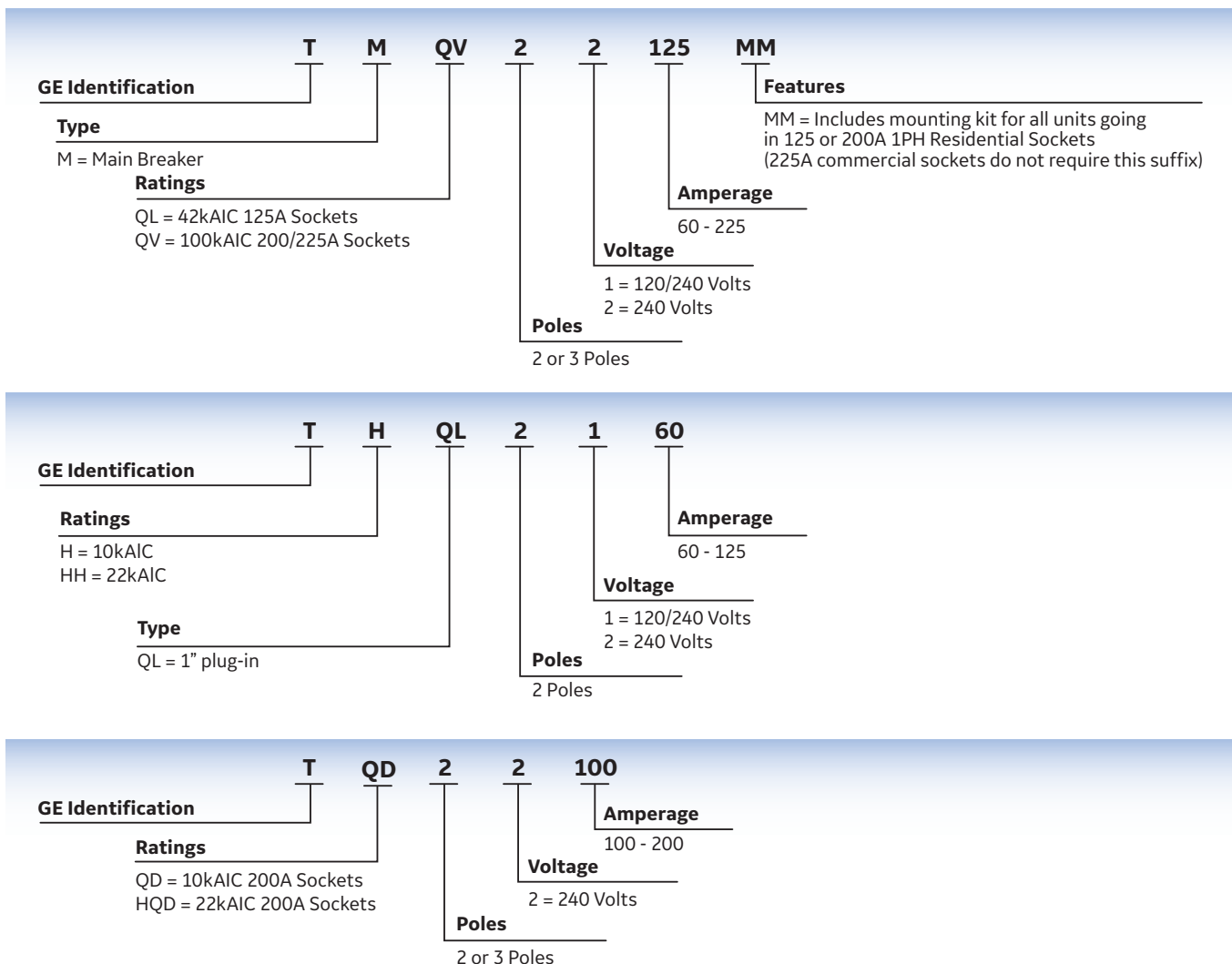

Tenant Main Circuit Breakers for 1PH Residential Meter Modules (800A & 1200A Horizontal Bussing)

Tenant Main Circuit Breakers for 125A, 2 Pole Sockets

Amps	10kAIC	22kAIC	Wire Size
60	THQL2160	THHQL2160	(1) #8-#3 CU; #8-#3AL
70	THQL2170	THHQL2170	(1) #6-1/0 CU; #4-#1/0 AL
80	THQL2180	THHQL2180	
90	THQL2190	THHQL2190	
100	THQL21100	THHQL21100	(1) #2-2/0 CU; #2-2/0 AL
110	THQL21110	THHQL21110	-
125	THQL21125	THHQL21125	(1) #2-2/0 CU; #2-2/0 AL

Amps	QL 42 kAIC	Wire Size
60	TMQL2160	#8-#1 (Cu) or #8-1/0 (Al)
70	TMQL2170	
80	TMQL2180	
90	TMQL2190	
100	TMQL2100	
110	TMQL2110	2/0 - #14
125	TMQL2125	

Tenant Main Circuit Breakers for 200A, 2 Pole Sockets

Amps	10kAIC	22kAIC	Wire Size
100	TQD22100	THQD22100	(1) #1-300 CU; #1-300 AL
125	TQD22125	THQD22125	
150	TQD22150	THQD22150	
175	TQD22175	THQD22175	
200	TQD22200	THQD22200	



Amps	QD Old Catalog # - Obsolete. Replaced by QV.	QV 100 kAIC New Catalog #	Wire Size
60	-	TMQV22060MM	#14-1/0 only
70	TMQD22070	TMQV22070MM	#4-4/0 only
80	TMQD22080	TMQV22080MM	
90	TMQD22090	TMQV22090MM	
100	TMQD22100	TMQV22100MM	
110	-	TMQV22110MM	
125	TMQD22125	TMQV22125MM	std = #4-4/0 ¹
150	TMQD22150	TMQV22150MM	
175	TMQD22175	TMQV22175MM	
200	TMQD22200	TMQV22200MM	

¹For 175A-200A use TMQV225L2 to get 300MCM terminals.

Tenant Main Circuit Breakers for 1PH Commercial Meter Stack Modules (1200A Horizontal Bussing)

Tenant Main Circuit Breakers for 225A, 2 Pole Sockets

Amps	10kAIC	Wire Size
15	TEB122015	(1) #14-3 CU; #12-1 AL
20	TEB122020	
25	TEB122025	
30	TEB122030	
35	TEB122035	
40	TEB122040	
45	TEB122045	
50	TEB122050	(1) #6/20 CU; #4-2/0 AL
60	TEB122060	
70	TEB122070	
80	TEB122080	(1) #1-300 CU; #1-300 AL
90	TEB122090	
100	TQD22100	
125	TQD22125	
150	TQD22150	
175	TQD22175	Use TMQV
200	TQD22200	
225	Use TMQV	

Amps	22kAIC	Wire Size
100	THQD22100	(1) #1-300 CU; #1-300 AL
125	THQD22125	
150	THQD22150	
175	THQD22175	
200	THQD22200	
225	Use TMQV	

Tenant Main Circuit Breakers for 200A/225A, 2 Pole Sockets

Amps	QD Old Catalog # - Obsolete. Replaced by QV.	QV 100 kAIC New Catalog #	Wire Size
60	–	TMQV22060MM	#14-1/0 only
70	TMQD22070	TMQV22070MM	#4-4/0 only
80	TMQD22080	TMQV22080MM	
90	TMQD22090	TMQV22090MM	
100	TMQD22100	TMQV22100MM	
110	–	TMQV22110MM	
125	TMQD22125	TMQV22125MM	std = #4-4/0 ²
150	TMQD22150	TMQV22150MM	
175	TMQD22175	TMQV22175MM	
200	TMQD22200	TMQV22200MM	
225	TMQD22225	TMQV22225MM	

² For 175A-225A use TMQV225L2 to get 300MCM terminals.



Tenant Main Circuit Breakers for 3PH Commercial Meter Stack Modules (1200A Horizontal Bussing)

Tenant Main Circuit Breakers for 200A/225A, 3 Pole Sockets

Amps	10kAIC	Wire Size
15	TEB132015	(1) #14-3 CU; #12-1 AL
20	TEB132020	
25	TEB132025	
30	TEB132030	
35	TEB132035	
40	TEB132040	
45	TEB132045	
50	TEB132050	(1) #6/20 CU; #4-2/0 AL
60	TEB132060	
70	TEB132070	
80	TEB132080	(1) #3-3/0 CU; #1-3/0 AL
90	TEB132090	
100	TEB132100	(1) #1-300 CU; #1-300 AL
125	TQD32125	
150	TQD32150	
175	TQD32175	
200	TQD32200	-
225	Use TMQV	

Amps	22kAIC	Wire Size
100	THQD32100	(1) #1-300 CU; #1-300 AL
125	THQD32125	
150	THQD32150	
175	THQD32175	
200	THQD32200	
225	Use TMQV	-



Amps	QD Old Catalog # - Obsolete. Replaced by QV.	QV 100 kAIC New Catalog #	Wire Size
60	-	TMQV32060	#14-1/0 only
70	TMQD32070	TMQV32070	#4-4/0 only
80	TMQD32080	TMQV32080	
90	TMQD32090	TMQV32090	
100	TMQD32100	TMQV32100	
110	-	TMQV32110	
125	TMQD32125	TMQV32125	std = #4-4/0 ³
150	TMQD32150	TMQV32150	
175	TMQD32175	TMQV32175	
200	TMQD32200	TMQV32200	
225	TMQD32225	TMQV32225	

³ For 175A-225A use TMQV225L3 to get 300MCM terminals.

