

Drop Wire Clamps



1-2 Pair Drop Wire Clamp

DROP WIRE CLAMP

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
903	1-2 ALUMINUM DROP WIRE CLAMP WITH SERRATED SHIM	25	20	33
909	1-2 PAIR DROP WIRE CLAMP STAINLESS WITH SERRATED SHIM	25	20	47
902	1-2 PAIR STAINLESS STEEL DROP WIRE CLAMP STAINLESS SERRATED SHIM	50	8	37
907N	1-2 PAIR STAINLESS STEEL DROP WIRE CLAMP WITH NEOPRENE SHIM	50	8	37
907D	1-2 PAIR STAINLESS STEEL DROP WIRE CLAMP WITH DIMPLED SHIM	50	8	38



Six Pair Drop Wire Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
960	SIX PAIR ALUMINUM DROP WIRE CLAMP WITH DIMPLED SHIM	2	25	6
963	SIX PAIR STAINLESS STEEL DROP WIRE CLAMP WITH DIMPLED SHIM	2	25	9
959	SIX PAIR STAINLESS STEEL DROP WIRE WITH CLAMP HEAVY SERRATED SHIM	2	25	10



ENLONGATED FIBER OPTIC DROP CLAMP

Drop Wire Clamps

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
904	ENLONGATED FIBER OPTIC DROP CLAMP	25	20	47



FIBER DROP CLAMP WITH CUSTOM SHIM

FIBER DROP CLAMP WITH CUSTOM SHIM

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
910	FIBER DROP CLAMP WITH CUSTOM SHIM	25	20	47



BLACK FIBER DROP CLAMP WITH CUSTOM SHIM

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
910B	BLACK FIBER DROP CLAMP WITH CUSTOM SHIM	25	20	47



RPX Drop Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
10085	RPX DROP CLAMP	25	2	13



Super Drop™ Clamp
SUPER DROP CLAMP

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2107	SUPER DROP™ CLAMP	50	1	37



CATV Drop Wire Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2100	CATV DROP WIRE CLAMP	2	25	6
1999	CATV DROP WIRE CLAMP W/LONG BAIL	50	1	4



Economy CATV Drop Wire Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2098	ECONOMY CATV DROP WIRE CLAMP	50	1	3



Insulated CATV Drop Wire Clamp
Insulated CATV Drop Wire Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2099	INSULATED DROP WIRE CLAMP	2	100	14



Messenger Grip Drop Clamps

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2002	MESSENGER GRIP DROP CLAMP	25	1	8



Integrated Clamp for Fiber and 1-2 Pair Flat Drop Cable (Metal Mouth™)
INTEGRATED CLAMP FOR FIBER AND 1-2 PAIR FLAT DROP CABLE (METAL MOUTH™)

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
992	INTEGRATED CLAMP FOR FIBER AND 1-2 PAIR FLAT DROP CABLE (METAL MOUTH™)	50	1	18

Lashing Clamps

D Cable Lashing Clamp

D CABLE LASHING CLAMP



PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
4040	D CABLE LASHING CLAMP	50	4	30

D CABLE LASHING CLAMP STAINLESS STEEL

D CABLE LASHING CLAMP STAINLESS STEEL



PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
4000	D CABLE LASHING CLAMP STAINLESS STEEL	50	4	30

E Cable Lashing Clamp



PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9053	E CABLE LASHING CLAMP	50	4	23

Lashing Wire




LASHING WIRE COIL

LASHING WIRE COIL

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2616	.038" LASHING WIRE COIL 302SS 1600' PER COIL	1	6	38
2615	.045" LASHING WIRE COIL 302SS 1200' PER COIL	1	6	40
2617	.045" LASHING WIRE COIL 430SS 1200' PER COIL	1	6	40
2618	.045" LASHING WIRE COIL 316SS 1200' PER COIL	1	6	40

Fiber Storage Snowshoe For Strand

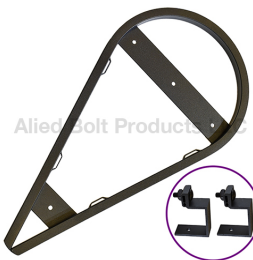

Fiber Storage Snowshoe For Strand

Fiber Storage Snowshoe For Strand

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9900-10	10" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH .65")	2	1	6
9900-12	12" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH .65")	2	1	6
9900-12W	12" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.25")	2	1	7
9900-16	16" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH .90")	2	1	8
9900-16W	16" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.5")	2	1	9
9900-18	18" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH .90")	2	1	9
9900-18W	18" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.75")	2	1	10
9900-20	20" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.25")	2	1	9
9900-24	24" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.25")	2	1	10
9900-30	30" FIBER STORAGE SNOWSHOE FOR STRAND (CHANNEL WIDTH 1.25")	2	1	12

Span Clamps



C Span Clamp

C Span Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
4044	C SPAN CLAMP	100	1	24



E Span Clamp

E Span Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9055	E SPAN CLAMP	5	20	45



O Span Clamp

O SPAN CLAMP WITH ONE SQUARE NUT

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
4075	O SPAN CLAMP WITH ONE SQUARE NUT	100	1	20



O SPAN CLAMP WITH TWO SQAURE NUTS AND TWO WASHERS

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
3003	O SPAN CLAMP WITH TWO SQAURE NUTS AND TWO WASHERS	100	1	25



O SPAN CLAMP WITH PIGTAIL BOLT

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1705	O SPAN CLAMP WITH PIGTAIL BOLT	100	1	20



Q Span Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
4042	Q SPAN CLAMP	25	4	17



Figure 8 Span Clamp

FIGURE 8 SPAN CLAMP

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
7023	FIGURE 8 SPAN CLAMP (.109"-.134")	50	1	13
7024	FIGURE 8 SPAN CLAMP (.148"-.250")	50	1	14




Multi-Drop Span Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9080	MULTI-DROP SPAN CLAMP	25	4	17
9080-2G	MULTI-DROP SPAN CLAMP SPAN WITH GROUNDING ATTACHMENT	25	4	27



Stacker Kit

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
7021	STACKER KIT	1	200	13

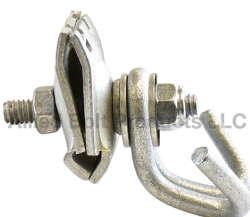

Ram's Horn Span Clamp

Ram's Horn Span Clamp

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9996	RAM'S HORN SPAN CLAMP	50	1	16

Figure 8 Drop Wire (Self-Supporting Drop Wire) Hardware



SUPPORT WIRE DEADEND WITH PROTECTIVE DEVICE ON TAIL WIRE

Support Wire Deadend With Protective Device On Tail Wire

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
AB505200	0.120" - 0.135" SUPPORT WIRE DEADEND WITH PROTECTIVE DEVICE ON TAIL WIRE	50	1	5



Support Wire Deadend

SUPPORT WIRE DEADEND

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
AB505600	0.062" - 0.100" SUPPORT WIRE DEADEND	50	1	4
AB505800	0.091" - 0.114" SUPPORT WIRE DEADEND	50	1	4
AB506200	0.120" - 0.135" SUPPORT WIRE DEADEND	50	1	9
AB519900	0.140" - 0.215" SUPPORT WIRE DEADEND	50	1	21



Support Wire Splice
SUPPORT WIRE SPLICE

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
AB505700	SUPPORT WIRE SPLICE 0.062" - 0.100"	50	1	1
AB505900	SUPPORT WIRE SPLICE 0.091" - 0.114"	50	1	6
AB506300	SUPPORT WIRE SPLICE 0.120" - 0.135"	50	1	6
AB503900	SUPPORT WIRE SPLICE 0.140" - 0.215"	50	1	21

Drop Wire 'S' Clips



S Wire Clip
S WIRE CLIP FOR MESSENGERED COAXIAL CABLE


PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
905	S WIRE CLIP FOR MESSENGERED COAXIAL CABLE	100	8	5



SC WIRE CLIP
SC WIRE CLIP

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
905P	SC WIRE CLIP FOR 1-2 PAIR DROP WIRE	25	25	5
908	SC WIRE CLIP FOR 6 PAIR DROP WIRE	25	16	4


Aerial Cable Damper

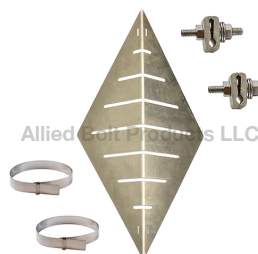

Aluminum Cable Damper
ALUMINUM CABLE DAMPER

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
9081	ALUMINUM CABLE DAMPER	1	1	4

Hangers

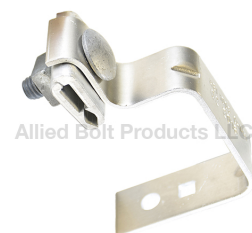

Single Tap Bracket
ALUMINUM TAP BRACKET

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1003	2-1/2" TAP BRACKET	50	1	10



Allied Bolt Products LLC

STEEL TAP BRACKET

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1015	2-1/2" STEEL TAP BRACKET	50	1	18



Allied Bolt Products LLC

STEEL TAP BRACKET W/ BONDING CONNECTIONS FOR A 4-WAY TAP


PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1005	2-1/2" STEEL TAP BRACKET W/ 4 BONDING CONNECTIONS	50	4	33



Allied Bolt Products LLC

Adjustable Tap Bracket

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1708	ADJUSTABLE TAP BRACKET	100	1	23

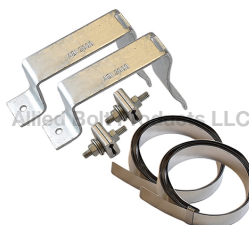

Allied Bolt Products LLC

Enclosure Mounting Kit

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
2000	ENCLOSURE MOUNTING KIT	2	4	7

Lashing Straps



Allied Bolt Products LLC

Abstrap™ Lashing Strap System

ABSTRAP™ WITH BUCKLE

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1086	10" ABSTRAP™ WITH BUCKLE	50	20	27
1070	13-1/2" ABSTRAP™ WITH BUCKLE	50	20	29
1085	16" ABSTRAP™ WITH BUCKLE	50	10	32
1087	22" ABSTRAP™ WITH BUCKLE	25	16	13
1071	27" ABSTRAP™ WITH BUCKLE	25	20	24
1088	40" ABSTRAP™ WITH BUCKLE	25	16	22



ABSTRAP™ BUCKLE

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1072	ABSTRAP™ BUCKLE	25	20	8



ABSTRAP™ TENSIONING TOOL

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1073	ABSTRAP™ TENSIONING TOOL	1	1	1



ABSTRAP™ STACKABLE SPACER

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1074	ABSTRAP™ STACKABLE SPACER	100	5	10



50' ABSTRAP™ REEL WITHOUT BUCKLE

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1075	50' ABSTRAP™ REEL WITHOUT BUCKLE	10	1	9



VERTICAL STEEL BASE FOR ABSTRAP™

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1081	VERTICAL STEEL BASE FOR ABSTRAP™	50	16	20



HORIZONTAL STEEL BASE FOR ABSTRAP™

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1080	HORIZONTAL STEEL BASE FOR ABSTRAP™	50	4	7



B DROP WIRE SUPPORT FOR ABSTRAP™

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1076	B DROP WIRE SUPPORT FOR ABSTRAP™	25	8	26



MOUNTING FASTENER (MASONRY) FOR ABSTRAP™

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1082	MOUNTING FASTENER (MASONRY) FOR ABSTRAP™	50	4	4



SCREW MOUNTING BASE FOR ABSTRAP™

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1077	#8 SCREW MOUNTING BASE FOR ABSTRAP™	25	4	2
1078	#10 SCREW MOUNTING BASE FOR ABSTRAP™	25	4	2
1079	#14 SCREW MOUNTING BASE FOR ABSTRAP™	25	4	3



ABSTRAP™ KIT

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
1083	ABSTRAP™ KIT (10) 50' REELS & (300) BUCKLES	1	1	13
1084	ABSTRAP™ KIT (5) 50' REELS & (150) BUCKLES	1	1	5

Lashed Cable Support

LASHED CABLE SUPPORT STAINLESS



PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
18912	10" LASHED CABLE SUPPORT STAINLESS	25	20	13
18911	10" LASHED CABLE SUPPORT STAINLESS - BULK PACK	500	1	13
18922	16" LASHED CABLE SUPPORT STAINLESS	25	20	20
18921	16" LASHED CABLE SUPPORT STAINLESS - BULK PACK	500	1	19
18932	22" LASHED CABLE SUPPORT STAINLESS	25	12	16
18942	28" LASHED CABLE SUPPORT STAINLESS	4	25	7
18952	34" LASHED CABLE SUPPORT STAINLESS	4	25	8
18956	45" LASHED CABLE SUPPORT STAINLESS	4	25	10
18962	50" LASHED CABLE SUPPORT STAINLESS	4	25	13
18972	66" LASHED CABLE SUPPORT STAINLESS	4	25	14
18982	78" LASHED CABLE SUPPORT STAINLESS	4	25	16



LASHED CABLE SUPPORT ZINC



PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
18910	10" LASHED CABLE SUPPORT ZINC	25	20	13
18909	10" LASHED CABLE SUPPORT ZINC - BULK PACK	500	1	13
18920	16" LASHED CABLE SUPPORT ZINC	25	20	20
18919	16" LASHED CABLE SUPPORT ZINC - BULK PACK	500	1	19
18930	22" LASHED CABLE SUPPORT ZINC	25	12	15
18940	28" LASHED CABLE SUPPORT ZINC	4	25	7
18950	34" LASHED CABLE SUPPORT ZINC	4	25	26
18955	45" LASHED CABLE SUPPORT ZINC	4	25	10
18960	50" LASHED CABLE SUPPORT ZINC	4	25	13
18970	66" LASHED CABLE SUPPORT ZINC	4	25	14
18980	78" LASHED CABLE SUPPORT ZINC	4	25	16


Cable Spacer



BELL CABLE SPACER

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
982	1/4" D SPACER CABLE	100	4	6
983	1/2" D SPACER CABLE	100	4	7
984	3/4" D SPACER CABLE	100	8	13
985	1" D SPACER CABLE	100	1	4
987	1-1/2" SPACER CABLE	100	1	8
989	2" SPACER CABLE	100	1	10
991	2-1/2" SPACER CABLE	100	1	5
993	3" D SPACER CABLE	100	1	14

Aluminum Ties

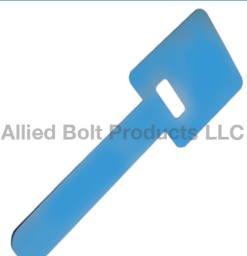

Scribe On Aluminum Tag


SCRIBE ON ALUMINUM TAG BLUE

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22000B	3-1/4" SCRIBE ON ALUMINUM TAG BLUE	25	40	7



SCRIBE ON ALUMINUM TAG GREEN

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22000G	3-1/4" SCRIBE ON ALUMINUM TAG GREEN	25	40	7

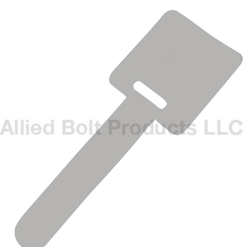

SCRIBE ON ALUMINUM TAG PLAIN

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22000	3-1/4" SCRIBE ON ALUMINUM TAG PLAIN	25	40	7



Allied Bolt Products LLC

SCRIBE ON ALUMINUM TAG RED


PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22000R	3-1/4" SCRIBE ON ALUMINUM TAG RED	25	40	7



Allied Bolt Products LLC

SCRIBE ON ALUMINUM TAG YELLOW

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22000Y	3-1/4" SCRIBE ON ALUMINUM TAG YELLOW	25	40	7

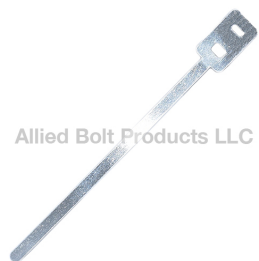

Allied Bolt Products LLC

Aluminum Cable Tie

CABLE TIE ALUMINUM

PART#	DESCRIPTION	PKG QTY	CTN QTY	CTN WT.
22110	7" CABLE TIE ALUMINUM	500	1	4
22100	10" CABLE TIE ALUMINUM	500	1	5