

Pass & Seymour



Decorator Devices TradeMaster® Decorator Switches

Extra-long, through-body strap eliminates floating installations and imperfect applications.

Low profile paddle offers the quality look and feel builders and homeowners love.

Ground screw location maximizes distance from terminal screw on adjacent device to eliminate risk of dead shorts.

External screw-pressure-plate back wire eliminates wrapping. Accepts #12 and #14 stranded and solid wire.

Narrow back body leaves more room for wires in the box.

TM870-LA

Decorator Devices

TradeMaster® Decorator Switches


15A, 120 & 120/277VAC

Pass & Seymour




Features


- Designer-style satin-finish rocker.
- High-impact resistant thermoplastic construction.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Push wire #14 AWG.
- Narrow back body leaves more room for wires in the box.
- Extra-long, through-body strap eliminates floating installations and imperfect applications.
- Smooth, quiet paddle action.
- Easy-access green hex head ground screw.
- Tri-drive ground, terminal and mounting screws.
- ON-OFF switches conform to NEC 430-104 requirements for kitchen disposal units.

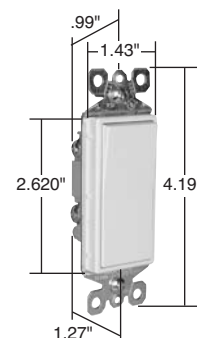


TM870-LA

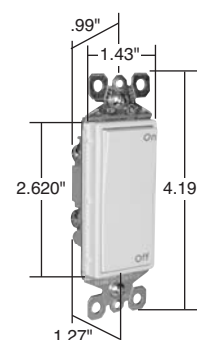

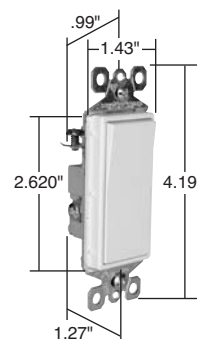

TM870-LAON

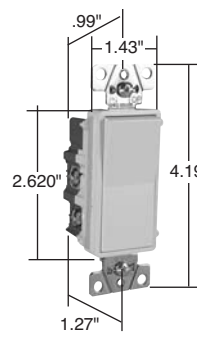

TM873-LA




TM874-LA

Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			 UL20	 C22.2 111
Single Pole Decorator Switches Grounding*				
TM870-I	15 120/277	Ivory	•	•
TM870-W	15 120/277	White	•	•
TM870	15 120/277	Brown	•	•
TM870-GRY	15 120/277	Gray	•	•
TM870-BK	15 120/277	Black	•	•
TM870-LA	15 120/277	Light Almond	•	•
Single Pole Decorator Switches Grounding with ON-OFF Indication				
TM870-ION	15 120/277	Ivory	•	•
TM870-WON	15 120/277	White	•	•
TM870-BKON	15 120/277	Black	•	•
TM870-LAON	15 120/277	Light Almond	•	•
Single Pole Illuminated Decorator Switches Grounding (Lighted when OFF)				
TM870-ISL	15 120/277	Ivory	•	•
TM870-WSL	15 120/277	White	•	•
TM870-LASL	15 120/277	Light Almond	•	•
Three-Way Decorator Switches Grounding*				
TM873-I	15 120/277	Ivory	•	•
TM873-W	15 120/277	White	•	•
TM873	15 120/277	Brown	•	•
TM873-GRY	15 120/277	Gray	•	•
TM873-BK	15 120/277	Black	•	•
TM873-LA	15 120/277	Light Almond	•	•
Three-Way Illuminated Decorator Switches Grounding (Lighted when OFF)				
TM873-ISL	15 120	Ivory	•	•
TM873-WSL	15 120	White	•	•
TM873-LASL	15 120	Light Almond	•	•
Four-Way Decorator Switches Grounding				
TM874-I	15 120/277	Ivory	•	•
TM874-W	15 120/277	White	•	•
TM874	15 120/277	Brown	•	•
TM874-BK	15 120/277	Black	•	•
TM874-LA	15 120/277	Light Almond	•	•

*For Configurable Solutions, see Page U-1.


Pass & Seymour

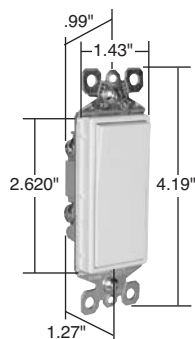

TM870-STMLACC



Momentary Contact

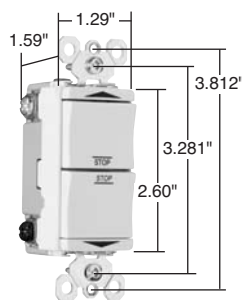

Maintained Contact



Decorator Devices

Decorator & Specification Grade Combination Momentary & Maintained Contact Switches

15A, 120 & 120/277VAC

Features

- Designer-style satin-finish rocker.
- High-impact resistant thermoplastic construction.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Push wire #14 AWG.
- Narrow back body leaves more room for wires in the box.
- Extra-long, through-body strap eliminates floating installations and imperfect applications.
- Smooth, quiet paddle action.
- Easy-access green hex head ground screw.
- Tri-drive ground, terminal and mounting screws.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance	
			 UL20	 C22.2 111
Single Pole Decorator Momentary Contact Switches				
TM870-STMICC	15 120/277	Ivory	•	•
TM870-STMWCC	15 120/277	White	•	•
TM870-STMLACC	15 120/277	Light Almond	•	•
TM870-STMBKCC	15 120/277	Black	•	•

Features

- Unique "Up/Down" switches match the look and feel of standard decorator switches.
- Impact-resistant face and body.
- Side and external screw-pressure-plate back wire accepts #12 and #14 AWG.
- All screws are tri-drive.
- Full wraparound heavy-gauge steel strap is plated for corrosion resistance and features lock-in tabs.
- Patent-pending split circuit tab — easily accessible, and can be reinstalled without a tool.

Catalog Number	Rating A. VAC	Color	3rd Party Compliance		
			cULus	UL20	UL508
Specification Grade Double Throw Momentary Contact Switches					
TM811-DTMOI	15 120	Ivory	•		•
TM811-DTMOW	15 120	White	•		•
TM811-DTMOLA	15 120	Light Almond	•		•
Specification Grade Double Throw Maintained Contact Switches					
TM811-DTMAI	15 120	Ivory	•	•	
TM811-DTMAW	15 120	White	•	•	
TM811-DTMALA	15 120	Light Almond	•	•	