

Malleable Iron 90° Liquidtight Connectors

For Liquidtight Flexible Metallic Conduit

Application:

To secure, ground seal Liquidtight Flexible Metal conduit, to boxes and enclosures

Features:

 
- Tapered threaded male hub NPT
- Compact, slim diameter with small turning radius
- Furnished with an insulated throat with steel locknut and sealing ring
- Liquidtight/Raintight/Oiltight
- Suitable for wet locations
- Long ferrule prevents pullout and tight bend conduit "pop-out"
- UL Listed liquidtight flexible metal conduit fittings are suitable for use in the following Hazardous Locations under NEC 501-4(b), 502-4(a)(2); Class I, Div.2; Class II, Div. 1 and 2; and Class III, Div. 1 and 2 and are suitable for grounding in sizes 3/8" through 1-1/2" under NEC 351-I

Standard Materials:


Malleable Iron/Steel Ferrule

Standard Finish:

Zinc Plated



TYPE SLT35T

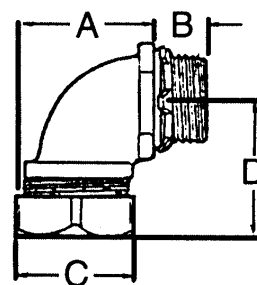

All Furnished with Insulated Throats

CATALOG NUMBER	TRADE SIZE	KO SIZE	DIM A	DIM B	DIM C	DIM D	UNIT PACK	STANDARD PACK	WEIGHT (LBS.) PER 100	NAED MFG #78-5994 UPC/DCI #
SLT25T	3/8"	1/2"	1.31	0.50	1.15	1.37	10	100	28	14259
SLT35T	1/2"	1/2"	1.43	0.50	1.28	1.37	10	100	31	14690
SLT36T	3/4"	3/4"	1.62	0.52	1.55	1.50	10	100	46	14700
SLT37T	1"	1"	1.93	0.65	1.80	1.81	5	50	77	14710
SLT38T	1-1/4"	1-1/4"	2.37	0.66	2.25	1.94	-	10	98	14389
SLT39T	1-1/2"	1-1/2"	2.68	0.73	2.44	2.40	-	10	124	14399
SLT40T	2"	2"	3.18	0.75	2.97	2.64	-	5	179	14409
SLT65T	2-1/2"	2-1/2"	8.31	1.01	4.01	7.81	-	1	847	14659
SLT66T	3"	3"	9.80	1.15	4.18	9.15	-	1	1243	14669
SLT67T	3-1/2"	3-1/2"	11.18	1.18	5.25	11.22	-	1	1914	14679
SLT68T	4"	4"	12.98	1.25	5.78	12.54	-	1	2399	14689

