



- LED & HID Models
- DLC LED Lamp Available

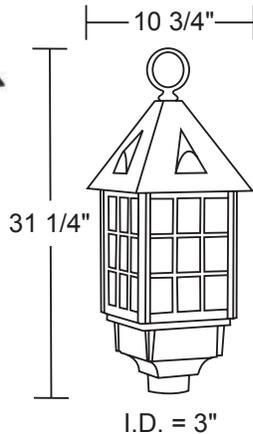

C35TF-



C34TF-

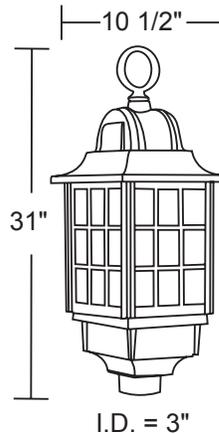

GUIDE: C34TC-L40C-BK



ITEM #	LENS	LIGHT SOURCE	COLOR	OPTIONS
C34T C35T	ACRYLIC F-Frosted	LED LIGHT SOURCE 120-277v DEDICATED LED L40-40W 4000lm E39 CORN COB LED 100-277v LC5-54W 7290lm, Type 5 ☆ LC3-40W 5600lm, Type 3 ☆ LCD-54W 5900lm, Dark Sky ☆	BK-Black BZ-Bronze WH-White	ACRYLIC BLACK OUT PANELS BP1-One Panel BP2-Two Panels BP3-Three Panels
		CCT C-4K W-3K B-5K		
		CCT C-4K(standard)		



4Kv medium base socket standard in HID, Mogul Upon Request.

120V HPF integral ballast standard in HID models, specify voltage for multi-tap.

☆ Lamp Included

GUIDE: C34TC-150MH-BK-R3



ITEM #	LENS	LIGHT SOURCE	COLOR	OPTIONS
C34T C35T	ACRYLIC F-Frosted	INCANDESCENT (1) 200W MAX Medium Base HPF MAGNETIC BALLAST 100MH-(1) 100W Metal Halide ☆ 150MH-(1) 150W Metal Halide ☆ 100H-(1) 100W HPS ☆ 150H-(1) 150W HPS ☆	BK-Black BZ-Bronze WH-White	MG-E39 Mogul Socket MT208-208v Multi-Tap MT240-240v Multi-Tap MT277-277v Multi-Tap R3-Type III Refractor R5-Type V Refractor (See Page 70 for Light Distribution) ACRYLIC BLACK OUT PANELS BP1-One Panel BP2-Two Panels BP3-Three Panels

SPEC SHEETS AND IES FILES AVAILABLE ONLINE. Specifications subject to change without notice. LED option information on page 6.